




# Scotchcal™

## High Performance Custom Striping Tape

### 2006 Color Card and Pattern Availability Chart

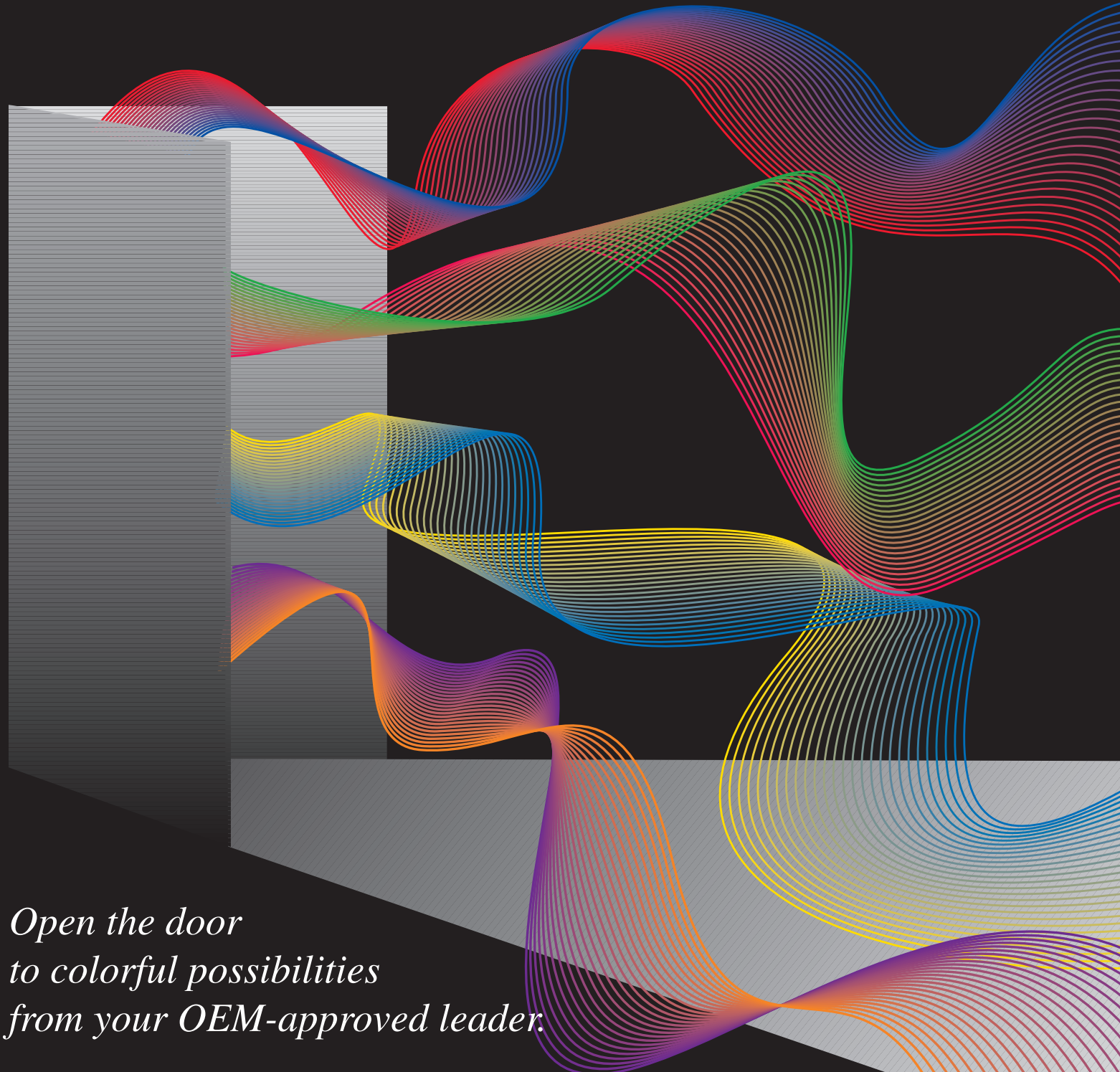

*Open the door  
to colorful possibilities  
from your OEM-approved leader.*

# 3M™ Scotchcal™

## High Performance Custom Striping Tape

### 2006 Color Card and Pattern Availability Chart



Color	Color Number	Multiple Stripe					Double Stripe			Single Stripe			40' Linerless No Premask																											
		150'	50'	150'	50'	150'	150'			50'	150'	150'																												
Deep Plum	39						724	723	720			771					727	726																						
Mulberry	95						724	723	722	720			771					729	726																					
Burgundy	10	764	763				732	725	724	723	722	721	720	713	710	707	687	775	774	771			733	731	730	729	728	727	726	705	704	703	702	701						
Burgundy Metallic	74			762	761		725	724	723	722	720	713						771																						
Dark Red	66						725	724	723	722	721	720	713						771																		703	702	701	
Red	04	696	764		762	761	732	725	724	723	722	721	720	713	710	707		775	774	771	736	734	733	731	730	729	728	727	726	705	704	703	702	701						
Tomato Red	76		763				732	725	724	723	722	721	720	713						771			734	733	731	730	729	728	727	726	705	704	703	702	701					
Bright Orange	68									723										771					731	730	729	728	727	726						703	702	701		
Bright Yellow	67									723				713								771				731	730	728	727	726						703	702	701		
Dark Green	69						724	723		720										771				731	730	729	728	727	726							702				
Myan Green	96									723				720	713								771				730													
Aqua	35									723				720	713												730													
Aquaessence	33									723				720	713								774	771				730	729	728	727	726								
Teal	71									723				720	713								771				730													
Northern Blue	37						724	723		720																													702	
Dark Blue Metallic	65						725	724	723	722	721	720	713								771				731	730	729	728	727	726										
Light Blue Metallic	57						725	724	723		720	713																												702
Midnight Blue	22									723				720	713								771				730													

### Single Stripe

Pattern No.	Width	Roll Length
701-	1/16"	40' roll linerless
704-	3/32"	40' roll linerless
702-	1/8"	40' roll linerless
705-	3/16"	40' roll linerless
703-	1/4"	40' roll linerless
726-	1/4"	150' roll
733-	3/8"	150' roll
727-	1/2"	150' roll
734-	5/8"	150' roll
728-	3/4"	150' roll
729-	7/8"	150' roll

730-	1"	150' roll
731-	2"	150' roll
736-	3"	50' roll
771-	2"	50' roll
774-	4"	50' roll
775-	6"	50' roll

### Double Stripe (Single-Color)

Pattern No.	Width	Roll Length
687-	1/8"	150' roll
710-	3/16"	50' roll
720-	1/4"	150' roll
721-	3/8"	150' roll
722-	1/2"	150' roll
713-	5/8"	50' roll
723-	3/4"	150' roll
707-	7/8"	50' roll
724-	1"	150' roll
725-	1 1/8"	150' roll
732-	1 1/4"	150' roll

### Multiple Stripe (Single-Color)

Pattern No.	Width	Roll Length
696-	1/16"	150' roll
Six 1/16" Stripes with Five 1/16" Voids		
761-	1 1/8"	150' roll

### Multiple Stripe (Single-Color)

Pattern No.	Width	Roll Length
762-	4 3/4"	50' roll
763-	1 1/2"	150' roll
764-	3 3/8"	50' roll

**Note: Colors shown are representative, to view actual samples visit your local distributor.**

Color	Color Number	Multiple Stripe					Double Stripe			Single Stripe			40' Linerless No Premask																					
		150'	50'	150'	50'	150'	150'			50'	150'	150'																						
Dark Blue	09		763	762	761	732	725	724	723	722	721	720	713	710	707	775	774	771	733	731	730	729	728	727	726	705	704	703	702	701				
Royal Blue	31							724	723			720	713			774	771			730		728	727	726										
Blue	08							725	724	723		720	713	707	775	774	771	733	731	730	729	728	727	726	705		703	702	701					
Azure Blue	41	696						724	723		720				771				730		728	727	726											
Medium Blue	54							725	723		720	713							730			727	726											
Ocean Blue	18								723		720	713			771				730			727	726											
Bright Blue	87								723		720				771				730	729	728	727	726			703	702							
Silver Blue	43						732	725	724	723		720	713			771			730	729		727	726											
Black Stardust	16						732	724	723	722	720	713			771				729		727	726												
Black	02	696	764	763	762	761	732	725	724	723	722	721	720	713	710	707	687	775	774	771	736	734	733	731	730	729	728	727	726	705	704	703	702	701
Low Gloss Black	93								723		720				771				730		728	727				703	702	701						
Medium Dark Gray	97								723	722	720	713		687					730			727	726											
Charcoal Metallic	63	696	764	763	762	761	732	725	724	723	722	721	720	713	710	707		775	774	771	734	733	731	730	729	728	727	726	705	704	703	702	701	
Ultra Charcoal	12								732	725	724	723	722	720					730		728	727	726				702							
Light Charcoal Metallic	50	696		763			732	725	724	723	722	721	720	713	710	707	687	775	774	771	734	733	731	730	729	728	727	726	705	704	703	702	701	
Medium Gray	19								732	724	723		720	713		687				730			727	726								701		
Medium Silver Metallic	83								725	724	723	722	721	720	713			771		733	730	729		727	726		703	702						
Light Slate Metallic	14								732	725	724	723	722	721	720	713			771			730	729	728	727	726		703	702					
Silver Metallic	05	696	764	763	762	761	732	725	724	723	722	721	720	713	710	707	687	775	774	771	736	734	733	731	730	729	728	727	726	705	704	703	702	701
Silver Starfire	20								732	725	724	723	722	720	713	710	707		771			731	730	729	728	727	726	705	704	703	702	701		
Silver Chips	23								732	725	724	723	722	720	713						730		728	727	726			703	702	701				

### Single Stripe

Pattern No.

701- 40' roll linerless  $\frac{1}{16}$ "

704- 40' roll linerless  $\frac{3}{32}$ "

702- 40' roll linerless  $\frac{1}{8}$ "

705- 40' roll linerless  $\frac{3}{16}$ "

703- 40' roll linerless  $\frac{1}{4}$ "

726- 150' roll  $\frac{3}{8}$ "

733- 150' roll  $\frac{7}{8}$ "

727- 150' roll  $\frac{1}{2}$ "

734- 150' roll  $\frac{5}{8}$ "

728- 150' roll  $\frac{3}{4}$ "

729- 150' roll  $\frac{7}{8}$ "

730- 150' roll 1"

731- 150' roll 2"

736- 50' roll 3"

771- 50' roll 2"

774- 50' roll 4"

775- 50' roll 6"

### Double Stripe (Single-Color)

Pattern No.

687- 150' roll  $\frac{1}{8}$ "

710- 50' roll  $\frac{1}{8}$ "

720- 150' roll  $\frac{3}{8}$ "

721- 150' roll  $\frac{1}{8}$ "

722- 150' roll  $\frac{1}{4}$ "

713- 50' roll  $\frac{1}{8}$ "

723- 150' roll  $\frac{3}{8}$ "

707- 50' roll  $\frac{1}{8}$ "

724- 150' roll  $\frac{1}{4}$ "

725- 150' roll  $\frac{3}{8}$ "

732- 150' roll  $\frac{1}{8}$ "

### Multiple Stripe (Single-Color)

Pattern No.

696- 150' roll  $\frac{1}{16}$ "

Six 1/16" Stripes with Five 1/16" Voids

761- 150' roll  $\frac{1}{16}$ "

### Multiple Stripe (Single-Color)

Pattern No.

762- 50' roll 4  $\frac{1}{8}$ "

763- 150' roll 1  $\frac{1}{8}$ "

764- 50' roll 3  $\frac{1}{8}$ "

**Note: Colors shown are representative, to view actual samples visit your local distributor.**



Color	Color Number	Multiple Stripe					Double Stripe					Single Stripe					40' Linerless No Premask																							
		150'	50'	150'	50'	150'	150'					50'	150'	150'					40' Linerless No Premask																					
Pewter	28						725	724	723	722	721	720						687						730						727	726									
Gray	73								723	722			720	713				687																702						
White	01						762	761	732	725	724	723	722	721	720	713	710	707	687	775	774	771	736	733	731	730	729	728	727	726	705	704	703	702	701					
Bright White	56						764	763			732	724	723	722									774	771			733	730	729	727	726									
White Diamond	30								732	725	724	723	722			720	713	710	707								771			731	730	729	728	727	726	705	704	703	702	701
Dark Brown	24										723	722			720	713			687					771				730			727	726								
Brown	07								732	725	724	723	722	721	720	713	710	707						774	771			731	730	729	728	727	726				703	702	701	
Brown Metallic	70								732	725	724	723			720	713								771				730	729	728	727	726								
Dark Tundra	51								732		724	723			720													730		728	727									
Nutmeg	21								732			723			720	713								771				730			727	726								
Buckskin	06								732	725	724	723	722	721	720	713	710	707	687					771			733	730	729	728	727	726				703	702	701		
Tan	17								725	724	723			720	713			687										730		727	726					703				
Camel Beige	60								732	725	724	723	722			720	713											730		728	727	726								
Gold Starfire	25								732		724	723	722			720	713							771				730			727	726								
Gold Metallic	03						696	764	763	762	761	732	725	724	723	722	721	720	713	710	707	687	775	774	771	736	734	733	731	730	729	728	727	726	705	704	703	702	701	
Bright Gold Metallic	99										725	724	723			720	713											730			727	726								
Light Gold Metallic	85						696				732	725	724	723	722	721	720	713	710	707		775		771	734	733	730	729	728	727	726	704	703	702						
Pastel Sandstone	78										732	725	724	723	722			720	713			687						730		727	726									

### Single Stripe

Pattern No.

701- 40' roll linerless  $\frac{1}{16}$ "

704- 40' roll linerless  $\frac{3}{32}$ "

702- 40' roll linerless  $\frac{1}{8}$ "

705- 40' roll linerless  $\frac{7}{16}$ "

703- 40' roll linerless  $\frac{1}{4}$ "

726- 150' roll  $\frac{1}{4}$ "

733- 150' roll  $\frac{3}{8}$ "

727- 150' roll  $\frac{1}{2}$ "

734- 150' roll  $\frac{5}{8}$ "

728- 150' roll  $\frac{3}{4}$ "

729- 150' roll  $\frac{7}{8}$ "

730- 150' roll 1"

731- 150' roll 2"

736- 50' roll 3"

771- 50' roll 2"

774- 50' roll 4"

775- 50' roll 6"

### Double Stripe (Single-Color)

Pattern No.

687- 150' roll  $\frac{1}{4}$ "

710- 50' roll  $\frac{1}{8}$ "

720- 150' roll  $\frac{3}{16}$ "

721- 150' roll  $\frac{1}{8}$ "

722- 150' roll  $\frac{1}{4}$ "

713- 50' roll  $\frac{1}{8}$ "

723- 150' roll  $\frac{3}{16}$ "

707- 50' roll  $\frac{1}{4}$ "

724- 150' roll  $\frac{1}{2}$ "

725- 150' roll  $\frac{3}{8}$ "

732- 150' roll  $\frac{1}{2}$ "

### Multiple Stripe (Single-Color)

Pattern No.

696- 150' roll  $\frac{1}{16}$ "

Six 1/16" Stripes with Five 1/16" Voids

761- 150' roll  $\frac{1}{16}$ "

### Multiple Stripe (Single-Color)

Pattern No.

762- 50' roll  $4\frac{3}{4}$ "

763- 150' roll  $1\frac{1}{8}$ "

764- 50' roll  $3\frac{3}{8}$ "

**Note: Colors shown are representative, to view actual samples visit your local distributor.**

## Duo - Tone - 746

5/16" x 150' roll  
Two-Color Pattern No. 746-\_\_\_

Silver Metallic (05) -01	Silver Metallic (05) -17	Light Charcoal Metallic (50) -33
Burgundy Metallic (74)	Charcoal Metallic (63)	Black (02) -35
Silver Metallic (05) -02	Red (04) -18	Silver Metallic (05) -35
Lt. Blue Metallic (57)	Black (02)	Light Charcoal Metallic (50) -50
Bright Blue (87) -04	Black (02) -24	Dark Red (66) -53
Blue (08)	Light Gold Metallic (85) -26	Pewter (28) -60
Dark Blue (09) -05	Dark Red (66) -25	Silver Metallic (05) -53
Blue (08)	Black (02)	Burgundy (10)
Camel Beige (60) -08	Bright White (56) -26	Silverchips (23) -60
Buckskin (06)	Silver Metallic (05) -27	Ultra Charcoal (12)
Silver Metallic (05) -15	Silver Metallic (05) -27	
Black (02)	Silver Blue (43)	

## Tri - Tone - 741

3/8" x 150' Roll  
Three-Color Pattern No. 741-\_\_\_

Silver Metallic (05) -01	Tomato Red (76) -08	Blue (08) -10
Charcoal Metallic (63)	Dark Red (66)	Light Blue Metallic (57)
Black (02)	Burgundy Metallic (74)	Dark Blue (09)
Camel Beige (60) -02	Bright Blue (87) -09	Light Gold Metallic (85) -22
Buckskin (06)	Blue (08)	Buckskin (06)
Brown (07)	Dark Blue (09)	Gold Starfire (25)

## Paint Break Stripes - (737 - 738 - 740)

\*These match the OEM-designed parts; however, they may be used on any vehicle.

Paint Break Stripe Available in 4 combinations  
1/2" x 150' roll  
Two-Color Pattern No. 737-\_\_\_

\* Fits Plymouth S Van and Dodge LE two-tone vehicles '91 - '94

-04	-50	-66	-71
Black (02) Red (04) Black (02)	Black (02) Light Charcoal Metallic (50) Black (02)	Black (02) Dark Red (66) Black (02)	Black (02) Teal (71) Black (02)

## Styline Striping - 747

5/16" x 150' Roll  
Two-Color Pattern No. 747-\_\_\_

Burgundy Metallic (74) -50	Dark Blue (09) -59	Black Stardust (16) -76
Silver Metallic (05)	Blue (08)	Gold Starfire (25)
Silver Metallic (05)	Blue (08)	Gold Starfire (25)
Burgundy Metallic (74) -51	Black (02) -61	Dark Red (66) -80
Red (04)	Red (04)	Pewter (28)
Red (04)	Red (04)	Pewter (28)
Charcoal Metallic (63) -54	Charcoal Metallic (63) -64	Silverchips (23) -82
Silver Metallic (05)	Pewter (28)	Ultra Charcoal (12)
Silver Metallic (05)	Pewter (28)	Ultra Charcoal (12)
Black (02) -56	Black (02) -66	
Silver Metallic (05)	Light Gold Metallic (85)	
Silver Metallic (05)	Light Gold Metallic (85)	

Paint Break Stripe Available in 3 combinations  
11/16" x 150' roll  
Two-Color Pattern No. 738-\_\_\_

\* Fits '91 & '92 Ford Aerostar two-tone vehicles

-10	-31	-60
Burgundy (10) Silver Metallic (05) Burgundy (10) Silver Metallic (05) Burgundy (10)	Royal Blue (31) Silver Metallic (05) Royal Blue (31) Silver Metallic (05) Royal Blue (31)	Camel Beige (60) Nutmeg (21) Camel Beige (60) Nutmeg (21) Camel Beige (60)

## Elite Striping - 748

3/16" x 150' Roll  
Two-Color Pattern No. 748-\_\_\_

Black (02) -01	Blue (08) -09	Dark Blue (09) -28
Gold Metallic (03)	Dark Blue (09)	Royal Blue (31)
Silver Metallic (05) -02	Silver Metallic (05) -10	Black (02) -29
Black (02)	Charcoal Metallic (63)	Light Charcoal Metallic (50)
White (01) -03	Gold Metallic (03) -11	Light Charcoal Metallic (50) -30
Silver Metallic (05)	Silver Metallic (05)	Silver Metallic (05)
Gold Metallic (03) -04	Silver Metallic (05) -14	Silver Blue (43) -35
Brown Metallic (70)	Burgundy (10)	Silver Metallic (05)
Burgundy (10) -06	Silver Metallic (05) -16	Silverchips (23) -65
Tomato Red (76)	Burgundy Metallic (74)	Ultra Charcoal (12)
Silver Metallic (05) -07	Charcoal Metallic (63) -25	
Tomato Red (76)	Light Slate Metallic (14)	
Lt. Gold Metallic (85) -08	Brown (07) -26	
Burgundy Metallic (74)	Buckskin (06)	

Paint Break Stripe Available in 4 combinations  
7/8" x 150' roll  
Two-Color Pattern No. 740-\_\_\_

\* Fits Ford Ranger and F-Series Trucks

-02	-06	-18	-40
NEW Ocean Blue (18) Black (02) Ocean Blue (18)	Buckskin (06) Camel Beige (60) Buckskin (06)	Ocean Blue (18) Bright Blue (87) Ocean Blue (18)	Medium Silver Metallic (83) Red (04) Medium Silver Metallic (83)

Note: Colors shown are representative, to view actual samples visit your local distributor.

## Scotchgard™ Paint Protection Film

Paint protection film is a clear-coated urethane film that helps preserve the paint finish while protecting surfaces vulnerable to stone chips, bug damage, abrasion and weathering. It is approved by major automotive manufacturers. It is normally applied to the hood, wheel wells and rocker panels, but it can be placed in other areas susceptible to environmental damage. The application is meant to be permanent; however, it can be removed if desired.

	Part Number	Size	Film Thickness
Rolls	84701	1" x 12.5 yards	12 mil
	84706	6" x 20 yards	12 mil
	84802	2" x 40 yards	6 mil
	84804	4" x 40 yards	6 mil
Strips	84806	6" x 40 yards	6 mil
	84904	4" x 84"	6 mil
	84906	6" x 84"	6 mil
	84911	12" x 84"	6 mil
Door Edge Guard	84901 <sup>†</sup>	.4" x 10 yards	6 mil
	84905 <sup>†</sup>	.4" x 40 yards	6 mil

## 3M™ Scotchcal™ Bulk Signwriter Film

- Signwriter Film is designed to be used with computer-aided graphic design equipment that uses friction feed rollers to move the film.
- Available Signwriter Film (AVAILABLE IN ALL COLORS):
 

769	16" x 150'
770	24" x 150'
772	16" x 30'
773	24" x 30'
- Signwriter Films are CUT TO ORDER.  
Note: Large volume orders may require extended leadtime.
- Signwriter Films are NON-RETURNABLE.
- Signwriter and Films are AVAILABLE IN ALL SCOTCHCAL FILM COLORS.
- Available Premask/Application Tape to use with 16" Signwriter Film (769 and 772) is 75951 - 15.5" x 150'.
- Available Premask/Application Tape to use with 24" Signwriter Film (770 and 773) is 76051 - 23.5" x 150'.

### How to Order by Part Number:

- Determine 3-digit Pattern No.
- Check color availability
- Add 2-digit Color No. to Pattern No.

### Example:

Pattern 723  
In color white (01)  
Pattern No. is 723 01

All pattern numbers indicated on the chart are stocked items available in any quantity. All patterns are available in all colors in a minimum quantity (except linerless patterns 701-705). Extra lead time may be required. Please contact your 3M sales representative for more information.

Bulk Signwriter Film <small>Designed to be used with computer-aided graphic design equipment that uses friction feed rollers to move the</small>				
Pattern Number	769-	770-	772-	773-
Roll Length	150'	150'	30'	30'
Roll Width	16"	24"	16"	24"

**Available in all colors. See back of color card for details.**

3M™ Scotchlite™ Reflective Film Series 680	Color	1/4" x 50'	1/2" x 50'	3" x 50'	1" x 50'	2" x 50'	4" x 50'	6" x 50'
		Order No.	Order No.	Order No.	Order No.	Order No.	Order No.	Order No.
Pattern No. 799- _____	White (Silver)	01	21	31	41	61	71	81
	Black	02	22	32	42	62	72	82
	Gold	03	23	33	43	63	73	83
	Red	04	24	34	44	64	74	84
	Blue	05	25	35	45	65	75	85
	Green	06	26	36	46	66	76	86
	Orange	07	27	37	47	67	77	87
	Yellow	08	28	38	48	68	78	88

## 3M™ Premask/Application Tape

This tape is primarily used as a protective layer when applying large graphics.

Part Number	Size
75906	6" x 150'
75951	15.5" x 150'
76051	23.5" x 150'

## 3M™ Scotchcal™ Application Accessories

- 71601 Blue applicator squeegee, 5/set
- 71602 Gold applicator squeegee, 5/set
- 71603 Low friction sleeve, 5/set
- 71604 Air release tool, 5/set
- 71607 Orange Applicator Squeegee, 1/env  
*(recommended for applying Scotchgard™ Paint Protection Film)*

## Available Colors

01	White	43	Silver Blue
02	Black	50	Light Charcoal Metallic
03	Gold Metallic	51	Dark Tundra
04	Red	54	Medium Blue
05	Silver Metallic	56	Bright White
06	Buckskin	57	Light Blue Metallic
07	Brown	60	Camel Beige
08	Blue	63	Charcoal Metallic
09	Dark Blue	65	Dark Blue Metallic
10	Burgundy	66	Dark Red
12	Ultra Charcoal	67	Bright Yellow
14	Light Slate Metallic	68	Bright Orange
16	Black Stardust	69	Dark Green
17	Tan	70	Brown Metallic
18	Ocean Blue	71	Teal
19	Medium Gray	73	Gray
20	Silver Starfire	74	Burgundy Metallic
21	Nutmeg	76	Tomato Red
22	Midnight Blue	78	Pastel Sandstone
23	Silverchips	79	Pale Gray
24	Dark Brown	83	Medium Silver Metallic
25	Gold Starfire	85	Light Gold Metallic
28	Pewter	87	Bright Blue
30	White Diamond	93	Low Gloss Black
31	Royal Blue	95	Mulberry
33	Aquaessence	96	Myan Green
35	Aqua	97	Medium Dark Gray
37	Northern Blue	99	Bright Gold Metallic
39	Deep Plum		
41	Azure Blue		

**Important Notice:** 3M warrants that the products described herein will upon delivery conform to 3M's written specifications or performance standards contained in any applicable 3M Product Bulletin. 3M makes no other warranties, express or implied, including any implied warranties of merchantability or fitness for a particular purpose. User is responsible for determining whether this 3M product is fit for user's particular purpose and suitable for user's method of application. 3M will, as Buyer's exclusive remedy, refund the purchase price or replace the quantity of 3M product proven to be defective. 3M shall not be liable for any other loss or damage, whether direct, indirect, special, incidental or consequential, regardless of the legal theory asserted.



### Automotive Aftermarket Division

3M Center, Building 223-6N-01  
St. Paul, MN 55144-1000  
Phone: 1-800-370-2619  
www.3M.com/automotive

3M and Scotchgard are trademarks of 3M.

The NASCAR™ Officially Licensed Logo is a Registered Trademark of the National Association for Stock Car Auto Racing Inc.

Printed in U.S.A.  
© 3M 2004 60-4400-7615-0