

Quick Reference

Search by part #



Check distributor part inventory

Stock Check

[CLICK HERE!](#)

Products

Browse Products

-By Device-

-By Product Line-

-Attachment Methods-

-Interface Materials-

-Accessories-

Useful Links

- [MSDS Safety Sheets](#)
- [How to Order?](#)
- [Find Sales Rep](#)
- [Find Distributor](#)
- [Sample Request](#)
- [Quote Request](#)
- [Catalog Request](#)
- [Building a Part #](#)
- [Part # Cross Ref](#)

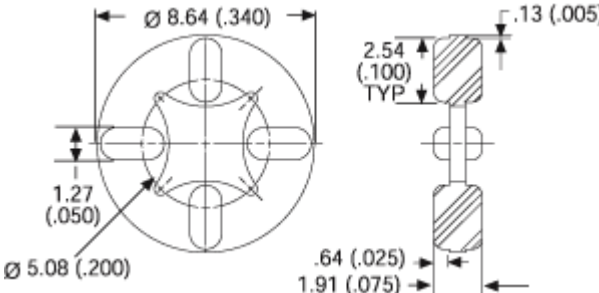
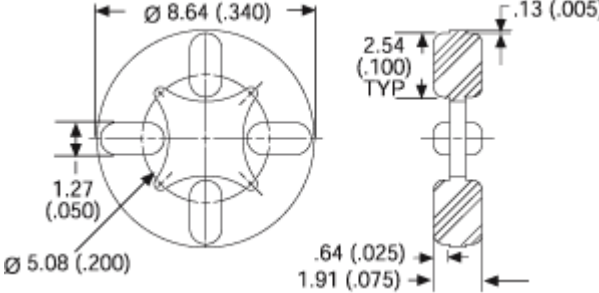
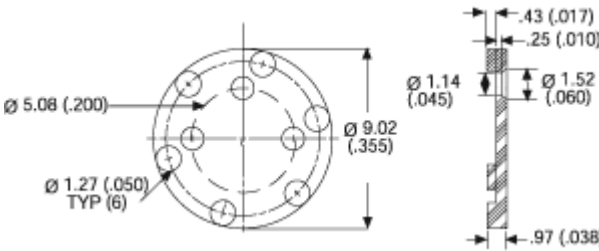
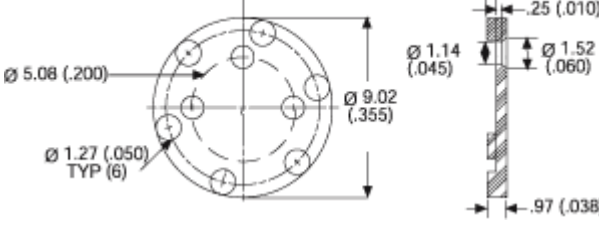
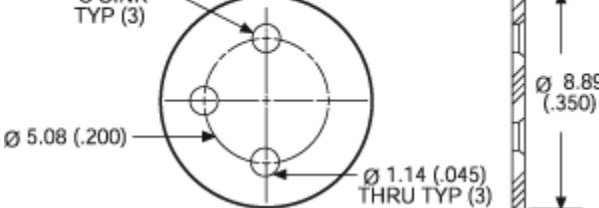

Accessories
Standard Mounting Pads

The following Mounting Pads are for use with TO-5

<p>7717-167DAPG</p> <p>(DAP)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 3.18 (0.125)</p>	<p>RoHS Compliant</p>
<p>7717-167NG</p> <p>(nylon)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 3.18 (0.125)</p>	<p>RoHS Compliant</p>
<p>7717-161DAPG</p> <p>(DAP)</p> <p>Leads: 4-Mar</p> <p>Outside Diameter mm (in): 8.64 (0.340)</p> <p>Thickness: 1.91 (0.075)</p>	<p>RoHS Compliant</p>
<p>7717-161NG</p> <p>(nylon)</p> <p>Leads: 4-Mar</p> <p>Outside Diameter mm (in): 8.64 (0.340)</p> <p>Thickness: 1.91 (0.075)</p>	<p>RoHS Compliant</p>
<p>7717-159NG</p> <p>(nylon)</p> <p>Leads: 5</p>	<p>RoHS Compliant</p>

<p>Outside Diameter mm (in): 9.53 (0.375)</p> <p>Thickness: 5.59 (0.220)</p>	
<p>7717-158TG</p> <p>RoHS Compliant</p>	
<p>(Teflon)</p>	
<p>Leads: 4</p>	
<p>Outside Diameter mm (in): 9.91 (0.390)</p>	
<p>Thickness: 0.25 (0.010)</p>	
<p>7717-131DAPG</p> <p>RoHS Compliant</p>	
<p>(DAP)</p>	
<p>Leads: 4</p>	
<p>Outside Diameter mm (in): 8.89 (0.350)</p>	
<p>Thickness: 0.97 (0.038)</p>	
<p>7717-131NG</p> <p>RoHS Compliant</p>	
<p>(nylon)</p>	
<p>Leads: 4</p>	
<p>Outside Diameter mm (in): 8.89 (0.350)</p>	
<p>Thickness: 0.97 (0.038)</p>	
<p>7717-114NG</p> <p>RoHS Compliant</p>	
<p>(nylon)</p>	
<p>Leads: 4</p>	
<p>Outside Diameter mm (in): 9.02 (0.355)</p>	
<p>Thickness: 1.17 (0.046)</p>	
<p>7717-4DAPG</p> <p>RoHS Compliant</p> <p></p>	
<p>(DAP)</p>	
<p>Leads: 4</p>	
<p>Outside Diameter mm (in): 9.53 (0.375)</p>	

<p>Thickness: 1.91 (0.075)</p>	
<p>7717-4NG (nylon) Leads: 4 Outside Diameter mm (in): 9.53 (0.375) Thickness: 1.91 (0.075)</p>	
<p>7717-5DAPG (DAP) Leads: 4 Outside Diameter mm (in): 8.89 (0.350) Thickness: 3.18 (0.125)</p>	
<p>7717-5NG (nylon) Leads: 4 Outside Diameter mm (in): 8.89 (0.350) Thickness: 3.18 (0.125)</p>	
<p>7717-15DAPG (DAP) Leads: 4 Outside Diameter mm (in): 8.89 (0.350) Thickness: 0.51 (0.020)</p>	
<p>7717-15NG (nylon) Leads: 4 Outside Diameter mm (in): 8.89 (0.350) Thickness: 0.51 (0.020)</p>	

<p>7717-3DAPG RoHS <input checked="" type="checkbox"/> Compliant Product Change Notice </p>	
<p>(DAP)</p>	
<p>Leads: 4-Mar</p>	
<p>Outside Diameter mm (in): 8.71 (0.343)</p>	
<p>Thickness: 1.91 (0.075)</p>	
<p>7717-3NG RoHS <input checked="" type="checkbox"/> Compliant Product Change Notice </p>	
<p>(nylon)</p>	
<p>Leads: 4-Mar</p>	
<p>Outside Diameter mm (in): 8.71 (0.343)</p>	
<p>Thickness: 1.91 (0.075)</p>	
<p>7717-79DAPG RoHS <input checked="" type="checkbox"/> Compliant Product Change Notice </p>	
<p>(DAP)</p>	
<p>Leads: 3</p>	
<p>Outside Diameter mm (in): 9.02 (0.355)</p>	
<p>Thickness: 0.97 (0.038)</p>	
<p>7717-79NG RoHS <input checked="" type="checkbox"/> Compliant Product Change Notice </p>	
<p>(nylon)</p>	
<p>Leads: 3</p>	
<p>Outside Diameter mm (in): 9.02 (0.355)</p>	
<p>Thickness: 0.97 (0.038)</p>	
<p>7717-178DAPG RoHS <input checked="" type="checkbox"/> Compliant Product Change Notice </p>	
<p>(DAP)</p>	
<p>Leads: 3</p>	
<p>Outside Diameter mm (in): 8.89 (0.350)</p>	
<p>Thickness: 0.53 (0.021)</p>	
<p>7717-178NG RoHS <input checked="" type="checkbox"/> Compliant Product Change Notice </p>	
<p>(nylon)</p>	
<p>Leads: 3</p>	
<p>Outside Diameter mm (in): 8.89 (0.350)</p>	
<p>Thickness: 0.53 (0.021)</p>	

<p style="text-align: right;"> RoHS ✓ Compliant Product Change Notice </p> <p>7717-86DAPG</p> <p>(DAP)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 1.91 (0.075)</p>	
<p style="text-align: right;"> RoHS ✓ Compliant Product Change Notice </p> <p>7717-86NG</p> <p>(nylon)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 1.91 (0.075)</p>	
<p style="text-align: right;"> RoHS ✓ Compliant </p> <p>7717-22NG</p> <p>(nylon)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 1.91 (0.075)</p>	
<p style="text-align: right;"> RoHS ✓ Compliant </p> <p>7717-22DAPG</p> <p>(DAP)</p> <p>Leads: 3</p> <p>Outside Diameter mm (in): 8.71 (0.343)</p> <p>Thickness: 1.91 (0.075)</p>	
<p style="text-align: right;"> RoHS ✓ Compliant </p> <p>7717-238NG</p> <p>(nylon)</p> <p>Leads: 4-Mar</p> <p>Outside Diameter mm (in): 10.16 (0.400)</p> <p>Thickness: 4.06 (0.160)</p>	
<p style="text-align: right;"> RoHS ✓ Compliant </p> <p>7717-300NG</p> <p>(nylon)</p> <p>Leads: Universal</p>	

<p>Outside Diameter mm (in): 11.18 (0.440)</p> <p>Thickness: 9.65 (0.380)</p>	
<p>7717-94NG</p> <p>RoHS Compliant</p>	
<p>(nylon)</p>	
<p>Leads: 4-Mar</p>	
<p>Outside Diameter mm (in): 8.89 (0.350)</p>	
<p>Thickness: 0.97 (0.038)</p>	