


NEW AQ SERIES: WATERPROOF FAN

ANY IP RATING CAN BE SATISFIED

Water jets from any direction
No harmful ingress

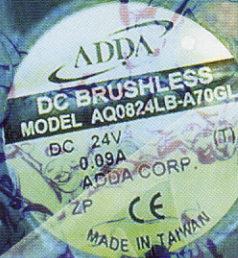

New

Specification: IP 55



▶▶▶ Protected from total touch protection and no harmful ingress of dust.

▶▶▶ Protected from water jets, from any directions and no harmful ingress of water.



Specialist in Thermal Solution System

Bearing type: ◎ = Ball

PHOTO	Frame size	Model NO.	Bearing Type	Voltage (V)	Current (A)	Power (W)	Speed (rpm)	AirFlow (CFM)	(CMM)	Pressure (mmAq)	(InH2O)	Noise (dB/A)	Weight (g)
	60x60x25mm	AQ0612HB-A70GL(T)	◎	12	0.23	2.76	4500	23.2	0.656	4.78	0.191	32.3	58
		AQ0612MB-A70GL(T)	◎	12	0.14	1.68	3500	18.0	0.509	3.00	0.120	24.0	
		AQ0612LB-A70GL(T)	◎	12	0.08	0.96	2500	13.2	0.373	1.60	0.064	16.1	
	70x70x25mm	AQ0712HB-A70GL(T)	◎	12	0.19	2.28	4200	34.0	0.971	5.43	0.217	35.5	62
		AQ0712MB-A70GL(T)	◎	12	0.16	1.92	3800	31.0	0.885	4.40	0.176	32.0	
		AQ0712LB-A70GL(T)	◎	12	0.12	1.44	3300	27.0	0.771	3.35	0.134	28.0	
	80x80x25mm	AQ0812HB-A70GL(T)	◎	12	0.25	3.00	3000	38.6	1.092	3.81	0.152	33.0	82
		AQ0812MB-A70GL(T)	◎	12	0.15	1.80	2500	32.9	0.931	2.85	0.114	28.3	
		AQ0812LB-A70GL(T)	◎	12	0.12	1.44	2100	27.6	0.781	1.95	0.078	22.5	
		AQ0812DB-A70GL(T)	◎	12	0.08	0.96	1600	20.5	0.580	1.27	0.051	15.0	
		AQ0824HB-A70GL(T)	◎	24	0.16	3.84	3200	40.0	1.132	4.28	0.171	35.0	
	92x92x25mm	AQ0824MB-A70GL(T)	◎	24	0.10	2.40	2400	30.0	0.849	2.50	0.100	27.0	103
		AQ0824LB-A70GL(T)	◎	24	0.09	2.16	2200	29.0	0.820	2.07	0.083	24.0	
		AQ0912HB-A70GL(T)	◎	12	0.25	3.00	2900	52.5	1.485	3.32	0.133	35.0	
		AQ0912MB-A70GL(T)	◎	12	0.17	2.04	2400	43.5	1.231	2.30	0.092	31.3	
		AQ0912LB-A70GL(T)	◎	12	0.13	1.56	2050	36.0	1.018	1.57	0.063	25.0	
	120x120x25mm	AQ0924HB-A70GL(T)	◎	24	0.15	3.60	2900	52.5	1.485	3.28	0.131	35.0	164
		AQ0924MB-A70GL(T)	◎	24	0.12	2.88	2500	45.0	1.273	2.38	0.095	31.5	
		AQ0924LB-A70GL(T)	◎	24	0.08	1.92	2300	41.6	1.177	2.18	0.087	29.8	
		AQ1212HB-A71GL	◎	12	0.37	4.44	2200	85.2	2.410	3.45	0.138	39.1	
		AQ1212MB-A71GL	◎	12	0.33	3.96	2050	80.5	2.277	2.97	0.119	38.0	
		AQ1212LB-A71GL	◎	12	0.24	2.88	1800	72.0	2.037	2.41	0.096	34.4	
		AQ1224MB-A71GL	◎	24	0.19	4.56	2200	85.2	2.410	3.45	0.138	39.1	
AQ1224LB-A71GL	◎	24	0.17	4.08	2050	80.5	2.277	2.97	0.119	38.0			
		AQ1224LB-A71GL	◎	24	0.14	3.36	1800	72.0	2.037	2.41	0.096	34.4	

2 wires, 3rd wire available

Specifications subject to change without notice.