



LED Driver Indoor 25W/1.05A-24V 230V

Product family description
 Designed specifically to optimally power Luxeon™ high-power LEDs
 Also perfectly operate the Philips LED-based systems, including LED Module System and LED String
 Dimming with LED driver 25W (1-10V) does not affect LED life

Features and Benefits

- Slim, compact housings (12W and 17W types) – matches spatially unobtrusive LED light sources
- Maximum freedom for system designers
- Constant DC current output for optimum operation and long life of high-power LEDs
- Long operating life (50.000 hours) matches that of LEDs
- Meet CE and ENEC approbation requirements
- Hazard-free – can be installed in virtually any location
- Insulated construction plus limited output voltage and current for safe operation
- Dimming driver (25W) allows variation of LED output from 5% to 100%

Applications

- Channel letter/contour lighting
- Architectural lighting
- Orientation (path) lighting
- Retail/theme lighting
- Entertainment lighting
- Emergency and security lighting

Product data	
Order code	927361 30
Full product code	871150092736130
loccod	
Full product name	LED Driver Indoor 25W/1.05A-24V 230V
Order product name	LED Driver Indoor 25W/1.05A-24V 230V
Packing type	Unpacked
Pieces per pack	1
Packing configuration	12
Packs per outerbox	12
Bar code on pack - EAN1	8711500927361
Bar code on intermediate packing - EAN2	


Product data	
Bar code on outerbox - EAN3	8711500927378
Logistic code(s) - 12NC	9137 001 81582
ILCOS code	
Net weight per piece	0.160 KG
Successor order code	
Name Extension	Driver Indoor
Rated Ballast-Lamp Power	25
Application code	25W/1.05A-24V
Line Voltage	230V
Line Frequency	50Hz
Mains voltage performance (AC)	-10%/+10%
Power Consumption Range	2.9-31.9 W
Efficiency	80 -
Power Output Range	2.3-25.5 W
Output Current	945-1155 mA
Crestfactor	1.5 -
Output Voltage Range	2.6-24.0 V
Total Harmonic Distortion IEC	
Conn.type input terminals	Insert
Conn.type output terminals	Insert
T-case maximum	85 C
T-ambient	60 C
T-storage	80 C
CE marking	Yes
ENEC certificate	No
Length A1	83.0 mm
Fixing Hole Distance Length A2	73.4 mm
Width B1	77.0 mm
Fixing Hole Distance Width B2	67.4 mm
Height C1	33.8 mm
Fixing Hole Diameter D1	4.4 mm




LED Driver Indoor

LED 25




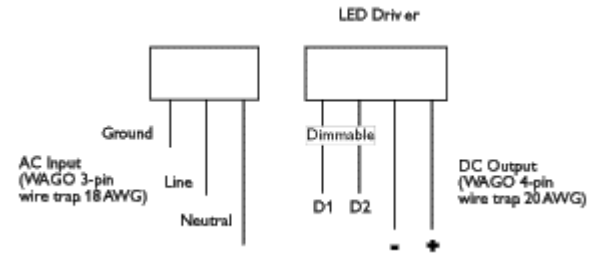

LED Driver Indoor 25W
LED 25

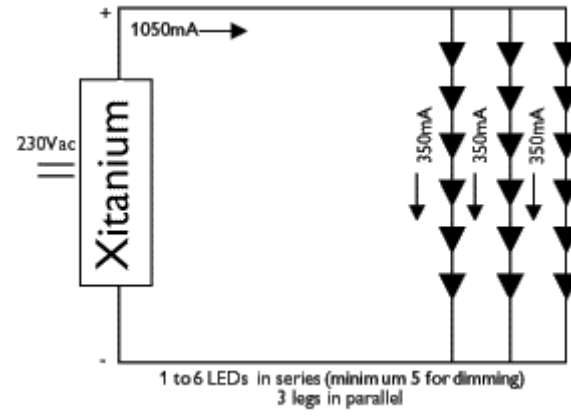

LED Driver Indoor
LED 25

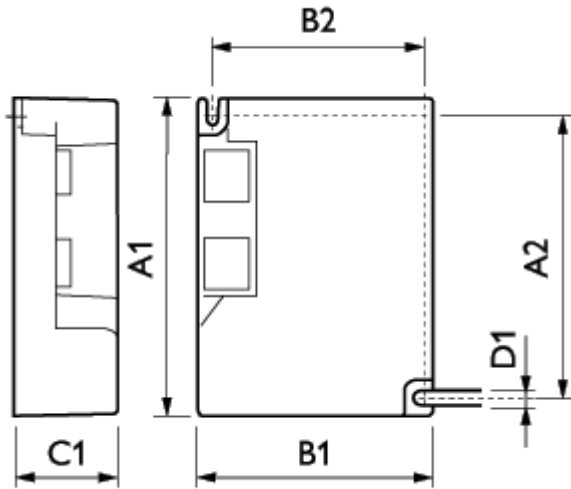

LED Driver Indoor

LED

	A1	A1	A2	A2	B1	B1
Full product name	Nom	Nom	Nom	Nom	Nom	Nom
LED Driver Indoor 25W/1.05A-24V 230V	83.0	83.0	73.4	73.4	77.0	77.0

	B2	B2	C1	C1	D1	D1
Full product name	Nom	Nom	Nom	Nom	Nom	Nom
LED Driver Indoor 25W/1.05A-24V 230V	67.4	67.4	33.8	33.8	4.4	4.4

Full product name
LED Driver Indoor 25W/1.05A-24V 230V

