


PCM-9361EG-S6A1E

3.5" SBC with Atom N270, GbE, LVDS, SATA, PCI-104

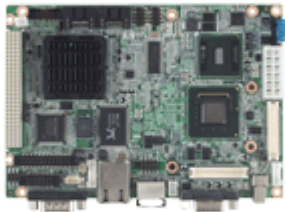

- Intel Atom N270 1.6 GHz Processor
- DDR2 Memory support up to 2 GB
- Supports VGA and 36-bit LVDS display
- Supports Gigabit Ethernet
- HD Audio Codec
- 5 x USB 2.0 ports
- 2 x SATA connectors
- PCI-104 expansion
- 2-year limited warranty

Specifications

Spec category	Spec Name	Spec
Processor	Chipset	Intel® 945GSE/ICH7M
Network	LAN	GbE
Expansion Supported	Slots	1 x PCI-104
I/O	COM	2
Memory	(Max)	2GB DDR2
Processor	Processor	Intel® ATOM™ N270
Processor	Max Speed	1.6GHz
Storage	SSD	CF I/II,SATA
I/O	USB	4 (2.0)
Display	Type	VGA 36-bit LVDS
Processor	CPU Type	Atom™ N270
Operating	Temp	0 ~ 60°C

Special \$263

Part No.	Description
PCM-9361EG-S6A1E	3.5" SBC with Atom N270, GbE, LVDS, SATA, PCI-104

Copyright© Advantech Co.Ltd. All Rights reserved.

Advantech eStore is the exclusive e-business website from Advantech devoted to the safe and stable on-line transaction of industrial computers.

Should you have any request for Advantech products or any inquiry on technical issues, please feel free to contact us. * Subject change without notice.