



Series 152FB Fusion Bonded Cable Jumpers

FEATURES:

- Aries Series 152FB Fusion Bonded Cable Jumpers are flexible...plug them directly into PC boards or sockets.
- Stranded wire conductors are fusion bonded with an overcoat of tin for easy soldering or socketing.
- Each jumper is shipped with protective tabs on both ends for maintaining proper conductor spacing.

SPECIFICATIONS:


- Insulation is UL VW-1, Style 2651 Polyvinyl Chloride (PVC) with optional polarization stripe on one side.
- Nominal insulation thickness is .009 [.23].
- Conductors are 26 gauge, 7-strand Copper Alloy with a fusion bonded overcoat of Tin.
- Operating temperature=-4°F to 221°F [-20°C to 105°C].
- Voltage rating=300 Vrms.
- Dielectric withstanding voltage=1500 Vrms.
- Insulation resistance=10,000 MOhms per 10 feet [3.05 meters].
- Resistance=40.3 Ohms per 1000 feet [304.8 meters].
- Propagation delay=1.3 ns/foot.

MOUNTING CONSIDERATIONS:

- Suggested PCB hole size=.033 ± .002 [.84 ± .05] dia.

Consult factory for sizes not shown

ALL DIMENSIONS: INCHES [MILLIMETERS]

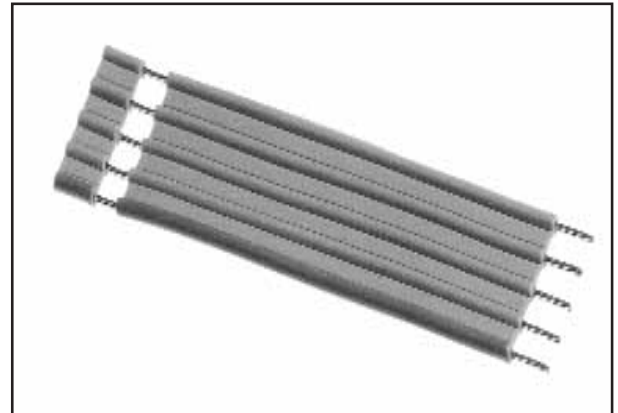

Note: Aries specializes in custom design and production. In addition to the standard products shown on this page, special materials, platings, sizes, and configurations can be furnished, depending on quantities. Aries reserves the right to change product specifications without notice.

ORDERING INFORMATION

XX-XXXXX-152FBX

No. of conductors (4 thru 22)

Cable length: "L" in inches:
EX: 2" = -002-
2.5" = -002.5-
2.25" = -002.25-
2.125" = -002.125-

Optional suffix:
P=Polarization stripe along one edge of cable**

Jumper series


No. of Conductors	Minimum Insulation Length
4 thru 8	1.000 [25.40]
9 and 10	1.250 [31.75]
11 thru 22	1.500 [38.10]

All tolerances ± .005 [.13] unless otherwise specified

**Aries reserves the right to ship with or without polarization stripe unless specified by customer.

"A"=NO. OF CONDUCTORS X .100 [2.54]
"B"=(NO. OF CONDUCTORS - 1) X .100 [2.54]

ALL CABLES SHIP WITH LEAD FREE MATERIAL UNLESS SPECIFIED BY CUSTOMER WHEN ORDERING

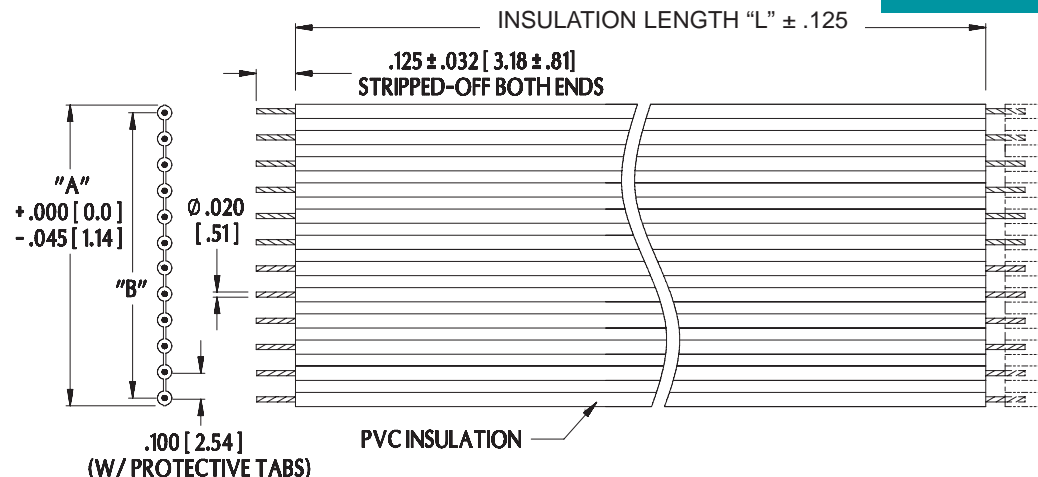

ARIES
ELECTRONICS, INC.
http://www.arieselec.com • info@arieselec.com

Frenchtown, NJ USA
TEL: (908) 996-6841
FAX: (908) 996-3891



11001
REV.F