


Winkelsensoren / Angle Sensors

(Conductive Plastic)

41624

VORGABUNG Supply	5 ± 0.1 V	
AUSGANGSSIGNAL Output signal	Analogic, voltage interface	
DICHTIGKEITSGRAD Sealing grade	IP 54	
TEMPERATURBEREICH Temperature range	-40 °C to +120 °C	
WINKELBEREICH Angle range (degrees)	105°	
AUSGANGSSPANNUNG Output – voltage range	0.15 V – 5 V	
RÜCKSTELLFEDER Return spring	yes	
WIDERSTAND Resistance	4.0 kOhm ± 20%	
LINEARITÄT Absolute linearity	± 3 %	
LEBENSDAUER (TYPISCH) Life time full stroke	Min. 2 mio. cycles	
ZITTERSPIELE Dither life time (± 2°)	Min. 10 mio. cycles	
ARTIKELNUMMER Order number	4162400011	

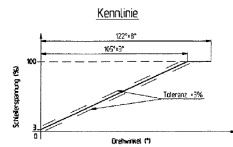

Maße / Dimensions:

