




- Cost Effective MT marking system for quick and accurate identification
- Push-On Tags fit all Altech DIN Rail mount terminal blocks
- Inserted individually or as strips of 10
- Quick and easy marking
- Blank Marking Tags for customer marking
- Order with horizontal/ vertical imprint
- Standard imprints with consecutive or identical numbers/ characters
- Custom imprint with short lead time
- Supplied in packs of 100 tags/ 10 strips

BLANK MARKING TAGS

Cat No./ Type	Standard Packs			Dimensions	
	Pack	Strips	Tags	H	W
MT2	1	10	100	4.9mm	5.8mm
MT3	1	20	100	5.0mm	10.0mm
MT4	1	10	100	5.0mm	4.8mm
MT5	1	10	100	9.5mm	4.5mm
MT6	1	10	100	9.5mm	5.6mm
MT8	1	10	100	10.5mm	7.5mm
MT9	1	10	100	10.3mm	8.7mm
MT10	1	20	100	10.4mm	9.5mm
MT12	1	20	100	10.4mm	11.4mm
MT16	1	20	100	10.5mm	15.4mm
MT2G	1	10	100	5.0mm	5.0mm
MT2B4	1	10	100	5.8mm	9.1mm
Continuous Tags					
MT6F	1	10	10	9.5mm	60.0mm
MT9F	1	10	10	10.3mm	90.0mm

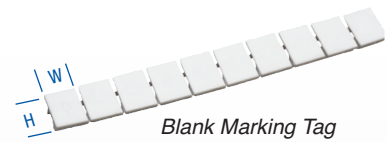

Blank Marking Tag




Horizontal Imprint



Vertical Imprint

HOW TO ORDER IMPRINTED MARKING TAGS

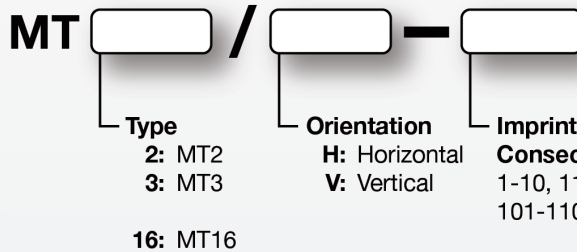

IMPRINT EXAMPLES FOR MT6

HORIZONTAL

Imprint	Cat. No.	Imprint	Cat. No.
1	MT6/H-1	131-140	MT6/H-131-140
2	MT6/H-2	141-150	MT6/H-141-150
3	MT6/H-3	151-160	MT6/H-151-160
4	MT6/H-4	161-170	MT6/H-161-170
5	MT6/H-5	171-180	MT6/H-171-180
6	MT6/H-6	181-190	MT6/H-181-190
7	MT6/H-7	191-200	MT6/H-191-200
8	MT6/H-8	1-100	MT6/H-1-100
9	MT6/H-9	1-50	MT6/H-1-50
10	MT6/H-10	A	MT6/H-A
1-10	MT6/H-1-10	B	MT6/H-B
11-20	MT6/H-11-20	C	MT6/H-C
21-30	MT6/H-21-30	L1	MT6/H-L1
31-40	MT6/H-31-40	L2	MT6/H-L2
41-50	MT6/H-41-50	L3	MT6/H-L3
51-60	MT6/H-51-60	N	MT6/H-N
61-70	MT6/H-61-70	R	MT6/H-R
71-80	MT6/H-71-80	S	MT6/H-S
81-90	MT6/H-81-90	X	MT6/H-X
91-100	MT6/H-91-100	Y	MT6/H-Y
101-110	MT6/H-101-110	Z	MT6/H-Z
111-120	MT6/H-111-120	Ground Symbol	MT6/H-GRND
121-130	MT6/H-121-130		

VERTICAL

Imprint	Cat. No.	Imprint	Cat. No.
1	MT6/V-1	131-140	MT6/V-131-140
2	MT6/V-2	141-150	MT6/V-141-150
3	MT6/V-3	151-160	MT6/V-151-160
4	MT6/V-4	161-170	MT6/V-161-170
5	MT6/V-5	171-180	MT6/V-171-180
6	MT6/V-6	181-190	MT6/V-181-190
7	MT6/V-7	191-200	MT6/V-191-200
8	MT6/V-8	1-100	MT6/V-1-100
9	MT6/V-9	1-50	MT6/V-1-50
10	MT6/V-10	A	MT6/V-A
1-10	MT6/V-1-10	B	MT6/V-B
11-20	MT6/V-11-20	C	MT6/V-C
21-30	MT6/V-21-30	L1	MT6/V-L1
31-40	MT6/V-31-40	L2	MT6/V-L2
41-50	MT6/V-41-50	L3	MT6/V-L3
51-60	MT6/V-51-60	N	MT6/V-N
61-70	MT6/V-61-70	R	MT6/V-R
71-80	MT6/V-71-80	S	MT6/V-S
81-90	MT6/V-81-90	X	MT6/V-X
91-100	MT6/V-91-100	Y	MT6/V-Y
101-110	MT6/V-101-110	Z	MT6/V-Z
111-120	MT6/V-111-120	Ground Symbol	MT6/V-GRND
121-130	MT6/V-121-130		