



REV	DESCRIPTION\PER REQUEST	DRAWN	DATE

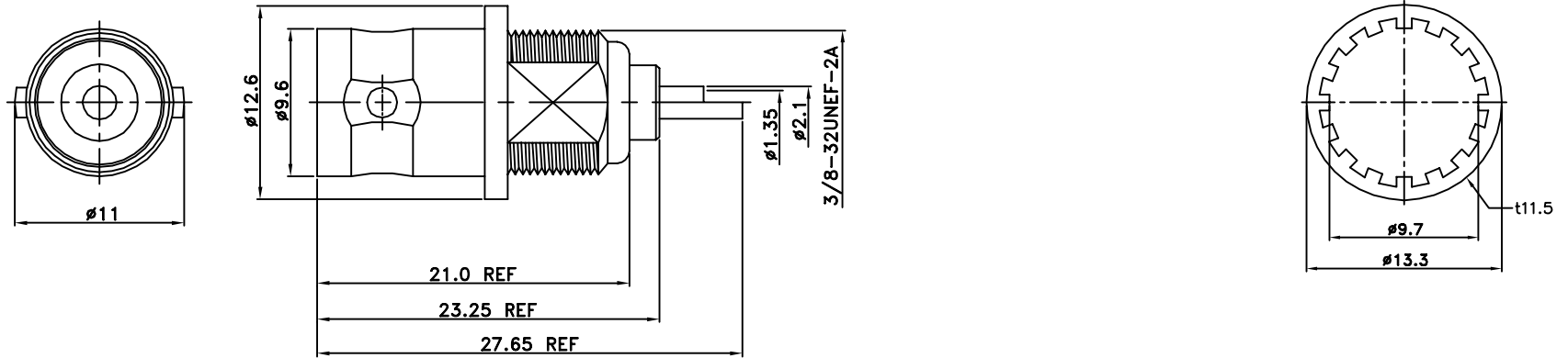

Electrical Specifications:
 Impedance: 50 ohm
 Voltage Rating: 500V
 Temperature, Operating: -55C to +85 C
 Frequency Range: 0-1GHz

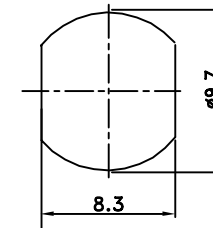

RECOMMENDED MOUNTING HOLE

5	Nut	1	Brass	Nickel
4	Washer	1	Steel	Nickel
3	Dielectric	1	PE/ABS	None
2	Pin	1	Brass	Gold
1	Body	1	Zinc	Nickel
NO	Description	Q'ty	Material	Finish

PART NO.	SPX44644
APPROVED	DATE 10/17/05
CHECKED	DATE 10/17/05
DRAWN	DATE 10/17/05
	KAI

* MAJOR DIMENSION			
UNLESS OTHERWISE NOTED TOLERANCES			
0.5-6	=	± 0.2	
6-30	=	± 0.4	
30-120	=	± 0.6	
120-315	=	± 1.0	
ANGLES= $\pm 1^\circ$			
SCALE	5/2	UNIT	mm

Bomar Interconnect Products, Inc.	
TITLE BNC BULKHEAD RECEPTACLE JACK	
DRAWING NO. SPX44644	REV C
FILE NO. W:\DWG\COMPOSE\BNC\BNC-1342-6-44644	