



PORTABLE PRINTERS AND LABELS

I.D. PRO Plus®, Brady LS2000 and BradyMarker™ XC Plus Labels

PRINTER MODEL	
PRO	= ID PRO/PRO Plus
LS	= LS2000
BMXC	= BradyMarker XC Plus
ALL	= All ID PRO, LS2000, BMXC

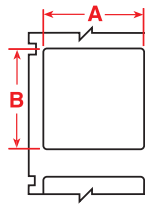

For use on components in control panels, electronic components and circuit boards, faceplates and electronic receptacles.

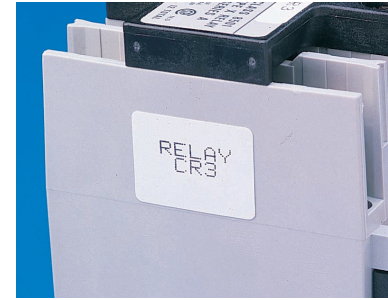

▶ COMPONENT AND GENERAL IDENTIFICATION LABELS

Part Number	Portable Printer Model	Labels Per Roll	Label Material	Label Width Inch (mm) A	Label Height Inch (mm) B	Maximum Lines of Print (PRO/LS)	Maximum Characters Across Large (PRO/LS)	Maximum Characters Across Small (PRO/LS)
CL-105-499	ALL	500	Nylon Cloth	0.500 (12.70)	0.275 (7.00)	1/1	3/3	4/7
CL-105-502	ALL	500	Vinyl Cloth	0.500 (12.70)	0.275 (7.00)	1/1	3/3	4/7
CL-105-607	ALL	500	Tamper-Proof Vinyl	0.500 (12.70)	0.275 (7.00)	1/1	3/3	4/7
CL-105-619	ALL	500	Polyester	0.500 (12.70)	0.275 (7.00)	1/1	3/3	4/7
CL-105-621	ALL	500	Translucent Polyester	0.500 (12.70)	0.275 (7.00)	1/1	3/3	4/7
CL-105-652	ALL	500	Polyimide	0.500 (12.70)	0.275 (7.00)	1/1	3/3	4/7
CL-105-969	ALL	500	Metallized Polyester	0.500 (12.70)	0.275 (7.00)	1/1	3/3	4/7
CL-0807-619	LS	500	Polyester	0.500 (12.70)	0.500 (12.70)	4	3	7
CL-0807-969	LS	500	Metallized Polyester	0.500 (12.70)	0.500 (12.70)	4	3	7
CL-0309-502	LS	500	Vinyl Cloth	0.650 (16.51)	0.187 (4.75)	1	4	9
CL-0309-619	LS	500	Polyester	0.650 (16.51)	0.187 (4.75)	1	4	9
CL-0311-619	LS	500	Polyester	0.800 (20.32)	0.200 (5.08)	1	5	11
CL-0311-652	LS	500	Polyimide Film	0.800 (20.32)	0.200 (5.08)	1	5	11
CL-0411-502	LS	500	Vinyl Cloth	0.750 (19.05)	0.250 (6.35)	2	5	11
CL-0411-619	LS	500	Polyester	0.750 (19.05)	0.250 (6.35)	2	5	11
CL-0411-652	LS	500	Polyimide Film	0.750 (19.05)	0.250 (6.35)	2	5	11
CL-0411-969	LS	500	Metallized Polyester	0.750 (19.05)	0.250 (6.35)	2	5	11
CL-0413-619	LS	500	Polyester	0.900 (22.86)	0.250 (6.35)	2	6	13
CL-0413-652	LS	500	Polyimide	0.900 (22.86)	0.250 (6.35)	2	6	13
CL-111-122	ALL	500	Paper	1.000 (25.40)	0.275 (7.00)	1/1	7/7	10/15
CL-111-499	ALL	500	Nylon Cloth	1.000 (25.40)	0.275 (7.00)	1/1	7/7	10/15
CL-111-502	ALL	500	Vinyl Cloth	1.000 (25.40)	0.275 (7.00)	1/1	7/7	10/15
CL-111-607	ALL	500	Tamper-Proof Vinyl	1.000 (25.40)	0.275 (7.00)	1/1	7/7	10/15
CL-111-619	ALL	500	Polyester	1.000 (25.40)	0.275 (7.00)	1/1	7/7	10/15
CL-111-621	ALL	500	Translucent Polyester	1.000 (25.40)	0.275 (7.00)	1/1	7/7	10/15
CL-111-637	ALL	500	Tedlar®	1.000 (25.40)	0.275 (7.00)	1/1	7/7	10/15
CL-111-652	ALL	500	Polyimide	1.000 (25.40)	0.275 (7.00)	1/1	7/7	10/15
CL-111-969	ALL	500	Metallized Polyester	1.000 (25.40)	0.275 (7.00)	1/1	7/7	10/15
CL-0423-502	LS	500	Vinyl Cloth	1.500 (38.10)	0.250 (6.35)	2	11	23
CL-0423-619	LS	500	Polyester	1.500 (38.10)	0.250 (6.35)	2	11	23
CL-0423-652	LS	500	Polyimide Film	1.500 (38.10)	0.250 (6.35)	2	11	23
CL-117-499	ALL	500	Nylon Cloth	1.500 (38.10)	0.275 (7.00)	1/1	10/11	15/23
CL-117-502	ALL	500	Vinyl Cloth	1.500 (38.10)	0.275 (7.00)	1/1	10/11	15/23
CL-117-619	ALL	500	Polyester	1.500 (38.10)	0.275 (7.00)	1/1	10/11	15/23
CL-117-621	ALL	500	Translucent Polyester	1.500 (38.10)	0.275 (7.00)	1/1	10/11	15/23
CL-117-637	ALL	500	Tedlar	1.500 (38.10)	0.275 (7.00)	1/1	10/11	15/23
CL-117-652	ALL	500	Polyimide	1.500 (38.10)	0.275 (7.00)	1/1	10/11	15/23
CL-117-969	ALL	500	Metallized Polyester	1.500 (38.10)	0.275 (7.00)	1/1	10/11	15/23
CL-0431-502	LS	500	Vinyl Cloth	2.000 (50.80)	0.250 (6.35)	1/1	10/11	15/23
CL-0431-619	LS	500	Polyester	2.000 (50.80)	0.250 (6.35)	2	15	31
CL-0431-652	LS	500	Polyimide Film	2.000 (50.80)	0.250 (6.35)	2	15	31
CL-0431-969	LS	500	Metallized Polyester	2.000 (50.80)	0.250 (6.35)	2	15	31
CL-211-499	ALL	500	Nylon Cloth	1.000 (25.40)	0.400 (10.16)	2/2	7/7	10/15
CL-211-502	ALL	500	Vinyl Cloth	1.000 (25.40)	0.400 (10.16)	2/2	7/7	10/15
CL-211-619	ALL	500	Polyester	1.000 (25.40)	0.400 (10.16)	2/2	7/7	10/15
CL-211-621	ALL	500	Translucent Polyester	1.000 (25.40)	0.400 (10.16)	2/2	7/7	10/15

Tedlar® is a registered trademark of DuPont.

PORTABLE PRINTERS AND LABELS I.D. PRO PLUS, BRADY LS2000 AND BRADYMARKER XC PLUS LABELS