




Catalog Number: CL-917-122
I.D. PRO® Plus, LS2000 & BradyMarker™ XC Plus Printer Labels

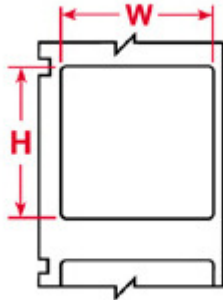

Application(s): Circuit Board & Component ID, General & Industrial Identification, General Identification, Panel Identification

Size: 1.500" W x 1.250" H (38.100 mm W x 31.750 mm H)

Printable Area: 1.500" W x 1.250" H (38.100 mm W x 31.750 mm H)

Max Characters Across: LARGE - I.D. PRO: 10, LS2000: 11. SMALL - I.D. PRO: 15, LS2000: 23

Max Lines of Print: I.D. PRO: 9, LS2000: 9

Label Type/Style: Tamper-Indicating

Color: White

Finish: Matte

Material Type: Paper

Material Description: Tamper-Evident Paper

Recommended Ribbon Series: R2000, R5000

Printer Compatibility: BradyMarker XC Plus, I.D. PRO Plus, LS2000

Special Properties: Fractures easily, prevents one-piece removal

RoHS Compatibility: Compliant with RoHS Directive. NOTE: All statements concerning RoHS Directive compliance refer to 2005/618/EC MCV amendment to RoHS Directive 2002/95/EC. Product compliance is based upon information provided by suppliers of the raw materials used by Brady to manufacture these products, or by independent laboratory testing of these products. As such, Brady makes no independent representations or warranties, express or implied, and assumes no liability in

connection with the use of this information.

QTY/UOM: 250/Roll