


Self-Laminating Wire and Cable Markers by Size

► BUTT-CUT

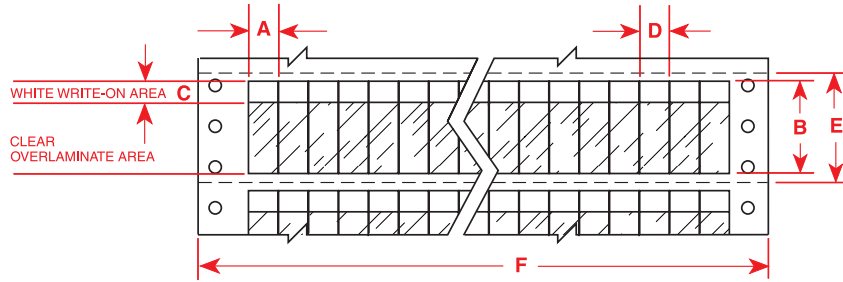

Part Number	Pieces Per Package	Material	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Write-On Height Inch (mm) C	Horizontal Repeat Inch (mm) D	Vertical Repeat Inch (mm) E	Web Width Inch (mm) F
0.300" Label Width — 6 or 8 lines per inch									
DAT-139-292-1,-10	1,000/10,000	Vinyl	16	0.300 (7.62)	0.75 (19.05)	0.375 (9.53)	0.300 (7.62)	1.000 (25.40)	5.800 (147.32)
DAT-142-292-1,-10	1,000/10,000	Vinyl	16	0.300 (7.62)	0.937 (23.80)	0.375 (9.53)	0.300 (7.62)	1.000 (25.40)	5.800 (147.32)
0.500" Label Width — 6 or 8 lines per inch									
DAT-145-292-1,-10	1,000/10,000	Vinyl	16	0.500 (12.70)	0.937 (23.80)	0.375 (9.53)	0.500 (12.70)	1.000 (25.40)	9.000 (228.60)
DAT-33-292-1,-10	1,000/10,000	Vinyl	16	0.500 (12.70)	1.437 (36.50)	0.500 (12.70)	0.500 (12.70)	1.500 (38.10)	9.000 (228.60)
DAT-53-642-1,-10	1,000/10,000	Polyvinylfluoride	16	0.500 (12.70)	1.437 (36.50)	0.500 (12.70)	0.500 (12.70)	1.500 (38.10)	9.000 (228.60)
SLSH-0515	1,664	Vinyl	16	0.500 (12.70)	1.437 (36.50)	0.500 (12.70)	0.500 (12.70)	1.500 (38.10)	9.000 (228.60)
0.800" Label Width — 6 or 8 lines per inch									
DAT-148-292-1,-10	1,000/10,000	Vinyl	10	0.800 (20.32)	0.937 (23.80)	0.375 (9.53)	0.800 (20.32)	1.000 (25.40)	9.000 (228.60)
1.000" Label Width — 6 or 8 lines per inch									
DAT-85-292-1,-10	1,000/10,000	Vinyl	8	1.000 (25.40)	0.750 (19.05)	0.375 (9.53)	1.000 (25.40)	1.000 (25.40)	9.000 (228.60)
DAT-85-292-BL**	2,500	Vinyl	8	1.000 (25.40)	0.750 (19.05)	0.375 (9.53)	1.000 (25.40)	1.000 (25.40)	9.000 (228.60)
DAT-85-292-BR**	2,500	Vinyl	8	1.000 (25.40)	0.750 (19.05)	0.375 (9.53)	1.000 (25.40)	1.000 (25.40)	9.000 (228.60)
DAT-85-292-GR**	2,500	Vinyl	8	1.000 (25.40)	0.750 (19.05)	0.375 (9.53)	1.000 (25.40)	1.000 (25.40)	9.000 (228.60)
DAT-85-292-GY**	2,500	Vinyl	8	1.000 (25.40)	0.750 (19.05)	0.375 (9.53)	1.000 (25.40)	1.000 (25.40)	9.000 (228.60)
DAT-85-292-OR**	2,500	Vinyl	8	1.000 (25.40)	0.750 (19.05)	0.375 (9.53)	1.000 (25.40)	1.000 (25.40)	9.000 (228.60)
DAT-85-292-PL**	2,500	Vinyl	8	1.000 (25.40)	0.750 (19.05)	0.375 (9.53)	1.000 (25.40)	1.000 (25.40)	9.000 (228.60)
DAT-85-292-RD**	2,500	Vinyl	8	1.000 (25.40)	0.750 (19.05)	0.375 (9.53)	1.000 (25.40)	1.000 (25.40)	9.000 (228.60)
DAT-85-292-YL**	2,500	Vinyl	8	1.000 (25.40)	0.750 (19.05)	0.375 (9.53)	1.000 (25.40)	1.000 (25.40)	9.000 (228.60)
DAT-151-292-1,-10	1,000/10,000	Vinyl	8	1.000 (25.40)	0.937 (23.80)	0.375 (9.53)	1.000 (25.40)	1.000 (25.40)	9.000 (228.60)
DAT-34-292-1,-10	1,000/10,000	Vinyl	8	1.000 (25.40)	1.437 (36.50)	0.500 (12.70)	1.000 (25.40)	1.500 (38.10)	9.000 (228.60)
DAT-34-292-BL**	2,500	Vinyl	8	1.000 (25.40)	1.437 (36.50)	0.500 (12.70)	1.000 (25.40)	1.500 (38.10)	9.000 (228.60)
DAT-34-292-BR**	2,500	Vinyl	8	1.000 (25.40)	1.437 (36.50)	0.500 (12.70)	1.000 (25.40)	1.500 (38.10)	9.000 (228.60)
DAT-34-292-GR**	2,500	Vinyl	8	1.000 (25.40)	1.437 (36.50)	0.500 (12.70)	1.000 (25.40)	1.500 (38.10)	9.000 (228.60)
DAT-34-292-GY**	2,500	Vinyl	8	1.000 (25.40)	1.437 (36.50)	0.500 (12.70)	1.000 (25.40)	1.500 (38.10)	9.000 (228.60)
DAT-34-292-OR**	2,500	Vinyl	8	1.000 (25.40)	1.437 (36.50)	0.500 (12.70)	1.000 (25.40)	1.500 (38.10)	9.000 (228.60)
DAT-34-292-PL**	2,500	Vinyl	8	1.000 (25.40)	1.437 (36.50)	0.500 (12.70)	1.000 (25.40)	1.500 (38.10)	9.000 (228.60)
DAT-34-292-RD**	2,500	Vinyl	8	1.000 (25.40)	1.437 (36.50)	0.500 (12.70)	1.000 (25.40)	1.500 (38.10)	9.000 (228.60)
DAT-34-292-YL**	2,500	Vinyl	8	1.000 (25.40)	1.437 (36.50)	0.500 (12.70)	1.000 (25.40)	1.500 (38.10)	9.000 (228.60)
DAT-54-642-10	10,000	Polyvinylfluoride	8	1.000 (25.40)	1.437 (36.50)	0.500 (12.70)	1.000 (25.40)	1.500 (38.10)	9.000 (228.60)
SLSH-1015	832	Vinyl	8	1.000 (25.40)	1.437 (36.50)	0.500 (12.70)	1.000 (25.40)	1.500 (38.10)	9.000 (228.60)
DAT-37-292-1,-10	1,000/10,000	Vinyl	8	1.000 (25.40)	2.250 (57.15)	0.750 (19.05)	1.000 (25.40)	2.500 (63.50)	9.000 (228.60)
DAT-37-292-BL**	2,500	Vinyl	8	1.000 (25.40)	2.250 (57.15)	0.750 (19.05)	1.000 (25.40)	2.500 (63.50)	9.000 (228.60)
DAT-37-292-BR**	2,500	Vinyl	8	1.000 (25.40)	2.250 (57.15)	0.750 (19.05)	1.000 (25.40)	2.500 (63.50)	9.000 (228.60)
DAT-37-292-GR**	2,500	Vinyl	8	1.000 (25.40)	2.250 (57.15)	0.750 (19.05)	1.000 (25.40)	2.500 (63.50)	9.000 (228.60)
DAT-37-292-GY**	2,500	Vinyl	8	1.000 (25.40)	2.250 (57.15)	0.750 (19.05)	1.000 (25.40)	2.500 (63.50)	9.000 (228.60)
DAT-37-292-OR**	2,500	Vinyl	8	1.000 (25.40)	2.250 (57.15)	0.750 (19.05)	1.000 (25.40)	2.500 (63.50)	9.000 (228.60)
DAT-37-292-PL**	2,500	Vinyl	8	1.000 (25.40)	2.250 (57.15)	0.750 (19.05)	1.000 (25.40)	2.500 (63.50)	9.000 (228.60)
DAT-37-292-RD**	2,500	Vinyl	8	1.000 (25.40)	2.250 (57.15)	0.750 (19.05)	1.000 (25.40)	2.500 (63.50)	9.000 (228.60)
DAT-37-292-YL**	2,500	Vinyl	8	1.000 (25.40)	2.250 (57.15)	0.750 (19.05)	1.000 (25.40)	2.500 (63.50)	9.000 (228.60)
SLSH-10225	608	Vinyl	8	1.000 (25.40)	2.250 (57.15)	0.750 (19.05)	1.000 (25.40)	2.500 (63.50)	9.000 (228.60)

**BL=blue, BR=brown, GR=green, GY=grey, OR=orange, PL=purple, RD=red, YL=yellow.
Standard product lead time of 10 working days.

Note: Labels in chart are sorted in order by width, height, 3 digit material number (within part number), then die number (within part number).