


Self-Laminating Wire and Cable Markers by Size

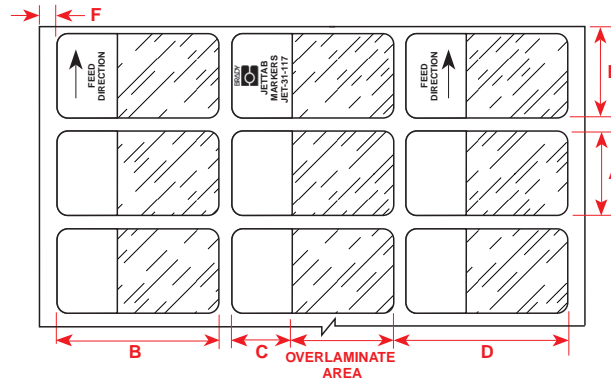

Part Number	Pieces Per Package	Material	Color	Labels Per Row	Width Inch (mm) A	Label Height Inch (mm) B	Label Height Inch (mm) C	Write-On Repeat Inch (mm) D	Horizontal Margin Inch (mm) E	Top Margin Inch (mm) F	Left Labels Per Sheet
0.500" Label Width											
JET-27-117-5	5,000	Vinyl	White/Transparent	8	0.500 (12.70)	0.750 (19.05)	0.380 (9.65)	1.000 (25.40)	0.750 (19.05)	0.425 (10.79)	128
JET-29-117-3	3,000	Vinyl	White/Transparent	5	0.500 (12.70)	1.380 (35.05)	0.500 (12.70)	1.600 (40.64)	0.750 (19.05)	0.425 (10.79)	80
0.950" Label Width											
JET-28-117-3	3,000	Vinyl	White/Transparent	8	0.950 (24.13)	0.750 (19.05)	0.380 (9.65)	0.250 (6.35)	0.750 (19.05)	0.425 (10.79)	72
JET-30-117-2	2,000	Vinyl	White/Transparent	5	0.950 (24.13)	1.380 (35.05)	0.500 (12.70)	1.600 (40.64)	0.750 (19.05)	0.425 (10.79)	45
JET-31-117-1	1,000	Vinyl	White/Transparent	3	0.950 (24.13)	2.250 (57.15)	0.750 (19.05)	2.625 (66.67)	0.750 (19.05)	0.425 (10.79)	27
JET-33-117-1	1,000	Vinyl	White/Transparent	3	0.950 (24.13)	3.750 (95.25)	1.000 (25.40)	4.000 (101.60)	0.750 (19.05)	0.425 (10.79)	18
1.800" Label Width											
JET-32-117-0.5	500	Vinyl	White/Transparent	3	1.800 (45.72)	2.250 (57.15)	0.750 (19.05)	0.375 (9.52)	0.750 (19.05)	0.425 (10.79)	15
JET-34-117-0.5	500	Vinyl	White/Transparent	2	1.800 (45.72)	3.750 (95.25)	1.000 (25.40)	4.000 (101.60)	0.750 (19.05)	0.425 (10.79)	10

Note: Labels in chart are sorted in order by width, height, 3 digit material number (within part number), then die number (within part number).

SELF-LAMINATING WIRE AND CABLE MARKERS BY SIZE INK JET LABELS