
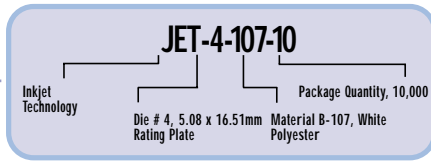


# Labels Index by Size

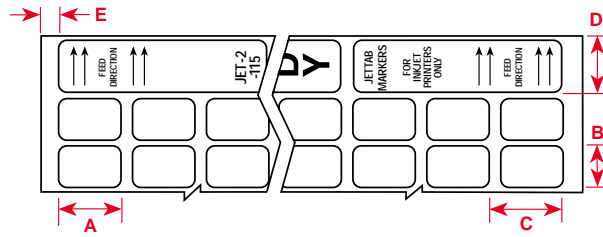

**REFERENCE EXPLANATION:**

Most BRADY part numbers for computer printable labels follow the same four-part format:

The first code indicates the technology, the second part is a number indicating the die size used (where applicable), the third part indicates the BRADY material used (where applicable), and the final code indicates package quantity.


Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Top Margin D mm	Left Margin E mm	Labels Per Sheet
<b>9.53 mm Label Width</b>										
JET-1-107-10	10,000	Polyester	White	17	9.53	9.53	11.93	19.05	7.62	357
<b>12.70 mm Label Width</b>										
JET-2-107-10	10,000	Polyester	White	9	12.70	19.05	22.70	19.05	7.62	153
JET-2-115-10	10,000	Cloth	White	9	12.70	19.05	22.70	19.05	7.62	153
JET-3-107-5	5,000	Polyester	White	5	12.70	36.50	41.02	19.05	7.62	85
JET-3-115-5	5,000	Cloth	White	5	12.70	36.50	41.02	19.05	7.62	59
<b>16.51 mm Label Width</b>										
JET-4-107-10	10,000	Polyester	White	26	16.51	5.08	7.82	19.05	7.62	338
JET-4-115-10	10,000	Cloth	White	26	16.51	5.08	7.82	19.05	7.62	338
JET-4-136-10	10,000	Polyester	White	26	16.51	5.08	7.82	19.05	7.62	338
JET-4-137-10	10,000	Tedlar®	White	26	16.51	5.08	7.82	19.05	7.62	338
JET-5-107-10	10,000	Polyester	White	25	16.51	6.35	8.10	19.05	7.62	325
<b>19.05 mm Label Width</b>										
JET-6-107-10	10,000	Polyester	White	25	19.05	6.35	8.10	19.05	7.62	275
JET-6-136-10	10,000	Polyester	Metallised	25	19.05	6.35	8.10	19.05	7.62	275
<b>20.32 mm Label Width</b>										
JET-7-107-10	10,000	Polyester	White	25	20.32	6.35	8.10	19.05	7.62	275
JET-8-107-10	10,000	Polyester	White	14	20.32	12.70	14.45	19.05	7.62	154
JET-8-113-10	10,000	Paper	White	14	20.32	12.70	14.45	19.05	7.62	154
JET-9-115-3	3,000	Cloth	White	5	20.32	36.50	41.02	19.05	7.62	55
<b>22.86 mm Label Width</b>										
JET-10-107-10	10,000	Polyester	White	25	22.86	6.35	8.10	19.05	7.62	250
JET-10-137-10	10,000	Tedlar®	White	25	22.86	6.35	8.10	19.05	7.62	250
<b>25.40 mm Label Width</b>										
JET-11-107-10	10,000	Polyester	White	25	25.40	6.35	8.10	19.05	7.62	225
JET-11-113-10	10,000	Paper	White	25	25.40	6.35	8.10	19.05	7.62	225
JET-11-114-10	10,000	Polyolefin	White	25	25.40	6.35	8.10	19.05	7.62	225
JET-12-107-10	10,000	Polyester	White	17	25.40	9.53	11.93	19.05	7.62	153
JET-12-114-10	10,000	Polyolefin	White	17	25.40	9.53	11.93	19.05	7.62	153
JET-12-115-10	10,000	Cloth	White	17	25.40	9.53	11.93	19.05	7.62	153
PJET-1-107-3	3,000	Polyester	White	9	25.40	12.70	23.49	19.05	7.62	63
JET-13-107-10	10,000	Polyester	White	14	25.40	12.70	14.45	19.05	7.62	126
JET-13-113-10	10,000	Paper	White	14	25.40	12.70	14.45	19.05	7.62	126
JET-13-114-10	10,000	Polyolefin	White	14	25.40	12.70	14.45	19.05	7.62	126
JET-13-115-10	10,000	Cloth	White	14	25.40	12.70	14.45	19.05	7.62	126
JET-13-136-10	10,000	Polyester	Metallised	14	25.40	12.70	14.45	19.05	7.62	126
JET-13-137-10	10,000	Tedlar®	White	14	25.40	12.70	14.45	19.05	7.62	126
JET-14-107-5	5,000	Polyester	White	9	25.40	19.05	22.70	19.05	7.62	81
JET-14-113-5	5,000	Paper	White	9	25.40	19.05	22.70	19.05	7.62	81
JET-14-115-5	5,000	Cloth	White	9	25.40	19.05	22.70	19.05	7.62	81

Tedlar® is a registered trademark of DuPont

**Note:** Labels are sorted in order by width, height, 3 digit material number (within reference).

# Labels Index by Size

CONTINUED

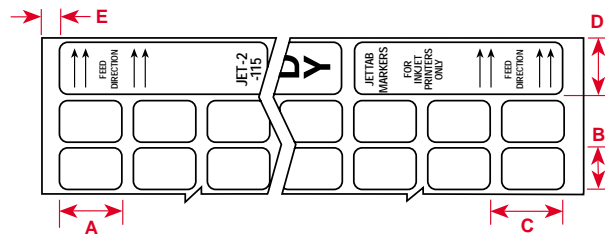


Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Horizontal Repeat C mm	Top Margin D mm	Left Margin E mm	Labels Per Sheet
<b>31.75 mm Label Width</b>										
JET-15-115-5	5,000	Cloth	White	9	31.75	19.05	22.70	19.05	7.62	63
JET-15-114-5	5,000	Polyolefin	White	9	31.75	19.05	22.70	19.05	7.62	63
JET-15-107-5	5,000	Polyester	White	9	31.75	19.05	22.70	19.05	7.62	63
<b>38.10 mm Label Width</b>										
JET-16-107-10	10,000	Polyester	White	25	38.10	6.35	8.10	19.05	7.62	225
JET-16-114-10	10,000	Polyolefin	White	25	38.10	6.35	8.10	19.05	7.62	225
JET-16-115-10	10,000	Cloth	White	25	38.10	6.35	8.10	19.05	7.62	225
JET-17-107-5	5,000	Polyester	White	14	38.10	12.70	14.45	19.05	7.62	84
JET-17-113-5	5,000	Paper	White	14	38.10	12.70	14.45	19.05	7.62	84
JET-18-107-3	3,000	Polyester	White	9	38.10	19.05	22.70	19.05	7.62	54
JET-18-113-3	3,000	Paper	White	9	38.10	19.05	22.70	19.05	7.62	54
JET-18-114-3	3,000	Polyolefin	White	9	38.10	19.05	22.70	19.05	7.62	54
JET-18-115-3	3,000	Cloth	White	9	38.10	19.05	22.70	19.05	7.62	54
JET-18-136-10	10,000	Polyester	Metallised	9	38.10	19.05	22.70	19.05	7.62	54
JET-18-137-10	10,000	Tedlar®	White	9	38.10	19.05	22.70	19.05	7.62	54
<b>44.45 mm Label Width</b>										
PJET-2-107-1.5	1,500	Polyester	White	6	44.45	25.40	22.70	19.05	7.62	24
JET-19-107-3	3,000	Polyester	White	7	44.45	25.40	29.21	19.05	7.62	35
JET-19-113-3	3,000	Paper	White	7	44.45	25.40	29.21	19.05	7.62	35
JET-19-136-3	3,000	Polyester	Metallised	7	44.45	25.40	29.21	19.05	7.62	35
<b>47.63 mm Label Width</b>										
JET-20-107-10	10,000	Polyester	White	25	47.63	6.35	8.10	19.05	7.62	125
JET-21-107-5	5,000	Polyester	White	25	47.63	9.53	11.93	19.05	7.62	85
JET-22-107-3	3,000	Polyester	White	25	47.63	21.16	25.65	19.05	7.62	40
JET-22-113-3	3,000	Paper	White	8	47.63	21.16	25.65	19.05	7.62	40
JET-22-114-3	3,000	Polyolefin	White	8	47.63	21.16	25.65	19.05	7.62	40
<b>50.80 mm Label Width</b>										
JET-23-107-5	5,000	Polyester	White	17	50.80	9.53	11.93	19.05	7.62	68
JET-23-115-5	5,000	Cloth	White	17	50.80	9.53	11.93	19.05	7.62	68
<b>69.85 mm Label Width</b>										
JET-24-113-5	500	Paper	White	3	69.85	69.85	8.10	19.05	3.30	9
<b>76.20 mm Label Width</b>										
JET-25-107-3	3,000	Polyester	White	17	76.20	9.53	11.93	19.05	7.62	51
<b>215.90 mm Label Width</b>										
JET-26-107-25SH	25	Polyester	White	1	215.90	279.40	-	-	-	1
JET-26-113-25SH	25	Paper	White	1	215.90	279.40	-	-	-	1
JET-26-136-25SH	25	Polyester	Metallised	1	215.90	279.40	-	-	-	1

Tedlar® is registered trademark of DuPont

**Note:** Labels are sorted in order by width, height, 3 digit material number (within reference).

# Self-Laminating Wire and Cable Markers by Size

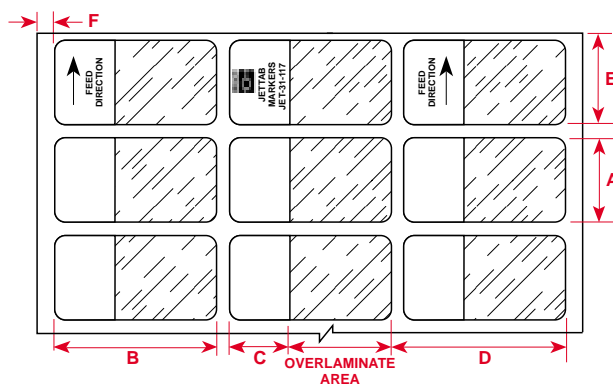

Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A mm	Label Height B mm	Write-On Height C mm	Horizontal Repeat D mm	Vertical Repeat E mm	Left Margin F mm	Labels Per Sheet	Max cable Diam. mm
<b>12.70 mm Label Width</b>												
JET-27-117-5	5,000	Vinyl	Vinyl/Transparent	16	12.70	19.05	9.53	25.40	15.24	10.80	128	3
JET-29-117-3	3,000	Vinyl	Vinyl/Transparent	16	12.70	34.93	12.70	40.64	15.24	10.80	80	7
<b>24.13 mm Label Width</b>												
JET-28-117-3	3,000	Vinyl	Vinyl/Transparent	9	24.13	19.05	9.53	25.40	26.67	10.80	72	3
JET-30-117-2	2,000	Vinyl	Vinyl/Transparent	9	24.13	34.93	12.70	40.64	26.67	10.80	45	7
JET-31-117-1	1,000	Vinyl	Vinyl/Transparent	9	24.13	57.15	19.05	66.67	26.67	10.80	27	12
JET-33-117-1	1,000	Vinyl	Vinyl/Transparent	9	24.13	95.25	25.40	101.60	26.67	10.70	18	22
<b>45.70 mm Label Width</b>												
JET-32-117-5	500	Vinyl	Vinyl/Transparent	5	45.70	57.15	19.05	66.67	48.26	10.80	15	12
JET-34-117-5	500	Vinyl	Vinyl/Transparent	5	45.70	95.25	24.40	101.60	48.26	10.80	10	22

**Note:** Labels are sorted in order by width, height, 3 digit material number (within reference).