




Catalog Number: LAT-14-747-1.5

LASERTAB® Laser Printable Labels

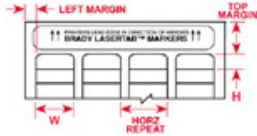

Description:

Blank, printable polyester labels for Laser Printers. This material is a UL recognized component and CSA accepted material when printed with designated laser printers. See UL file MH17154 and CSA Acceptance Record LS 41833 for specific details.

Specification:

Application(s): General & Industrial Identification, General ID, General Identification, Panel Identification, Through Hole - Top, Voice/Data Identification

Size: 1.875" W x 1.330" H (47.630 mm W x 33.780 mm H)

Sheet Size: 8.500" x 11.000" (215.9 mm x 279.4 mm)

Printable Area: 1.875" W x 0.833" H (47.630 mm W x 33.780 mm H)

Label Type/Style: Label

Horizontal Repeat: 2.000" (50.80 mm)

Color: White

Finish: Matte

Qty Per Row: 4

Material Type: Polyester

Material: Permanent Polyester

Description:

After Process: Yes, this material will work with this application

Left Margin: 0.315" (8.00 mm)

Printer: Laser Printers

Compatibility:

Qty Per Sheet: 28

Surface Mount Technology: No, this material does not work with this application

Top Margin: 0.834" (21.18 mm)

RoHS Compatibility: Compliant with RoHS Directive. NOTE: All statements concerning RoHS Directive compliance refer to 2005/618/EC MCV amendment to RoHS Directive 2002/95/EC. Product compliance is based upon information provided by suppliers of the raw materials used by Brady to manufacture these products, or by independent laboratory testing of these products. As such, Brady makes no independent representations or warranties, express or implied, and assumes no liability in connection with the use of this information.

QTY/UOM: 1,500/Package