

# TLS 2200® Label Rolls: General ID

www.BradyID.com/tls2200

## TLS 2200® General Identification Labels:

### B-423 Polyester Labels

Color: White Finish: Gloss

White polyester thermal transfer label with a glossy finish. Widely used for component identification, barcoding, asset and inventory tracking. UL rated for surfaces commonly used in solar panel manufacturing.

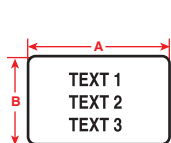


Figure 29

 


Figure 33

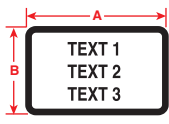


Figure 46  
(Includes black border)

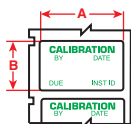


Figure 51

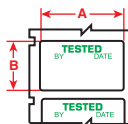


Figure 52

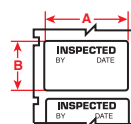


Figure 53

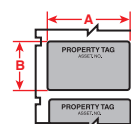


Figure 54

Diagram	Part Number	B-#	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Row	Labels Per Pkg	Rec. Ribbon
Fig. 29	PTL-1-423	423	Polyester	White	0.250 (6.4)	0.250 (6.4)	1	750	R6010
Fig. 29	PTL-3-423	423	Polyester	White	0.375 (9.5)	0.375 (9.5)	1	500	R6010
Fig. 29	PTL-4-423	423	Polyester	White	0.400 (10.6)	0.400 (10.2)	1	500	R6010
Fig. 29	BPTL-7-423	423	Polyester	White	0.500 (12.7)	0.500 (12.7)	1	5000	R6010
Fig. 29	PTL-5-423	423	Polyester	White	0.500 (12.7)	0.200 (5.1)	1	750	R6010
Fig. 53	PTL-6-423	423	Polyester	White	0.500 (12.7)	0.275 (7.0)	1	750	R6010
Fig. 29	PTL-7-423	423	Polyester	White	0.500 (12.7)	0.500 (12.7)	1	500	R6010
Fig. 33	PTL-8-423	423	Polyester	White	0.500 (12.7)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010
Fig. 29	PTL-9-423	423	Polyester	White	0.650 (16.5)	0.200 (5.1)	1	750	R6010
Fig. 29	PTL-10-423	423	Polyester	White	0.750 (19.1)	0.250 (6.4)	1	750	R6010
Fig. 29	PTL-13-423	423	Polyester	White	0.900 (22.9)	0.250 (6.4)	1	750	R6010
Fig. 29	BPTL-16-423	423	Polyester	White	1.000 (25.4)	0.375 (9.5)	1	5000	R6010
Fig. 29	BPTL-17-423	423	Polyester	White	1.000 (25.4)	0.500 (12.7)	1	5000	R6010
Fig. 29	BPTL-19-423	423	Polyester	White	1.000 (25.4)	1.000 (25.4)	1	2500	R6010
Fig. 29	BPTL-20-423	423	Polyester	White	1.000 (25.4)	2.000 (50.8)	1	1000	R6010
Fig. 29	PTL-14-423	423	Polyester	White	1.000 (25.4)	0.187 (4.8)	1	750	R6010
Fig. 29	PTL-15-423	423	Polyester	White	1.000 (25.4)	0.275 (7.0)	1	750	R6010
Fig. 29	PTL-16-423	423	Polyester	White	1.000 (25.4)	0.375 (9.5)	1	500	R6010
Fig. 29	PTL-17-423	423	Polyester	White	1.000 (25.4)	0.500 (12.7)	1	500	R6010
Fig. 29	PTL-19-423	423	Polyester	White	1.000 (25.4)	1.000 (25.4)	1	250	R6010
Fig. 46	PTL-24-423-BK	423	Polyester	White	1.130 (28.7)	0.500 (12.7)	1	500	R6010
Fig. 29	PTL-25-423	423	Polyester	White	1.250 (31.8)	0.250 (6.4)	1	750	R6010
Fig. 29	BPTL-29-423	423	Polyester	White	1.500 (38.1)	0.500 (12.7)	1	5000	R6010
Fig. 29	PTL-27-423	423	Polyester	White	1.500 (38.1)	0.125 (3.2)	1	750	R6010
Fig. 29	PTL-28-423	423	Polyester	White	1.500 (38.1)	0.250 (6.4)	1	750	R6010
Fig. 29	PTL-29-423	423	Polyester	White	1.500 (38.1)	0.500 (12.7)	1	500	R6010
Fig. 51	PTL-30-423-CALI	423	Polyester	White	1.500 (38.1)	0.750 (19.1)	1	250	R6010
Fig. 53	PTL-30-423-INSP	423	Polyester	Black on White	1.500 (38.1)	0.750 (19.1)	1	250	R6010
Fig. 52	PTL-30-423-TEST	423	Polyester	White	1.500 (38.1)	0.750 (19.1)	1	250	R6010
Fig. 29	PTL-31-423	423	Polyester	White	1.500 (38.1)	1.000 (25.4)	1	250	R6010
Fig. 29	PTL-32-423	423	Polyester	White	1.500 (38.1)	1.500 (38.1)	1	250	R6010
Fig. 54	PTL-35-423-PROP	423	Polyester	Black on Silver	1.630 (41.4)	0.750 (19.1)	1	250	R6010
Fig. 29	PTL-20-423	423	Polyester	White	2.000 (50.8)	1.000 (25.4)	1	100	R6010
Fig. 29	PTL-2-423	423	Polyester	White	2.000 (50.8)	0.250 (6.4)	1	100	R6010
Fig. 29	PTL-26-423	423	Polyester	White	2.750 (69.9)	1.250 (31.8)	1	100	R6010
Fig. 29	PTL-22-423	423	Polyester	White	3.000 (76.2)	1.000 (25.4)	1	100	R6010
Fig. 29	PTL-37-423	423	Polyester	White	3.000 (76.2)	1.900 (48.3)	1	100	R6010
Fig. 29	PTL-23-423	423	Polyester	White	4.000 (101.6)	1.000 (25.4)	1	100	R6010
Fig. 29	PTL-38-423	423	Polyester	White	4.000 (101.6)	1.900 (48.3)	1	100	R6010

See all TLS 2200® print ribbon parts on page 53 and full material descriptions on pages 164-170.