


TLS 2200® / TLS PC Link™ Label Index by Size

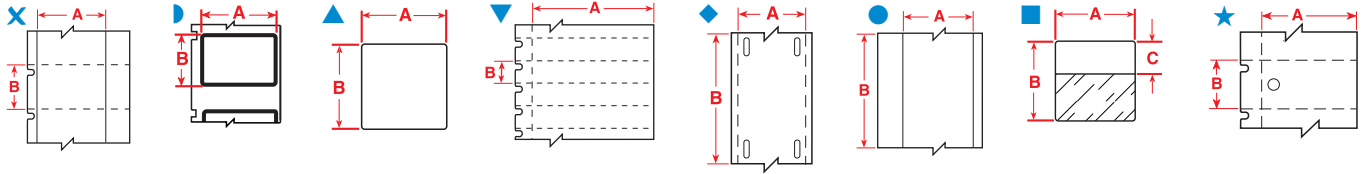

TLS 2200 / TLS PC LINK LABEL INDEX BY SIZE PORTABLE PRINTERS AND LABELS

Diagram	Part Number	Pieces Per Package	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Write-On Height C Inch (mm)	Maximum Characters Per Line For Font: 2	Maximum Lines Of Text For Font: 2
1.250" Label Width									
▲	PTL-25-423	750	Polyester	White	1.250 (31.75)	0.250 (6.35)		31	2
▲	PTL-25-426	750	Polyimide	Amber	1.250 (31.75)	0.250 (6.35)		31	2
▲	PTL-25-457	750	Polyimide	White	1.250 (31.75)	0.250 (6.35)		31	2
▲	PTL-25-477	750	Polyimide	White	1.250 (31.75)	0.250 (6.35)		31	2
▲	PTL-25-478	750	Polyimide	White	1.250 (31.75)	0.250 (6.35)		31	2
▲	PTL-25-479	750	Polyimide	White	1.250 (31.75)	0.250 (6.35)		31	2
▲	PTL-25-495	750	PEN	White	1.250 (31.75)	0.250 (6.35)		31	2
▲	PTL-112-490	500	Polyester	White	1.250 (31.75)	0.375 (9.53)		31	2
1.300" Label Width									
●	PTL-100-432	1	Polyester	Clear	1.300 (33.02)	50 ft (15.24 m)		31	2
●	PTL-100-483	1	Polyester	White	1.300 (33.02)	50 ft (15.24 m)		31	2
●	PTL-100-489	1	Polyester	White	1.300 (33.02)	50 ft (15.24 m)		31	2
1.375" Label Width									
▲	PTL-65-483	250	Polyester	White	1.375 (34.93)	1.00 (25.40)		35	10
1.500" Label Width									
▲	PTL-27-423	750	Polyester	White	1.500 (38.10)	0.125 (3.18)		37	1
▲	PTL-27-426	750	Polyimide	Amber	1.500 (38.10)	0.125 (3.18)		37	1
▲	PTL-27-457	750	Polyimide	White	1.500 (38.10)	0.125 (3.18)		37	1
▲	PTL-27-477	750	Polyimide	White	1.500 (38.10)	0.125 (3.18)		37	1
▲	PTL-27-478	750	Polyimide	White	1.500 (38.10)	0.125 (3.18)		37	1
▲	PTL-27-479	750	Polyimide	White	1.500 (38.10)	0.125 (3.18)		37	1
▲	PTL-27-495	750	PEN	White	1.500 (38.10)	0.125 (3.18)		37	1
▲	PTL-108-461	750	Self-laminating Polyester	Translucent	1.500 (38.10)	0.187 (4.75)	0.700 (17.78)	15	1
▲	PTL-28-423	750	Polyester	White	1.500 (38.10)	0.250 (6.35)		37	2
▲	PTL-28-426	750	Polyimide	Amber	1.500 (38.10)	0.250 (6.35)		37	2
▲	PTL-28-430	750	Polyester	Clear	1.500 (38.10)	0.250 (6.35)		37	2
▲	PTL-28-457	750	Polyimide	White	1.500 (38.10)	0.250 (6.35)		37	2
▲	PTL-28-473	750	Polyester	White	1.500 (38.10)	0.250 (6.35)		37	2
▲	PTL-28-477	750	Polyimide	White	1.500 (38.10)	0.250 (6.35)		37	2
▲	PTL-28-478	750	Polyimide	White	1.500 (38.10)	0.250 (6.35)		37	2
▲	PTL-28-479	750	Polyimide	White	1.500 (38.10)	0.250 (6.35)		37	2
▲	PTL-28-495	750	PEN	White	1.500 (38.10)	0.250 (6.35)		37	2
▲	PTL-45-422	500	Polyester	White	1.500 (38.10)	0.375 (9.53)		37	3
▲	PTL-45-430	500	Polyester	Clear	1.500 (38.10)	0.375 (9.53)		37	3
▲	PTL-29-422	500	Polyester	White	1.500 (38.10)	0.500 (12.70)		37	5
▲	PTL-29-423	500	Polyester	White	1.500 (38.10)	0.500 (12.70)		37	5
▲	BPTL-29-423	5000	Polyester	White	1.500 (38.10)	0.500 (12.70)		37	5
▲	PTL-29-428	500	Metallized	Silver	1.500 (38.10)	0.500 (12.70)		37	5
▲	PTL-29-430	500	Clear	Gloss	1.500 (38.10)	0.500 (12.70)		37	5
▲	PTL-29-434	500	Polyester	Metallized	1.500 (38.10)	0.500 (12.70)		37	5
▲	PTL-29-435	500	Polyester	Metallized	1.500 (38.10)	0.500 (12.70)		37	5
▲	PTL-29-437	500	Tedlar®	White	1.500 (38.10)	0.500 (12.70)		37	5
▲	PTL-29-459	500	Polyester	White	1.500 (38.10)	0.500 (12.70)		37	5
▲	PTL-29-483	500	Polyester	White	1.500 (38.10)	0.500 (12.70)		37	5
▲	PTL-29-486	500	Polyester	Silver	1.500 (38.10)	0.500 (12.70)		37	5
▲	PTL-29-489	500	Polyester	White	1.500 (38.10)	0.500 (12.70)		37	5
▲	PTL-29-498	500	Vinyl Cloth	White	1.500 (38.10)	0.500 (12.70)		11	16

Any label two inches or larger in width is rotated on liner.

Note: Labels in chart are sorted in order by width, height, 3 digit material number (within part number), then die number (within part number).