


Label Index by Size

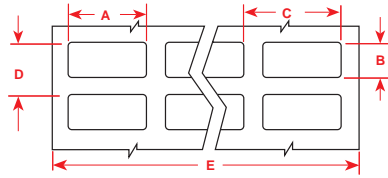

Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
0.650" Label Width										
THT-14-351-10	10,000	Tamper-Resistant Vinyl	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6202
THT-14-354-10	10,000	Polyester/Paper	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6202
THT-14-423-10	10,000	Polyester	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-423-10	10,000	Polyester	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-426-10	10,000	Polyimide	Amber	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R4300
THT-47-426-10	10,000	Polyimide	Amber	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R4311
THT-14-436-10	10,000	Removable Polyimide	Amber	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R4311
THT-14-437-10	10,000	Tedlar®	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R4311
THT-14-438-10	10,000	Tamper-Evident Polyester	Silver	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R4311
THT-14-457-10	10,000	Polyimide	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-457-10	10,000	Polyimide	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-459-10	10,000	Polyester	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-14-473-10	10,000	Polyester	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-473-10	10,000	Polyester	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-477-10	10,000	Polyimide	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-477-10	10,000	Polyimide	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-478-10	10,000	Polyimide	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-478-10	10,000	Polyimide	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-479-10	10,000	Polyimide	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-479-10	10,000	Polyimide	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-487-10	10,000	Polyimide	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-487-10	10,000	Polyimide	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-488-10	10,000	Polyester	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R4300
THT-14-495-10	10,000	PEN	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-495-10	10,000	PEN	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-497-10	10,000	Polyimide	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-497-10	10,000	Polyimide	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-498-10	10,000	Vinyl Cloth	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R4311
0.700" Label Width										
THT-57-423-10	10,000	Polyester	White	4	0.700 (17.78)	0.375 (9.53)	0.800 (20.32)	0.475 (12.07)	3.350 (85.09)	R6002
THT-57-426-10	10,000	Polyimide	Amber	4	0.700 (17.78)	0.375 (9.53)	0.800 (20.32)	0.475 (12.07)	3.350 (85.09)	R4300
THT-57-473-10	10,000	Polyester	White	4	0.700 (17.78)	0.375 (9.53)	0.800 (20.32)	0.475 (12.07)	3.350 (85.09)	R6002
THT-100-473-10	10,000	Polyester	White	1	0.700 (17.78)	0.375 (9.53)	—	0.475 (12.07)	0.900 (22.86)	R6011
0.750" Label Width										
THT-1-351-10	10,000	Tamper-Resistant Vinyl	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6202
THT-46-354-10	10,000	Polyester/Paper	White	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R6206
THT-1-423-10	10,000	Polyester	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-46-423-10	10,000	Polyester	White	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R6006
THT-1-426-10	10,000	Polyimide	Amber	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R4300
THT-46-426-10	10,000	Polyimide	Amber	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R4311
THT-1-428-10	10,000	Metallized Polyester	Silver	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R4300
THT-1-435-10	10,000	Glossy Metallized Polyester	Silver	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-1-436-10	10,000	Removable Polyimide	Amber	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R4300
THT-1-437-10	10,000	Tedlar	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R4300
THT-1-438-10	10,000	Tamper-Evident Polyester	Silver	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R4300
THT-1-457-10	10,000	Polyimide	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-46-457-10	10,000	Polyimide	White	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R6006
THT-1-459-10	10,000	Polyester	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-1-473-10	10,000	Polyester	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-46-473-10	10,000	Polyester	White	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R6006

Note: Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).
 Tedlar® is a registered trademark of DuPont.

LABEL INDEX BY SIZE THERMAL TRANSFER LABELS