


**Part Number: THT-5-425-10**

## Thermal Transfer Printable Labels

Printable, polypropylene labels for thermal transfer printers. Please Note: This material is UL & CSA approved with its respective ribbon.

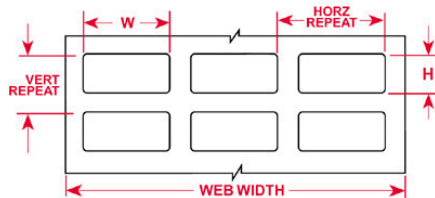

## Specifications:

<b>Size:</b>	1.000" W x 0.500" H (25.40 mm W x 12.70 mm H)
<b>Printable Area:</b>	1.000" W x 0.500" H (25.40 mm W x 12.70 mm H)
<b>Label Type/Style:</b>	Label
<b>Color:</b>	White
<b>Finish:</b>	Matte
<b>Material Type:</b>	Polypropylene
<b>Material Description:</b>	Permanent Polypropylene
<b>Adhesive:</b>	Acrylic
<b>Agency Approval(s)/Compliance:</b>	CSA Approved, Halogen-Free (DIN VDE 0472/parts 815), UL Recognized
<b>Special Properties:</b>	Excellent solvent resistance
<b>Vertical Repeat:</b>	0.600" (15.24 mm)
<b>Horizontal Repeat:</b>	1.075" (27.31 mm)
<b>Web Width:</b>	3.350" (85.09 mm)
<b>Application(s):</b>	General & Industrial Identification
<b>Recommended Ribbon Series:</b>	6200
<b>Printer Compatibility:</b>	Brady 1244, Brady 1344, Brady 200MVP Plus, Brady 2461, Brady 300MVP Plus, Brady 300X-Plus II, Brady 3481, Brady 360X-Plus II, Brady 600X-Plus II, Brady 6441, Brady BBP429, Brady IP™, Tagus™ T200, Tagus™ T300, Thermal Transfer Printers
<b>RoHS Compatibility:</b>	Compliant with RoHS Directive.

