


Label Index by Size

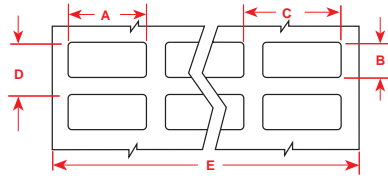

LABEL INDEX BY SIZE THERMAL TRANSFER LABELS

Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
1.000" Label Width (Cont.)										
THT-42-477-10	10,000	Polyimide	White	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (6.93)	1.200 (30.48)	R6006
THT-42-478-10	10,000	Polyimide	White	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (6.93)	1.200 (30.48)	R6006
THT-42-479-10	10,000	Polyimide	White	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (6.93)	1.200 (30.48)	R6006
THT-42-487-10	10,000	Polyimide	White	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (6.93)	1.200 (30.48)	R6006
THT-42-495-10	10,000	PEN	White	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (6.93)	1.200 (30.48)	R6006
THT-42-497-10	10,000	Polyimide	White	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (6.93)	1.200 (30.48)	R6006
THT-51-423-10	10,000	Polyester	White	3	1.000 (25.40)	0.250 (6.35)	1.075 (27.31)	0.375 (9.53)	3.350 (85.09)	R6002
THT-103-423-10	10,000	Polyester	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-51-426-10	10,000	Polyimide	Amber	3	1.000 (25.40)	0.250 (6.35)	1.075 (27.31)	0.375 (9.53)	3.350 (85.09)	R4300
THT-103-426-10	10,000	Polyimide	Amber	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R4306
THT-103-457-10	10,000	Polyimide	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-103-473-10	10,000	Polyester	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-103-477-10	10,000	Polyimide	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-103-495-10	10,000	PEN	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-103-478-10	10,000	Polyimide	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-103-479-10	10,000	Polyimide	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-103-487-10	10,000	Polyimide	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-103-497-10	10,000	Polyimide	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-3-422-10	10,000	Polyester	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6002
THT-3-423-10	10,000	Polyester	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6002
THT-3-426-10	10,000	Polyimide	Amber	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R4300
THT-3-428-10	10,000	Metallized Polyester	Silver	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R4300
THT-3-430-10	10,000	Polyester	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6002
THT-58-457-10	10,000	Polyimide	White	1	1.000 (25.40)	0.375 (9.53)	—	0.475 (12.07)	1.200 (30.48)	R6006
THT-3-473-10	10,000	Polyester	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6002
THT-58-473-10	10,000	Polyester	White	1	1.000 (25.40)	0.375 (9.53)	—	0.475 (12.07)	1.200 (30.48)	R6006
THT-3-478-10	10,000	Polyimide	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6002
THT-58-478-10	10,000	Polyimide	White	1	1.000 (25.40)	0.375 (9.53)	—	0.475 (12.07)	1.200 (30.48)	R6006
THT-3-479-10	10,000	Polyimide	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6002
THT-58-479-10	10,000	Polyimide	White	1	1.000 (25.40)	0.375 (9.53)	—	0.475 (12.07)	1.200 (30.48)	R6006
THT-3-495-10	10,000	PEN	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6002
THT-58-495-10	10,000	PEN	White	1	1.000 (25.40)	0.375 (9.53)	—	0.475 (12.07)	1.200 (30.48)	R6006
THT-152-499-3	3,000	Nylon Cloth	White	2	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	2.300 (58.42)	R4306
THT-163-499-3	3,000	Nylon Cloth	White	1	1.000 (25.40)	0.375 (9.53) dia.	—	0.875 (22.22)	1.675 (42.55)	R4306
XHT-3-8423-10	10,000	Polyester	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6206
THT-5-351-10	10,000	Tamper-Resistant Vinyl	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6202
THT-59-351-10	10,000	Tamper-Resistant Vinyl	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6206
THT-5-352-10	10,000	Tamper-Resistant Vinyl	Silver	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-59-352-10	10,000	Tamper-Resistant Vinyl	Silver	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6006
THT-59-354-10	10,000	Polyester/Paper	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6206
THT-39-358-10	10,000	Tamper-Resistant Acetate	Clear	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.625 (15.88)	3.350 (85.09)	R6202
THT-59-359-10	10,000	Tamper-Resistant Acetate	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6206
THT-5-422-10	10,000	Polyester	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-5-423-10	10,000	Polyester	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-59-423-10	10,000	Polyester	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6006
THT-5-426-10	10,000	Polyimide	Amber	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R4300
THT-5-428-10	10,000	Metallized Polyester	Silver	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R4300
THT-39-430-10	10,000	Polyester	Clear	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.625 (15.88)	3.350 (85.09)	R6002
THT-5-433-10	10,000	Removable Polyester	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-5-434-10	10,000	Metallized Polyester	Silver	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-5-435-10	10,000	Glossy Metallized Polyester	Silver	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-5-437-10	10,000	Tedlar®	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R4300
THT-5-437-10-YL	10,000	Tedlar	Yellow	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R4300
THT-5-438-10	10,000	Tamper-Evident Polyester	Silver	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R4300

Note: Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).

Tedlar® is a registered trademark of DuPont.