


**THTHD-108-426-2.5**

Thermal Transfer technology  
Die # 108, 0.150" x 1.500"  
Package Quantity, 2,500  
Material B-426, White Vinyl Cloth

**PART NUMBER EXPLANATION:**

Most Brady part numbers for printable labels follow the same four-part format:

The first code indicates the technology, the second part is a number indicating the die size used (where applicable), the third part indicates the Brady material used (where applicable), and the final code indicates package quantity.

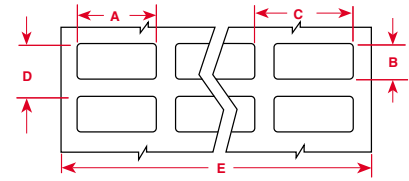


Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
<b>0.150" Label Width</b>										
THTHD-108-426-2.5*	2,500	Polyimide	Amber	1	0.150 (3.81)	1.500 (38.10)	—	1.600 (40.64)	0.450 (11.43)	R4311
THTHD-108-457-2.5*	2,500	Polyimide	White	1	0.150 (3.81)	1.500 (38.10)	—	1.600 (40.64)	0.450 (11.43)	R6011
THTHD-108-477-2.5*	2,500	Polyimide	White	1	0.150 (3.81)	1.500 (38.10)	—	1.600 (40.64)	0.450 (11.43)	R6011
THTHD-108-478-2.5*	2,500	Polyimide	White	1	0.150 (3.81)	1.500 (38.10)	—	1.600 (40.64)	0.450 (11.43)	R6011
THTHD-108-487-2.5*	2,500	Polyimide	White	1	0.150 (3.81)	1.500 (38.10)	—	1.600 (40.64)	0.450 (11.43)	R6011
THTHD-108-495-2.5*	2,500	PEN	White	1	0.150 (3.81)	1.500 (38.10)	—	1.600 (40.64)	0.450 (11.43)	R6011
<b>0.187" Label Width</b>										
THTHD-42-426-4*	4,000	Polyimide	Amber	1	0.187 (4.75)	1.000 (25.40)	—	1.100 (27.94)	0.450 (11.43)	R4311
THTHD-42-457-4*	4,000	Polyimide	White	1	0.187 (4.75)	1.000 (25.40)	—	1.100 (27.94)	0.450 (11.43)	R6011
THTHD-42-477-4*	4,000	Polyimide	White	1	0.187 (4.75)	1.000 (25.40)	—	1.100 (27.94)	0.450 (11.43)	R6011
THTHD-42-478-4*	4,000	Polyimide	White	1	0.187 (4.75)	1.000 (25.40)	—	1.100 (27.94)	0.450 (11.43)	R6011
THTHD-42-487-4*	4,000	Polyimide	White	1	0.187 (4.75)	1.000 (25.40)	—	1.100 (27.94)	0.450 (11.43)	R6011
THTHD-42-495-4*	4,000	PEN	White	1	0.187 (4.75)	1.000 (25.40)	—	1.100 (27.94)	0.450 (11.43)	R6011
<b>0.200" Label Width</b>										
THTHD-47-426-5.5*	5,500	Polyimide	Amber	1	0.200 (5.08)	0.650 (16.51)	—	0.725 (18.42)	0.450 (11.43)	R4311
THTHD-47-457-5.5*	5,500	Polyimide	White	1	0.200 (5.08)	0.650 (16.51)	—	0.725 (18.42)	0.450 (11.43)	R6011
THTHD-47-477-5.5*	5,500	Polyimide	White	1	0.200 (5.08)	0.650 (16.51)	—	0.725 (18.42)	0.450 (11.43)	R6011
THTHD-47-478-5.5*	5,500	Polyimide	White	1	0.200 (5.08)	0.650 (16.51)	—	0.725 (18.42)	0.450 (11.43)	R6011
THTHD-47-487-5.5*	5,500	Polyimide	White	1	0.200 (5.08)	0.650 (16.51)	—	0.725 (18.42)	0.450 (11.43)	R6011
THTHD-47-495-5.5*	5,500	PEN	White	1	0.200 (5.08)	0.650 (16.51)	—	0.725 (18.42)	0.450 (11.43)	R6011
<b>0.240" Label Width</b>										
THT-94-498-2	1	Vinyl Cloth	White	1	0.240 (6.10)	165 ft (50.80 m)	—	—	1000 (25.40)	R4311
<b>0.250" Label Width</b>										
THT-70-350-5	5,000	Polyester/Paper	White	7	0.250 (6.35)	0.250 (6.35)	0.320 (8.13)	0.350 (8.89)	2.370 (60.20)	R6000
THT-70-350-20	20,000	Polyester/Paper	White	7	0.250 (6.35)	0.250 (6.35)	0.320 (8.13)	0.350 (8.89)	2.370 (60.20)	R6000
THT-70-354-20	20,000	Polyester/Paper	White	7	0.250 (6.35)	0.250 (6.35)	0.320 (8.13)	0.350 (8.89)	2.370 (60.20)	R6200
THT-11-423-10	10,000	Polyester	White	12	0.250 (6.35)	0.250 (6.35)	0.250 (6.35)	0.375 (9.53)	3.200 (81.28)	R6002
THT-11-426-10	10,000	Polyimide	Amber	12	0.250 (6.35)	0.250 (6.35)	0.250 (6.35)	0.375 (9.53)	3.200 (81.28)	R4300
THTHD-70-426-12*	12,000	Polyimide	Amber	1	0.250 (6.35)	0.250 (6.35)	—	0.350 (8.89)	0.450 (11.43)	R4311
THT-11-436-10	10,000	Polyimide	Amber	12	0.250 (6.35)	0.250 (6.35)	0.250 (6.35)	0.375 (9.53)	3.200 (81.28)	R4300
THT-11-457-10	10,000	Polyimide	White	12	0.250 (6.35)	0.250 (6.35)	0.250 (6.35)	0.375 (9.53)	3.200 (81.28)	R6002
THT-70-457-20	20,000	Polyimide	White	7	0.250 (6.35)	0.250 (6.35)	0.320 (8.13)	0.350 (8.89)	2.370 (60.20)	R6000
THTHD-70-457-12*	12,000	Polyimide	White	1	0.250 (6.35)	0.250 (6.35)	—	0.350 (8.89)	0.450 (11.43)	R6011
THT-11-473-10	10,000	Polyester	White	12	0.250 (6.35)	0.250 (6.35)	0.250 (6.35)	0.375 (9.53)	3.200 (81.28)	R6002
THT-70-473-20	20,000	Polyester	White	7	0.250 (6.35)	0.250 (6.35)	0.320 (8.13)	0.350 (8.89)	2.370 (60.20)	R6000
THT-70-477-20	20,000	Polyimide	White	7	0.250 (6.35)	0.250 (6.35)	0.320 (8.13)	0.350 (8.89)	2.370 (60.20)	R6000
THTHD-70-477-12*	12,000	Polyimide	White	1	0.250 (6.35)	0.250 (6.35)	—	0.350 (8.89)	0.450 (11.43)	R6011
THT-70-478-20	20,000	Polyimide	White	7	0.250 (6.35)	0.250 (6.35)	0.320 (8.13)	0.350 (8.89)	2.370 (60.20)	R6000
THTHD-70-478-12*	12,000	Polyimide	White	1	0.250 (6.35)	0.250 (6.35)	—	0.350 (8.89)	0.450 (11.43)	R6011
THT-70-479-20	20,000	Polyimide	White	7	0.250 (6.35)	0.250 (6.35)	0.320 (8.13)	0.350 (8.89)	2.370 (60.20)	R6000
THT-70-487-20	20,000	Polyimide	White	7	0.250 (6.35)	0.250 (6.35)	0.320 (8.13)	0.350 (8.89)	2.370 (60.20)	R6000
THTHD-70-487-12*	12,000	Polyimide	White	1	0.250 (6.35)	0.250 (6.35)	—	0.350 (8.89)	0.450 (11.43)	R6011
THT-70-495-20	20,000	PEN	White	7	0.250 (6.35)	0.250 (6.35)	0.320 (8.13)	0.350 (8.89)	2.370 (60.20)	R6000
THTHD-70-495-12*	12,000	PEN	White	1	0.250 (6.35)	0.250 (6.35)	—	0.350 (8.89)	0.450 (11.43)	R6011
THT-70-497-20	20,000	Polyimide	White	7	0.250 (6.35)	0.250 (6.35)	0.320 (8.13)	0.350 (8.89)	2.370 (60.20)	R6000
THTHD-46-426-5*	5,000	Polyimide	Amber	1	0.250 (6.35)	0.750 (18.75)	—	0.850 (21.59)	0.450 (11.43)	R4311
THTHD-46-457-5*	5,000	Polyimide	White	1	0.250 (6.35)	0.750 (18.75)	—	0.850 (21.59)	0.450 (11.43)	R6011
THTHD-46-477-5*	5,000	Polyimide	White	1	0.250 (6.35)	0.750 (18.75)	—	0.850 (21.59)	0.450 (11.43)	R6011
THTHD-46-478-5*	5,000	Polyimide	White	1	0.250 (6.35)	0.750 (18.75)	—	0.850 (21.59)	0.450 (11.43)	R6011
THTHD-46-487-5*	5,000	Polyimide	White	1	0.250 (6.35)	0.750 (18.75)	—	0.850 (21.59)	0.450 (11.43)	R6011
THTHD-46-495-5*	5,000	PEN	White	1	0.250 (6.35)	0.750 (18.75)	—	0.850 (21.59)	0.450 (11.43)	R6011
THTHD-49-426-4.5*	4,500	Polyimide	Amber	1	0.250 (6.35)	0.900 (22.86)	—	1.000 (25.40)	0.450 (11.43)	R4311

**Note:** Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).

\*For use with Hover-Davis vertical format label feeders.

Label Index by Size

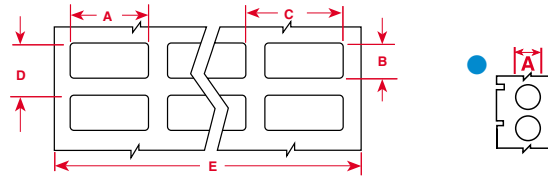


LABEL INDEX BY SIZE THERMAL TRANSFER LABELS

Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
<b>0.250" Label Width (Cont.)</b>										
THTHD-49-457-4.5*	4,500	Polyimide	White	1	0.250 (6.35)	0.900 (22.86)	—	1.000 (25.40)	0.450 (11.43)	R6011
THTHD-49-477-4.5*	4,500	Polyimide	White	1	0.250 (6.35)	0.900 (22.86)	—	1.000 (25.40)	0.450 (11.43)	R6011
THTHD-49-478-4.5*	4,500	Polyimide	White	1	0.250 (6.35)	0.900 (22.86)	—	1.000 (25.40)	0.450 (11.43)	R6011
THTHD-49-487-4.5*	4,500	Polyimide	White	1	0.250 (6.35)	0.900 (22.86)	—	1.000 (25.40)	0.450 (11.43)	R6011
THTHD-49-495-4.5*	4,500	PEN	White	1	0.250 (6.35)	0.900 (22.86)	—	1.000 (25.40)	0.450 (11.43)	R6011
THTHD-103-426-4*	4,000	Polyimide	Amber	1	0.250 (6.35)	1.000 (25.40)	—	1.100 (27.94)	0.450 (11.43)	R4311
THTHD-103-457-4*	4,000	Polyimide	White	1	0.250 (6.35)	1.000 (25.40)	—	1.100 (27.94)	0.450 (11.43)	R6011
THTHD-103-477-4*	4,000	Polyimide	White	1	0.250 (6.35)	1.000 (25.40)	—	1.100 (27.94)	0.450 (11.43)	R6011
THTHD-103-478-4*	4,000	Polyimide	White	1	0.250 (6.35)	1.000 (25.40)	—	1.100 (27.94)	0.450 (11.43)	R6011
THTHD-103-487-4*	4,000	Polyimide	White	1	0.250 (6.35)	1.000 (25.40)	—	1.100 (27.94)	0.450 (11.43)	R6011
THTHD-103-495-4*	4,000	PEN	White	1	0.250 (6.35)	1.000 (25.40)	—	1.100 (27.94)	0.450 (11.43)	R6011
THTHD-43-426-3.5*	3,500	Polyimide	Amber	1	0.250 (6.35)	1.250 (31.75)	—	1.350 (34.29)	0.450 (11.43)	R4311
THTHD-43-457-3.5*	3,500	Polyimide	White	1	0.250 (6.35)	1.250 (31.75)	—	1.350 (34.29)	0.450 (11.43)	R6011
THTHD-43-477-3.5*	3,500	Polyimide	White	1	0.250 (6.35)	1.250 (31.75)	—	1.350 (34.29)	0.450 (11.43)	R6011
THTHD-43-478-3.5*	3,500	Polyimide	White	1	0.250 (6.35)	1.250 (31.75)	—	1.350 (34.29)	0.450 (11.43)	R6011
THTHD-43-487-3.5*	3,500	Polyimide	White	1	0.250 (6.35)	1.250 (31.75)	—	1.350 (34.29)	0.450 (11.43)	R6011
THTHD-43-495-3.5*	3,500	PEN	White	1	0.250 (6.35)	1.250 (31.75)	—	1.350 (34.29)	0.450 (11.43)	R6011
THTHD-44-426-3*	4,000	Polyimide	Amber	1	0.250 (6.35)	1.375 (34.93)	—	1.475 (37.47)	0.450 (11.43)	R4311
THTHD-44-457-3*	3,000	Polyimide	White	1	0.250 (6.35)	1.375 (34.93)	—	1.475 (37.47)	0.450 (11.43)	R6011
THTHD-44-477-3*	3,000	Polyimide	White	1	0.250 (6.35)	1.375 (34.93)	—	1.475 (37.47)	0.450 (11.43)	R6011
THTHD-44-478-3*	3,000	Polyimide	White	1	0.250 (6.35)	1.375 (34.93)	—	1.475 (37.47)	0.450 (11.43)	R6011
THTHD-44-487-3*	3,000	Polyimide	White	1	0.250 (6.35)	1.375 (34.93)	—	1.475 (37.47)	0.450 (11.43)	R6011
THTHD-44-495-3*	3,000	PEN	White	1	0.250 (6.35)	1.375 (34.93)	—	1.475 (37.47)	0.450 (11.43)	R6011
THT-90-498-5	5,000	Vinyl Cloth	White	6	0.250 (6.35)	1.437 (36.50)	0.350 (8.89)	1.562 (39.68)	2.200 (55.88)	R4300
THTHD-45-426-2.5*	2,500	Polyimide	Amber	1	0.250 (6.35)	1.500 (38.10)	—	1.600 (40.64)	0.450 (11.43)	R4311
THTHD-45-457-2.5*	2,500	Polyimide	White	1	0.250 (6.35)	1.500 (38.10)	—	1.600 (40.64)	0.450 (11.43)	R6011
THTHD-45-477-2.5*	2,500	Polyimide	White	1	0.250 (6.35)	1.500 (38.10)	—	1.600 (40.64)	0.450 (11.43)	R6011
THTHD-45-478-2.5*	2,500	Polyimide	White	1	0.250 (6.35)	1.500 (38.10)	—	1.600 (40.64)	0.450 (11.43)	R6011
THTHD-45-487-2.5*	2,500	Polyimide	White	1	0.250 (6.35)	1.500 (38.10)	—	1.600 (40.64)	0.450 (11.43)	R6011
THTHD-45-495-2.5*	2,500	PEN	White	1	0.250 (6.35)	1.500 (38.10)	—	1.600 (40.64)	0.450 (11.43)	R6011
<b>0.315" Label Width</b>										
THT-104-354-20	20,000	Polyester/Paper	White	6	0.315 (8.00)	0.177 (4.50)	0.375 (9.53)	0.278 (7.06)	2.39 (60.71)	R6200
THT-104-497-20	20,000	Polyimide	White	6	0.315 (8.00)	0.177 (4.50)	0.375 (9.53)	0.278 (7.06)	2.39 (60.71)	R6000
THT-71-457-20	20,000	Polyimide	White	6	0.315 (8.00)	0.315 (8.00)	0.375 (9.53)	0.415 (10.54)	2.39 (60.71)	R6000
THT-71-478-20	20,000	Polyimide	White	6	0.315 (8.00)	0.315 (8.00)	0.375 (9.53)	0.415 (10.54)	2.39 (60.71)	R6000
THT-71-479-20	20,000	Polyimide	White	6	0.315 (8.00)	0.315 (8.00)	0.375 (9.53)	0.415 (10.54)	2.39 (60.71)	R6000
THT-71-495-20	20,000	PEN	White	6	0.315 (8.00)	0.315 (8.00)	0.375 (9.53)	0.415 (10.54)	2.39 (60.71)	R6000
<b>0.318" Label Width</b>										
THT-93-498-2	1	Vinyl Cloth	White	1	0.318 (8.08)	165 ft (50.80 m)	—	—	1.000 (25.40)	R4311
<b>0.375" Label Width</b>										
THT-143-499-3●	3,000	Nylon Cloth	White	4	0.375 (9.53) dia.	—	0.475 (12.07)	0.500 (12.70)	2.000 (50.80)	R4302
THT-38-423-10	10,000	Polyester	White	7	0.375 (9.53)	0.375 (9.53)	0.437 (11.10)	0.475 (12.07)	3.200 (81.28)	R6002
THT-38-426-10	10,000	Polyimide	Amber	7	0.375 (9.53)	0.375 (9.53)	0.437 (11.10)	0.475 (12.07)	3.200 (81.28)	R4300
THT-38-457-10	10,000	Polyimide	White	7	0.375 (9.53)	0.375 (9.53)	0.437 (11.10)	0.475 (12.07)	3.200 (81.28)	R6002
THT-38-473-10	10,000	Polyester	White	7	0.375 (9.53)	0.375 (9.53)	0.437 (11.10)	0.475 (12.07)	3.200 (81.28)	R6002
THT-38-477-10	10,000	Polyimide	White	7	0.375 (9.53)	0.375 (9.53)	0.437 (11.10)	0.475 (12.07)	3.200 (81.28)	R6002
THT-38-478-10	10,000	Polyimide	White	7	0.375 (9.53)	0.375 (9.53)	0.437 (11.10)	0.475 (12.07)	3.200 (81.28)	R6002
THT-38-479-10	10,000	Polyimide	White	7	0.375 (9.53)	0.375 (9.53)	0.437 (11.10)	0.475 (12.07)	3.200 (81.28)	R6002
THT-38-487-10	10,000	Polyimide	White	7	0.375 (9.53)	0.375 (9.53)	0.437 (11.10)	0.475 (12.07)	3.200 (81.28)	R6002
THT-38-495-10	10,000	PEN	White	7	0.375 (9.53)	0.375 (9.53)	0.437 (11.10)	0.475 (12.07)	3.200 (81.28)	R6002
THT-38-497-10	10,000	Polyimide	White	7	0.375 (9.53)	0.375 (9.53)	0.437 (11.10)	0.475 (12.07)	3.200 (81.28)	R6002
THT-92-498-2	1	Vinyl Cloth	White	1	0.375 (9.53)	165 ft (50.80 m)	—	—	1.000 (25.40)	R4311

**Note:** Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).


\*For use with Hover-Davis vertical format label feeders.

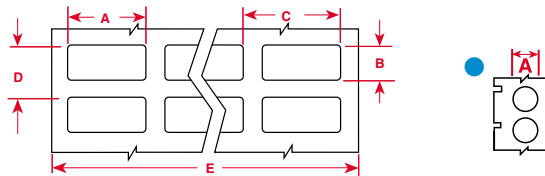

Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
<b>0.500" Label Width</b>										
THT-144-499-3●	3,000	Nylon Cloth	White	3	0.500 (12.70)	dia.	0.600 (15.24)	0.625 (15.88)	1.900 (48.26)	R4302
THT-36-422-10	10,000	Polyester	White	5	0.500 (12.70)	0.200 (5.08)	0.625 (15.88)	0.300 (7.62)	3.200 (81.28)	R6002
THT-36-423-10	10,000	Polyester	White	5	0.500 (12.70)	0.200 (5.08)	0.625 (15.88)	0.300 (7.62)	3.200 (81.28)	R6002
THT-36-473-10	10,000	Polyester	White	5	0.500 (12.70)	0.200 (5.08)	0.625 (15.88)	0.300 (7.62)	3.200 (81.28)	R6002
THT-97-423-10	10,000	Polyester	White	1	0.500 (12.70)	0.200 (5.08)	—	0.300 (7.62)	0.700 (17.78)	R6011
THT-97-457-10	10,000	Polyimide	White	1	0.500 (12.70)	0.200 (5.08)	—	0.300 (7.62)	0.700 (17.78)	R6011
THT-97-473-10	10,000	Polyester	White	1	0.500 (12.70)	0.200 (5.08)	—	0.300 (7.62)	0.700 (17.78)	R6011
THT-97-477-10	10,000	Polyimide	White	1	0.500 (12.70)	0.200 (5.08)	—	0.300 (7.62)	0.700 (17.78)	R6011
THT-97-478-10	10,000	Polyimide	White	1	0.500 (12.70)	0.200 (5.08)	—	0.300 (7.62)	0.700 (17.78)	R6011
THT-97-479-10	10,000	Polyimide	White	1	0.500 (12.70)	0.200 (5.08)	—	0.300 (7.62)	0.700 (17.78)	R6011
THT-97-487-10	10,000	Polyimide	White	1	0.500 (12.70)	0.200 (5.08)	—	0.300 (7.62)	0.700 (17.78)	R6011
THT-97-495-10	10,000	PEN	White	1	0.500 (12.70)	0.200 (5.08)	—	0.300 (7.62)	0.700 (17.78)	R6011
THT-97-497-10	10,000	Polyimide	White	1	0.500 (12.70)	0.200 (5.08)	—	0.300 (7.62)	0.700 (17.78)	R6011
THT-96-354-10	10,000	Polyester/Paper	White	4	0.500 (12.70)	0.275 (6.99)	0.600 (15.24)	0.375 (9.53)	2.500 (63.50)	R6200
THT-96-473-10	10,000	Polyester	White	4	0.500 (12.70)	0.275 (6.99)	0.600 (15.24)	0.375 (9.53)	2.500 (63.50)	R6000
THT-96-477-10	10,000	Polyimide	White	4	0.500 (12.70)	0.275 (6.99)	0.600 (15.24)	0.375 (9.53)	2.500 (63.50)	R6000
THT-96-487-10	10,000	Polyimide	White	4	0.500 (12.70)	0.275 (6.99)	0.600 (15.24)	0.375 (9.53)	2.500 (63.50)	R6000
THT-96-497-10	10,000	Polyimide	White	4	0.500 (12.70)	0.275 (6.99)	0.600 (15.24)	0.375 (9.53)	2.500 (63.50)	R6000
THT-148-422-10	10,000	Polyester	White	4	0.500 (12.70)	0.375 (9.50)	0.600 (15.24)	0.475 (12.07)	2.500 (63.50)	R6002
THT-148-430-10	10,000	Polyester	Clear	4	0.500 (12.70)	0.375 (9.50)	0.600 (15.24)	0.500 (12.70)	2.500 (63.50)	R6002
THT-12-351-10	10,000	Tamper-Resistant Vinyl	White	5	0.500 (12.70)	0.437 (11.10)	0.662 (16.81)	0.537 (13.64)	3.350 (85.09)	R6202
THT-12-423-10	10,000	Polyester	White	5	0.500 (12.70)	0.437 (11.10)	0.662 (16.81)	0.537 (13.64)	3.350 (85.09)	R6002
THT-12-426-10	10,000	Polyimide	Amber	5	0.500 (12.70)	0.437 (11.10)	0.662 (16.81)	0.537 (13.64)	3.350 (85.09)	R4300
THT-12-428-10	10,000	Metallized Polyester	Silver	5	0.500 (12.70)	0.437 (11.10)	0.662 (16.81)	0.537 (13.64)	3.350 (85.09)	R4300
THT-12-433-10	10,000	Removable Polyester	White	5	0.500 (12.70)	0.437 (11.10)	0.662 (16.81)	0.537 (13.64)	3.350 (85.09)	R6002
THT-12-435-10	10,000	Glossy Metallized Polyester	Silver	5	0.500 (12.70)	0.437 (11.10)	0.662 (16.81)	0.537 (13.64)	3.350 (85.09)	R6002
THT-12-438-10	10,000	Tamper-Evident Polyester	Silver	5	0.500 (12.70)	0.437 (11.10)	0.662 (16.81)	0.537 (13.64)	3.350 (85.09)	R4300
THT-12-457-10	10,000	Polyimide	White	5	0.500 (12.70)	0.437 (11.10)	0.662 (16.81)	0.537 (13.64)	3.350 (85.09)	R6002
THT-12-473-10	10,000	Polyester	White	5	0.500 (12.70)	0.437 (11.10)	0.662 (16.81)	0.537 (13.64)	3.350 (85.09)	R6002
THT-12-477-10	10,000	Polyimide	White	5	0.500 (12.70)	0.437 (11.10)	0.662 (16.81)	0.537 (13.64)	3.350 (85.09)	R6002
THT-12-478-10	10,000	Polyimide	White	5	0.500 (12.70)	0.437 (11.10)	0.662 (16.81)	0.537 (13.64)	3.350 (85.09)	R6002
THT-12-479-10	10,000	Polyimide	White	5	0.500 (12.70)	0.437 (11.10)	0.662 (16.81)	0.537 (13.64)	3.350 (85.09)	R6002
THT-12-487-10	10,000	Polyimide	White	5	0.500 (12.70)	0.437 (11.10)	0.662 (16.81)	0.537 (13.64)	3.350 (85.09)	R6002
THT-12-495-10	10,000	PEN	White	5	0.500 (12.70)	0.437 (11.10)	0.662 (16.81)	0.537 (13.64)	3.350 (85.09)	R6002
THT-12-497-10	10,000	Polyimide	White	5	0.500 (12.70)	0.437 (11.10)	0.662 (16.81)	0.537 (13.64)	3.350 (85.09)	R6002
THT-149-358-10	10,000	Tamper-Resistant Acetate	Clear	4	0.500 (12.70)	0.500 (12.70)	0.600 (15.24)	0.600 (15.24)	2.500 (63.50)	R6202
THT-99-359-10	10,000	Tamper-Resistant Acetate	White	4	0.500 (12.70)	0.500 (12.70)	—	0.600 (15.24)	0.700 (17.78)	R6211
THT-149-422-10	10,000	Polyester	White	4	0.500 (12.70)	0.500 (12.70)	0.600 (15.24)	0.600 (15.24)	2.500 (63.50)	R6002
THT-149-430-10	10,000	Polyester	Clear	4	0.500 (12.70)	0.500 (12.70)	0.600 (15.24)	0.605 (15.38)	2.500 (63.50)	R6002
THT-99-473-10	10,000	Polyimide	White	1	0.500 (12.70)	0.500 (12.70)	—	0.600 (15.24)	0.700 (17.78)	R6011
THT-99-477-10	10,000	Polyimide	White	1	0.500 (12.70)	0.500 (12.70)	—	0.600 (15.24)	0.700 (17.78)	R6011
THT-99-478-10	10,000	Polyimide	White	1	0.500 (12.70)	0.500 (12.70)	—	0.600 (15.24)	0.700 (17.78)	R6011
THT-99-479-10	10,000	Polyimide	White	1	0.500 (12.70)	0.500 (12.70)	—	0.600 (15.24)	0.700 (17.78)	R6011
THT-99-487-10	10,000	Polyimide	White	1	0.500 (12.70)	0.500 (12.70)	—	0.600 (15.24)	0.700 (17.78)	R6011
THT-99-495-10	10,000	PEN	White	1	0.500 (12.70)	0.500 (12.70)	—	0.600 (15.24)	0.700 (17.78)	R6011
THT-99-497-10	10,000	Polyimide	White	1	0.500 (12.70)	0.500 (12.70)	—	0.600 (15.24)	0.700 (17.78)	R6011
THT-149-7566-10	10,000	Tamper-Evident Polyester	Clear	4	0.500 (12.70)	0.500 (12.70)	0.600 (15.24)	0.600 (15.24)	2.500 (63.50)	R6002
THT-68-498-10	10,000	Vinyl Cloth	White	4	0.500 (12.70)	0.750 (19.05)	0.600 (15.24)	0.850 (21.59)	2.500 (63.50)	R4300
THT-68-499-10	10,000	Nylon Cloth	White	4	0.500 (12.70)	0.750 (19.05)	0.600 (15.24)	0.850 (21.59)	2.500 (63.50)	R4902
THT-87-498-10	10,000	Vinyl Cloth	White	6	0.500 (12.70)	1.440 (36.50)	0.600 (15.24)	1.562 (39.68)	3.700 (93.98)	R4300
<b>0.590" Label Width</b>										
DSTHT-15-390-1	1,000	Polypropylene	White	1	0.590 (15.00)	0.163 (4.14)	—	0.402 (10.21)	—	R6200
DSTHT-15-390-2.5	2,500	Polypropylene	White	1	0.590 (15.00)	0.163 (4.14)	—	0.402 (10.21)	—	R6200

Note: Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).


Label Index by Size

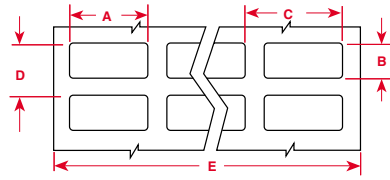

Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
<b>0.650" Label Width</b>										
THT-14-351-10	10,000	Tamper-Resistant Vinyl	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6202
THT-14-354-10	10,000	Polyester/Paper	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6202
THT-14-423-10	10,000	Polyester	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-423-10	10,000	Polyester	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-426-10	10,000	Polyimide	Amber	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R4300
THT-47-426-10	10,000	Polyimide	Amber	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R4311
THT-14-436-10	10,000	Removable Polyimide	Amber	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R4311
THT-14-437-10	10,000	Tedlar®	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R4311
THT-14-438-10	10,000	Tamper-Evident Polyester	Silver	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R4311
THT-14-457-10	10,000	Polyimide	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-457-10	10,000	Polyimide	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-459-10	10,000	Polyester	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-14-473-10	10,000	Polyester	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-473-10	10,000	Polyester	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-477-10	10,000	Polyimide	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-477-10	10,000	Polyimide	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-478-10	10,000	Polyimide	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-478-10	10,000	Polyimide	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-479-10	10,000	Polyimide	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-479-10	10,000	Polyimide	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-487-10	10,000	Polyimide	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-487-10	10,000	Polyimide	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-488-10	10,000	Polyester	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R4300
THT-14-495-10	10,000	PEN	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-495-10	10,000	PEN	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-497-10	10,000	Polyimide	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R6002
THT-47-497-10	10,000	Polyimide	White	1	0.650 (16.51)	0.200 (5.08)	—	0.300 (7.62)	0.850 (21.59)	R6011
THT-14-498-10	10,000	Vinyl Cloth	White	4	0.650 (16.51)	0.200 (5.08)	0.700 (17.78)	0.300 (7.62)	2.950 (74.93)	R4311
<b>0.700" Label Width</b>										
THT-57-423-10	10,000	Polyester	White	4	0.700 (17.78)	0.375 (9.53)	0.800 (20.32)	0.475 (12.07)	3.350 (85.09)	R6002
THT-57-426-10	10,000	Polyimide	Amber	4	0.700 (17.78)	0.375 (9.53)	0.800 (20.32)	0.475 (12.07)	3.350 (85.09)	R4300
THT-57-473-10	10,000	Polyester	White	4	0.700 (17.78)	0.375 (9.53)	0.800 (20.32)	0.475 (12.07)	3.350 (85.09)	R6002
THT-100-473-10	10,000	Polyester	White	1	0.700 (17.78)	0.375 (9.53)	—	0.475 (12.07)	0.900 (22.86)	R6011
<b>0.750" Label Width</b>										
THT-1-351-10	10,000	Tamper-Resistant Vinyl	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6202
THT-46-354-10	10,000	Polyester/Paper	White	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R6206
THT-1-423-10	10,000	Polyester	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-46-423-10	10,000	Polyester	White	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R6006
THT-1-426-10	10,000	Polyimide	Amber	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R4300
THT-46-426-10	10,000	Polyimide	Amber	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R4311
THT-1-428-10	10,000	Metallized Polyester	Silver	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R4300
THT-1-435-10	10,000	Glossy Metallized Polyester	Silver	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-1-436-10	10,000	Removable Polyimide	Amber	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R4300
THT-1-437-10	10,000	Tedlar	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R4300
THT-1-438-10	10,000	Tamper-Evident Polyester	Silver	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R4300
THT-1-457-10	10,000	Polyimide	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-46-457-10	10,000	Polyimide	White	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R6006
THT-1-459-10	10,000	Polyester	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-1-473-10	10,000	Polyester	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-46-473-10	10,000	Polyester	White	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R6006

**Note:** Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).  
 Tedlar® is a registered trademark of DuPont.


LABEL INDEX BY SIZE THERMAL TRANSFER LABELS

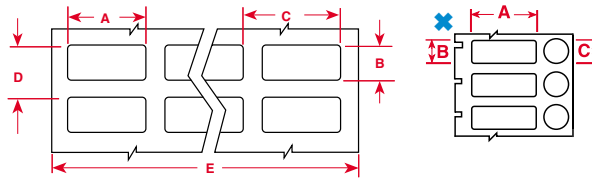

Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
<b>0.750" Label Width (Cont.)</b>										
THT-1-477-10	10,000	Polyimide	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-46-477-10	10,000	Polyimide	White	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R6006
THT-1-478-10	10,000	Polyimide	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-1-498-10	10,000	Vinyl Cloth	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R4311
THT-46-478-10	10,000	Polyimide	White	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R6006
THT-1-479-10	10,000	Polyimide	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-46-479-10	10,000	Polyimide	White	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R6006
THT-1-487-10	10,000	Polyimide	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-46-487-10	10,000	Polyimide	White	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R6006
THT-1-488-10	10,000	Polyester	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R4300
THT-1-495-10	10,000	PEN	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-46-495-10	10,000	PEN	White	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R6006
THT-1-497-10	10,000	Polyimide	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6002
THT-46-497-10	10,000	Polyimide	White	1	0.750 (19.05)	0.250 (6.35)	—	0.350 (8.89)	0.950 (24.13)	R6006
XHT-1-8423-10	10,000	Polyester	White	4	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	0.350 (8.89)	3.350 (85.09)	R6202
THT-50-423-10	10,000	Polyester	White	4	0.750 (19.05)	0.750 (19.05)	0.800 (20.32)	0.875 (22.23)	3.350 (85.09)	R6002
THT-50-426-10	10,000	Polyimide	Amber	4	0.750 (19.05)	0.750 (19.05)	0.800 (20.32)	0.875 (22.23)	3.350 (85.09)	R4300
THT-91-498-5	5,000	Vinyl Cloth	White	4	0.750 (19.05)	0.937 (23.8)	0.875 (22.23)	1.062 (26.98)	3.500 (88.90)	R4300
<b>0.800" Label Width</b>										
THT-95-498-5	5,000	Vinyl Cloth	White	3	0.800 (20.32)	1.437 (36.50)	0.900 (22.86)	1.562 (39.68)	2.800 (71.12)	R4300
THT-69-499-3	3,000	Nylon Cloth	White	2	0.800 (20.32)	1.437 (36.50)	0.900 (22.86)	1.540 (39.12)	1.900 (48.26)	R4902
THT-162-499-10	10,000	Nylon Cloth	White	4	0.800 (20.32)	1.437 (36.50)	0.600 (15.24)	1.562 (39.67)	3.700 (93.98)	R4902
<b>0.900" Label Width</b>										
THT-2-423-10	10,000	Polyester	White	3	0.900 (22.86)	0.250 (6.35)	1.125 (28.58)	0.350 (8.89)	3.350 (85.09)	R6002
THT-49-423-10	10,000	Polyester	White	1	0.900 (22.86)	0.250 (6.35)	—	0.350 (8.89)	1.100 (27.94)	R6006
THT-2-426-10	10,000	Polyimide	Amber	3	0.900 (22.86)	0.250 (6.35)	1.125 (28.58)	0.350 (8.89)	3.350 (85.09)	R4300
THT-49-426-10	10,000	Polyimide	Amber	1	0.900 (22.86)	0.250 (6.35)	—	0.350 (8.89)	1.100 (27.94)	R4311
THT-2-437-10	10,000	Tedlar®	White	3	0.900 (22.86)	0.250 (6.35)	1.125 (28.58)	0.350 (8.89)	3.350 (85.09)	R4300
THT-2-457-10	10,000	Polyimide	White	3	0.900 (22.86)	0.250 (6.35)	1.125 (28.58)	0.350 (8.89)	3.350 (85.09)	R6002
THT-49-457-10	10,000	Polyimide	White	1	0.900 (22.86)	0.250 (6.35)	—	0.350 (8.89)	1.100 (27.94)	R6006
THT-2-473-10	10,000	Polyester	White	3	0.900 (22.86)	0.250 (6.35)	1.125 (28.58)	0.350 (8.89)	3.350 (85.09)	R6002
THT-49-473-10	10,000	Polyester	White	1	0.900 (22.86)	0.250 (6.35)	—	0.350 (8.89)	1.100 (27.94)	R6006
THT-2-478-10	10,000	Polyester	White	3	0.900 (22.86)	0.250 (6.35)	1.125 (28.58)	0.350 (8.89)	3.350 (85.09)	R6002
THT-49-478-10	10,000	Polyester	White	1	0.900 (22.86)	0.250 (6.35)	—	0.350 (8.89)	1.100 (27.94)	R6006
THT-2-479-10	10,000	Polyester	White	3	0.900 (22.86)	0.250 (6.35)	1.125 (28.58)	0.350 (8.89)	3.350 (85.09)	R6002
THT-49-479-10	10,000	Polyester	White	1	0.900 (22.86)	0.250 (6.35)	—	0.350 (8.89)	1.100 (27.94)	R6006
THT-2-488-10	10,000	Polyester	White	3	0.900 (22.86)	0.250 (6.35)	1.125 (28.58)	0.350 (8.89)	3.350 (85.09)	R4300
THT-2-495-10	10,000	PEN	White	3	0.900 (22.86)	0.250 (6.35)	1.125 (28.58)	0.350 (8.89)	3.350 (85.09)	R4300
THT-49-495-10	10,000	PEN	White	3	0.900 (22.86)	0.250 (6.35)	1.125 (28.58)	0.350 (8.89)	3.350 (85.09)	R4300
XHT-2-8423-10	10,000	Polyester	White	3	0.900 (22.86)	0.250 (6.35)	1.125 (28.58)	0.350 (8.89)	3.350 (85.09)	R6202
THT-125-499-3	3,000	Nylon Cloth	White	1	0.900 (22.86)	0.500 (12.70)	—	1.000 (25.40)	1.100 (27.94)	R4306
THT-126-499-3*	3,000	Nylon Cloth	White	2	0.900 (22.86)	0.500 (12.70) dia.	0.500 (12.70)	0.600 (15.24)	1.700 (43.18)	R4302
THT-140-488-3	3,000	Polyester	White	2	0.900 (22.86)	0.750 (19.05)	—	0.875 (22.23)	2.100 (53.34)	R4306
THT-141-488-3	3,000	Polyester	White	2	0.900 (22.86)	0.900 (22.86)	—	1.000 (25.40)	2.100 (53.34)	R4306
THT-164-488-1	1,000	Polyester	White	1	0.900 (22.86)	0.900 (22.86)	—	1.000 (25.40)	1.100 (27.94)	R4306
<b>1.000" Label Width</b>										
THT-42-354-10	10,000	Polyester/Paper	White	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (7.29)	1.200 (30.48)	R6206
THT-41-423-10	10,000	Polyester	White	3	1.000 (25.40)	0.187 (4.75)	1.075 (27.31)	0.287 (7.29)	3.350 (85.09)	R6002
THT-42-423-10	10,000	Polyester	White	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (7.29)	1.200 (30.48)	R6006
THT-41-426-10	10,000	Polyimide	Amber	3	1.000 (25.40)	0.187 (4.75)	1.075 (27.31)	0.287 (7.29)	3.350 (85.09)	R4300
THT-42-426-10	10,000	Polyimide	Amber	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (7.29)	1.200 (30.48)	R4306
THT-42-457-10	10,000	Polyimide	White	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (7.29)	1.200 (30.48)	R6006

**Note:** Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).  
 Tedlar® is a registered trademark of DuPont.

Label Index by Size

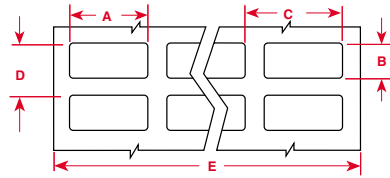


LABEL INDEX BY SIZE THERMAL TRANSFER LABELS

Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
<b>1.000" Label Width (Cont.)</b>										
THT-42-477-10	10,000	Polyimide	White	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (6.93)	1.200 (30.48)	R6006
THT-42-478-10	10,000	Polyimide	White	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (6.93)	1.200 (30.48)	R6006
THT-42-479-10	10,000	Polyimide	White	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (6.93)	1.200 (30.48)	R6006
THT-42-487-10	10,000	Polyimide	White	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (6.93)	1.200 (30.48)	R6006
THT-42-495-10	10,000	PEN	White	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (6.93)	1.200 (30.48)	R6006
THT-42-497-10	10,000	Polyimide	White	1	1.000 (25.40)	0.187 (4.75)	—	0.287 (6.93)	1.200 (30.48)	R6006
THT-51-423-10	10,000	Polyester	White	3	1.000 (25.40)	0.250 (6.35)	1.075 (27.31)	0.375 (9.53)	3.350 (85.09)	R6002
THT-103-423-10	10,000	Polyester	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-51-426-10	10,000	Polyimide	Amber	3	1.000 (25.40)	0.250 (6.35)	1.075 (27.31)	0.375 (9.53)	3.350 (85.09)	R4300
THT-103-426-10	10,000	Polyimide	Amber	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R4306
THT-103-457-10	10,000	Polyimide	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-103-473-10	10,000	Polyester	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-103-477-10	10,000	Polyimide	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-103-495-10	10,000	PEN	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-103-478-10	10,000	Polyimide	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-103-479-10	10,000	Polyimide	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-103-487-10	10,000	Polyimide	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-103-497-10	10,000	Polyimide	White	1	1.000 (25.40)	0.250 (6.35)	—	0.350 (8.89)	1.200 (30.48)	R6006
THT-3-422-10	10,000	Polyester	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6002
THT-3-423-10	10,000	Polyester	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6002
THT-3-426-10	10,000	Polyimide	Amber	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R4300
THT-3-428-10	10,000	Metallized Polyester	Silver	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R4300
THT-3-430-10	10,000	Polyester	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6002
THT-58-457-10	10,000	Polyimide	White	1	1.000 (25.40)	0.375 (9.53)	—	0.475 (12.07)	1.200 (30.48)	R6006
THT-3-473-10	10,000	Polyester	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6002
THT-58-473-10	10,000	Polyester	White	1	1.000 (25.40)	0.375 (9.53)	—	0.475 (12.07)	1.200 (30.48)	R6006
THT-3-478-10	10,000	Polyimide	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6002
THT-58-478-10	10,000	Polyimide	White	1	1.000 (25.40)	0.375 (9.53)	—	0.475 (12.07)	1.200 (30.48)	R6006
THT-3-479-10	10,000	Polyimide	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6002
THT-58-479-10	10,000	Polyimide	White	1	1.000 (25.40)	0.375 (9.53)	—	0.475 (12.07)	1.200 (30.48)	R6006
THT-3-495-10	10,000	PEN	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6002
THT-58-495-10	10,000	PEN	White	1	1.000 (25.40)	0.375 (9.53)	—	0.475 (12.07)	1.200 (30.48)	R6006
THT-152-499-3	3,000	Nylon Cloth	White	2	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	2.300 (58.42)	R4306
THT-163-499-3	3,000	Nylon Cloth	White	1	1.000 (25.40)	0.375 (9.53) dia.	—	0.875 (22.22)	1.675 (42.55)	R4306
XHT-3-8423-10	10,000	Polyester	White	3	1.000 (25.40)	0.375 (9.53)	1.075 (27.31)	0.475 (12.07)	3.350 (85.09)	R6206
THT-5-351-10	10,000	Tamper-Resistant Vinyl	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6202
THT-59-351-10	10,000	Tamper-Resistant Vinyl	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6206
THT-5-352-10	10,000	Tamper-Resistant Vinyl	Silver	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-59-352-10	10,000	Tamper-Resistant Vinyl	Silver	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6006
THT-59-354-10	10,000	Polyester/Paper	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6206
THT-39-358-10	10,000	Tamper-Resistant Acetate	Clear	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.625 (15.88)	3.350 (85.09)	R6202
THT-59-359-10	10,000	Tamper-Resistant Acetate	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6206
THT-5-422-10	10,000	Polyester	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-5-423-10	10,000	Polyester	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-59-423-10	10,000	Polyester	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6006
THT-5-426-10	10,000	Polyimide	Amber	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R4300
THT-5-428-10	10,000	Metallized Polyester	Silver	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R4300
THT-39-430-10	10,000	Polyester	Clear	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.625 (15.88)	3.350 (85.09)	R6002
THT-5-433-10	10,000	Removable Polyester	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-5-434-10	10,000	Metallized Polyester	Silver	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-5-435-10	10,000	Glossy Metallized Polyester	Silver	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-5-437-10	10,000	Tedlar®	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R4300
THT-5-437-10-YL	10,000	Tedlar	Yellow	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R4300
THT-5-438-10	10,000	Tamper-Evident Polyester	Silver	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R4300

**Note:** Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).


Tedlar® is a registered trademark of DuPont.

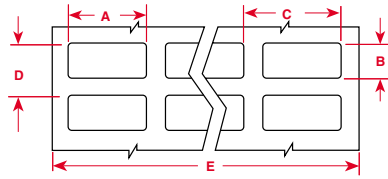

Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
<b>1.000" Label Width (Cont.)</b>										
THT-59-438-10	10,000	Tamper-Evident Polyester	Silver	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R4306
THT-5-449-10	10,000	Polypropylene	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6202
THT-59-457-10	10,000	Polyimide	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6006
THT-5-459-10	10,000	Polyester	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-5-473-10	10,000	Polyester	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-59-473-10	10,000	Polyester	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6006
THT-59-477-10	10,000	Polyimide	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6006
THT-5-478-10	10,000	Polyimide	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-59-478-10	10,000	Polyimide	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6006
THT-5-479-10	10,000	Polyimide	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-59-479-10	10,000	Polyimide	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6006
THT-5-483-10	10,000	Polyester	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-59-483-10	10,000	Polyester	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6006
THT-5-486-10	10,000	Metallized Polyester	Silver	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R4300
THT-59-486-5	5,000	Metallized Polyester	Silver	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R4306
THT-59-487-10	10,000	Polyimide	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6006
THT-5-488-10	10,000	Polyester	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R4300
THT-5-489-10	10,000	Polyester	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R4300
THT-59-489-10	10,000	Polyester	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R4306
THT-5-495-10	10,000	PEN	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-59-495-10	10,000	PEN	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6006
THT-59-497-10	10,000	Polyimide	White	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6006
THT-5-498-10	10,000	Vinyl Cloth	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R4300
THT-5-7546-10	10,000	Tamper-Evident Polyester	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6006
THT-59-7546-10	10,000	Tamper-Evident Polyester	White	1	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6006
THT-39-7566-10	10,000	Tamper-Evident Polyester	Clear	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.625 (15.88)	3.350 (85.09)	R6006
THT-5-7576-10	10,000	Tamper-Evident Polyester	Silver	3	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6006
THT-59-7576-10	10,000	Tamper-Evident Polyester	Silver	1	1.000 (25.40)	0.500 (12.70)	—	0.600 (15.24)	1.200 (30.48)	R6006
XTHT-5-8423-10	10,000	Polyester	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6202
XTHT-5-8425-10	10,000	Polyolefin	White	3	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	0.600 (15.24)	3.350 (85.09)	R6002
THT-88-498-5	5,000	Vinyl Cloth	White	2	1.000 (25.40)	0.750 (19.05)	1.100 (27.94)	0.875 (22.23)	2.300 (58.42)	R4300
THT-117-427-5	5,000	Vinyl	White	2	1.000 (25.40)	1.250 (31.75)	1.100 (27.94)	1.375 (34.93)	2.300 (58.42)	R4300
THT-89-498-5	5,000	Vinyl Cloth	White	3	1.000 (25.40)	1.440 (36.50)	1.100 (27.94)	1.562 (39.68)	3.400 (86.36)	R4300
<b>1.100" Label Width</b>										
THT-31-423-10	10,000	Polyester	White	2	1.100 (27.94)	0.380 (9.65)	1.200 (30.48)	0.500 (12.70)	2.500 (63.50)	R6002
<b>1.181" Label Width</b>										
DSTHT-30-390-2.5	2,500	Polypropylene	White	1	1.181 (30.00)	0.163 (4.14)	—	0.402 (10.21)	—	R6206
DSTHT-30-390-1	1,000	Polypropylene	White	1	1.181 (30.00)	0.163 (4.14)	—	0.402 (10.21)	—	R6206
<b>1.250" Label Width</b>										
THT-43-354-10	10,000	Polyester/Paper	White	1	1.250 (31.75)	0.250 (6.35)	—	0.350 (8.89)	1.450 (36.83)	R6006
THT-13-423-10	10,000	Polyester	White	2	1.250 (31.75)	0.250 (6.35)	1.300 (33.02)	0.375 (9.53)	2.750 (69.85)	R6002
THT-43-423-10	10,000	Polyester	White	1	1.250 (31.75)	0.250 (6.35)	—	0.350 (8.89)	1.450 (36.83)	R6006
THT-13-426-10	10,000	Polyimide	Amber	2	1.250 (31.75)	0.250 (6.35)	1.300 (33.02)	0.375 (9.53)	2.750 (69.85)	R4300
THT-43-426-10	10,000	Polyimide	Amber	1	1.250 (31.75)	0.250 (6.35)	—	0.350 (8.89)	1.450 (36.83)	R4306
THT-13-433-10	10,000	Removable Polyester	White	2	1.250 (31.75)	0.250 (6.35)	1.300 (33.02)	0.375 (9.53)	2.750 (69.85)	R6002
THT-13-449-10	10,000	Polypropylene	White	2	1.250 (31.75)	0.250 (6.35)	1.300 (33.02)	0.375 (9.53)	2.750 (69.85)	R6202
THT-13-457-10	10,000	Polyimide	White	2	1.250 (31.75)	0.250 (6.35)	1.300 (33.02)	0.375 (9.53)	2.750 (69.85)	R6002
THT-43-457-10	10,000	Polyimide	White	1	1.250 (31.75)	0.250 (6.35)	—	0.350 (8.89)	1.450 (36.83)	R6006
THT-13-473-10	10,000	Polyester	White	2	1.250 (31.75)	0.250 (6.35)	1.300 (33.02)	0.375 (9.53)	2.750 (69.85)	R6002
THT-43-473-10	10,000	Polyester	White	1	1.250 (31.75)	0.250 (6.35)	—	0.350 (8.89)	1.450 (36.83)	R6006
THT-43-477-10	10,000	Polyimide	White	1	1.250 (31.75)	0.250 (6.35)	—	0.350 (8.89)	1.450 (36.83)	R6006
THT-43-478-10	10,000	Polyimide	White	1	1.250 (31.75)	0.250 (6.35)	—	0.350 (8.89)	1.450 (36.83)	R6006
THT-43-479-10	10,000	Polyimide	White	1	1.250 (31.75)	0.250 (6.35)	—	0.350 (8.89)	1.450 (36.83)	R6006
THT-43-487-10	10,000	Polyimide	White	1	1.250 (31.75)	0.250 (6.35)	—	0.350 (8.89)	1.450 (36.83)	R6006

Note: Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).

Label Index by Size

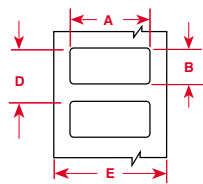


Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
<b>1.250" Label Width (Cont.)</b>										
THT-43-495-10	10,000	PEN	White	1	1.250 (31.75)	0.250 (6.35)	—	0.350 (8.89)	1.450 (36.83)	R6006
THT-43-497-10	10,000	Polyimide	White	1	1.250 (31.75)	0.250 (6.35)	—	0.350 (8.89)	1.450 (36.83)	R6006
THT-29-423-10	10,000	Polyester	White	2	1.250 (31.75)	0.375 (9.53)	1.300 (33.02)	0.475 (12.07)	2.750 (69.85)	R6002
THT-29-426-10	10,000	Polyimide	Amber	2	1.250 (31.75)	0.375 (9.53)	1.300 (33.02)	0.475 (12.07)	2.750 (69.85)	R4300
THT-29-437-10	10,000	Tedlar®	White	2	1.250 (31.75)	0.375 (9.53)	1.300 (33.02)	0.475 (12.07)	2.750 (69.85)	R4300
THT-29-437-10-YL	10,000	Tedlar	Yellow	2	1.250 (31.75)	0.375 (9.53)	1.300 (33.02)	0.475 (12.07)	2.750 (69.85)	R4300
THT-29-478-10	10,000	Polyester	White	2	1.250 (31.75)	0.375 (9.53)	1.300 (33.02)	0.475 (12.07)	2.750 (69.85)	R6002
THT-29-479-10	10,000	Polyester	White	2	1.250 (31.75)	0.375 (9.53)	1.300 (33.02)	0.475 (12.07)	2.750 (69.85)	R6002
THT-154-490-3	3,000	Polyester	White	1	1.250 (31.75)	0.375 (9.53)	—	0.500 (12.07)	1.450 (36.83)	R4300
THT-29-495-10	10,000	PEN	White	2	1.250 (31.75)	0.375 (9.53)	1.300 (33.02)	0.475 (12.07)	2.750 (69.85)	R6002
<b>1.375" Label Width</b>										
THT-40-423-10	10,000	Polyester	White	2	1.375 (34.93)	0.250 (6.35)	1.475 (37.47)	0.375 (9.53)	3.050 (77.47)	R6002
THT-44-423-10	10,000	Polyester	White	1	1.375 (34.93)	0.250 (6.35)	—	0.350 (8.89)	1.600 (40.64)	R6006
THT-40-426-10	10,000	Polyimide	Amber	2	1.375 (34.93)	0.250 (6.35)	1.475 (37.47)	0.375 (9.53)	3.050 (77.47)	R4300
THT-44-426-10	10,000	Polyimide	Amber	1	1.375 (34.93)	0.250 (6.35)	—	0.350 (8.89)	1.600 (40.64)	R4306
THT-40-457-10	10,000	Polyimide	White	2	1.375 (34.93)	0.250 (6.35)	1.475 (37.47)	0.375 (9.53)	3.050 (77.47)	R6002
THT-44-457-10	10,000	Polyimide	White	1	1.375 (34.93)	0.250 (6.35)	—	0.350 (8.89)	1.600 (40.64)	R6006
THT-40-477-10	10,000	Polyimide	White	2	1.375 (34.93)	0.250 (6.35)	1.475 (37.47)	0.375 (9.53)	3.050 (77.47)	R6002
THT-44-477-10	10,000	Polyimide	White	1	1.375 (34.93)	0.250 (6.35)	—	0.350 (8.89)	1.600 (40.64)	R6006
THT-44-478-10	10,000	Polyimide	White	1	1.375 (34.93)	0.250 (6.35)	—	0.350 (8.89)	1.600 (40.64)	R6006
THT-44-479-10	10,000	Polyimide	White	1	1.375 (34.93)	0.250 (6.35)	—	0.350 (8.89)	1.600 (40.64)	R6006
THT-40-487-10	10,000	Polyimide	White	2	1.375 (34.93)	0.250 (6.35)	1.475 (37.47)	0.375 (9.53)	3.050 (77.47)	R6002
THT-44-487-10	10,000	Polyimide	White	1	1.375 (34.93)	0.250 (6.35)	—	0.350 (8.89)	1.600 (40.64)	R6006
THT-40-497-10	10,000	Polyimide	White	2	1.375 (34.93)	0.250 (6.35)	1.475 (37.47)	0.375 (9.53)	3.050 (77.47)	R6002
THT-44-495-10	10,000	PEN	White	1	1.375 (34.93)	0.250 (6.35)	—	0.350 (8.89)	1.600 (40.64)	R6006
THT-44-497-10	10,000	Polyimide	White	1	1.375 (34.93)	0.250 (6.35)	—	0.350 (8.89)	1.600 (40.64)	R6006
<b>1.500" Label Width</b>										
THT-28-423-10	10,000	Polyester	White	2	1.500 (38.10)	0.125 (3.18)	1.650 (41.91)	0.250 (6.35)	3.350 (85.09)	R6002
THT-28-426-10	10,000	Polyimide	Amber	2	1.500 (38.10)	0.125 (3.18)	1.650 (41.91)	0.250 (6.35)	3.350 (85.09)	R4300
THT-60-457-10	10,000	Polyimide	White	1	1.500 (38.10)	0.125 (3.18)	—	0.225 (5.72)	1.700 (43.18)	R6000
THT-60-477-10	10,000	Polyimide	White	1	1.500 (38.10)	0.125 (3.18)	—	0.225 (5.72)	1.700 (43.18)	R6000
THT-60-478-10	10,000	Polyimide	White	1	1.500 (38.10)	0.125 (3.18)	—	0.225 (5.72)	1.700 (43.18)	R6000
THT-60-479-10	10,000	Polyimide	White	1	1.500 (38.10)	0.125 (3.18)	—	0.225 (5.72)	1.700 (43.18)	R6000
THT-60-487-10	10,000	Polyimide	White	1	1.500 (38.10)	0.125 (3.18)	—	0.225 (5.72)	1.700 (43.18)	R6000
THT-60-495-10	10,000	PEN	White	1	1.500 (38.10)	0.125 (3.18)	—	0.225 (5.72)	1.700 (43.18)	R6000
THT-60-497-10	10,000	Polyimide	White	1	1.500 (38.10)	0.125 (3.18)	—	0.225 (5.72)	1.700 (43.18)	R6000
THT-4-351-10	10,000	Tamper-Resistant Vinyl	White	2	1.500 (38.10)	0.250 (6.35)	1.650 (41.91)	0.350 (8.89)	3.350 (85.09)	R6202
THT-4-423-10	10,000	Polyester	White	2	1.500 (38.10)	0.250 (6.35)	1.650 (41.91)	0.350 (8.89)	3.350 (85.09)	R6002
THT-45-423-10	10,000	Polyester	White	1	1.500 (38.10)	0.250 (6.35)	—	0.350 (8.89)	1.700 (43.18)	R6000
THT-4-426-10	10,000	Polyimide	Amber	2	1.500 (38.10)	0.250 (6.35)	1.650 (41.91)	0.350 (8.89)	3.350 (85.09)	R4300
THT-45-426-10	10,000	Polyimide	Amber	1	1.500 (38.10)	0.250 (6.35)	—	0.350 (8.89)	1.700 (43.18)	R4302
THT-4-457-10	10,000	Polyimide	White	2	1.500 (38.10)	0.250 (6.35)	1.650 (41.91)	0.350 (8.89)	3.350 (85.09)	R6002
THT-45-457-10	10,000	Polyimide	White	1	1.500 (38.10)	0.250 (6.35)	—	0.350 (8.89)	1.700 (43.18)	R6000
THT-4-473-10	10,000	Polyester	White	2	1.500 (38.10)	0.250 (6.35)	1.650 (41.91)	0.350 (8.89)	3.350 (85.09)	R6002
THT-45-473-10	10,000	Polyester	White	1	1.500 (38.10)	0.250 (6.35)	—	0.350 (8.89)	1.700 (43.18)	R6000
THT-45-477-10	10,000	Polyimide	White	1	1.500 (38.10)	0.250 (6.35)	—	0.350 (8.89)	1.700 (43.18)	R6000
THT-4-478-10	10,000	Polyester	White	2	1.500 (38.10)	0.250 (6.35)	1.650 (41.91)	0.350 (8.89)	3.350 (85.09)	R6002
THT-45-478-10	10,000	Polyimide	White	1	1.500 (38.10)	0.250 (6.35)	—	0.350 (8.89)	1.700 (43.18)	R6000
THT-4-479-10	10,000	Polyester	White	2	1.500 (38.10)	0.250 (6.35)	1.650 (41.91)	0.350 (8.89)	3.350 (85.09)	R6002
THT-45-479-10	10,000	Polyimide	White	1	1.500 (38.10)	0.250 (6.35)	—	0.350 (8.89)	1.700 (43.18)	R6000
THT-45-487-10	10,000	Polyimide	White	1	1.500 (38.10)	0.250 (6.35)	—	0.350 (8.89)	1.700 (43.18)	R6000
THT-4-495-10	10,000	PEN	White	2	1.500 (38.10)	0.250 (6.35)	1.650 (41.91)	0.350 (8.89)	3.350 (85.09)	R6002
THT-45-495-10	10,000	PEN	White	1	1.500 (38.10)	0.250 (6.35)	—	0.350 (8.89)	1.700 (43.18)	R6000
THT-45-497-10	10,000	Polyimide	White	1	1.500 (38.10)	0.250 (6.35)	—	0.350 (8.89)	1.700 (43.18)	R6000

**Note:** Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).  
 Tedlar® is a registered trademark of DuPont.

LABEL INDEX BY SIZE THERMAL TRANSFER LABELS



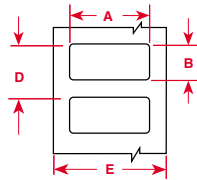


Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
<b>1.500" Label Width (Cont.)</b>										
XHTT-4-8423-10	10,000	Polyester	White	2	1.500 (38.10)	0.250 (6.35)	1.605 (41.91)	0.350 (8.89)	3.350 (85.09)	R6202
THT-102-422-10	10,000	Polyester	White	1	1.500 (38.10)	0.370 (9.40)	—	0.500 (12.70)	1.700 (43.18)	R6000
THT-147-358-10	10,000	Tamper-Resistant Acetate	Clear	1	1.500 (38.10)	0.375 (9.53)	1.605 (41.91)	0.475 (12.06)	3.350 (85.09)	R6002
THT-147-359-10	10,000	Tamper-Resistant Acetate	White	2	1.500 (38.10)	0.375 (9.53)	1.605 (41.91)	0.475 (12.06)	3.350 (85.09)	R6002
THT-147-422-10	10,000	Polyester	White	2	1.500 (38.10)	0.375 (9.53)	1.605 (41.91)	0.475 (12.06)	3.350 (85.09)	R6002
THT-147-430-10	10,000	Polyester	Clear	2	1.500 (38.10)	0.375 (9.53)	1.605 (41.91)	0.500 (12.70)	3.350 (85.09)	R6002
THT-147-7566-10	10,000	Polyester	Clear	2	1.500 (38.10)	0.375 (9.53)	1.605 (41.91)	0.500 (12.70)	3.350 (85.09)	R6002
THT-37-351-10	10,000	Tamper-Resistant Vinyl	White	2	1.500 (38.10)	0.500 (12.70)	1.650 (41.91)	0.600 (15.24)	3.350 (85.09)	R6202
THT-37-352-10	10,000	Tamper-Resistant Vinyl	Silver	2	1.500 (38.10)	0.500 (12.70)	1.650 (41.91)	0.600 (15.24)	3.350 (85.09)	R6002
THT-37-422-10	10,000	Metallized Polyester	Silver	2	1.500 (38.10)	0.500 (12.70)	1.650 (41.91)	0.600 (15.24)	3.350 (85.09)	R6002
THT-37-423-10	10,000	Polyester	White	2	1.500 (38.10)	0.500 (12.70)	1.650 (41.91)	0.600 (15.24)	3.350 (85.09)	R6002
THT-37-428-10	10,000	Metallized Polyester	Silver	2	1.500 (38.10)	0.500 (12.70)	1.650 (41.91)	0.600 (15.24)	3.350 (85.09)	R4300
THT-37-430-10	10,000	Metallized Polyester	Silver	2	1.500 (38.10)	0.500 (12.70)	1.650 (41.91)	0.600 (15.24)	3.350 (85.09)	R6002
THT-37-434-10	10,000	Metallized Polyester	Silver	2	1.500 (38.10)	0.500 (12.70)	1.650 (41.91)	0.600 (15.24)	3.350 (85.09)	R6002
THT-37-438-10	10,000	Tamper-Evident Polyester	Silver	2	1.500 (38.10)	0.500 (12.70)	1.650 (41.91)	0.600 (15.24)	3.350 (85.09)	R4300
THT-37-483-10	10,000	Polyester	White	2	1.500 (38.10)	0.500 (12.70)	1.650 (41.91)	0.600 (15.24)	3.350 (85.09)	R6002
THT-37-486-10	10,000	Metallized Polyester	Silver	2	1.500 (38.10)	0.500 (12.70)	1.650 (41.91)	0.600 (15.24)	3.350 (85.09)	R4300
THT-37-489-10	10,000	Polyester	White	2	1.500 (38.10)	0.500 (12.70)	1.650 (41.91)	0.600 (15.24)	3.350 (85.09)	R4300
THT-37-7546-10	10,000	Tamper-Evident Polyester	White	2	1.500 (38.10)	0.500 (12.70)	1.650 (41.91)	0.600 (15.24)	3.350 (85.09)	R6002
THT-37-7576-10	10,000	Tamper-Evident Polyester	Silver	2	1.500 (38.10)	0.500 (12.70)	1.650 (41.91)	0.600 (15.24)	3.350 (85.09)	R6002
THT-6-351-10	10,000	Tamper-Resistant Vinyl	White	2	1.500 (38.10)	0.750 (19.05)	1.650 (41.91)	0.875 (22.23)	3.350 (85.09)	R6202
THT-6-352-10	10,000	Tamper-Resistant Vinyl	Silver	2	1.500 (38.10)	0.750 (19.05)	1.650 (41.91)	0.875 (22.23)	3.350 (85.09)	R6002
THT-6-354-10	10,000	Polyester/Paper	White	2	1.500 (38.10)	0.750 (19.05)	1.650 (41.91)	0.875 (22.23)	3.350 (85.09)	R6202
THT-6-423-10	10,000	Polyester	White	2	1.500 (38.10)	0.750 (19.05)	1.650 (41.91)	0.875 (22.23)	3.350 (85.09)	R6002
THT-135-427-AW-3*	3,000	Vinyl	White	1	1.500 (38.10)	0.750 (19.05)	—	0.875 (22.23)	1.700 (43.18)	R4302
THT-6-428-10	10,000	Metallized Polyester	Silver	2	1.500 (38.10)	0.750 (19.05)	1.650 (41.91)	0.875 (22.23)	3.350 (85.09)	R4300
THT-6-434-10	10,000	Metallized Polyester	Silver	2	1.500 (38.10)	0.750 (19.05)	1.650 (41.91)	0.875 (22.23)	3.350 (85.09)	R6002
THT-6-438-10	10,000	Tamper-Evident Polyester	Silver	2	1.500 (38.10)	0.750 (19.05)	1.650 (41.91)	0.875 (22.23)	3.350 (85.09)	R4300
THT-6-486-10	10,000	Metallized Polyester	Silver	2	1.500 (38.10)	0.750 (19.05)	1.650 (41.91)	0.875 (22.23)	3.350 (85.09)	R4300
THT-136-499-3	3,000	Nylon Cloth	White	1	1.500 (38.10)	0.750 (19.05)	—	0.875 (22.23)	1.700 (43.18)	R4302
THT-6-7546-10	10,000	Tamper-Evident Polyester	White	2	1.500 (38.10)	0.750 (19.05)	1.650 (41.91)	0.875 (22.23)	3.350 (85.09)	R6002
THT-6-7576-10	10,000	Tamper-Evident Polyester	Silver	2	1.500 (38.10)	0.750 (19.05)	1.650 (41.91)	0.875 (22.23)	3.350 (85.09)	R6002
THT-105-437	1	Tedlar®	White	1	1.500 (38.10)	300 ft (91.44 m)	—	300 ft (91.44 m)	1.750 (44.45)	R4302
THT-105-437-YL	1	Tedlar	Yellow	1	1.500 (38.10)	300 ft (91.44 m)	—	300 ft (91.44 m)	1.750 (44.45)	R4302
<b>1.625" Label Width</b>										
THT-155-490-3	3,000	Polyester	White	1	1.625 (41.28)	0.600 (15.24)	—	0.700 (17.78)	1.825 (46.36)	R4300
<b>1.750" Label Width</b>										
THT-72-457-10	10,000	Polyimide	White	1	1.750 (44.45)	0.250 (6.35)	—	0.350 (8.89)	1.950 (49.53)	R6000
THT-72-478-10	10,000	Polyimide	White	1	1.750 (44.45)	0.250 (6.35)	—	0.350 (8.89)	1.950 (49.53)	R6000
THT-72-479-10	10,000	Polyimide	White	1	1.750 (44.45)	0.250 (6.35)	—	0.350 (8.89)	1.950 (49.53)	R6000
THT-72-495-10	10,000	PEN	White	1	1.750 (44.45)	0.250 (6.35)	—	0.350 (8.89)	1.950 (49.53)	R6000
THT-72-497-10	10,000	Polyimide	White	1	1.750 (44.45)	0.250 (6.35)	—	0.350 (8.89)	1.950 (49.53)	R6000
<b>1.900" Label Width</b>										
THT-156-490-3	3,000	Polyester	White	1	1.900 (48.26)	1.000 (25.40)	—	1.100 (27.94)	2.100 (53.34)	R4300
<b>1.938" Label Width</b>										
THT-150-412-1	1,000	Polypropylene	White	1	1.938 (49.25)	0.375 (9.53)	—	0.375 (9.53)	2.200 (55.88)	R6200

**Note:** Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).

\*The label is all white.

Tedlar® is a registered trademark of DuPont.


Label Index by Size

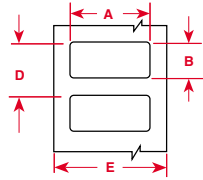

Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
<b>2.000" Label Width</b>										
THT-15-351-2.5	2,500	Tamper-Resistant Vinyl	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R6200
THT-15-423-2.5	2,500	Polyester	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R6000
THT-48-423-10	10,000	Polyester	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-15-426-2.5	2,500	Polyimide	Amber	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R4302
THT-48-426-10	10,000	Polyimide	Amber	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R4302
THT-15-457-2.5	2,500	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R6000
THT-48-457-10	10,000	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-15-473-2.5	2,500	Polyester	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R6000
THT-48-473-10	10,000	Polyester	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-15-477-2.5	2,500	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R6000
THT-48-477-10	10,000	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-48-478-10	10,000	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-48-479-10	10,000	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-15-487-2.5	2,500	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R6000
THT-48-487-10	10,000	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-15-488-2.5	2,500	Polyester	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R4302
THT-48-495-10	10,000	PEN	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-48-497-10	10,000	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R6000
THT-15-497-2.5	2,500	Polyimide	White	1	2.000 (50.80)	0.250 (6.35)	—	0.375 (9.53)	2.200 (55.88)	R6000
THT-151-499-3	3,000	Nylon Cloth	White	1	2.000 (50.80)	0.250 (6.35)	—	0.350 (8.89)	2.200 (55.88)	R4302
THT-79-423-10	10,000	Polyester	White	1	2.000 (50.80)	0.400 (10.16)	—	0.500 (12.70)	2.200 (55.88)	R6000
THT-53-351-3	3,000	Tamper-Resistant Vinyl	White	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R6200
THT-53-352-3	3,000	Tamper-Resistant Vinyl	Silver	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R6000
THT-53-423-3	3,000	Polyester	White	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R6000
THT-53-424-3	3,000	Paper	White	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R4302
THT-53-428-3	3,000	Metallized Polyester	Silver	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R4302
THT-53-438-3	3,000	Tamper-Evident Polyester	Silver	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R4302
THT-53-486-3	3,000	Metallized Polyester	Silver	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R4302
THT-53-7546-3	3,000	Tamper-Evident Polyester	White	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R6000
THT-53-7576-3	3,000	Tamper-Evident Polyester	Silver	1	2.000 (50.80)	0.500 (12.70)	—	0.600 (15.24)	2.200 (55.88)	R6000
THT-17-351-3	3,000	Tamper-Resistant Vinyl	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6200
THT-17-352-3	3,000	Tamper-Resistant Vinyl	Silver	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6000
THT-17-354-3	3,000	Polyester/Paper	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6200
THT-17-358-3	3,000	Tamper-Resistant Acetate	Clear	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6200
THT-17-359-3	3,000	Tamper-Resistant Acetate	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6200
THT-17-7566-3	3,000	Tamper-Evident Polyester	Clear	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6200
XHT-17-8425-5	5,000	Polypropylene	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6000
THT-17-402-5.2	5,200	Paper	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.125 (53.98)	R6100
THT-17-408-3	3,000	Paper	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6100
THT-17-422-3	3,000	Polyester	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6000
THT-17-423-3	3,000	Polyester	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6000
THT-17-424-3	3,000	Paper	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R4302
THT-137-427-AW-3*	3,000	Vinyl	White/ Transparent	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R4302
THT-17-428-3	3,000	Metallized Polyester	Silver	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R4302
THT-17-430-3	3,000	Polyester	Clear	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6000
THT-17-434-3	3,000	Metallized Polyester	Silver	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6000
THT-17-438-3	3,000	Tamper-Evident Polyester	Silver	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R4302
THT-17-449-3	3,000	Polypropylene	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6200
THT-17-483-3	3,000	Polyester	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6000
THT-17-486-3	3,000	Metallized Polyester	Silver	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R4302
THT-17-488-3	3,000	Polyester	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R4302

**Note:** Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).

LABEL INDEX BY SIZE THERMAL TRANSFER LABELS

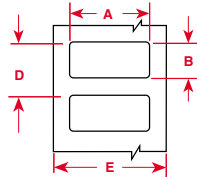


Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
<b>2.000" Label Width (Cont.)</b>										
THT-17-489-3	3,000	Polyester	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R4302
THT-137-499-3	3,000	Nylon Cloth	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R4302
THT-17-7546-3	3,000	Tamper-Evident Polyester	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6000
THT-17-7576-3	3,000	Tamper-Evident Polyester	Silver	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.88)	R6000
XHTT-17-8423-5	5,000	Polyester	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.58)	R6200
XHTT-17-8425-5	5,000	Polyolefin	White	1	2.000 (50.80)	1.000 (25.40)	—	1.125 (28.58)	2.200 (55.58)	R6000
THT-106-423	1	Polyester	White	1	2.000 (50.80)	300 ft (9144 m)	—	300 ft (9144 m)	2.200 (55.88)	R6000
THT-106-428	1	Metallized Polyester	Silver	1	2.000 (50.80)	300 ft (9144 m)	—	300 ft (9144 m)	2.200 (55.88)	R4302
THT-106-439	1	Colored Vinyl	White	1	2.000 (50.80)	300 ft (9144 m)	—	300 ft (9144 m)	2.200 (55.88)	R6000
THT-106-483	1	Polyester	White	1	2.000 (50.80)	300 ft (9144 m)	—	300 ft (9144 m)	2.200 (55.88)	R6000
THT-106-486	1	Metallized Polyester	White	1	2.000 (50.80)	300 ft (9144 m)	—	300 ft (9144 m)	2.200 (55.88)	R4302
<b>2.200" Label Width</b>										
THT-157-490-3	3,000	Polyester	White	1	2.200 (55.88)	1.500 (38.10)	—	1.625 (42.28)	2.400 (60.96)	R4300
<b>2.500" Label Width</b>										
THT-142-423-2.5	2,500	Polyester	White	1	2.500 (63.50)	0.200 (5.08)	—	0.300 (7.62)	2.700 (68.58)	R6002
<b>2.625" Label Width</b>										
THT-131-461-3	3,000	Vinyl	White/ Transparent	1	2.625 (66.68)	1.000 (25.40)	—	1.125 (28.58)	2.825 (71.76)	R4300
<b>2.750" Label Width</b>										
THT-7-351-10	10,000	Tamper-Resistant Vinyl	White	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R6202
THT-7-352-10	10,000	Tamper-Resistant Vinyl	Silver	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R6002
THT-7-358-3	3,000	Tamper-Resistant Acetate	Clear	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R6202
THT-7-359-3	3,000	Tamper-Resistant Acetate	White	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R6202
THT-7-422-3	3,000	Polyester	White	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R6002
THT-7-423-3	3,000	Polyester	White	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R6002
THT-7-424-3	3,000	Paper	White	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R4300
THT-7-428-3	3,000	Metallized Polyester	Silver	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R4300
THT-7-438-3	3,000	Tamper-Evident Polyester	Silver	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R4300
THT-7-483-3	3,000	Polyester	White	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R6002
THT-7-486-3	3,000	Metallized Polyester	Silver	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R4300
THT-7-489-3	3,000	Polyester	White	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R4300
THT-7-7546-10	10,000	Tamper-Evident Polyester	White	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R6002
THT-7-7566-3	3,000	Tamper-Evident Polyester	Clear	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R6002
THT-7-7576-10	10,000	Tamper-Evident Polyester	Silver	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R6002
XHTT-7-8425-3	3,000	Polypropylene	White	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R6202
XHTT-7-8425-5	5,000	Polypropylene	White	1	2.750 (69.85)	1.250 (31.75)	—	1.375 (34.93)	2.950 (74.93)	R6202
<b>2.875" Label Width</b>										
THT-159-422-5	5,000	Polyester	White	1	2.875 (73.03)	0.375 (9.53)	—	1.375 (34.93)	2.950 (74.93)	R6202
<b>3.000" Label Width</b>										
THT-16-423-2.5	2,500	Polyester	White	1	3.000 (76.20)	0.250 (6.35)	—	0.375 (9.53)	3.200 (81.28)	R6002
THT-16-426-2.5	2,500	Polyimide	Amber	1	3.000 (76.20)	0.250 (6.35)	—	0.375 (9.53)	3.200 (81.28)	R4300
THT-16-478-2.5	2,500	Polyimide	White	1	3.000 (76.20)	0.250 (6.35)	—	0.375 (9.53)	3.200 (81.28)	R6002
THT-16-479-2.5	2,500	Polyimide	White	1	3.000 (76.20)	0.250 (6.35)	—	0.375 (9.53)	3.200 (81.28)	R6002
THT-16-495-2.5	2,500	PEN	White	1	3.000 (76.20)	0.250 (6.35)	—	0.375 (9.53)	3.200 (81.28)	R6002
THT-16-497-2.5	2,500	Polyimide	White	1	3.000 (76.20)	0.250 (6.35)	—	0.375 (9.53)	3.200 (81.28)	R6002
THT-18-351-3	3,000	Tamper-Resistant Vinyl	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6202
THT-18-352-3	3,000	Tamper-Resistant Vinyl	Silver	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-358-3	3,000	Tamper-Resistant Acetate	Clear	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6202
THT-18-359-3	3,000	Tamper-Resistant Acetate	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6202
THT-18-402-5.2	5,200	Paper	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6102
THT-18-407-3	3,000	Polyolefin	Clear	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6202

**Note:** Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).

\*For use with Hover-Davis vertical format label feeders.


Label Index by Size

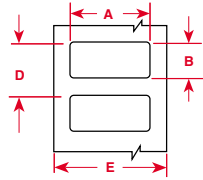

Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
<b>3.000" Label Width (Cont.)</b>										
THT-18-408-3	3,000	Paper	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6102
THT-18-422-3	3,000	Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-423-3	3,000	Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-424-3	3,000	Paper	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R4300
THT-18-428-3	3,000	Metallized Polyester	Silver	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R4300
THT-18-430-3	3,000	Polyester	Clear	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-433-3	3,000	Removable Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-434-3	3,000	Metallized Polyester	Silver	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-435-3	3,000	Glossy Metallized Polyester	Silver	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-438-3	3,000	Tamper-Evident Polyester	Silver	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R4300
THT-18-449-3	3,000	Polypropylene	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6202
THT-18-483-3	3,000	Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-486-3	3,000	Metallized Polyester	Silver	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R4300
THT-18-488-3	3,000	Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R4300
THT-18-489-3	3,000	Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R4300
THT-18-7546-3	3,000	Tamper-Evident Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-7566-3	3,000	Tamper-Evident Polyester	Clear	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-18-7576-3	3,000	Tamper-Evident Polyester	Silver	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
XHT-18-8423-5	5,000	Polyester	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6202
XHT-18-8425-5	5,000	Polyolefin	White	1	3.000 (76.20)	1.000 (25.40)	—	1.125 (28.58)	3.200 (81.28)	R6002
THT-19-351-1	1,000	Tamper-Resistant Vinyl	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6202
THT-19-352-1	1,000	Tamper-Resistant Vinyl	Silver	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-358-1	1,000	Tamper-Resistant Acetate	Clear	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6202
THT-19-359-1	1,000	Tamper-Resistant Acetate	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6202
THT-19-402-3	3,000	Paper	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6102
THT-19-407-1	1,000	Polyolefin	Clear	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6202
THT-19-408-1	1,000	Paper	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6102
THT-19-422-1	1,000	Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-423-1	1,000	Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-424-1	1,000	Paper	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R4300
THT-19-428-1	1,000	Metallized Polyester	Silver	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R4300
THT-19-430-1	1,000	Polyester	Clear	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-432-1	1,000	Polyester	Clear	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-433-1	1,000	Removable Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-434-1	1,000	Metallized Polyester	Silver	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-435-1	1,000	Glossy Metallized Polyester	Silver	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-438-1	1,000	Tamper-Evident Polyester	Silver	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R4300
THT-19-449-1	1,000	Polypropylene	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6202
THT-19-459-1	1,000	Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-483-1	1,000	Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-486-1	1,000	Metallized Polyester	Silver	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R4300
THT-19-488-1	1,000	Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R4300
THT-19-489-1	1,000	Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R4300
THT-19-7546-1	1,000	Tamper-Evident Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-19-7576-1	1,000	Tamper-Evident Polyester	Silver	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
XHT-19-8423-3	3,000	Polyester	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6202
XHT-19-8425-3	3,000	Polyolefin	White	1	3.000 (76.20)	2.000 (50.80)	—	2.125 (53.98)	3.200 (81.28)	R6002
THT-20-402-11	1,100	Paper	White	1	3.000 (76.20)	5.000 (127.00)	—	5.125 (130.18)	3.200 (81.28)	R6102
THT-20-408-1	1,000	Paper	White	1	3.000 (76.20)	5.000 (127.00)	—	5.125 (130.18)	3.200 (81.28)	R6102
THT-20-424-1	1,000	Paper	White	1	3.000 (76.20)	5.000 (127.00)	—	5.125 (130.18)	3.200 (81.28)	R4300
XHT-20-8425-1	1,000	Polypropylene	White	1	3.000 (76.20)	5.000 (127.00)	—	5.125 (130.18)	3.200 (81.28)	R6202
THT-21-407	1	Polyolefin	Clear	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R6202
THT-21-423	1	Polyester	White	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R6002
THT-21-424	1	Paper	White	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R4300
THT-21-428	1	Metallized Polyester	Silver	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R4300
THT-21-430	1	Polyester	Clear	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R6002

**Note:** Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).

LABEL INDEX BY SIZE THERMAL TRANSFER LABELS

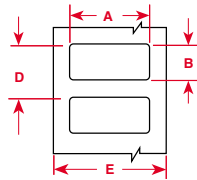


Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
<b>3.000" Label Width (Cont.)</b>										
THT-21-434	1	Metallized Polyester	Silver	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R6002
THT-21-437	1	Tedlar®	White	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R4300
THT-21-437-YL	1	Tedlar	Yellow	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R4300
THT-21-438	1	Tamper-Evident Polyester	Silver	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R4300
THT-21-439	1	Colored Vinyl	White	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R6002
THT-21-483	1	Polyester	White	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R6002
THT-21-486	1	Metallized Polyester	Silver	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R4300
THT-21-489	1	Polyester	White	1	3.000 (76.20)	300 ft (91.44 m)	—	300 ft (91.44 m)	3.200 (81.28)	R4300
<b>3.600" Label Width</b>										
THT-160-422-5	5,000	Polyester	White	1	3.600 (91.44)	0.375 (9.50)	—	0.475 (12.07)	3.800 (96.52)	R6007
<b>3.750" Label Width</b>										
THT-158-490-3	3,000	Polyester	White	1	3.750 (95.25)	1.500 (38.10)	—	1.625 (41.28)	3.950 (100.33)	R4300
<b>4.000" Label Width</b>										
THT-55-402-3	3,000	Paper	White	1	4.000 (101.60)	2.000 (50.80)	—	2.125 (53.98)	4.200 (106.68)	R6107
THT-55-408-1	1,000	Paper	White	1	4.000 (101.60)	2.000 (50.80)	—	2.125 (53.98)	4.200 (106.68)	R6107
THT-55-423-1	1,000	Polyester	White	1	4.000 (101.60)	2.000 (50.80)	—	2.125 (53.98)	4.200 (106.68)	R6007
THT-55-424-1	1,000	Paper	White	1	4.000 (101.60)	2.000 (50.80)	—	2.125 (53.98)	4.200 (106.68)	R4307
THT-55-428-1	1,000	Metallized Polyester	Silver	1	4.000 (101.60)	2.000 (50.80)	—	2.125 (53.98)	4.200 (106.68)	R4307
THT-55-434-1	1,000	Metallized Polyester	Silver	1	4.000 (101.60)	2.000 (50.80)	—	2.125 (53.98)	4.200 (106.68)	R6007
THT-55-435-1	1,000	Glossy Metallized Polyester	Silver	1	4.000 (101.60)	2.000 (50.80)	—	2.125 (53.98)	4.200 (106.68)	R6007
THT-55-449-1	1,000	Polypropylene	White	1	4.000 (101.60)	2.000 (50.80)	—	2.125 (53.98)	4.200 (106.68)	R6207
THT-55-483-1	1,000	Polyester	White	1	4.000 (101.60)	2.000 (50.80)	—	2.125 (53.98)	4.200 (106.68)	R6007
THT-55-488-1	1,000	Polyester	White	1	4.000 (101.60)	2.000 (50.80)	—	2.125 (53.98)	4.200 (106.68)	R4307
THT-55-489-1	1,000	Polyester	White	1	4.000 (101.60)	2.000 (50.80)	—	2.125 (53.98)	4.200 (106.68)	R4307
XHTHT-55-8423-3	3,000	Polyester	White	1	4.000 (101.60)	2.000 (50.80)	—	2.125 (53.98)	4.200 (106.68)	R6207
XHTHT-55-8425-3	3,000	Polyolefin	White	1	4.000 (101.60)	2.000 (50.80)	—	2.125 (53.98)	4.200 (106.68)	R6007
THT-76-422-1	1,000	Polyester	White	1	4.000 (101.60)	3.000 (76.20)	—	3.125 (79.38)	4.200 (106.68)	R6007
THT-76-449-1	1,000	Polypropylene	White	1	4.000 (101.60)	3.000 (76.20)	—	3.125 (79.38)	4.200 (106.68)	R6207
THT-76-483-1	1,000	Polyester	White	1	4.000 (101.60)	3.000 (76.20)	—	3.125 (79.38)	4.200 (106.68)	R6007
THT-76-489-1	1,000	Polyester	White	1	4.000 (101.60)	3.000 (76.20)	—	3.125 (79.38)	4.200 (106.68)	R4300
XHTHT-76-8425-1	1,000	Polypropylene	White	1	4.000 (101.60)	3.000 (76.20)	—	3.125 (79.38)	4.200 (106.68)	R6207
THT-77-402-1.4	1,400	Paper	White	1	4.000 (101.60)	4.000 (101.60)	—	4.125 (104.78)	4.125 (104.78)	R6107
THT-161-423-1	1,000	Polyester	White	1	4.000 (101.60)	4.000 (101.60)	—	4.125 (104.78)	4.200 (106.68)	R6007
THT-161-483-1	1,000	Polyester	White	1	4.000 (101.60)	4.000 (101.60)	—	4.125 (104.78)	4.200 (106.68)	R6007
THT-161-486-1	1,000	Metallized Polyester	Silver	1	4.000 (101.60)	4.000 (101.60)	—	4.125 (104.78)	4.200 (106.68)	R4307
THT-25-402-1	1,000	Paper	White	1	4.000 (101.60)	6.000 (152.40)	—	6.125 (155.58)	4.200 (106.68)	R6107
THT-25-408-1	1,000	Paper	White	1	4.000 (101.60)	6.000 (152.40)	—	6.125 (155.58)	4.200 (106.68)	R6107
THT-25-424-1	1,000	Paper	White	1	4.000 (101.60)	6.000 (152.40)	—	6.125 (155.58)	4.200 (106.68)	R4307
THT-78-402-0.9	900	Paper	White	1	4.000 (101.60)	6.500 (165.10)	—	6.625 (168.28)	4.125 (104.78)	R6107
THT-78-408-1	1,000	Paper	White	1	4.000 (101.60)	6.500 (165.10)	—	6.625 (168.28)	4.200 (106.68)	R6107
THT-107-423	1	Polyester	White	1	4.000 (101.60)	300 ft (91.44 m)	—	300 ft (91.44 m)	4.200 (106.68)	R6007
THT-107-428	1	Metallized Polyester	Silver	1	4.000 (101.60)	300 ft (91.44 m)	—	300 ft (91.44 m)	4.200 (106.68)	R4307
THT-107-439	1	Colored Vinyl	White	1	4.000 (101.60)	300 ft (91.44 m)	—	300 ft (91.44 m)	4.200 (106.68)	R6007
THT-107-483	1	Polyester	White	1	4.000 (101.60)	300 ft (91.44 m)	—	300 ft (91.44 m)	4.200 (106.68)	R6007
THT-107-486	1	Metallized Polyester	Silver	1	4.000 (101.60)	300 ft (91.44 m)	—	300 ft (91.44 m)	4.200 (106.68)	R4307

**Note:** Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).

Tedlar® is a registered trademark of DuPont.

PermaShield™ Markers by Size

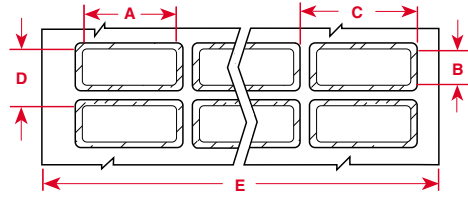


Clear polyester (B-966) overlaminate extends 0.125" outside of label on each side.

Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Horizontal Repeat Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
<b>1.250" Label Width</b>										
THT-22-423-2	2,000	Polyester	White	2	1.250 (31.75)	0.750 (19.05)	1.650 (41.91)	1.125 (28.58)	3.350 (85.09)	R6002
THT-22-428-2	2,000	Metallized Polyester	Silver	2	1.250 (31.75)	0.750 (19.05)	1.650 (41.91)	1.125 (28.58)	3.350 (85.09)	R4300
<b>2.000" Label Width</b>										
THT-23-423-2	2,000	Polyester	White	1	2.000 (50.80)	1.000 (25.40)	NA	1.375 (34.93)	2.450 (62.23)	R6000
THT-23-428-2	2,000	Metallized Polyester	Silver	1	2.000 (50.80)	1.000 (25.40)	NA	1.375 (34.93)	2.450 (62.23)	R4302
<b>2.750" Label Width</b>										
THT-24-423-1	1,000	Polyester	White	1	2.750 (69.85)	1.750 (44.45)	NA	2.125 (53.98)	3.200 (81.28)	R6002
THT-24-428-1	1,000	Metallized Polyester	Silver	1	2.750 (69.85)	1.750 (44.45)	NA	2.125 (53.98)	3.200 (81.28)	R4300

**Note:** Labels in chart are sorted in order by width, height, 3 or 4 digit material number (within part number), then die number (within part number).

\* This product is sold in Japan under the Overlaminated Labels name and not under the PermaShield name.

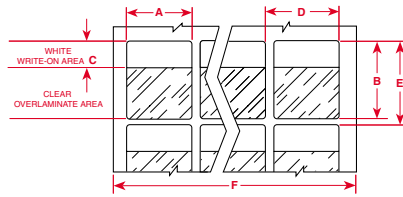


Part Number	Pieces Per Pkg.	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Write-On Height Inch (mm) C	Horizontal Repeat Inch (mm) D	Vertical Repeat Inch (mm) E	Web Width Inch (mm) F	Recommended Ribbon
<b>0.500" Label Width</b>											
THT-80-427-5	5,000	Vinyl	White/Transparent	4	0.500 (12.70)	0.750 (19.05)	0.375 (9.53)	0.600 (15.24)	0.950 (24.13)	2.500 (63.50)	R4302
THT-113-427-5	5,000	Vinyl	White/Transparent	4	0.500 (12.70)	1.000 (25.90)	0.375 (9.53)	0.600 (15.24)	1.125 (28.58)	2.500 (63.50)	R4302
THT-114-427-5	5,000	Vinyl	White/Transparent	4	0.500 (12.70)	1.250 (31.75)	0.500 (12.70)	0.600 (15.24)	1.375 (34.93)	2.500 (63.50)	R4302
THT-8-427-10	10,000	Vinyl	White/Transparent	5	0.500 (12.70)	1.437 (36.50)	0.500 (12.70)	0.662 (16.81)	1.625 (41.28)	3.350 (85.09)	R4300
<b>0.750" Label Width</b>											
THT-56-427-10	10,000	Vinyl	White/Transparent	4	0.750 (19.05)	0.938 (23.81)	0.375 (9.52)	0.800 (20.32)	1.125 (28.58)	3.350 (85.09)	R4300
THT-73-427-10	10,000	Vinyl	White/Transparent	4	0.750 (19.05)	1.750 (44.45)	0.500 (12.70)	0.800 (20.32)	1.875 (47.63)	3.350 (85.09)	R4300
<b>0.800" Label Width</b>											
THT-74-427-10	10,000	Vinyl	White/Transparent	4	0.800 (20.32)	1.437 (36.50)	0.500 (12.70)	0.800 (20.32)	1.625 (41.28)	3.350 (85.09)	R4300
<b>1.000" Label Width</b>											
THT-115-427-5	5,000	Vinyl	White/Transparent	2	1.000 (25.40)	0.750 (19.05)	0.375 (9.53)	1.100 (27.94)	0.875 (22.23)	2.300 (58.42)	R4302
THT-116-427-5	5,000	Vinyl	White/Transparent	2	1.000 (25.40)	1.000 (25.40)	0.375 (9.53)	1.100 (27.94)	1.125 (28.58)	2.300 (58.42)	R4302
THT-9-427-10	10,000	Vinyl	White/Transparent	3	1.000 (25.40)	1.437 (36.50)	0.500 (12.70)	1.075 (27.30)	1.625 (41.28)	3.350 (85.09)	R4300
THT-75-427-3	3,000	Vinyl	White/Transparent	2	1.000 (25.40)	2.250 (57.15)	0.750 (19.05)	1.100 (27.94)	2.375 (60.33)	2.300 (58.42)	R4302
THT-10-427-3	3,000	Vinyl	White/Transparent	3	1.000 (25.40)	3.750 (95.25)	1.000 (25.40)	1.075 (27.30)	4.000 (101.60)	3.350 (85.09)	R4300
THT-139-461-2	2,000	Polyester	White/Transparent	1	1.000 (25.40)	5.250 (133.35)	1.500 (38.10)	N/A	5.325 (135.26)	1.200 (30.48)	R4306
THT-81-427-1	1,000	Vinyl	White/Transparent	2	1.000 (25.40)	6.000 (152.40)	1.500 (38.10)	1.100 (27.94)	6.187 (157.15)	2.200 (55.88)	R4302
<b>1.500" Label Width</b>											
THT-118-427-5	5,000	Vinyl	White/Transparent	1	1.500 (38.10)	1.000 (25.40)	0.375 (9.53)	N/A	1.125 (28.58)	1.700 (43.18)	R4302
THT-119-427-2.5	2,500	Vinyl	White/Transparent	1	1.500 (38.10)	1.500 (38.10)	0.500 (12.70)	N/A	1.625 (41.28)	1.700 (43.18)	R4302
<b>1.750" Label Width</b>											
THT-120-427-5	5,000	Vinyl	White/Transparent	1	1.750 (44.45)	1.000 (25.40)	0.375 (9.53)	N/A	1.125 (28.58)	1.950 (49.53)	R4302
THT-121-427-2.5	2,500	Vinyl	White/Transparent	1	1.750 (44.45)	1.500 (38.10)	0.500 (12.70)	N/A	1.625 (41.28)	1.950 (49.53)	R4302
<b>2.000" Label Width</b>											
THT-27-427-1	1,000	Vinyl	White/Transparent	1	2.000 (50.80)	3.750 (95.25)	1.000 (25.40)	N/A	4.000 (101.60)	2.200 (55.88)	R4302
THT-82-427-5	5,000	Vinyl	White/Transparent	1	2.000 (50.80)	6.000 (152.40)	1.500 (38.10)	N/A	6.250 (158.75)	2.200 (55.88)	R4302
THT-83-427-5	5,000	Vinyl	White/Transparent	1	2.000 (50.80)	7.000 (177.80)	1.500 (38.10)	N/A	7.187 (182.55)	2.200 (55.88)	R4302
<b>2.500" Label Width</b>											
THT-26-427-1	1,000	Vinyl	White/Transparent	1	2.500 (63.50)	2.250 (57.15)	0.750 (19.05)	N/A	2.438 (61.93)	2.700 (68.58)	R4300

Perforations exist between each row of self-laminating labels for easy tear off and fan folding.

**Note:** Labels in chart are sorted in order by width, height, 3 digit material number (within part number), then die number (within part number).

## Self-Laminating Labels by Size

### One-Across Rotated

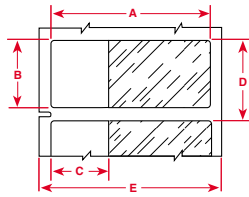

Part Number	Pieces Per Package	Material	Color	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Write-On Height Inch (mm) C	Vertical Repeat Inch (mm) D	Web Width Inch (mm) E	Recommended Ribbon
<b>0.500" Label Width</b>										
THT-61-427-5	5,000	Vinyl	White/Transparent	1	0.500 (12.70)	1.437 (36.50)	0.500 (12.70)	0.687 (17.45)	1.637 (41.58)	R4306
<b>0.750" Label Width</b>										
THT-62-427-3.5	3,500	Vinyl	White/Transparent	1	0.750 (19.05)	1.750 (44.45)	0.500 (12.70)	0.937 (23.80)	1.950 (49.53)	R4302
<b>0.800" Label Width</b>										
THT-63-427-3.5	3,500	Vinyl	White/Transparent	1	0.800 (20.32)	1.437 (36.50)	0.500 (12.70)	0.987 (25.07)	1.637 (41.58)	R4306
<b>1.000" Label Width</b>										
THT-64-427-3	3,000	Vinyl	White/Transparent	1	1.000 (25.40)	2.250 (57.15)	0.750 (19.05)	1.187 (30.15)	2.450 (62.23)	R4302
THT-65-427-3	3,000	Vinyl	White/Transparent	1	1.000 (25.40)	3.750 (95.25)	1.000 (25.40)	1.187 (30.15)	3.950 (100.33)	R4307
THT-84-427-3	3,000	Vinyl	White/Transparent	1	1.000 (25.40)	6.000 (152.40)	1.500 (38.10)	1.20 (30.48)	6.200 (157.48)	R4308
<b>1.625" Label Width</b>										
THT-133-461-3	3,000	Polyester	White/Transparent	1	1.625 (41.28)	0.600 (15.24)	1.000 (25.40)	0.700 (17.78)	1.825 (46.35)	R4302
<b>1.800" Label Width</b>										
THT-123-461-3	3,000	Polyester	White/Transparent	1	1.800 (45.72)	0.375 (9.53)	0.750 (19.05)	0.475 (12.07)	2.000 (50.80)	R4302
THT-122-461-3	3,000	Polyester	White/Transparent	1	1.800 (45.72)	0.500 (12.70)	0.750 (19.05)	0.625 (15.88)	2.000 (50.80)	R4302
<b>1.900" Label Width</b>										
THT-66-427-1.5	1,500	Vinyl	White/Transparent	1	1.900 (48.26)	3.187 (80.95)	0.750 (19.05)	2.150 (54.61)	3.387 (86.03)	R4300
<b>2.000" Label Width</b>										
THT-67-427-1.5	1,500	Vinyl	White/Transparent	1	2.000 (50.80)	2.250 (57.15)	0.750 (19.05)	2.187 (55.55)	2.450 (62.23)	R4302
THT-85-427-2	2,000	Vinyl	White/Transparent	1	2.000 (50.80)	6.000 (152.40)	1.500 (38.10)	2.200 (55.88)	6.200 (157.48)	R4308
THT-86-427-2	2,000	Vinyl	White/Transparent	1	2.000 (50.80)	7.000 (177.80)	1.500 (38.10)	2.200 (55.88)	7.200 (182.88)	R4308
<b>2.200" Label Width</b>										
THT-127-427-3	3,000	Vinyl	White/Transparent	1	2.200 (55.88)	0.500 (12.70)	0.750 (19.05)	0.625 (15.88)	2.400 (60.96)	R4302
THT-127-461-3	3,000	Polyester	White/Transparent	1	2.200 (55.88)	0.500 (12.70)	0.750 (19.05)	0.625 (15.88)	2.400 (60.96)	R4302
<b>2.625" Label Width</b>										
THT-153-461-3	3,000	Polyester	White/Transparent	1	2.625 (66.68)	0.600 (15.24)	1.000 (25.40)	0.750 (19.05)	2.825 (71.76)	R4300
THT-131-427-3	3,000	Vinyl	White/Transparent	1	2.625 (66.68)	1.000 (25.40)	1.000 (25.40)	1.125 (28.58)	2.825 (71.76)	R4300
<b>3.500" Label Width</b>										
THT-134-461-3	3,000	Polyester	White/Transparent	1	3.500 (88.90)	1.500 (38.10)	1.250 (31.75)	1.625 (41.28)	3.700 (93.98)	R4307

Perforations exist between each row of self-laminating labels for easy tear off and fan folding.

**Note:** Labels in chart are sorted in order by width, height, 3 digit material number (within part number), then die number (within part number).

## Tags by Size

### One-Across

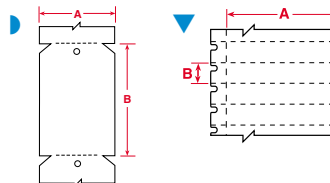


Diagram	Pieces Part Number	Per Package	Material	Color	Tag Width Inch (mm) A	Tag Height Inch (mm) B	Recommended Ribbon
<b>1.938" Label Width</b>							
▼	THT-150-412-1	1,000	Polyethylene Tag	White	1.938 (49.20)	0.375 (9.53)	R6200
<b>3.000" Label Width</b>							
▶	THT-33-109-0.5	500	Polyethylene Tag	White	3.000 (76.20)	6.000 (152.40)	R4300
▶	THT-33-411-1	2 rolls of 500	Polyolefin Tag	White	3.000 (76.20)	6.000 (152.40)	R4300
▶	THT-33-412-1	2 rolls of 500	Polypropylene Tag	White	3.000 (76.20)	6.000 (152.40)	R6202

**Note:** Labels in chart are sorted in order by width, height, 3 digit material number (within part number), then die number (within part number).