

THT Labels: Asset Tracking

www.BradyID.com

3" Core Asset Tracking Labels:

B-428 Polyester Labels

Color: Silver Metallic Finish: Matte

Thermal transfer printable metallized polyester with matte finish. Withstands solvents and variable temperatures. Excellent for serial and rating plate applications with name-plate quality and a metal-looking finish.

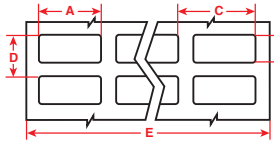


Figure 1

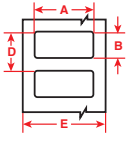


Figure 2

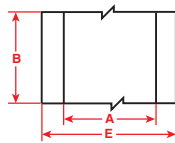


Figure 3

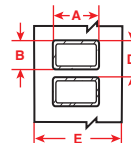


Figure 11



Diagram	Part Number	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Horiz. Repeat C Inch (mm)	Vert. Repeat D Inch (mm)	Web Width E Inch (mm)	Labels Per Row	Labels Per Pkg	Rec. Ribbon
Fig. 1	THT-12-428-10	Polyester	Silver	0.500 (12.7)	0.437 (11.1)	0.662 (16.8)	0.537 (13.6)	3.350 (85.1)	5	10,000	R4307
Fig. 1	THT-1-428-10	Polyester	Silver	0.750 (19.1)	0.250 (6.4)	0.800 (20.3)	0.350 (8.9)	3.350 (85.1)	4	10,000	R4307
Fig. 1	THT-3-428-10	Polyester	Silver	1.000 (25.4)	0.375 (9.5)	1.075 (27.3)	0.475 (12.1)	3.350 (85.1)	3	10,000	R4307
Fig. 1	THT-5-428-10	Polyester	Silver	1.000 (25.4)	0.500 (12.7)	1.075 (27.3)	0.600 (15.2)	3.350 (85.1)	3	10,000	R4307
Fig. 10	THT-22-428-2	Polyester	Silver	1.250 (31.8)	0.750 (19.1)	1.650 (41.9)	1.125 (28.6)	3.350 (85.1)	2	2,000	R4300
Fig. 1	THT-37-428-10	Polyester	Silver	1.500 (38.1)	0.500 (12.7)	1.650 (41.9)	0.600 (15.2)	3.350 (85.1)	2	10,000	R4307
Fig. 1	THT-6-428-10	Polyester	Silver	1.500 (38.1)	0.750 (19.1)	1.650 (41.9)	0.875 (22.2)	3.350 (85.1)	2	10,000	R4307
Fig. 3	THT-106-428	Polyester	Silver	2.000 (50.8)	300 ft. (91.4 m)	-	300 ft. (91.4 m)	2.200 (55.9)	1	1 Roll Cont.	R4302
Fig. 2	THT-17-428-3	Polyester	Silver	2.000 (50.8)	1.000 (25.4)	-	1.125 (28.6)	2.200 (55.9)	1	3,000	R4302
Fig. 2	THT-53-428-3	Polyester	Silver	2.000 (50.8)	0.500 (12.7)	-	0.600 (15.2)	2.200 (55.9)	1	3,000	R4302
Fig. 11	THT-23-428-2	Polyester	Silver	2.000 (50.8)	1.000 (25.4)	-	1.375 (34.9)	2.450 (62.2)	1	2,000	R4302
Fig. 2	THT-7-428-3	Polyester	Silver	2.750 (69.9)	1.250 (31.8)	-	1.375 (34.9)	2.950 (74.9)	1	3,000	R4300
Fig. 11	THT-24-428-1	Polyester	Silver	2.750 (69.9)	1.750 (44.5)	-	3.200 (81.3)	-	1	1,000	R4300
Fig. 2	THT-18-428-3	Polyester	Silver	3.000 (76.2)	1.000 (25.4)	-	1.125 (28.6)	3.200 (81.3)	1	3,000	R4300
Fig. 2	THT-19-428-1	Polyester	Silver	3.000 (76.2)	2.000 (50.8)	-	2.125 (54.0)	3.200 (81.3)	1	1,000	R4300
Fig. 3	THT-21-428	Polyester	Silver	3.000 (76.2)	300 ft. (91.4 m)	-	300 ft. (91.4 m)	3.200 (81.3)	1	1 Roll Cont.	R4300
Fig. 3	THT-107-428	Polyester	Silver	4.000 (101.6)	300 ft. (91.4 m)	-	300 ft. (91.4 m)	4.200 (106.7)	1	1 Roll Cont.	R4307
Fig. 2	THT-55-428-1	Polyester	Silver	4.000 (101.6)	2.000 (50.8)	-	2.125 (54.0)	4.200 (106.7)	1	1,000	R4307

NOTICE BBP[®]11 PRINTER ONLY: The following part numbers ending with "-SC" are 1" Small Core Rolls specially designed for use in the BBP11 Printer and do not require the BBP11 media adaptor accessory. View page 68 for more information.

Fig. 1	THT-5-428-5-SC	Polyester	Silver	1.000 (25.4)	0.500 (12.7)	1.075 (27.3)	0.600 (15.2)	3.350 (85.1)	3	5,000	R4313
Fig. 2	THT-17-428-1.5-SC	Polyester	Silver	2.000 (50.8)	1.000 (25.4)	-	1.125 (28.6)	2.200 (55.9)	1	1,500	R4313
Fig. 2	THT-18-428-1.5-SC	Polyester	Silver	3.000 (76.2)	1.000 (25.4)	-	1.125 (28.6)	3.200 (81.3)	1	1,500	R4313

3" Core Asset Tracking Labels:

B-430 Polyester Labels

Color: Clear Finish: Gloss

Translucent, high performance polyester material with a glossy finish. Non-colored label with permanent adhesive. Good for general purpose thermal transfer printing.

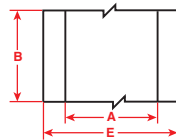


Figure 3

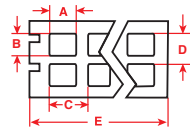


Figure 6

 


Figure 9



Diagram	Part Number	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Horiz. Repeat C Inch (mm)	Vert. Repeat D Inch (mm)	Web Width E Inch (mm)	Labels Per Row	Labels Per Pkg	Rec. Ribbon
Fig. 6	THT-149-430-10	Polyester	Clear	0.500 (12.7)	0.500 (12.7)	0.600 (15.2)	0.625 (15.9)	2.500 (63.5)	4	10,000	R6002
Fig. 6	THT-39-430-10	Polyester	Clear	1.000 (25.4)	0.500 (12.7)	1.075 (27.3)	0.625 (15.9)	3.350 (85.1)	3	10,000	R6007
Fig. 9	THT-17-430-3	Polyester	Clear	2.000 (50.8)	1.000 (25.4)	-	1.125 (28.6)	2.200 (55.9)	1	3,000	R6000
Fig. 9	THT-18-430-3	Polyester	Clear	3.000 (76.2)	1.000 (25.4)	-	1.125 (28.6)	3.200 (81.3)	1	3,000	R6002
Fig. 9	THT-19-430-1	Polyester	Clear	3.000 (76.2)	2.000 (50.8)	-	2.125 (54.0)	3.200 (81.3)	1	1,000	R6002
Fig. 3	THT-21-430	Polyester	Clear	3.000 (76.2)	300 ft. (91.4 m)	-	300 ft. (91.4 m)	3.200 (81.3)	1	1 Roll Cont.	R6002

NOTICE BBP[®]11 PRINTER ONLY: The following part numbers ending with "-SC" are 1" Small Core Rolls specially designed for use in the BBP11 Printer and do not require the BBP11 media adaptor accessory. View page 68 for more information.

Fig. 9	THT-17-430-1.5-SC	Polyester	Clear	2.000 (50.8)	1.000 (25.4)	-	1.125 (28.6)	2.200 (55.9)	1	1,500	R6013
Fig. 9	THT-18-430-1.5-SC	Polyester	Clear	3.000 (76.2)	1.000 (25.4)	-	1.125 (28.6)	3.200 (81.3)	1	1,500	R6013