




Product Number: THT-53-486-3
Thermal Transfer Printable Labels

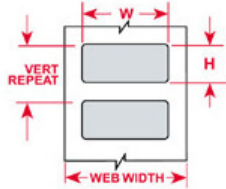

Specifications:

Application(s): General & Industrial Identification

Agency CSA Approved, UL Recognized

Approval(s)/Compliance:

Size: 2.000" W x 0.500" H (50.800 mm W x 12.700 mm H)

Printable Area: 2.000" W x 0.500" H (50.800 mm W x 12.700 mm H)

Web Width: 2.200" (55.88 mm)

Label Type/Style: Label

Vertical Repeat: 0.600" (15.24 mm)

Color: Silver

Finish: Matte

Brady Material #: B-486

Qty Per Row: 1

Material Type: Polyester

Material Description: Ultra Aggressive Metallized Polyester

Recommended Ribbon Series: 4300

Suggested Ribbon Part#: R4302

Printer Compatibility: BBP81, Brady 1244, Brady 1344, Brady 200MVP Plus, Brady 2461, Brady 300MVP Plus, Brady 300X-Plus II, Brady 3481, Brady 360X-Plus II, Brady 600X-Plus II, Brady 6441, Brady IP, Tagus T200, Tagus T300, Thermal Transfer Printers

Surface: Highly Textured, Low Surface Energy, Powder Coated, Smooth, Textured/Rough

Special Properties: Designed for powder coated surfaces, Ultra-aggressive adhesive

RoHS Compatibility: Compliant with RoHS Directive. NOTE: All statements concerning RoHS Directive compliance refer to 2005/618/EC MCV amendment to RoHS Directive 2002/95/EC. Product compliance is based upon information provided by suppliers of the raw materials used by Brady to manufacture these products, or by independent laboratory testing of these products. As such, Brady makes no independent representations or warranties, express or implied, and assumes no liability in connection with the use of this information.

QTY/UOM: 3,000/Roll