


Thermal Transfer Printable Labels

THT-82-427-0.5

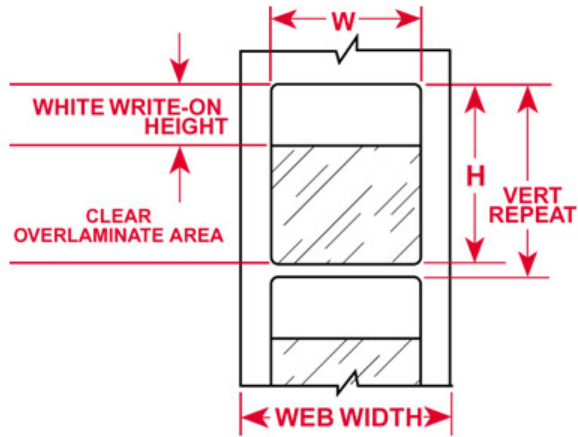

- Description:** Thermal Transfer Printable Labels
- Size:** 2.000" W x 6.000" H (50.80mm W x 152.40mm H)
- Brady Material #:** B-427
- Material Description:** Self-Laminating Vinyl
- Application(s):** Panel Identification, Wire & Cable Marking
- QTY/UOM:** 500/Roll

Size: 2.000" W x 6.000" H (50.80 mm W x 152.40 mm H)

Printable Area: 2.000" W x 1.500" H (50.80 mm W x 38.10 mm H)

Style: Roll-Form, Radius Corners

Label Type/Style: Self-Laminating Label

Color: White/Translucent

Finish: Matte

Qty Per Row: 1

Material Type: Vinyl

Brady Material #: [B-427](#)

Material Description: Self-Laminating Vinyl

Adhesive: Acrylic

Agency Approval(s)/Compliance: UL Recognized

RoHS Compatibility: Compliant with RoHS Directive. NOTE: All statements concerning RoHS Directive compliance refer to 2005/618/EC MCV amendment to RoHS Directive 2002/95/EC. Product compliance is based upon information provided by suppliers of the raw materials used by Brady to manufacture these products, or by independent laboratory testing of these products. As such, Brady makes no independent representations or warranties, express or implied, and assumes no liability in connection with the use of this information.

Special Properties: Excellent abrasion and smudge resistance, Excellent water & oil resistance, Self-Extinguishing, Self-Laminating

Vertical Repeat: 6.250" (158.75 mm)

Web Width: 2.200" (55.88 mm)

Recommended Ribbon Series: 4300

Acceptable Ribbon Series: 6200, 4500 (colors)

Printer Compatibility: Brady 1244, Brady 1344, Brady 200MVP Plus, Brady 2461, Brady 300MVP Plus, Brady 300X-Plus II, Brady 3481, Brady 360X-Plus II, Brady 600X-Plus II, Brady 6441, Brady IP™, Tagus™ T200, Tagus™ T300, Thermal Transfer Printers

Application(s): Panel Identification, Wire & Cable Marking