


Self-Laminating Wire and Cable Markers by Size

► BUTT-CUT

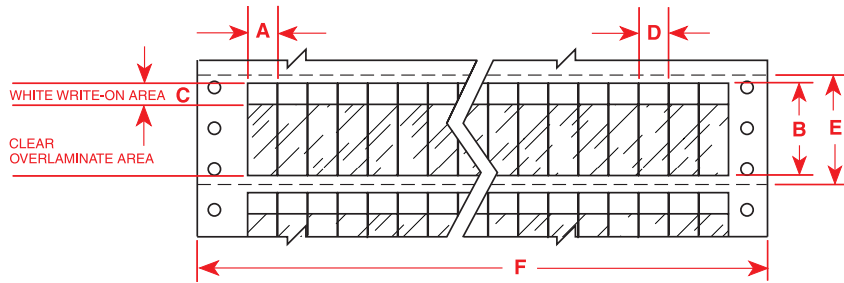

Part Number	Pieces Per Package	Material	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Write-On Height Inch (mm) C	Horizontal Repeat Inch (mm) D	Vertical Repeat Inch (mm) E	Web Width Inch (mm) F
<b>1.000" Label Width — 6 or 8 lines per inch (Cont.)</b>									
DAT-39-292-1,-2.5	1,000/2,500	Vinyl	8	1.000 (25.40)	3.750 (95.25)	1.000 (25.40)	1.000 (25.40)	4.000 (101.60)	9.000 (228.60)
DAT-39-292-BL**	2,500	Vinyl	8	1.000 (25.40)	3.750 (95.25)	1.000 (25.40)	1.000 (25.40)	4.000 (101.60)	9.000 (228.60)
DAT-39-292-BR**	2,500	Vinyl	8	1.000 (25.40)	3.750 (95.25)	1.000 (25.40)	1.000 (25.40)	4.000 (101.60)	9.000 (228.60)
DAT-39-292-GR**	2,500	Vinyl	8	1.000 (25.40)	3.750 (95.25)	1.000 (25.40)	1.000 (25.40)	4.000 (101.60)	9.000 (228.60)
DAT-39-292-GY**	2,500	Vinyl	8	1.000 (25.40)	3.750 (95.25)	1.000 (25.40)	1.000 (25.40)	4.000 (101.60)	9.000 (228.60)
DAT-39-292-OR**	2,500	Vinyl	8	1.000 (25.40)	3.750 (95.25)	1.000 (25.40)	1.000 (25.40)	4.000 (101.60)	9.000 (228.60)
DAT-39-292-PL**	2,500	Vinyl	8	1.000 (25.40)	3.750 (95.25)	1.000 (25.40)	1.000 (25.40)	4.000 (101.60)	9.000 (228.60)
DAT-39-292-RD**	2,500	Vinyl	8	1.000 (25.40)	3.750 (95.25)	1.000 (25.40)	1.000 (25.40)	4.000 (101.60)	9.000 (228.60)
DAT-39-292-YL**	2,500	Vinyl	8	1.000 (25.40)	3.750 (95.25)	1.000 (25.40)	1.000 (25.40)	4.000 (101.60)	9.000 (228.60)
SLSH-10375	408	Vinyl	8	1.000 (25.40)	3.750 (95.25)	1.000 (25.40)	1.000 (25.40)	4.000 (101.60)	9.000 (228.60)
<b>2.000" Label Width — 6 or 8 lines per inch</b>									
DAT-35-292-1,-10	1,000/10,000	Vinyl	4	2.000 (50.80)	1.437 (36.50)	0.500 (12.70)	2.000 (50.80)	1.500 (38.10)	9.000 (228.60)
SLSH-2015	416	Vinyl	4	2.000 (50.80)	1.437 (36.50)	0.500 (12.70)	2.000 (50.80)	1.500 (38.10)	9.000 (228.60)
DAT-38-292-1,-2.5	1,000/2,500	Vinyl	4	2.000 (50.80)	2.250 (57.15)	0.750 (19.05)	2.000 (50.80)	2.500 (63.50)	9.000 (228.60)
DAT-38-292-BL**	2,500	Vinyl	4	2.000 (50.80)	2.250 (57.15)	0.750 (19.05)	2.000 (50.80)	2.500 (63.50)	9.000 (228.60)
DAT-38-292-BR**	2,500	Vinyl	4	2.000 (50.80)	2.250 (57.15)	0.750 (19.05)	2.000 (50.80)	2.500 (63.50)	9.000 (228.60)
DAT-38-292-GR**	2,500	Vinyl	4	2.000 (50.80)	2.250 (57.15)	0.750 (19.05)	2.000 (50.80)	2.500 (63.50)	9.000 (228.60)
DAT-38-292-GY**	2,500	Vinyl	4	2.000 (50.80)	2.250 (57.15)	0.750 (19.05)	2.000 (50.80)	2.500 (63.50)	9.000 (228.60)
DAT-38-292-OR**	2,500	Vinyl	4	2.000 (50.80)	2.250 (57.15)	0.750 (19.05)	2.000 (50.80)	2.500 (63.50)	9.000 (228.60)
DAT-38-292-PL**	2,500	Vinyl	4	2.000 (50.80)	2.250 (57.15)	0.750 (19.05)	2.000 (50.80)	2.500 (63.50)	9.000 (228.60)
DAT-38-292-RD**	2,500	Vinyl	4	2.000 (50.80)	2.250 (57.15)	0.750 (19.05)	2.000 (50.80)	2.500 (63.50)	9.000 (228.60)
DAT-38-292-YL**	2,500	Vinyl	4	2.000 (50.80)	2.250 (57.15)	0.750 (19.05)	2.000 (50.80)	2.500 (63.50)	9.000 (228.60)
SLSH-20225	304	Vinyl	4	2.000 (50.80)	2.250 (57.15)	0.750 (19.05)	2.000 (50.80)	2.500 (63.50)	9.000 (228.60)
DAT-40-292-1,-2.5	1,000/2,500	Vinyl	4	2.000 (50.80)	3.750 (95.25)	1.000 (25.40)	2.000 (50.80)	4.000 (101.60)	9.000 (228.60)
DAT-40-292-BL**	2,500	Vinyl	4	2.000 (50.80)	3.750 (95.25)	1.000 (25.40)	2.000 (50.80)	4.000 (101.60)	9.000 (228.60)
DAT-40-292-BR**	2,500	Vinyl	4	2.000 (50.80)	3.750 (95.25)	1.000 (25.40)	2.000 (50.80)	4.000 (101.60)	9.000 (228.60)
DAT-40-292-GR**	2,500	Vinyl	4	2.000 (50.80)	3.750 (95.25)	1.000 (25.40)	2.000 (50.80)	4.000 (101.60)	9.000 (228.60)
DAT-40-292-GY**	2,500	Vinyl	4	2.000 (50.80)	3.750 (95.25)	1.000 (25.40)	2.000 (50.80)	4.000 (101.60)	9.000 (228.60)
DAT-40-292-OR**	2,500	Vinyl	4	2.000 (50.80)	3.750 (95.25)	1.000 (25.40)	2.000 (50.80)	4.000 (101.60)	9.000 (228.60)
DAT-40-292-PL**	2,500	Vinyl	4	2.000 (50.80)	3.750 (95.25)	1.000 (25.40)	2.000 (50.80)	4.000 (101.60)	9.000 (228.60)
DAT-40-292-RD**	2,500	Vinyl	4	2.000 (50.80)	3.750 (95.25)	1.000 (25.40)	2.000 (50.80)	4.000 (101.60)	9.000 (228.60)
DAT-40-292-YL**	2,500	Vinyl	4	2.000 (50.80)	3.750 (95.25)	1.000 (25.40)	2.000 (50.80)	4.000 (101.60)	9.000 (228.60)
SLSH-20375	204	Vinyl	4	2.000 (50.80)	3.750 (95.25)	1.000 (25.40)	2.000 (50.80)	4.000 (101.60)	9.000 (228.60)

\*\*BL=blue, BR=brown, GR=green, GY=grey, OR=orange, PL=purple, RD=red, YL=yellow.  
Standard product lead time of 10 working days.

Note: Labels in chart are sorted in order by width, height, 3 digit material number (within part number), then die number (within part number).