


Self-Laminating Wire and Cable Markers by Size

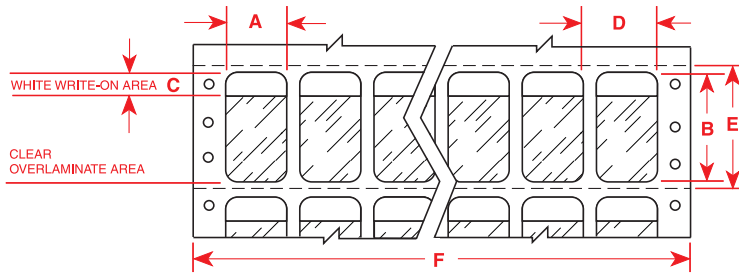

Part Number	Pieces Per Package	Material	Labels Per Row	Label Width Inch (mm) A	Label Height Inch (mm) B	Write-On Height Inch (mm) C	Horizontal Repeat Inch (mm) D	Vertical Repeat Inch (mm) E	Web Width Inch (mm) F
2.000" Label Width — 6 or 8 lines per inch									
DAT-9-292*-1,-2.5	1000/2500	Vinyl	6	2.000 (50.80)	5.937 (150.80)	1.500 (38.10)	2.100 (53.34)	6.000 (152.40)	13.500 (342.90)
DAT-75-292-1,-2.5	1,000/2,500	Vinyl	3	2.000 (50.80)	5.937 (150.80)	1.500 (38.10)	2.100 (53.34)	6.000 (152.40)	7.000 (177.80)
DAT-75-292-BL**	2,500	Vinyl	3	2.000 (50.80)	5.937 (150.80)	1.500 (38.10)	2.100 (53.34)	6.000 (152.40)	7.000 (177.80)
DAT-75-292-BR**	2,500	Vinyl	3	2.000 (50.80)	5.937 (150.80)	1.500 (38.10)	2.100 (53.34)	6.000 (152.40)	7.000 (177.80)
DAT-75-292-GR**	2,500	Vinyl	3	2.000 (50.80)	5.937 (150.80)	1.500 (38.10)	2.100 (53.34)	6.000 (152.40)	7.000 (177.80)
DAT-75-292-GY**	2,500	Vinyl	3	2.000 (50.80)	5.937 (150.80)	1.500 (38.10)	2.100 (53.34)	6.000 (152.40)	7.000 (177.80)
DAT-75-292-OR**	2,500	Vinyl	3	2.000 (50.80)	5.937 (150.80)	1.500 (38.10)	2.100 (53.34)	6.000 (152.40)	7.000 (177.80)
DAT-75-292-PL**	2,500	Vinyl	3	2.000 (50.80)	5.937 (150.80)	1.500 (38.10)	2.100 (53.34)	6.000 (152.40)	7.000 (177.80)
DAT-75-292-RD**	2,500	Vinyl	3	2.000 (50.80)	5.937 (150.80)	1.500 (38.10)	2.100 (53.34)	6.000 (152.40)	7.000 (177.80)
DAT-75-292-YL**	2,500	Vinyl	3	2.000 (50.80)	5.937 (150.80)	1.500 (38.10)	2.100 (53.34)	6.000 (152.40)	7.000 (177.80)
DAT-14-292*-1,-2.5	1,000/2,500	Vinyl	4	2.000 (50.80)	7.437 (188.90)	1.500 (38.10)	2.200 (55.88)	7.500 (190.50)	9.400 (238.76)
DAT-65-292-1,-2.5	1,000/2,500	Vinyl	3	2.000 (50.80)	7.437 (188.90)	1.500 (38.10)	2.100 (53.34)	7.500 (190.50)	7.200 (182.88)
DAT-159-292-1,-2.5	1,000/2,500	Vinyl	3	2.000 (50.80)	8.437 (214.30)	1.500 (38.10)	2.100 (53.34)	8.500 (215.90)	7.200 (182.88)
DAT-159-292-BL**	2,500	Vinyl	3	2.000 (50.80)	8.437 (214.30)	1.500 (38.10)	2.100 (53.34)	8.500 (215.90)	7.200 (182.88)
DAT-159-292-BR**	2,500	Vinyl	3	2.000 (50.80)	8.437 (214.30)	1.500 (38.10)	2.100 (53.34)	8.500 (215.90)	7.200 (182.88)
DAT-159-292-GR**	2,500	Vinyl	3	2.000 (50.80)	8.437 (214.30)	1.500 (38.10)	2.100 (53.34)	8.500 (215.90)	7.200 (182.88)
DAT-159-292-GY**	2,500	Vinyl	3	2.000 (50.80)	8.437 (214.30)	1.500 (38.10)	2.100 (53.34)	8.500 (215.90)	7.200 (182.88)
DAT-159-292-OR**	2,500	Vinyl	3	2.000 (50.80)	8.437 (214.30)	1.500 (38.10)	2.100 (53.34)	8.500 (215.90)	7.200 (182.88)
DAT-159-292-PL**	2,500	Vinyl	3	2.000 (50.80)	8.437 (214.30)	1.500 (38.10)	2.100 (53.34)	8.500 (215.90)	7.200 (182.88)
DAT-159-292-RD**	2,500	Vinyl	3	2.000 (50.80)	8.437 (214.30)	1.500 (38.10)	2.100 (53.34)	8.500 (215.90)	7.200 (182.88)
DAT-159-292-YL**	2,500	Vinyl	3	2.000 (50.80)	8.437 (214.30)	1.500 (38.10)	2.100 (53.34)	8.500 (215.90)	7.200 (182.88)

*Size does not fit narrow carriage (80-column) printers. See p. 158 for identical narrow carriage labels.

**BL=blue, BR=brown, GR=green, GY=grey, OR=orange, PL=purple, RD=red, YL=yellow.
Standard product lead time of 10 working days.

Note: Labels in chart are sorted in order by width, height, 3 digit material number (within part number), then die number (within part number).