

BUD Enclosures



NEMA SHEET METAL BOXES 16 Gauge Steel


Design Features:

Designed to meet NEMA 1, 2, 4, 4X, 12, 13 and IP65 ratings. UL listed and tested to UL508-4X requirements. Continuous seam welded 16 ga. steel construction. Cover closes securely with unique key provided. Wall mounting holes located inside for security. Bonding studs for grounding are provided on base and door. Easily machined and modified to your particular requirements.

- Finish: Smooth Gray Powder Coat

Accessories:

- Includes 14 ga. steel, zinc plated removable inner panel

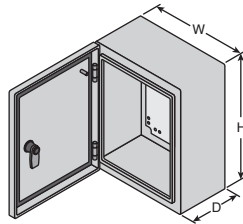

For quantities of 25 and up, call for quote.

MOUSER STOCK NO.	Bud Part No.	Dimensions: in.			Price Each			
		D	W	H	1	2	5	10
563-SNB3730	SNB3730	5.91	7.87	9.84	49.60	37.20	33.10	32.24
563-SNB3731	SNB3731	5.91	9.84	11.81	45.99	42.05	41.40	36.80
563-SNB3732	SNB3732	7.87	9.84	11.81	58.00	43.50	38.70	37.70
563-SNB3733	SNB3733	5.91	11.81	11.81	60.60	45.45	40.40	39.39
563-SNB3734	SNB3734	7.87	11.81	11.81	54.59	51.87	49.15	46.42
563-SNB3735	SNB3735	5.91	11.81	15.75	68.60	51.45	45.70	44.59
563-SNB3736	SNB3736	7.87	11.81	15.75	72.80	54.60	48.56	47.32
563-SNB3737	SNB3737	7.87	15.75	15.75	86.20	64.65	57.41	56.03

NEMA SHEET METAL BOXES 14 Gauge Steel with Mounting Brackets

Design Features:

Made from durable 14 ga. steel. Designed to meet NEMA 1, 2, 4, 4X, 12, 13 and IP65 and UL508-4X ratings. Hinged cover clamps to base with stainless screws and brackets for a watertight seal. Also comes with a 14 gauge steel, powder coated removable inner panel.

- Finish: Gray Powder Coat



For quantities of 25 and up, call for quote.

MOUSER STOCK NO.	Bud Part No.	Dimensions: in.			Price Each			
		D	W	H	1	5	10	25
563-SN-3700	SN-3700	4.00	6.00	3.00	40.70	34.45	30.60	28.70
563-SN-3701	SN-3701	6.00	8.00	3.50	55.20	41.40	36.80	35.88
563-SN-3702	SN-3702	6.00	6.00	4.00	50.70	38.03	33.76	32.96
563-SN-3703	SN-3703	10.00	12.00	5.00	89.50	67.13	59.71	58.18
563-SN-3704	SN-3704	8.00	10.00	6.00	84.80	63.57	56.49	55.13
563-SN-3705	SN-3705	12.00	12.00	6.00	104.60	78.45	69.77	67.99
563-SN-3706	SN-3706	12.00	14.00	6.00	114.10	85.58	76.03	74.17
563-SN-3707	SN-3707	14.00	16.00	6.00	136.30	102.25	90.87	88.60
563-SN-3708	SN-3708	12.00	14.00	8.00	130.00	97.50	86.63	84.50
563-SN-3709	SN-3709	14.00	16.00	10.00	168.00	126.00	111.96	109.20

FIBERGLASS NEMA BOX


Design Features:

Durable and easy to machine fiberglass reinforced plastic (SMC). Provides outstanding protection against corrosion. Chemical resistant and impervious to dents. Designed to meet NEMA 1, 2, 4, 4X, 12, 13, and IP66. Stainless steel hinge, screws, and wall mounting brackets. UL listed and tested to UL508-4X requirements.

- Finish: Light Gray

Accessories:

- Comes with steel, powder coated removable inner panel

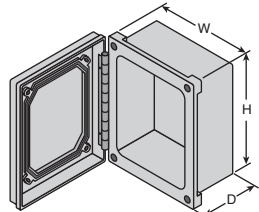


For quantities of 25 and up, call for quote.

MOUSER STOCK NO.	Bud Part No.	Dimensions: in.			Price Each			
		D	W	H	1	2	5	10
563-NF6610	NF6610	4.50	7.74	7.74	39.70	29.80	26.50	25.81
563-NF6611	NF6611	4.50	7.76	9.64	45.10	33.83	30.03	29.31
563-NF6612	NF6612	6.50	9.90	11.78	59.00	44.22	39.29	38.35
563-NF6613	NF6613	6.50	11.90	13.78	70.30	52.69	46.82	45.70
563-NF6614	NF6614	6.50	13.89	15.79	82.30	61.73	54.86	53.50

SLOPING PANEL CABINETS

Hinged top opens completely for access to components mounted on chassis.

- Finish: Metallic Gray

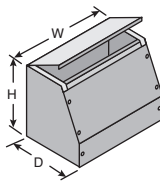


For quantities of 25 and up, call for quote.

MOUSER STOCK NO.	Bud Part No.	Dimensions: in.			Chassis to Fit	Price Each			
		D	W	H		1	2	5	10
563-C-1584	C-1584	7.31	7.06	6.50	AC-402	69.30	52.20	47.47	45.05
563-C-1585	C-1585	7.31	9.06	6.50	AC-405	66.80	50.18	46.39	43.43
563-C-1586	C-1586	7.31	11.06	6.50	AC-1413	78.35	58.78	52.46	50.90
563-C-1587	C-1587	8.00	8.06	8.00	AC-405	75.40	56.74	52.28	49.02
563-C-1588	C-1588	8.00	10.06	8.00	AC-406	83.80	62.96	56.14	54.47
563-C-1892	C-1892	8.50	13.06	8.00	AC-407	93.32	83.97	74.84	72.61
563-C-1893	C-1893	10.50	18.06	10.00	AC-415	137.62	123.87	110.48	107.19
563-C-1894	C-1894	8.00	14.06	8.00	AC-409	85.12	76.59	71.09	66.24
563-C-1896	C-1896	8.18	18.06	9.00	AC-1416	118.42	106.60	95.00	92.18

CONVERTA BOXES

.050" aluminum. Welded base and two-sided cover attached with self-tapping screws. Components or controls can be mounted to any surface.

- Finish: Natural

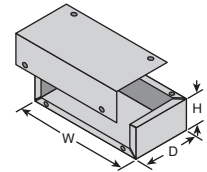

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Bud Part No.	Dimensions: in.			Price Each			
		D	W	H	1	5	10	25
563-CU341A	CU-341-A	3.00	4.00	1.50	12.35	10.24	9.25	8.20
563-CU452A	CU-452-A	4.00	5.00	2.00	14.60	12.20	11.00	9.75
563-CU482A	CU-482-A	4.00	8.00	2.00	17.30	14.45	13.00	11.55
563-CU592A	CU-592-A	5.00	9.50	2.50	19.80	16.54	14.90	13.25
563-CU622A	CU-622-A	6.00	12.00	2.50	26.00	21.74	19.60	17.40
563-CU712A	CU-712-A	7.00	15.00	2.50	35.80	29.90	26.90	23.90

SNC SERIES NEMA SHEET METAL BOXES


With Lift-off Screw Cover

Similar to the popular SNB series, but provides the option of an alternative secure screw closure. Wall mounting holes inside for security. Bonding studs for grounding are provided on base and door. Designed to meet NEMA 1, 2, 4, 4X and IP65 and UL508-4X. Continuous seam welded 16 ga. steel constructions.

- Finish: Smooth Gray

Accessories:

- Comes with 14 ga. steel, zinc plated removable inner panel and stainless steel wall mounting bracket

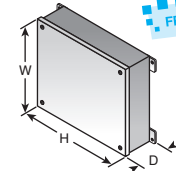


For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Bud Part No.	Dimensions: in.			Price Each			
		D	W	H	1	5	10	25
563-SNC-3750	SNC-3750	5.91	7.87	9.84	59.40	49.50	44.55	39.60
563-SNC-3751	SNC-3751	5.91	9.84	11.81	64.20	53.50	48.15	42.80
563-SNC-3752	SNC-3752	7.87	9.84	11.81	67.10	55.90	50.30	44.70
563-SNC-3753	SNC-3753	5.91	11.81	11.81	69.50	57.90	52.10	46.30
563-SNC-3754	SNC-3754	7.87	11.81	11.81	73.95	61.60	55.45	49.30
563-SNC-3755	SNC-3755	5.91	11.81	15.75	77.30	64.40	57.95	51.50
563-SNC-3756	SNC-3756	7.87	11.81	15.75	81.00	67.50	60.75	54.00
563-SNC-3757	SNC-3757	7.87	15.75	15.75	100.50	83.75	75.40	67.00

ALUMINUM DIE CAST NEMA 4X ENCLOSURE

With EMI/RFI Shielding

Can be mounted without need of removing cover with exposure of internal components. Rugged #ADC-12 alloy die cast aluminum. Thick wall construction provides strength and rigidity for heavy duty applications. One-piece molded outer Silicone gasket provides reliable and long lasting sealing to meet NEMA 4X & IP65 requirements. Second wire-mesh with sponge rubber gasket provides excellent EMI/RFI protection. Captive cover assembly screws located outside the sealing area.

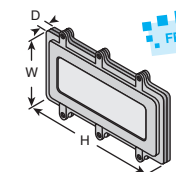


For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Bud Part No.	Dimensions: in.			Price Each			
		D	W	H	1	10	100	200
Natural Finish								
563-ANS-3801	ANS-3801	1.77	3.79	3.79	17.40	14.50	13.05	11.60
563-ANS-3803	ANS-3803	2.64	3.79	3.79	18.60	15.50	13.95	12.40
563-ANS-3805	ANS-3805	1.77	3.78	7.56	28.40	23.65	21.30	18.90
563-ANS-3807	ANS-3807	2.64	3.78	7.56	30.80	25.65	23.10	20.50
563-ANS-3809	ANS-3809	2.60	6.81	10.79	56.10	46.75	42.10	37.40
563-ANS-3811	ANS-3811	3.94	6.81	10.79	62.80	52.35	47.10	41.90
563-ANS-3813	ANS-3813	1.97	3.94	5.91	25.60	21.35	19.20	17.10
563-ANS-3815	ANS-3815	2.95	3.94	5.91	30.30	25.25	22.75	20.20
563-ANS-3817	ANS-3817	1.97	5.91	7.87	46.80	39.00	35.10	31.20
563-ANS-3819	ANS-3819	2.95	5.91	7.87	51.80	43.15	38.85	34.50
Black Finish								
563-ANS-3801-B	ANS-3801-B	1.77	3.79	3.79	22.10	18.40	16.55	14.70
563-ANS-3803-B	ANS-3803-B	2.64	3.79	3.79	23.90	19.90	17.90	15.90
563-ANS-3805-B	ANS-3805-B	1.77	3.78	7.56	35.10	29.25	26.35	23.40
563-ANS-3807-B	ANS-3807-B	2.64	3.78	7.56	38.80	32.35	29.10	25.90
563-ANS-3809-B	ANS-3809-B	2.60	6.81	10.79	76.05	56.76	51.00	44.93
563-ANS-3811-B	ANS-3811-B	3.94	6.81	10.79	76.00	63.35	57.00	50.70
563-ANS-3813-B	ANS-3813-B	1.97	3.94	5.91	32.20	26.85	24.15	21.50
563-ANS-3815-B	ANS-3815-B	2.95	3.94	5.91	38.20	31.85	28.65	25.50
563-ANS-3817-B	ANS-3817-B	1.97	5.91	7.87	57.40	47.85	43.05	38.30
563-ANS-3819-B	ANS-3819-B	2.95	5.91	7.87	63.70	53.10	47.80	42.50

DIE CAST EXTERNAL MOUNTING BRACKETS

 External mounting brackets enable die cast boxes to be wall or panel mounted without opening the box. Package consists of 4 brackets and attaching screws. Can be used with all AN and ANS series Bud die cast boxes except for AN-2901 and AN-2902.



For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Bud Part No.	Color	Price Each			
			1	5	10	25
563-ANX-1390	ANX-1390	Natural	3.75	3.57	3.40	3.17
563-ANX-1390-B	ANX-1390-B	Black	6.24	5.94	5.65	5.27
563-ANX-1390-G	ANX-1390-G	Gray	6.24	5.94	5.65	5.27