



The worldwide leader in thermal management solutions

[News](#) [About Us](#) [Contact Us](#) [Global Manufacturing](#) [Shop Aavid](#)

[Products](#)

[Solutions](#)

[Industries](#)

Search Aavid

[Register or Sign Into Your Account](#)


[Cart](#)

[Knowledge Center](#)

[Design Help](#)

» [Mounting Pads](#)

7717-16DAPG

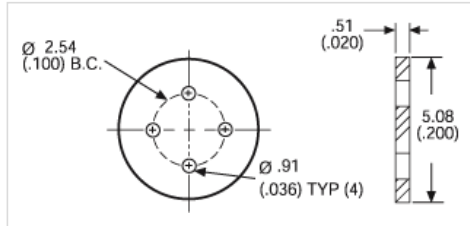

QTY IN STOCK: 1,500

ENTER QTY:

[VIEW PRICE](#)

Need assistance?

Call us: 1-855-32-AAVID
Email: estore@aavid.com

[» Help Page](#)

The Fine Print

[Product Return Policy](#)
[Terms & Conditions](#)
[Privacy Policy](#)

Standard Mounting Pads, TO-18

Diallyl Phthalate

Leads: 4

Diameter: 5.08

Thickness: 0.51

[Download PCN](#)

Material Specifications

Suffix	Base Material	Maximum Operating Temperature		Color
		Continuous	Deflection	
-N	Nylon base resin per ASTM STD D4066-82 PA111	121.0°C 250°F	243.3°C 470°F	Natural
-DAP*	Diallyl Phthalate per MIL-M-14G Type SDG	204.4°C 400°F	282.2°C 540°F	Black only

* All "-DAP" mounting pads meet UL 94V-0

Note: Please specify material for each mounting pad:

"N" = nylon; "Dap" = Diallyl Phtalante.

Example: 7717-3N, 7717-86DAP

Customer Assistance

- [Contact Us](#)
- [Get Design Assistance](#)
- [Find a Distributor](#)
- [Find a Sales Rep](#)
- [Request a Quote](#)
- [Placing an Order](#)
- [Terms and Conditions](#)
- [Returns](#)

Popular Products

- [Fans](#)
- [Extrusions](#)
- [Board Level](#)
- [Liquid Cooling](#)
- [Heat Pipe Technology](#)
- [Heat Sink Accessories](#)
- [Interface Materials](#)

Our Company

- [News and Events](#)
- [Management Team](#)
- [Worldwide Locations](#)
- [Directions to Headquarters](#)
- [Disclaimer](#)
- [Customer Survey](#)
- [Privacy Policy](#)

Connect with Aavid

Sign up for Aavid News & Alerts

Email Address [GO!](#)

Like / Follow / Connect



© Copyright 2015 Aavid Thermalloy, LLC.

USA: 1.855.32.AAVID Europe: 39.051.764002 Asia: 86.21.6115.2000 x 8122