



**Your experts for
safety, facility
and equipment
identification**

Product Catalog

ToughStripe® Floor Marking

BradyID.com/s36

ToughStripe Floor Marking Die-cut Shapes

- All the durability and high visibility of ToughStripe Floor Marking Tape, but in die-cut shapes



Dots

	3.5 in. Dia. 350/roll
Yellow	104403
Red	104400
White	104405
Green	104401
Blue	104402
Black	104404



Arrows

	2 in. x 5 in. 100/pack	3 in. x 8 in. 100/pack	4 in. x 10 in. 100/pack
Yellow	104415	104421	104427
Red	104412	104418	104424
White	104417	104423	104429
Green	104413	104419	104425
Blue	104414	104420	104426
Black	104416	104422	104428



Footprints

	10 ft. x 3.5 in. 5 right and 5 left/pack
Yellow	104409
Red	104406
White	104411
Green	104407
Blue	104408
Black	104410



Corner Marks

	2 in. x 5 in. 20/pack	3 in. x 8 in. 20/pack	4 in. x 10 in. 20/pack
Yellow	104433	104445	104457
Red	104430	104442	104454
White	104435	104447	104459
Green	104431	104443	104455
Blue	104432	104444	104456
Black	104434	104446	104458



Center Marks

	2 in. x 5 in. 20/pack	3 in. x 8 in. 20/pack	4 in. x 10 in. 20/pack
Yellow	104469	104475	104481
Red	104466	104472	104478
White	104471	104477	104483
Green	104467	104473	104479
Blue	104468	104474	104480
Black	104470	104476	104482



Divider Marks

	2 in. x 5 in. 20/pack	3 in. x 8 in. 20/pack	4 in. x 10 in. 20/pack
Yellow	104439	104451	104463
Red	104436	104448	104460
White	104441	104453	104465
Green	104437	104449	104461
Blue	104438	104450	104462
Black	104440	104452	104464

Pre-Spaced ToughStripe Shapes

Quickly lay straight, evenly spaced shapes. Simply lay down the continuous tape, then remove the clear transfer tape. No need to apply markings one by one.

	3.5 in. x 100 ft. 55 dots/18 in. apart	2 in. x 5 in. x 100 ft. 52 arrows/18 in. apart	2 in. x 8 in. x 100 ft. 46 dashes/18 in. apart
Yellow	104523	104529	104556
Red	104521	104526	142179
White	104522	104555	142177
Green	104520	104527	142181
Blue	104524	104528	142180
Black	104525	104554	142178



Pre-Printed ToughStripe Tape

Stock or custom legends available (18 character limit)

Legend	Color	2 in. x 100 ft.	3 in. x 100 ft.	4 in. x 100 ft.
QA Inspection Area	Blk on Org	121364	121365	121366
Caution ESD Area	Blk on Ylw	121367	121368	121369



Facility Marking Tape



Print-On-Demand ToughStripe Tape (B-483)

ToughStripe is available as a printable material for several of Brady's printers, allowing you to create custom floor labels for your facility. Simply print desired label from a select Brady printer, position label on floor and apply included B-634 polyester overlaminate for print protection.


Benchtop printers
See page 49

BMP®71 Portable Printer
See page 152

Toughstripe Floor Marking Signs

Toughstripe B-534 polyester floor signs resist harsh chemicals and are specifically designed to alert workers of potential dangers and enforce protective equipment requirements.

- Exceeds safety standards for clean, dry non-slip surfaces per ANSI A1264.2-2006 and OSHA 1910.22
- Black areas of signs are coated with anti-slip tread
- 3-mil thickness, service temperature 0° F to 130° F (18° C to 54° C)
- US Patent No 8,302,337

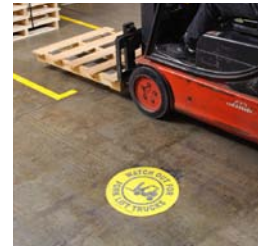

Arrow Symbol
104489 - 17 in. dia.



Emergency Exit
104495 - 17 in. dia.



Emergency Stairs
104496 - 17 in. dia.



Exit Arrow
104490 - 17 in. dia.



Fire Extinguisher
104492 - 17 in. dia.



Fire Alarm
104493 - 17 in. dia.



Fire Hose
104494 - 17 in. dia.



Pedestrian Traffic Only
104509 - 17 in. dia.



Watch Out For Fork Lift
104501 - 17 in. dia.



Warning Forklift Traffic
104512 - 17 in. dia.



Production Area
104513 - 17 in. dia.



First Aid w/Arrow
104486 - 17 in. dia.



Safety Shower
104487 - 17 in. dia.



Eye Wash
104507 - 17 in. dia.



Stop
104511 - 17 in. dia.



Keep Aisles Clear
104508 - 17 in. dia.



Radiation Area
104488 - 14 in. x 18 in.




First Aid
104491 - 14 in. x 18 in.



Do Not Enter
104497 - 14 in. x 18 in.



Chemical Storage
104498 - 14 in. x 18 in.

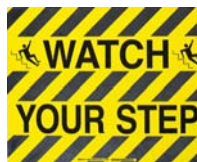

Watch Your Step
104499 - 14 in. x 18 in.




No Smoking
104500 - 14 in. x 18 in.




Ear Protection Area
104502 - 14 in. x 18 in.



Eye Protection Area
104503 - 14 in. x 18 in.

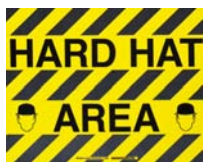

Hard Hat Area
104504 - 14 in. x 18 in.

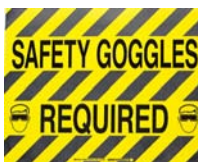

Safety Goggles Required
104505 - 14 in. x 18 in.



Biohazard
104506 - 14 in. x 18 in.



Safety Glasses Required
104510 - 14 in. x 18 in.