

Dot Matrix - Benchtops



Benchtop Dot Matrix Label Materials

Brady benchtop dot matrix printers are discontinued, but Brady continues to stock the following label supplies and ribbons for the printers.

Looking for portable dot matrix materials? View page 92.

General ID - Rounded Corner Labels

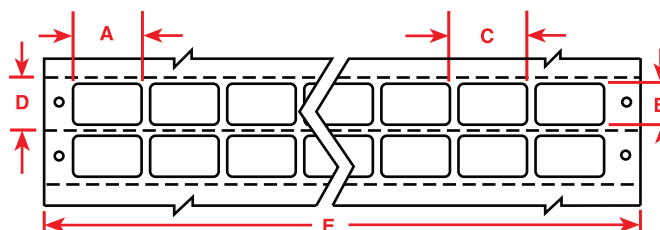


Fig. D1

Diagram	Catalog #	B-#	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Horizontal Repeat C Inch (mm)	Vertical Repeat D Inch (mm)	Web Width E Inch (mm)	Labels Per Row	Labels Per Pkg
B-499 Nylon Cloth											
D1	DAT-67-499-10	B-499	Nylon Cloth	White	0.500 (12.7)	0.750 (19.05)	0.600 (15.24)	1.000 (25.40)	8.100 (205.74)	12	10,000
D1	DAT-5-499-10	B-499	Nylon Cloth	White	0.800 (20.32)	1.437 (36.50)	0.900 (22.86)	1.500 (38.10)	6.300 (160.02)	6	10,000
D1	DAT-18-499-10	B-499	Nylon Cloth	White	1.000 (25.4)	0.500 (12.70)	1.100 (27.94)	0.667 (16.94)	8.600 (218.44)	7	10,000
B-502 Vinyl Cloth											
D1	DAT-119-502-10	B-502	Vinyl Cloth	White	0.375 (9.53)	0.375 (9.53)	0.500 (12.70)	0.500 (12.70)	8.900 (226.06)	16	10,000
D1	DAT-67-502-10	B-502	Vinyl Cloth	White	0.500 (12.7)	0.750 (19.05)	0.600 (15.24)	1.000 (25.40)	8.100 (205.74)	12	10,000
D1	* DAT-31-502-10	B-502	Vinyl Cloth	White	0.500 (12.7)	0.750 (19.05)	0.600 (15.24)	1.000 (25.40)	9.300 (236.22)	14	10,000
D1	DAT-24-502-10	B-502	Vinyl Cloth	White	0.500 (12.7)	1.437 (36.50)	0.600 (15.24)	1.500 (38.10)	8.100 (205.74)	12	10,000
D1	DAT-25-502-10	B-502	Vinyl Cloth	White	0.750 (19.05)	0.250 (6.35)	0.900 (22.86)	0.330 (8.46)	9.000 (228.60)	9	10,000
D1	DAT-124-502-10	B-502	Vinyl Cloth	White	0.750 (19.05)	0.250 (6.35)	0.900 (22.86)	0.375 (9.53)	9.000 (228.60)	9	10,000
D1	DAT-5-502-10	B-502	Vinyl Cloth	White	0.800 (20.32)	1.437 (36.50)	0.900 (22.86)	1.500 (38.10)	6.300 (160.02)	6	10,000
D1	DAT-11-502-10	B-502	Vinyl Cloth	White	1.000 (25.4)	0.375 (9.53)	1.100 (27.94)	0.500 (12.70)	8.600 (218.44)	7	10,000
D1	DAT-18-502-10	B-502	Vinyl Cloth	White	1.000 (25.4)	0.500 (12.70)	1.100 (27.94)	0.667 (16.94)	8.600 (218.44)	7	10,000
D1	DAT-83-502-10	B-502	Vinyl Cloth	White	1.000 (25.4)	0.750 (19.05)	1.100 (27.94)	1.000 (25.40)	8.600 (218.44)	7	10,000
D1	DAT-160-502-10	B-502	Vinyl Cloth	White	1.250 (31.75)	0.530 (13.46)	1.600 (40.64)	0.625 (15.88)	7.300 (185.42)	4	10,000
D1	DAT-64-502-10	B-502	Vinyl Cloth	White	2.000 (50.80)	0.375 (9.53)	2.100 (53.34)	0.500 (12.70)	7.200 (182.88)	3	10,000
D1	* DAT-12-502-10	B-502	Vinyl Cloth	White	2.000 (50.80)	0.375 (9.53)	2.100 (53.34)	0.500 (12.70)	9.300 (236.22)	4	10,000
D1	DAT-13-502-10	B-502	Vinyl Cloth	White	3.000 (76.20)	0.375 (9.53)	3.100 (78.74)	0.500 (12.70)	7.100 (180.34)	2	10,000
B-609 Paper											
D1	BCDAT-1-609-5	B-609	Paper	White	2.000 (50.80)	0.900 (22.86)	2.100 (53.34)	1.000 (25.40)	7.200 (182.88)	3	5,000
D1	BCDAT-3-609-5	B-609	Paper	White	2.000 (50.80)	1.437 (36.50)	2.100 (53.34)	1.500 (38.10)	7.200 (182.88)	3	5,000
D1	BCDAT-2-609-5	B-609	Paper	White	3.000 (76.20)	0.900 (22.86)	3.100 (78.74)	1.000 (25.40)	7.100 (180.34)	2	5,000
D1	BCDAT-4-609-5	B-609	Paper	White	3.000 (76.20)	1.437 (36.50)	3.100 (78.74)	1.500 (38.10)	7.100 (180.34)	2	5,000
D1	BCDAT-6-609-5	B-609	Paper	White	3.000 (76.20)	1.900 (48.26)	3.100 (78.74)	2.000 (50.80)	7.100 (180.34)	2	5,000
D1	BCDAT-5-609-5	B-609	Paper	White	3.900 (99.06)	1.437 (36.50)	4.000 (101.60)	1.500 (38.10)	8.900 (226.06)	2	5,000
B-619 Polyester											
D1	DAT-118-619-10	B-619	Polyester	White	0.375 (9.53)	0.375 (9.53)	0.500 (12.70)	0.500 (12.70)	8.900 (226.06)	16	10,000
D1	DAT-179-619-10	B-619	Polyester	White	0.400 (10.16)	0.200 (5.08)	0.500 (12.70)	0.250 (6.35)	8.900 (226.06)	16	10,000
D1	DAT-17-619-10	B-619	Polyester	White	0.650 (16.51)	0.200 (5.08)	0.800 (20.32)	0.250 (6.35)	8.850 (224.79)	10	10,000
D1	DAT-27-619-10	B-619	Polyester	White	0.750 (19.05)	0.250 (6.35)	0.900 (22.86)	0.330 (8.46)	9.000 (228.60)	9	10,000
D1	DAT-126-619-10	B-619	Polyester	White	0.750 (19.05)	0.250 (6.35)	0.900 (22.86)	0.375 (9.53)	9.000 (228.60)	9	10,000
D1	DAT-60-619-10	B-619	Polyester	White	0.900 (22.86)	0.250 (6.35)	1.000 (25.40)	0.330 (8.46)	8.900 (226.06)	8	10,000
D1	DAT-134-619-10	B-619	Polyester	White	0.900 (22.86)	0.250 (6.35)	1.000 (25.40)	0.375 (9.53)	8.900 (226.06)	8	10,000
D1	DAT-181-619-10	B-619	Polyester	White	1.000 (25.4)	0.250 (6.35)	1.100 (27.94)	0.330 (8.46)	8.600 (218.44)	7	10,000
D1	DAT-51-619-10	B-619	Polyester	White	1.000 (25.4)	0.375 (9.53)	1.100 (27.94)	0.500 (12.70)	8.600 (218.44)	7	10,000
D1	DAT-20-619-10	B-619	Polyester	White	1.000 (25.4)	0.500 (12.70)	1.100 (27.94)	0.667 (16.94)	8.600 (218.44)	7	10,000
D1	BCDAT-8-619-5	B-619	Polyester	White	1.500 (38.1)	0.250 (6.35)	1.600 (40.64)	0.375 (9.53)	7.300 (185.42)	4	5,000

* Does not fit narrow carriage (80-column) printers.

Dot Matrix - Benchtops

Diagram	Catalog #	B-#	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Horizontal Repeat C Inch (mm)	Vertical Repeat D Inch (mm)	Web Width E Inch (mm)	Labels Per Row	Labels Per Pkg
D1	BCDAT-10-619-10	B-619	Polyester	White	2.000 (50.80)	0.375 (9.53)	2.100 (53.34)	0.500 (12.70)	7.200 (182.88)	3	10,000
D1	BCDAT-1-619-5	B-619	Polyester	White	2.000 (50.80)	0.900 (22.86)	2.100 (53.34)	1.000 (25.40)	7.200 (182.88)	3	5,000
D1	BCDAT-3-619-5	B-619	Polyester	White	2.000 (50.80)	1.437 (36.50)	2.100 (53.34)	1.500 (38.10)	7.200 (182.88)	3	5,000
D1	BCDAT-5-619-5	B-619	Polyester	White	3.900 (99.06)	1.437 (36.50)	4.000 (101.60)	1.500 (38.10)	8.900 (226.06)	2	5,000
B-637 Polyvinylfluoride											
D1	DAT-56-637-10	B-637	Polyvinylfluoride	White	0.650 (16.51)	0.200 (5.08)	0.800 (20.32)	0.250 (6.35)	8.850 (224.79)	10	10,000
D1	DAT-161-637-10	B-637	Polyvinylfluoride	White	0.750 (19.05)	0.250 (6.35)	0.900 (22.86)	0.330 (8.46)	9.000 (228.60)	9	10,000
D1	* DAT-1-637-10	B-637	Polyvinylfluoride	White	0.900 (22.86)	0.250 (6.35)	1.000 (25.40)	0.330 (8.46)	10.900 (276.86)	10	10,000
D1	DAT-49-637-10	B-637	Polyvinylfluoride	White	0.900 (22.86)	0.250 (6.35)	1.000 (25.40)	0.330 (8.46)	8.900 (226.06)	8	10,000
D1	DAT-132-637-10	B-637	Polyvinylfluoride	White	0.900 (22.86)	0.250 (6.35)	1.000 (25.40)	0.375 (9.53)	8.900 (226.06)	8	10,000
D1	DAT-57-637-10	B-637	Polyvinylfluoride	White	1.000 (25.4)	0.500 (12.70)	1.100 (27.94)	0.667 (16.94)	8.600 (218.44)	7	10,000
D1	DAT-73-637-10	B-637	Polyvinylfluoride	White	1.250 (31.75)	0.375 (9.53)	1.400 (35.56)	0.500 (12.70)	7.950 (201.93)	5	10,000
D1	* DAT-10-637-10	B-637	Polyvinylfluoride	White	1.250 (31.75)	0.375 (9.53)	1.400 (35.56)	0.500 (12.70)	10.750 (273.05)	7	10,000
D1	DAT-74-637-10	B-637	Polyvinylfluoride	Gray	1.250 (31.75)	0.375 (9.53)	1.400 (35.56)	0.500 (12.70)	7.950 (201.93)	5	10,000
D1	DAT-99-637-10	B-637	Polyvinylfluoride	Yellow	1.000 (25.4)	0.500 (12.70)	1.100 (27.94)	0.667 (16.94)	8.600 (218.44)	7	10,000
D1	* DAT-2-637-10	B-637	Polyvinylfluoride	Yellow	1.250 (31.75)	0.375 (9.53)	1.400 (35.56)	0.500 (12.70)	10.750 (273.05)	7	10,000
D1	DAT-72-637-10	B-637	Polyvinylfluoride	Yellow	1.250 (31.75)	0.375 (9.53)	1.400 (35.56)	0.500 (12.70)	7.950 (201.93)	5	10,000
B-652 Polyimide											
D1	DAT-115-652-10	B-652	Polyimide	Amber	0.375 (9.53)	0.375 (9.53)	0.500 (12.70)	0.500 (12.70)	8.900 (226.06)	16	10,000
D1	DAT-58-652-10	B-652	Polyimide	Amber	0.650 (16.51)	0.200 (5.08)	0.800 (20.32)	0.250 (6.35)	8.850 (224.79)	10	10,000
D1	DAT-96-652-10	B-652	Polyimide	Amber	0.750 (19.05)	0.250 (6.35)	0.900 (22.86)	0.330 (8.46)	9.000 (228.60)	9	10,000
D1	DAT-128-652-10	B-652	Polyimide	Amber	0.750 (19.05)	0.250 (6.35)	0.900 (22.86)	0.375 (9.53)	9.000 (228.60)	9	10,000
D1	DAT-50-652-10	B-652	Polyimide	Amber	0.900 (22.86)	0.250 (6.35)	1.000 (25.40)	0.330 (8.46)	8.900 (226.06)	8	10,000
D1	DAT-59-652-10	B-652	Polyimide	Amber	1.000 (25.4)	0.500 (12.70)	1.100 (27.94)	0.667 (16.94)	8.600 (218.44)	7	10,000
D1	BCDAT-8-652-5	B-652	Polyimide	Amber	1.500 (38.1)	0.250 (6.35)	1.600 (40.64)	0.375 (9.53)	7.300 (185.42)	4	5,000
D1	BCDAT-11-652-10	B-652	Polyimide	Amber	3.000 (76.20)	0.375 (9.53)	3.100 (78.74)	0.500 (12.70)	7.100 (180.34)	2	10,000
B-969 Metallized Polyester											
D1	DAT-47-969-10	B-969	Metallized Polyester	Silver	1.000 (25.4)	0.500 (12.70)	1.100 (27.94)	0.667 (16.94)	8.600 (218.44)	7	10,000
D1	DAT-170-969-10	B-969	Metallized Polyester	Silver	1.600 (40.64)	0.375 (9.53)	1.700 (43.18)	0.500 (12.70)	7.700 (195.58)	4	10,000
D1	DAT-77-969-5	B-969	Metallized Polyester	Silver	2.000 (50.80)	0.900 (22.86)	2.100 (53.34)	1.000 (25.40)	7.200 (182.88)	3	5,000
D1	DAT-78-969-5	B-969	Metallized Polyester	Silver	3.000 (76.20)	0.900 (22.86)	3.100 (78.74)	1.000 (25.40)	7.100 (180.34)	2	5,000
D1	DAT-82-969-5	B-969	Metallized Polyester	Silver	3.000 (76.20)	1.900 (48.26)	3.100 (78.74)	2.000 (50.80)	7.100 (180.34)	2	5,000

General ID - Square Corner Labels

Diagram	Catalog #	B-#	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Horizontal Repeat C Inch (mm)	Vertical Repeat D Inch (mm)	Web Width E Inch (mm)	Labels Per Row	Labels Per Pkg
D1	DAT-137-502-10	B-502	Vinyl Cloth	White	0.300 (7.62)	0.750 (19.05)	0.300 (7.62)	1.000 (25.40)	5.800 (147.32)	16	10,000
D1	DAT-140-502-10	B-502	Vinyl Cloth	White	0.300 (7.62)	0.937 (23.8)	0.300 (7.62)	1.000 (25.40)	5.800 (147.32)	16	10,000
D1	DAT-43-502-10	B-502	Vinyl Cloth	White	0.500 (12.7)	0.437 (11.10)	0.500 (12.70)	0.500 (12.70)	9.000 (228.60)	16	10,000
D1	DAT-45-619-10	B-619	Polyester	White	0.500 (12.7)	0.437 (11.10)	0.500 (12.70)	0.500 (12.70)	9.000 (228.60)	16	10,000
D1	DAT-171-652-10	B-652	Polyimide	Amber	0.500 (12.7)	0.437 (11.10)	0.500 (12.70)	0.500 (12.70)	9.000 (228.60)	16	10,000
D1	DAT-143-502-10	B-502	Vinyl Cloth	White	0.500 (12.7)	0.937 (23.80)	0.500 (12.70)	1.000 (25.40)	9.000 (228.60)	16	10,000
D1	DAT-146-502-10	B-502	Vinyl Cloth	White	0.800 (20.32)	0.937 (23.80)	0.800 (20.32)	1.000 (25.40)	9.000 (228.60)	10	10,000
D1	DAT-149-502-10	B-502	Vinyl Cloth	White	1.000 (25.4)	0.937 (23.80)	1.000 (25.40)	1.000 (25.40)	9.000 (228.60)	8	10,000

* Does not fit narrow carriage (80-column) printers.