



**Your experts for
safety, facility
and equipment
identification**

Product Catalog

BradyPrinter M611 / BMP®61 Materials

BradyID.com/s36

Asset Tracking Materials

Non-Metallized Asset Tracking Labels (B-422, B-423, B-430 and B-483)

- **B-422 Polyester Material:** Permanent adhesive, good for powder-coated and textured surfaces. Temp. range: -40° F to 212° F (-40° C to 100° C). UL recognized
- **B-423 Glossy White Polyester Material:** UL recognized for outdoor use on glass, thermoset polyester plastic and polyvinyl fluoride plastic
- **B-430 Clear Polyester Material:** High-performance glossy polyester material with permanent adhesive. Good for general purpose thermal transfer printing
- **B-483 Ultra-Aggressive Polyester Material:** Permanent adhesive for powder-coated and textured surfaces. Temp. range: -40° F to 248° F (-40° C to 120° C). UL recognized
- **B-8459 Polyester Material:** Permanent adhesive, excellent resistance to most chemicals, oils and water. Temp. range: -40° F to 212° F (-40° C to 100° C). UL recognized
- **B-8591 Outdoor Polyester Material:** Permanent adhesive, 12-year outdoor durability, resists UV, abrasion and fluids

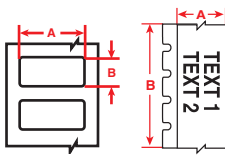


Figure 2



Figure 33

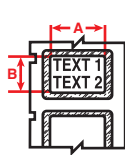


Figure 40
w/ overlaminate

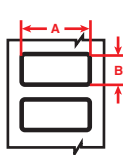


Figure 46
w/ black border

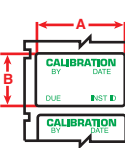


Figure 51

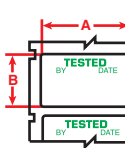


Figure 52

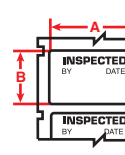


Figure 53

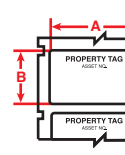


Figure 54b

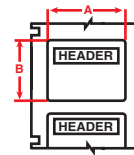


Figure 72

Fits Printers	Figure	Catalog #	B#	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Roll	Rec. Ribbon (M611 / BMP61)
B-422 Permanent Polyester									
M611, BMP61, 71*, TLS	Fig. 2	PTL-39-422	B-422	Polyester	White	0.375 (9.53)	0.600 (15.2)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 33	PTL-46-422	B-422	Polyester	White	0.375 (9.53)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-5-422	B-422	Polyester	White	0.500 (12.7)	0.200 (5.1)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-44-422	B-422	Polyester	White	0.500 (12.7)	0.375 (9.5)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-7-422	B-422	Polyester	White	0.500 (12.7)	0.500 (12.7)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 33	PTL-8-422	B-422	Polyester	White	0.500 (12.7)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-16-422	B-422	Polyester	White	1.000 (25.4)	0.375 (9.5)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-17-422	B-422	Polyester	White	1.000 (25.4)	0.500 (12.7)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-19-422	B-422	Polyester	White	1.000 (25.4)	1.000 (25.4)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-22-422	B-422	Polyester	White	1.000 (25.4)	3.000 (76.2)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-23-422	B-422	Polyester	White	1.000 (25.4)	4.000 (101.6)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 33	PTL-42-422	B-422	Polyester	White	1.000 (25.4)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-45-422	B-422	Polyester	White	1.500 (38.1)	0.375 (9.5)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-29-422	B-422	Polyester	White	1.500 (38.1)	0.500 (12.7)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-30-422	B-422	Polyester	White	1.500 (38.1)	0.750 (19.1)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-32-422	B-422	Polyester	White	1.500 (38.1)	1.500 (38.1)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 54	PTL-35-422-PROP	B-422	Polyester	White	1.630 (41.4)	0.750 (19.1)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 33	PTL-43-422	B-422	Polyester	White	1.900 (48.26)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-37-422	B-422	Polyester	White	1.900 (48.3)	3.000 (76.2)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-38-422	B-422	Polyester	White	1.900 (48.3)	4.000 (101.6)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-20-422	B-422	Polyester	White	2.000 (50.8)	1.000 (25.4)	100	M61-R6010
B-422 PermsShield Polyester with overlaminate layer									
M611, BMP61, 71*, TLS	Fig. 40	PTPSL-17-422	B-422	Polyester	White	1.000 (25.4)	0.500 (12.7)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 40	PTPSL-26-422	B-422	Polyester	White	1.250 (31.8)	2.750 (69.85)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 40	PTPSL-50-422	B-422	Polyester	White	1.650 (41.9)	3.000 (76.2)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 40	PTPSL-20-422	B-422	Polyester	White	2.000 (50.8)	1.000 (25.4)	100	M61-R6010
B-423 Glossy Permanent Polyester									
M611, BMP61, 71*, TLS	Fig. 2	PTL-1-423	B-423	Polyester	White	0.250 (6.35)	0.250 (6.4)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-3-423	B-423	Polyester	White	0.375 (9.53)	0.375 (9.5)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-4-423	B-423	Polyester	White	0.400 (10.2)	0.400 (10.2)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-5-423	B-423	Polyester	White	0.500 (12.7)	0.200 (5.1)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-6-423	B-423	Polyester	White	0.500 (12.7)	0.275 (7)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-7-423	B-423	Polyester	White	0.500 (12.7)	0.500 (12.7)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 33	PTL-8-423	B-423	Polyester	White	0.500 (12.7)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-9-423	B-423	Polyester	White	0.650 (16.51)	0.200 (5.1)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-10-423	B-423	Polyester	White	0.750 (19.05)	0.250 (6.4)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-13-423	B-423	Polyester	White	0.900 (22.86)	0.250 (6.4)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-14-423	B-423	Polyester	White	1.000 (25.4)	0.187 (4.7)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-15-423	B-423	Polyester	White	1.000 (25.4)	0.275 (7)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-16-423	B-423	Polyester	White	1.000 (25.4)	0.375 (9.5)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 51	PTL-30-423-CALI	B-423	Polyester	White	1.500 (38.1)	0.750 (19.05)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 52	PTL-30-423-TEST	B-423	Polyester	White	1.500 (38.1)	0.750 (19.05)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 53	PTL-30-423-INSP	B-423	Polyester	White	1.500 (38.1)	0.750 (19.05)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-17-423	B-423	Polyester	White	1.000 (25.4)	0.500 (12.7)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-19-423	B-423	Polyester	White	1.000 (25.4)	1.000 (25.4)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-22-423	B-423	Polyester	White	1.000 (25.4)	3.000 (76.2)	100	M61-R6010

Non-Metallized Asset Tracking Labels (continued)

Fits Printers	Figure	Catalog #	B#	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Roll	Rec. Ribbon (M611 / BMP61)
M611, BMP61, 71*, TLS	Fig. 2	PTL-23-423	B-423	Polyester	White	1.000 (25.4)	4.000 (101.6)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 46	PTL-24-423-BK	B-423	Polyester	White	1.130 (28.7)	0.500 (12.7)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-25-423	B-423	Polyester	White	1.250 (31.75)	0.250 (6.4)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-26-423	B-423	Polyester	White	1.250 (31.75)	2.750 (69.9)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-27-423	B-423	Polyester	White	1.500 (38.1)	0.125 (3.2)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-28-423	B-423	Polyester	White	1.500 (38.1)	0.250 (6.4)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-29-423	B-423	Polyester	White	1.500 (38.1)	0.500 (12.7)	500	M61-R6010
M611, BMP61	Fig. 2	M61-30-423	B-423	Polyester	White	1.500 (38.1)	0.750 (19.05)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-31-423	B-423	Polyester	White	1.500 (38.1)	1.000 (25.4)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-32-423	B-423	Polyester	White	1.500 (38.1)	1.500 (38.1)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 54	PTL-35-423-PROP	B-423	Polyester	White	1.630 (41.4)	0.750 (19.1)	250	M61-R6010
M611, BMP61	Fig. 2	M61-52-423	B-423	Polyester	White	1.900 (48.3)	0.600 (15.2)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-37-423	B-423	Polyester	White	1.900 (48.3)	3.000 (76.2)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-38-423	B-423	Polyester	White	1.900 (48.3)	4.000 (101.6)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-2-423	B-423	Polyester	White	2.000 (50.8)	0.250 (6.4)	100	M61-R6010
M611, BMP61	Fig. 2	M61-61-423	B-423	Polyester	White	2.000 (50.8)	0.500 (12.7)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-20-423	B-423	Polyester	White	2.000 (50.8)	1.000 (25.4)	100	M61-R6010
B-430 Clear Polyester									
M611, BMP61, 71*, TLS	Fig. 2	PTL-71-430	B-430	Polyester	Clear	0.350 (8.89)	0.200 (5.1)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 34	PTL-39-430	B-430	Polyester	Clear	0.375 (9.53)	0.600 (15.2)	750	M61-R6010
M611, BMP61	Fig. 33	M61C-375-430	B-430	Polyester	Clear	0.375 (9.53)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61, 71*, TLS	Fig. 33	PTL-46-430	B-430	Polyester	Clear	0.375 (9.53)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-6-430	B-430	Polyester	Clear	0.500 (12.7)	0.275 (7)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-44-430	B-430	Polyester	Clear	0.500 (12.7)	0.375 (9.5)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-7-430	B-430	Polyester	Clear	0.500 (12.7)	0.500 (12.7)	500	M61-R6010
M611, BMP61	Fig. 33	M61C-500-430	B-430	Polyester	Clear	0.500 (12.7)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61, 71*, TLS	Fig. 33	PTL-8-430	B-430	Polyester	Clear	0.500 (12.7)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61	Fig. 2	M61-9-430	B-430	Polyester	Clear	0.650 (16.51)	0.200 (5.1)	750	M61-R6010
M611, BMP61	Fig. 2	M61-10-430	B-430	Polyester	Clear	0.750 (19.05)	0.250 (6.4)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-16-430	B-430	Polyester	Clear	1.000 (25.4)	0.375 (9.5)	500	M61-R6010
M611, BMP61	Fig. 2	M61-98-430	B-430	Polyester	Clear	1.000 (25.4)	0.375 (9.5)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-17-430	B-430	Polyester	Clear	1.000 (25.4)	0.500 (12.7)	500	M61-R6010
M611, BMP61	Fig. 2	M61-22-430	B-430	Polyester	Clear	1.000 (25.4)	1.000 (25.4)	100	M61-R6010
M611, BMP61	Fig. 2	M61-37-430	B-430	Polyester	Clear	1.000 (25.4)	3.000 (76.2)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 33	PTL-42-430	B-430	Polyester	Clear	1.000 (25.4)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61	Fig. 2	M61-198-430	B-430	Polyester	Clear	1.250 (31.75)	2.750 (69.9)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-28-430	B-430	Polyester	Clear	1.500 (38.1)	0.250 (6.4)	750	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-45-430	B-430	Polyester	Clear	1.500 (38.1)	0.375 (9.5)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-29-430	B-430	Polyester	Clear	1.500 (38.1)	0.500 (12.7)	500	M61-R6010
M611, BMP61	Fig. 2	M61-30-430	B-430	Polyester	Clear	1.500 (38.1)	0.750 (19.05)	250	M61-R6010
M611, BMP61	Fig. 2	M61-52-430	B-430	Polyester	Clear	1.900 (48.26)	0.600 (15.2)	250	M61-R6010
M611, BMP61	Fig. 2	M61-78-430	B-430	Polyester	Clear	1.900 (48.26)	1.000 (25.4)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 33	PTL-43-430	B-430	Polyester	Clear	1.900 (48.26)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61	Fig. 2	M61-61-430	B-430	Polyester	Clear	2.000 (50.8)	0.500 (12.7)	100	M61-R6010
B-483 Ultra-Aggressive Polyester									
M611, BMP61, 71*, TLS	Fig. 33	PTL-101-483	B-483	Polyester	White	0.250 (6.35)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-61-483	B-483	Polyester	White	0.500 (12.7)	2.000 (50.8)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 33	PTL-8-483	B-483	Polyester	White	0.500 (12.7)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-62-483	B-483	Polyester	White	0.750 (19.05)	4.000 (101.6)	50	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-63-483	B-483	Polyester	White	0.750 (19.05)	8.000 (203.2)	50	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-16-483	B-483	Polyester	White	1.000 (25.4)	0.375 (9.5)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-17-483	B-483	Polyester	White	1.000 (25.4)	0.500 (12.7)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-19-483	B-483	Polyester	White	1.000 (25.4)	1.000 (25.4)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 33	PTL-42-483	B-483	Polyester	White	1.000 (25.4)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61, 71*, TLS	Fig. 46	PTL-24-483-BK	B-483	Polyester	White	1.130 (28.7)	0.500 (12.7)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 33	PTL-100-483	B-483	Polyester	White	1.300 (33.02)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-65-483	B-483	Polyester	White	1.375 (34.93)	1.000 (25.4)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-29-483	B-483	Polyester	White	1.500 (38.1)	0.500 (12.7)	500	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-30-483	B-483	Polyester	White	1.500 (38.1)	0.750 (19.1)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-31-483	B-483	Polyester	White	1.500 (38.1)	1.000 (25.4)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-32-483	B-483	Polyester	White	1.500 (38.1)	1.500 (38.1)	250	M61-R6010
M611, BMP61, 71*, TLS	Fig. 33	PTL-43-483	B-483	Polyester	White	1.900 (48.26)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-20-483	B-483	Polyester	White	2.000 (50.8)	1.000 (25.4)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-37-483	B-483	Polyester	White	1.900 (48.3)	3.000 (76.2)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 72	PTL-37-483-WARNING	B-483	Polyester	White	1.900 (48.3)	3.000 (76.2)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-23-483	B-483	Polyester	White	1.000 (25.4)	4.000 (101.6)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 2	PTL-38-483	B-483	Polyester	White	1.900 (48.3)	4.000 (101.6)	100	M61-R6010
M611, BMP61, 71*, TLS	Fig. 72	PTL-38-483-WARNING	B-483	Polyester	White	1.900 (48.3)	4.000 (101.6)	100	M61-R6010
B-8459 Adhesive Polyester									
M611, BMP61	Fig. 2	M61-9-8459	B-8459	Polyester	White	0.650 (16.51)	0.200 (5.1)	750	M61-R6010
M611, BMP61	Fig. 2	M61-17-8459	B-8459	Polyester	White	1.000 (25.4)	0.500 (12.7)	500	M61-R6010
M611, BMP61	Fig. 2	M61-29-8459	B-8459	Polyester	White	1.500 (38.10)	0.500 (12.7)	500	M61-R6010
M611, BMP61	Fig. 2	M61-30-8459	B-8459	Polyester	White	1.500 (38.10)	0.750 (19.05)	250	M61-R6010
B-8591 Outdoor Polyester									
M611, BMP61	Fig. 2	M61-196-8591	B-8591	Polyester	White	1.180 (30.0)	1.970 (50.0)	100	M61-R6610
M611, BMP61	Fig. 33	M61C-1900-8591	B-8591	Polyester	White	1.900 (48.3)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6610
M611, BMP61	Fig. 33	M61C-1000-8591	B-8591	Polyester	White	1.000 (25.4)	50 ft. (15.24 m)	1 roll (cont.)	M61-R6610