


Pre-Printed Wire Marker Cards



ClipSleeve™ Wire Markers

- Place the flared “shoe” end of the wand against the wire and push sleeve onto the wire
- Split sleeve with “chevron” locking design snaps on the wire, won’t slip or slide
- ClipSleeve applicator wands are color coded for easy identification of sleeve sizes

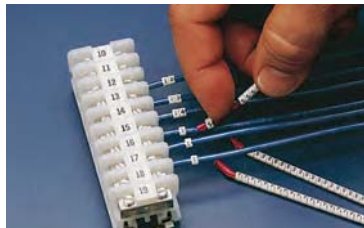

For Wire Size
0.037” up to 0.232”

	SIZE 03	SIZE 05	SIZE 07	SIZE 09	SIZE 10	SIZE 13	SIZE 15	SIZE 18
For Wire Sizes Inch (mm)	0.037-0.051 (0.94-1.30)	0.053-0.073 (1.35-1.85)	0.075-0.087 (1.901-2.21)	0.098-0.110 (2.49-2.79)	0.110-0.134 (2.79-3.40)	0.134-0.181 (3.40-4.60)	0.154-0.177 (3.90-4.50)	0.181-0.232 (4.60-5.89)
Approx. Wire Gauge	26, 24	22, 20	18	18	16, 14	14	14, 12	10, 8
Qty. Per Pack	300/pack	300/pack	300/pack	300/pack	300/pack	300/pack	300/pack	300/pack
Legend	Catalog #	Catalog #	Catalog #	Catalog #	Catalog #	Catalog #	Catalog #	Catalog #
0	SCN03-0	SCN05-0	SCN07-0	SCN09-0	SCN10-0	SCN13-0	SCN15-0	SCN18-0
1	SCN03-1	SCN05-1	SCN07-1	SCN09-1	SCN10-1	SCN13-1	SCN15-1	SCN18-1
2	SCN03-2	SCN05-2	SCN07-2	SCN09-2	SCN10-2	SCN13-2	SCN15-2	SCN18-2
3	SCN03-3	SCN05-3	SCN07-3	SCN09-3	SCN10-3	SCN13-3	SCN15-3	SCN18-3
(replace asterisks with a number 4 to 9)	SCN03-*	SCN05-*	SCN07-*	SCN09-*	SCN10-*	SCN13-*	SCN15-*	SCN18-*
0 - 9	SCNC-03	SCNC-05	SCNC-07	SCNC-09	SCNC-10	SCNC-13	SCNC-15	SCNC-18
A	SCN03-A	SCN05-A	SCN07-A	SCN09-A	SCN10-A	SCN13-A	SCN15-A	SCN18-A
B	SCN03-B	SCN05-B	SCN07-B	SCN09-B	SCN10-B	SCN13-B	SCN15-B	SCN18-B
C	SCN03-C	SCN05-C	SCN07-C	SCN09-C	SCN10-C	SCN13-C	SCN15-C	SCN18-C
(replace asterisks with a letter D to Z)	SCN03-*	SCN05-*	SCN07-*	SCN09-*	SCN10-*	SCN13-*	SCN15-*	SCN18-*
A - M	-	-	SCN07-A-M	SCN09-A-M	SCN10-A-M	SCN13-A-M	SCN15-A-M	SCN18-A-M
N - Z	-	-	SCN07-N-Z	SCN09-N-Z	SCN10-N-Z	SCN13-N-Z	SCN15-N-Z	SCN18-N-Z
+	SCN03-PLUS	SCN05-PLUS	SCN07-PLUS	SCN09-PLUS	SCN10-PLUS	SCN13-PLUS	SCN15-PLUS	SCN18-PLUS
-	SCN03-MINUS	SCN05-MINUS	SCN07-MINUS	SCN09-MINUS	SCN10-MINUS	SCN13-MINUS	SCN15-MINUS	SCN18-MINUS
BLANK	-	SCN05-BLANK	SCN07-BLANK	SCN09-BLANK	SCN10-BLANK	SCN13-BLANK	SCN15-BLANK	SCN18-BLANK

Pre-Printed Labels



For Wire Size
0.236” to 0.670”

	SIZE 23	SIZE 36	SIZE 45	SIZE 61
For Wire Sizes Inch (mm)	0.236-0.299 (5.99-7.59)	0.362-0.413 (9.19-10.49)	0.453-0.512 (11.51-13.00)	0.610-0.670 (15.49-17.02)
Approx. Wire Gauge	8, 4	4, 2	2, 1, 0, 00	00, 000
Qty. Per Pack	50/pack	50/pack	50/pack	50/pack
Legend	Catalog #	Catalog #	Catalog #	Catalog #
0	SCN23-0	SCN36-0	SCN45-0	SCN61-0
1	SCN23-1	SCN36-1	SCN45-1	SCN61-1
2	SCN23-2	SCN36-2	SCN45-2	SCN61-2
3	SCN23-3	SCN36-3	SCN45-3	SCN61-3
(replace asterisks with a number 4 to 9)	SCN23-*	SCN36-*	SCN45-*	SCN61-*
A	SCN23-A	SCN36-A	SCN45-A	SCN61-A
B	SCN23-B	SCN36-B	SCN45-B	SCN61-B
C	SCN23-C	SCN36-C	SCN45-C	SCN61-C
(replace asterisks with a letter D to Z)	SCN23-*	SCN36-*	SCN45-*	SCN61-*
+	SCN23-PLUS	SCN36-PLUS	SCN45-PLUS	SCN61-PLUS
-	SCN23-MINUS	SCN36-MINUS	SCN45-MINUS	SCN61-MINUS

Wire Marker Cards




Empty Applicator Wands

Catalog #		Qty.
SCN23-AW	Empty Size 23 Sleeve Wand Applicators	10 pack

Pre-Printed Wire Marker Cards

Pre-Printed Wire Marker Cards

Repositionable vinyl cloth material is able to withstand moderate heat, oil and dirt. Labels hold tightly to the wire due to their high adhesion properties and can be re-used with ease if repositioning is required. Available in black on matte white background.

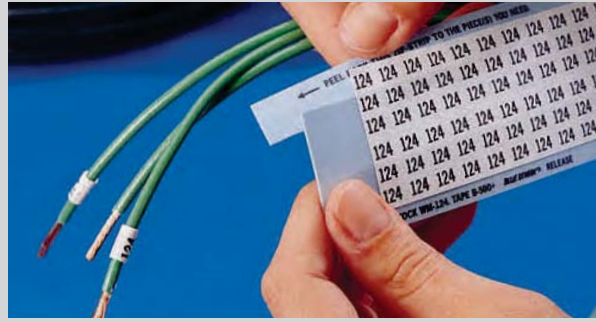

Part# Prefix	Material		Color	Finish	Max. Service Temp.	Description
HH-	B-12	Acetate Cloth	White	Matte	221°F (105°C)	Wire marker for varnish dip or baking cycles. Oil and heat resistant.
AF-	B-184	Aluminum Foil	Silver	Matte	266°F (130°C)	Permanent debossed marking. Heat, oil, solvent and abrasion resistant.
WM-	B-500	Vinyl Cloth	Various	Matte	180°F (82°C)	All-purpose marker. Moderate heat, oil and dirt resistance. High adhesion.
TWM-, TMM- (mini), TMXM- (micro)	B-702	Vinyl Film	White	Gloss	221°F (105°C)	Vinyl coated; machine tool labeling. Oil and mild solvent resistant. High adhesion.

Blank - Colored Cards

WM-, TWM- Height: 1.5" (38mm)


TMM- Height: 0.5" (38mm)

Color	Markers Per Card	Cards Per Pkg	B-500 Vinyl Cloth (WM-)	B-702 Vinyl Film (TWM-)	B-702 Vinyl Film Miniature (TMM-)
Black	36	25	WM-COL-BK-PK	TWM-COL-BK-PK	TMM-COL-BK-PK
Brown	36	25	WM-COL-BR-PK	TWM-COL-BR-PK	TMM-COL-BR-PK
Dark Blue	36	25	WM-COL-DB-PK	TWM-COL-DB-PK	TMM-COL-DB-PK
Dark Green	36	25	WM-COL-DG-PK	-	TMM-COL-DG-PK
Gray	36	25	WM-COL-GY-PK	-	TMM-COL-GY-PK
Light Blue	36	25	WM-COL-LB-PK	TWM-COL-LB-PK	TMM-COL-LB-PK
Light Green	36	25	WM-COL-LG-PK	TWM-COL-LG-PK	TMM-COL-LG-PK
Maroon	36	25	WM-COL-MR-PK	TWM-COL-MR-PK	TMM-COL-MR-PK
Olive	36	25	-	-	TMM-COL-OL-PK
Orange	36	25	WM-COL-OR-PK	-	TMM-COL-OR-PK
Pink	36	25	WM-COL-PK-PK	TWM-COL-PK-PK	TMM-COL-PK-PK
Purple	36	25	WM-COL-PL-PK	-	TMM-COL-PL-PK
Red	36	25	WM-COL-RD-PK	TWM-COL-RD-PK	TMM-COL-RD-PK
Tan	36	25	WM-COL-TN-PK	TWM-COL-TN-PK	TMM-COL-TN-PK
White	36	25	WM-COL-WF-PK	TWM-COL-WF-PK	TMM-COL-WF-PK
Yellow	36	25	WM-COL-YL-PK	TWM-COL-YL-PK	TMM-COL-YL-PK

WM and TWM also available with markers scored in two. To order, replace "PK" with "SC-PK" or visit BradyID.com.

Blank - Self-laminating Write-On

Legend	Marker Size	Markers Per Card	Cards Per Pkg	B-292 Self-Laminating
Blank / Write-On	0.75 in H x 0.25 in W x 0.24 in Dia	36	25	SLFW-250-PK
Blank / Write-On	0.75 in H x 0.344 in W x 0.24 in Dia	26	25	SLFW-344-PK
Blank / Write-On	0.75 in H x 0.5 in W x 0.24 in Dia	18	25	SLFW-500-PK
Blank / Write-On	0.75 in H x 0.75 in W x 0.24 in Dia	12	25	SLFW-750-PK
Blank / Write-On	0.75 in H x 1 in W x 0.24 in Dia	9	25	SLFW-100-PK
Blank / Write-On	0.75 in H x 1.5 in W x 0.24 in Dia	6	25	SLFW-150-PK
Blank / Write-On	0.375 in H x 0.187 in W x 0.12 in Dia	96	25	SLHW-188-PK
Blank / Write-On	0.375 in H x 0.25 in W x 0.12 in Dia	72	25	SLHW-250-PK
Blank / Write-On	0.375 in H x 0.344 in W x 0.12 in Dia	52	25	SLHW-344-PK
Blank / Write-On	0.375 in H x 0.5 in W x 0.12 in Dia	36	25	SLHW-500-PK
Blank / Write-On	0.375 in H x 0.75 in W x 0.12 in Dia	24	25	SLHW-750-PK
Blank / Write-On	0.375 in H x 1 in W x 0.12 in Dia	18	25	SLHW-100-PK

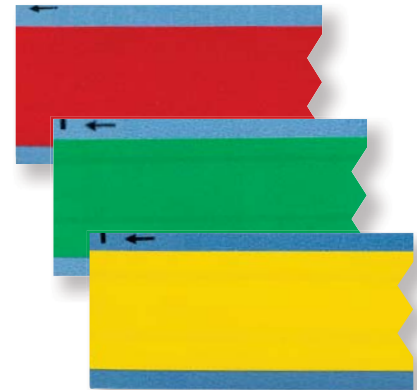

SLFW- markers



SLHW- markers

Pre-Printed Labels

Wire Marker Cards