



PRODUCT, WIRE, CABLE & INDUSTRIAL
IDENTIFICATION

BradyID.com

High-performance
labeling solutions
for the harshest
environments



3" Core Materials - Metallized Polyester

B-435 Metallized Polyester Material

Color: Silver Metallic **Finish:** Gloss

Printable metallized polyester withstands numerous solvents and variable temperatures. Ideal for serial and rating plate applications with name-plate quality and a metal looking finish.

Performance Attributes:

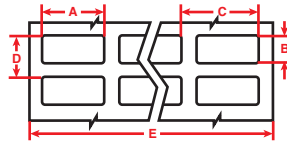


Figure 1

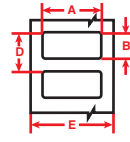


Figure 2



Diagram	Catalog #	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Horiz. Repeat C Inch (mm)	Vert. Repeat D Inch (mm)	Web Width E Inch (mm)	Labels Per Row	Labels Per Pkg	Rec. Ribbon
Fig. 1	THT-12-435-10	Polyester	Silver	0.500 (12.7)	0.437 (11.1)	-	-	-	5	10,000	R6007
Fig. 1	THT-1-435-10	Polyester	Silver	0.750 (19.1)	0.250 (6.4)	0.800 (20.3)	0.350 (8.9)	3.350 (85.1)	4	10,000	R6007
Fig. 1	THT-5-435-10	Polyester	Silver	1.000 (25.4)	0.500 (12.7)	1.075 (27.3)	0.600 (15.2)	3.350 (85.1)	3	10,000	R6007
Fig. 2	THT-17-435-3	Polyester	Silver	2.000 (50.8)	1.000 (25.4)	-	1.125 (28.6)	2.200 (55.9)	1	3,000	R6000
Fig. 2	THT-18-435-3	Polyester	Silver	3.000 (76.2)	1.000 (25.4)	-	1.125 (28.6)	3.200 (81.3)	1	3,000	R6002
Fig. 2	THT-19-435-1	Polyester	Silver	3.000 (76.2)	2.000 (50.8)	-	2.125 (54.0)	3.200 (81.3)	1	1,000	R6002
Fig. 2	THT-184-435-1	Polyester	Silver	3.000 (76.2)	3.000 (76.2)	-	3.125 (79.38)	3.200 (81.28)	1	1,000	R6000
Fig. 2	THT-20-435-3	Polyester	Silver	3.000 (76.2)	5.000 (127.0)	-	5.125 (130.18)	3.200 (81.28)	1	1,000	R6000
Fig. 2	THT-55-435-1	Polyester	Silver	4.000 (101.6)	2.000 (50.8)	-	2.125 (54.0)	4.200 (106.7)	1	1,000	R6007
Fig. 2	THT-25-435-1	Polyester	Silver	4.000 (101.6)	6.000 (152.4)	-	6.125 (155.58)	4.200 (106.68)	1	1,000	R6000

B-480 Metallized Polyester Material

Color: Silver Metallic **Finish:** Matte

Thermal transfer polyester material with metallic-looking finish (non-metallized) and aggressive adhesive for powder coated or rough surface applications. Ideal for barcoded asset tracking and rating plate applications.

Performance Attributes:

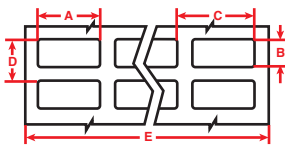


Figure 1

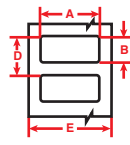


Figure 2

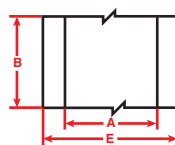


Figure 3



Diagram	Catalog #	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Horiz. Repeat C Inch (mm)	Vert. Repeat D Inch (mm)	Web Width E Inch (mm)	Labels Per Row	Labels Per Pkg	Rec. Ribbon
Fig. 1	THT-12-480-10	Polyester	Silver	0.500 (12.7)	0.437 (11.1)	0.662 (16.8)	0.537 (13.6)	3.350 (85.1)	5	10,000	R6007
Fig. 1	THT-1-480-10	Polyester	Silver	0.750 (19.1)	0.250 (6.4)	0.800 (20.3)	0.350 (8.9)	3.350 (85.1)	4	10,000	R6007
Fig. 1	THT-3-480-10	Polyester	Silver	1.000 (25.4)	0.375 (9.5)	1.075 (27.3)	0.475 (12.1)	3.350 (85.1)	3	10,000	R6007
Fig. 1	THT-5-480-10	Polyester	Silver	1.000 (25.4)	0.500 (12.7)	1.075 (27.3)	0.600 (15.2)	3.350 (85.1)	3	10,000	R6007
Fig. 1	THT-37-480-10	Polyester	Silver	1.500 (38.1)	0.500 (12.7)	1.650 (41.9)	0.600 (15.2)	3.350 (85.1)	2	10,000	R6007
Fig. 1	THT-6-480-10	Polyester	Silver	1.500 (38.1)	0.750 (19.1)	1.650 (41.9)	0.875 (22.2)	3.350 (85.1)	2	10,000	R6007
Fig. 3	THT-106-480	Polyester	Silver	2.000 (50.8)	300 ft. (91.4 m)	-	300 ft. (91.4 m)	2.200 (55.9)	1	1 roll (cont.)	R6000
Fig. 2	THT-17-480-3	Polyester	Silver	2.000 (50.8)	1.000 (25.4)	-	1.125 (28.6)	2.200 (55.9)	1	3,000	R6000
Fig. 2	THT-53-480-3	Polyester	Silver	2.000 (50.8)	0.500 (12.7)	-	0.600 (15.2)	2.200 (55.9)	1	3,000	R6000
Fig. 2	THT-7-480-3	Polyester	Silver	2.750 (69.9)	1.250 (31.8)	-	1.375 (34.9)	2.950 (74.9)	1	3,000	R6002
Fig. 2	THT-18-480-3	Polyester	Silver	3.000 (76.2)	1.000 (25.4)	-	1.125 (28.6)	3.200 (81.3)	1	3,000	R6002
Fig. 2	THT-19-480-1	Polyester	Silver	3.000 (76.2)	2.000 (50.8)	-	2.125 (54.0)	3.200 (81.3)	1	1,000	R6002
Fig. 3	THT-21-480	Polyester	Silver	3.000 (76.2)	300 ft. (91.4 m)	-	300 ft. (91.4 m)	3.200 (81.3)	1	1 roll (cont.)	R6002
Fig. 3	THT-107-480	Polyester	Silver	4.000 (101.6)	300 ft. (91.4 m)	-	300 ft. (91.4 m)	4.200 (106.7)	1	1 roll (cont.)	R6007
Fig. 2	THT-55-480-1	Polyester	Silver	4.000 (101.6)	2.000 (50.8)	-	2.125 (54.0)	4.200 (106.7)	1	1,000	R6007

3" Core Materials - Metallized Polyester

B-486 Metallized Polyester Material

Color: Silver Metallic

Finish: Matte

Thermal transfer printable metallized polyester material. Designed for high adhesion to textured metals, powder coated surfaces and low surface energy plastics. Withstands numerous solvents and variable temperatures.

Performance Attributes:

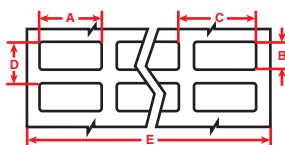


Figure 1

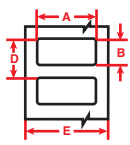


Figure 2

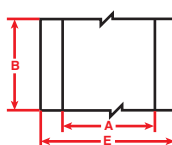


Figure 3



Diagram	Catalog #	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Horiz. Repeat C Inch (mm)	Vert. Repeat D Inch (mm)	Web Width E Inch (mm)	Labels Per Row	Labels Per Pkg	Rec. Ribbon
Fig. 1	THT-5-486-10	Polyester	Silver	1.000 (25.4)	0.500 (12.7)	1.075 (27.3)	0.600 (15.2)	3.350 (85.1)	3	10,000	R4307
Fig. 2	THT-59-486-10	Polyester	Silver	1.000 (25.4)	0.500 (12.7)	-	0.600 (15.2)	1.200 (30.5)	1	10,000	R4306
Fig. 1	THT-37-486-10	Polyester	Silver	1.500 (38.1)	0.500 (12.7)	1.650 (41.9)	0.600 (15.2)	3.350 (85.1)	2	10,000	R4307
Fig. 1	THT-6-486-10	Polyester	Silver	1.500 (38.1)	0.750 (19.1)	1.650 (41.9)	0.875 (22.2)	3.350 (85.1)	2	10,000	R4307
Fig. 3	THT-106-486	Polyester	Silver	2.000 (50.8)	300 ft. (91.4 m)	-	300 ft. (91.4 m)	2.200 (55.9)	1	1 roll (cont.)	R4302
Fig. 2	THT-17-486-3	Polyester	Silver	2.000 (50.8)	1.000 (25.4)	-	1.125 (28.6)	2.200 (55.9)	1	3,000	R4302
Fig. 2	THT-53-486-3	Polyester	Silver	2.000 (50.8)	0.500 (12.7)	-	0.600 (15.2)	2.200 (55.9)	1	3,000	R4302
Fig. 2	THT-7-486-3	Polyester	Silver	2.750 (69.9)	1.250 (31.8)	-	1.375 (34.9)	2.950 (74.9)	1	3,000	R4300
Fig. 2	THT-18-486-3	Polyester	Silver	3.000 (76.2)	1.000 (25.4)	-	1.125 (28.6)	3.200 (81.3)	1	3,000	R4300
Fig. 2	THT-19-486-1	Polyester	Silver	3.000 (76.2)	2.000 (50.8)	-	2.125 (54.0)	3.200 (81.3)	1	1,000	R4300
Fig. 2	THT-184-486-1	Polyester	Silver	3.000 (76.2)	3.000 (76.2)	-	3.125 (79.38)	3.200 (81.28)	1	1,000	R4300
Fig. 3	THT-21-486	Polyester	Silver	3.000 (76.2)	300 ft. (91.4 m)	-	300 ft. (91.4 m)	3.200 (81.3)	1	1 roll (cont.)	R4300
Fig. 3	THT-107-486	Polyester	Silver	4.000 (101.6)	300 ft. (91.4 m)	-	300 ft. (91.4 m)	4.200 (106.7)	1	1 roll (cont.)	R4307
Fig. 2	THT-161-486-1	Polyester	Silver	4.000 (101.6)	4.000 (101.6)	-	4.125 (104.8)	4.200 (106.7)	1	1,000	R4307
Fig. 2	THT-25-486-1	Polyester	Silver	4.000 (101.6)	6.000 (152.4)	-	6.125 (155.58)	4.200 (106.68)	1	1,000	R4300

B-8591 Weather Resistant Metallized Polyester Material

Color: Silver

Finish: Glossy

An extremely outdoor durable, print-on-demand thermal transfer label solution that resists UV, abrasion and fluids. 12+ year outdoor durability reduces identification failures and the costs associated with losing this information. No over laminate means durability is drastically improved without adding an over laminate over the print. Quick and easy application with pressure-sensitive adhesive. Meets regulatory specifications for Halogen Free Applications

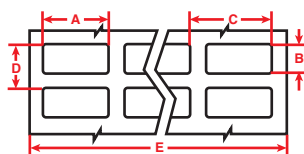


Figure 1

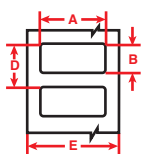


Figure 2

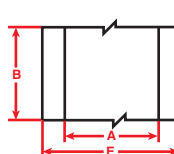


Figure 3



Diagram	Catalog #	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Web Width E Inch (mm)	Labels Per Row	Labels Per Pkg	Rec. Ribbon
Fig. 1	THT-11-8591-10-SL	Polyester	Silver	0.250 (6.35)	0.250 (6.35)	3.200 (81.3)	12	10,000	R6600
Fig. 1	THT-5-8591-10-SL	Polyester	Silver	1.000 (25.4)	0.500 (12.7)	3.350 (85.1)	3	10,000	R6600
Fig. 1	THT-6-8591-10-SL	Polyester	Silver	1.500 (38.1)	0.750 (19.1)	3.350 (85.1)	2	10,000	R6600
Fig. 2	THT-17-8591-3-SL	Polyester	Silver	2.000 (50.8)	1.000 (25.4)	2.200 (55.9)	1	3,000	R6600
Fig. 2	THT-18-8591-3-SL	Polyester	Silver	3.000 (76.2)	1.000 (25.4)	3.200 (81.3)	1	3,000	R6600
Fig. 2	THT-19-8591-1-SL	Polyester	Silver	3.000 (76.2)	2.000 (50.8)	3.200 (81.3)	1	1,000	R6600
Fig. 3	THT-21-8591-SL	Polyester	Silver	3.000 (76.2)	300 ft. (91.4 m)	3.200 (81.3)	1	1 roll (cont.)	R6600
Fig. 2	THT-55-8591-1-SL	Polyester	Silver	4.000 (101.6)	2.000 (50.8)	4.200 (106.7)	1	1,000	R6600
Fig. 3	THT-107-8591-SL	Polyester	Silver	4.000 (101.6)	300 ft. (91.4 m)	4.200 (106.7)	1	1 roll (cont.)	R6600
Fig. 2	THT-161-8591-1-SL	Polyester	Silver	4.000 (101.6)	4.000 (101.6)	4.200 (106.7)	1	1,000	R6600

Also available in white, black and yellow. See page 161.