


TDA Series

Ultra-miniature Surface Mount Half-pitch DIP Switches

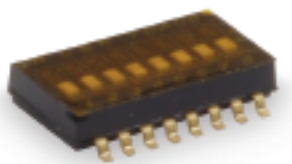

DIP



Features/Benefits

- **Bifurcated contact for increased electrical reliability**
- **Process sealed for surface mount soldering and washable processing**
- **RoHS compliant**

Typical Applications

- **Hand-held electronic devices**
- **Portable computer and electronic devices**
- **Instrumentation and controls**

Specifications

SWITCH FUNCTION: SPST – 2, 4, 6, 8 & 10 positions.

CONTACT RATING:

24 V DC, 25 mA (switching).

50 V DC, 100 mA (steady state).

MECHANICAL AND ELECTRICAL LIFE: 1,000 cycles.

CONTACT RESISTANCE: 100 milliohms max.

INSULATION RESISTANCE: 100 megohms @ 100 V DC min.

DIELECTRIC STRENGTH: 300 V AC min.

STORAGE TEMPERATURE: -40°C to 85°C.

OPERATING TEMPERATURE: -40°C to 85°C.

OPERATING FORCE: 4,9N max.

SOLDERABILITY: Per MIL-STD-202F method 208D, or

EIA RS-186E method 9 (1 hour steam aging).

PACKAGING: Switches supplied in rigid dispensing tubes in full tube quantities only, this may affect order quantity. Numbers of switches per tube varies with model. Tape and reel packaging is 2,000 per reel.

Materials

CASE & COVER: PPS (UL94V-0)

ACTUATOR: LCP (UL94V-0).

CONTACTS: Copper alloy, with gold plate over nickel plate.

TERMINALS: Copper alloy, with gold flash over nickel plate.

All terminals are insert molded.

 

TAPE SEAL: Polyimide.

Note: Specifications and materials listed above are for switches with standard options. For information on specific and custom switches, consult Customer Service Center.

Note: All switches supplied in "OFF" position.

How To Order

Complete part numbers for TDA Series are shown below.

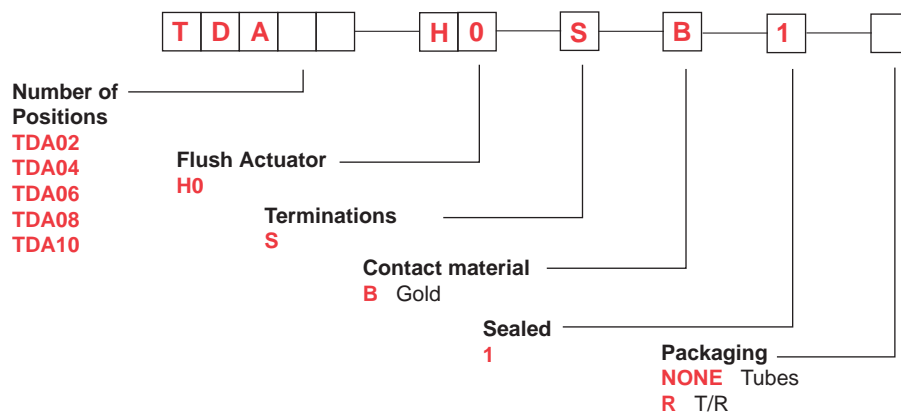

Dimensions are shown: Inch (mm)
Specifications and dimensions subject to change




TDA Series Ultra-miniature Surface Mount Half-pitch DIP Switches



DIP



TDA08H0SB1

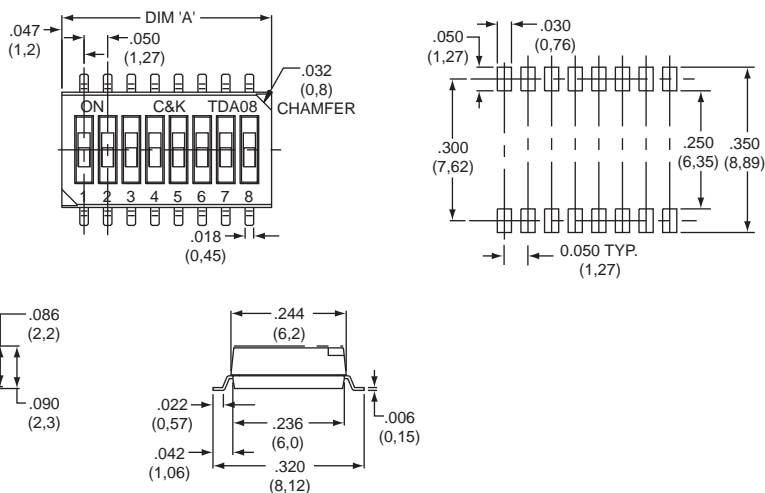


Tube Package

ROHS PART NUMBER	NO. POS.	DIM. 'A'	QUANTITY PER TUBE
TDA02H0SB1	2	.144 (3,67)	125
TDA04H0SB1	4	.244 (6,21)	70
TDA06H0SB1	6	.344 (8,75)	50
TDA08H0SB1	8	.444 (11,29)	40
TDA10H0SB1	10	.544 (13,83)	30



Schematic

SPST

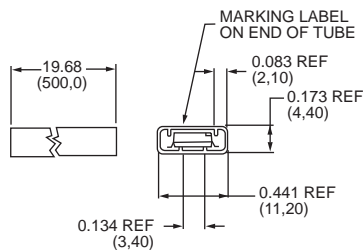

Tape & Reel Package

ROHS PART NUMBER	NO. POS.	DIM. 'W'	QUANTITY PER REEL
TDA02H0SB1R	2	.630 (16,0)	2000
TDA04H0SB1R	4	.630 (16,0)	2000
TDA06H0SB1R	6	.630 (16,0)	2000
TDA08H0SB1R	8	.945 (24,0)	2000
TDA10H0SB1R	10	.945 (24,0)	2000

 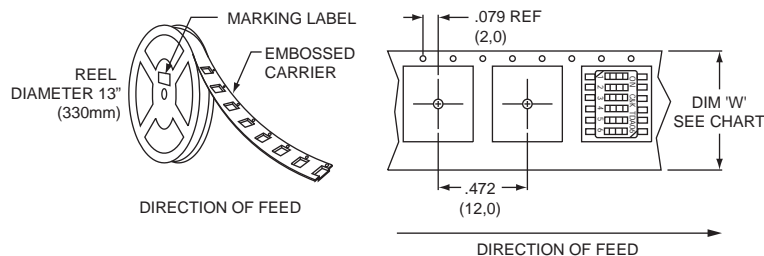

Dimensions are shown: Inch (mm)
Specifications and dimensions subject to change

