

EM2929 Series Euro-Mag Terminal Blocks

Hi-Current; 10.16 Centers

SPECIFICATIONS

Rating: 65A, 600V

Center Spacing: .400" (10.16 mm)

Wire Range: #6-20 AWG

Housing Material: UL rated 94V0 Thermoplastic

Contact Material: Tin Plated Copper

Cage Clamp: Steel, Chromate Plated

Screw Size: M4 Stainless Steel

Operating Temperature: 105°C (221°F) max., -40°C (-40°F) min.

Torque Rating: 15 in.-lb.

Recommended PCB Hole Diameters: .055" (1.40)

Construction: Mold to length


Agency Information: UL/CSA; CE Certified

EM292908

TABLE A

Poles	L (mm)
2	20.34
3	30.50
4	40.66
5	50.82
6	60.98
7	71.14
8	81.30

To convert to inches, divide by 25.4

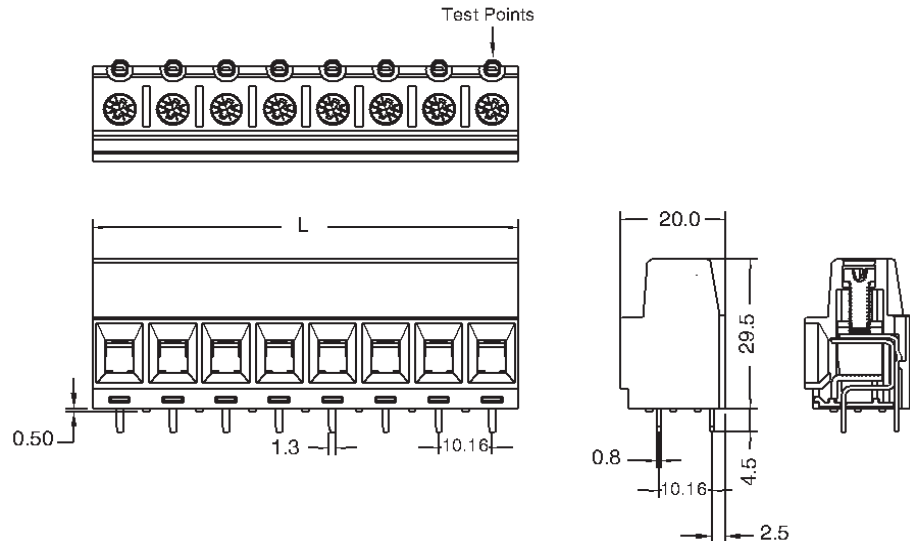

Part Numbering System

Series

of Poles

EM2929

□□

02 to 08