




Product Number: 551-3508-100F

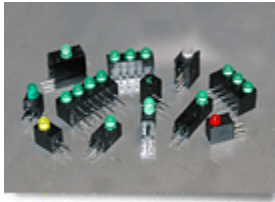



General Description

Series	551
Configuration	3 mm Lens
Description	3 mm CBI
Package Options	Bulk Packaging
Sizes	3mm
Lamp Type	Single Housing
Viewing	Right Angle
Polarity	Cathode Right
Lens Style	Untinted, Diffused
LED Centerline	3.81mm
Solder Temperature	260 for 6 secs
Operating Temperature	-30 to +85
Storage Temperature	-30 to +100

Absolute Maximum Ratings (Ta = 25°)

Operating Characteristics

		
Color	Red	Green
Peak Wave Length	630	560
Luminous Intensity Min	2	2
Luminous Intensity Typical	4	4
Forward Voltage Typical	2	2.1
Forward Voltage Max	2.5	2.5
Power Dissipation Max	75mW	75mW