


NO.		
1	MODEL 1	A09-HASM-675
2	ANTENNA TYPE	DIPOLE ANTENNA
3	ANTENNA üø	90° ?ó TYPE
4	FREQUENCY	902–928 MHz
5	CONNECTOR TYPE	RPSMA Male
6	V.S.W.R	1.9:1 11
7	GAIN	2.15dBi ±1.0

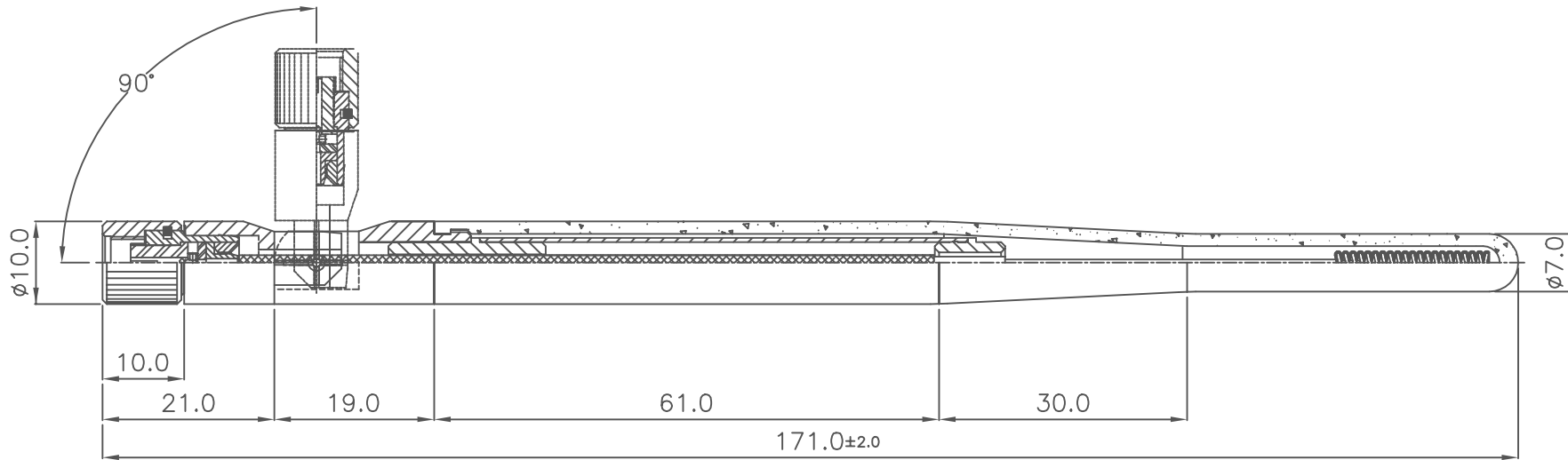

DO NOT SCALE DRAWINGS FOR DIMENSIONS

ALL DIMENSIONS ARE IN INCHES UNLESS OTHERWISE SPECIFIED

Property of: MaxStream, Inc. Orem, Utah, USA	Part Description: 900MHz Half-wave Dipole Antenna w/ Articulated joint, RPSMA connector		Date: 29 JAN 03	Part Number: A09-HASM-675
	Drawn By:	Approved By: Jan Finlinson	Revision #: 1	Drawing Number A09-HASM-675.pdf