


[Request more info](#)
Part Number : 5513207F




This is a
RoHS Compliant Product
[To learn more click here](#)

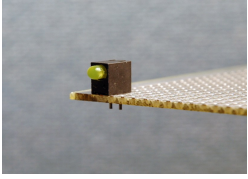

General Description


Series	551
Configuration	3 mm Lens
Description	3 mm CBI
Package Options	Bulk Packaging
Sizes	3mm
Lamp Type	Single Housing
Viewing	Right Angle
Polarity	Cathode Right
Lens Style	Untinted, Diffused
Viewing Angle	80
LED Centerline	5.08mm

Absolute Maximum Ratings (Ta = 25°)

Solder Temperature	260 for 5 secs
Operating Temperature	-55 to +100
Storage Temperature	-55 to +100

Operating Characteristics

Color	Red 	Yellow 
Peak Wave Length	630	585
Luminous Intensity Min	1.7	1.7
Luminous Intensity Typical	5.6	5.6
Forward Voltage Typical	2	2.1
Forward Voltage Max	2.8	2.8
Test Current mA	20mA	
Power Dissipation Max	100mW	60mW

[EAX Login](#) 
[Site Map](#)
[Privacy and Cookies Policy](#)
[Terms and Conditions](#)
[Dialight BTI](#)
[Alert Services](#)
