

### Approvals



### Life expectancy




L-10 LIFE AT 40°C:  
80 000 hours

### Brushless DC Motor

Electrical protection: impedance protected  
Housing material: aluminium  
Impeller material: plastic UL 94 VO  
Weight: 840 g  
Bearing system: ball bearings

### Available with:

- Speed sensor
- Alarm
- IP54 / IP55

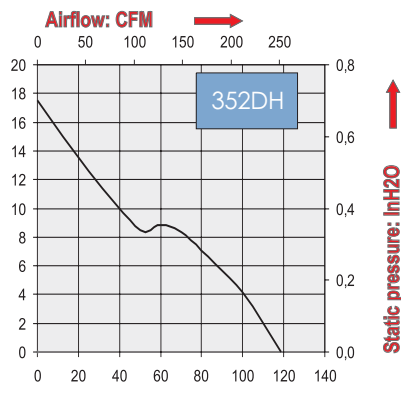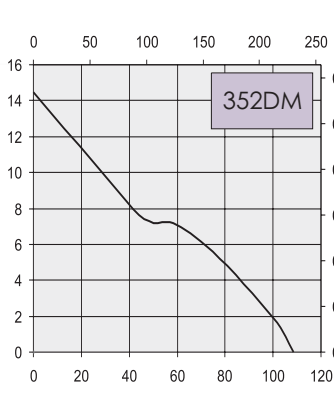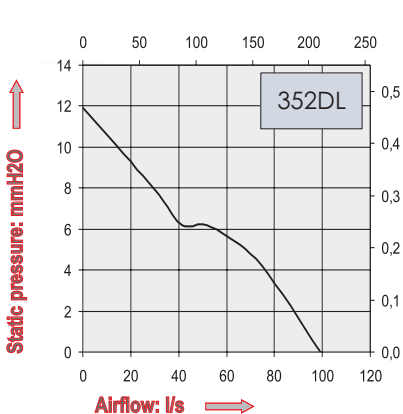

Part Number	Nominal voltage	Airflow	Noise level	Nominal speed	Input Power	Voltage range	Connection type		Operating temperature	
	V	l/s	dB(A)	RPM	W	V	Leads	Terminals	Min.°C	Max.°C
352DL1LM11000	12	99,2	50	2800	10,1	(8-14)	X		-10	70
352DL2LM11000	24	99,2	50	2800	10,1	(12-28)	X		-10	70
352DL4LM11000	48	99,2	50	2800	11,5	(24-56)	X		-10	70
352DM1LM11000	12	108,7	52	3050	12,6	(8-14)	X		-10	70
352DM2LM11000	24	108,7	52	3050	11,8	(12-28)	X		-10	70
352DM4LM11000	48	108,7	52	3050	13,9	(24-56)	X		-10	70
352DH1LM11000	12	118,8	55	3350	16,8	(8-14)	X		-10	70
352DH2LM11000	24	118,8	55	3350	15,1	(12-28)	X		-10	70
352DH4LM11000	48	118,8	55	3350	16,8	(24-56)	X		-10	70

### Additional versions:

Higher speeds (see page 34)

### Accessories:

Refer to Accessories leaflet