

## CABLE CLIPS &amp; CLAMPS



### ASK/RAK Series Adhesive Mount Aluminum Clamp

**Specifications:**

- Material: Aluminum, Bright Finish

**Features:**

- Aluminum arms are flexed around bundle
- Lightweight and durable
- Adhesive mount for quick installation

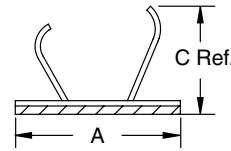
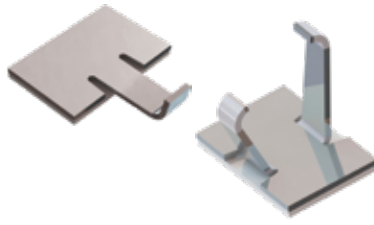


Figure 1

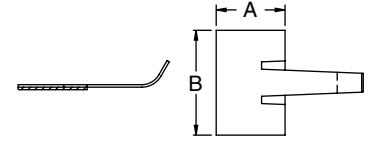


Figure 2

| Item No. | Figure | Ø Max Bundle |     | A    |      | B Base Depth |      | Bulk Pack Qty |
|----------|--------|--------------|-----|------|------|--------------|------|---------------|
|          |        | in           | mm  | in   | mm   | in           | mm   |               |
| ASK-3    | 1      | 0.234        | 6.0 | 0.44 | 11.3 | 0.66         | 16.8 | 250           |
| ASK-6    | 1      | 0.375        | 9.5 | 0.62 | 15.7 | 0.74         | 18.8 | 250           |
| RAK-1    | 2      | 0.234        | 6.0 | 0.44 | 11.3 | 0.67         | 17.1 | 250           |
| RAK-2    | 2      | 0.375        | 9.5 | 0.64 | 16.3 | 0.76         | 19.3 | 250           |



### VCC Series Vinyl Coated Adjustable Steel Clamp

 **Specifications:**

- Material: PVC Coated Soft Steel
- Color: Body - Steel Coating - Black

**Features:**

- For bundling and clamping cable or tubing securely
- Vinyl coating grips and insulates the cable
- Easily bends and forms to desired shape for varying holding diameters

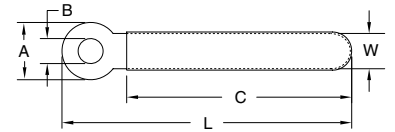

| Item No.   | Ø Bundle |      | C Ref. |       | L Ref. |       | W Ref. |     | A     |     | Ø B   |     | Pack Qty | Bulk Pack Qty |
|------------|----------|------|--------|-------|--------|-------|--------|-----|-------|-----|-------|-----|----------|---------------|
|            | in       | mm   | in     | mm    | in     | mm    | in     | mm  | in    | mm  | in    | mm  |          |               |
| VCC-83028  | 0.22     | 5.7  | 0.71   | 18.0  | 1.10   | 28.0  | 0.12   | 3.0 | 0.315 | 8.0 | 0.118 | 3.0 | 1        | 1000          |
| VCC-83535  | 0.31     | 7.9  | 0.98   | 25.0  | 1.34   | 35.0  | 0.20   | 5.0 | 0.315 | 8.0 | 0.138 | 3.5 | 1        | 1000          |
| VCC-83540  | 0.37     | 9.5  | 1.18   | 30.0  | 1.57   | 40.0  | 0.12   | 3.0 | 0.315 | 8.0 | 0.138 | 3.5 | 1        | 1000          |
| VCC-63048  | 0.50     | 12.7 | 1.57   | 40.0  | 1.89   | 48.0  | 0.08   | 2.0 | 0.236 | 6.0 | 0.118 | 3.0 | 1        | 1000          |
| VCC-84554  | 0.52     | 13.3 | 1.65   | 42.0  | 2.13   | 54.0  | 0.19   | 4.8 | 0.315 | 8.0 | 0.177 | 4.5 | 1        | 1000          |
| VCC-63254  | 0.57     | 14.6 | 1.81   | 46.0  | 2.13   | 54.0  | 0.14   | 3.6 | 0.236 | 6.0 | 0.126 | 3.2 | 1        | 1000          |
| VCC-83664  | 0.66     | 16.9 | 2.09   | 53.0  | 2.52   | 64.0  | 0.20   | 5.0 | 0.315 | 8.0 | 0.161 | 4.1 | 1        | 1000          |
| VCC-84576  | 0.81     | 20.7 | 2.56   | 65.0  | 2.99   | 76.0  | 0.18   | 4.5 | 0.315 | 8.0 | 0.177 | 4.5 | 1        | 1000          |
| VCC-84584  | 0.90     | 22.9 | 2.83   | 72.0  | 3.31   | 84.0  | 0.18   | 4.5 | 0.315 | 8.0 | 0.177 | 4.5 | 1        | 1000          |
| VCC-845126 | 1.40     | 35.6 | 4.41   | 112.0 | 4.96   | 126.0 | 0.24   | 6.0 | 0.315 | 8.0 | 0.177 | 4.5 | 1        | 100           |



### PCC Series Adhesive Mount Vinyl Coated Adjustable Steel Clamp

 **Specifications:**

- Material: Soft Steel with PVC Coating
- Color: White

**Features:**

- Protects and insulates wires or components
- Flexible arm holds flat, round, or oddly shaped components
- Arm may be opened or closed repeatedly and reshaped for varying holding diameters

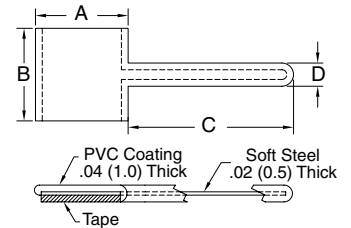

| Item No. | A Ref. |      | B    |      | C Ref. |      | D Ref. |     | Bulk Pack Qty |
|----------|--------|------|------|------|--------|------|--------|-----|---------------|
|          | in     | mm   | in   | mm   | in     | mm   | in     | mm  |               |
| PCC-5    | 0.31   | 8.0  | 0.31 | 8.0  | 0.59   | 15.0 | 0.08   | 2.1 | 1000          |
| PCC-9    | 0.55   | 14.0 | 0.55 | 14.0 | 0.98   | 25.0 | 0.14   | 3.5 | 500           |
| PCC-12   | 0.75   | 19.0 | 0.75 | 19.0 | 1.58   | 40.0 | 0.16   | 4.0 | 500           |


### PFC Series Adhesive Mount Foam Coated Adjustable Steel Clamp

**Specifications:**

- Material: Foam Coated Aluminum
- Color: Grey Coated

**Features:**

- Made of aluminum with a protective foam coating on the inside of the clamp that protects cables and fibers
- Flexible arm holds flat, round or oddly shaped components
- Arm may be opened or closed repeatedly and reshaped for varying holding diameters

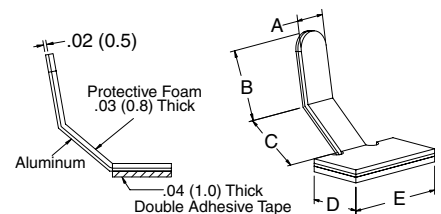

| Item No. | A Ref. |     | B Ref. |      | C Ref. |      | D     |      | E     |      | Bulk Pack Qty |
|----------|--------|-----|--------|------|--------|------|-------|------|-------|------|---------------|
|          | in     | mm  | in     | mm   | in     | mm   | in    | mm   | in    | mm   |               |
| PFC-25M  | 0.189  | 4.8 | 0.494  | 12.6 | 0.437  | 11.1 | 0.397 | 10.1 | 0.751 | 19.1 | 1000          |
| PFC-50M  | 0.205  | 5.2 | 0.573  | 14.6 | 0.555  | 14.1 | 0.553 | 14.1 | 0.982 | 25.0 | 1000          |