


MALE / FEMALE THREADED STANDOFFS

CBMFTS/NTS Series Male & Female Threaded Standoff

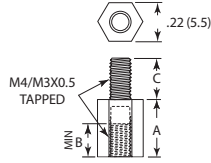

Specifications:

- Material: Nylon 6/6
- Color: Natural
- Flame Class: UL94 V-2

CBMFTS Series (Threaded Standoffs) can be used with the following screws and nuts:

Threads: M3 & M4

SCREWS:

SXHM Series - SCSM Series -
Page: 784 Page: 787


NUTS:

SPXM Series - NHSM Series -
Page: 786 Page: 813



Item No.	M3	M4	A		B (Min)		C (Min)		Bulk Pack Qty.
			In	mm	In	mm	In	mm	
CBMFTS205A	—	—	0.197	5.0	0.118	3.0	0.236	6.0	1000
CBMFTS210A	—	—	0.236	6.0	0.157	4.0	0.236	6.0	1000
NTS-7	—	—	0.276	7.0	0.240	6.1	0.250	6.4	1000
CBMFTS220A	—	—	0.295	7.5	0.197	5.0	0.236	6.0	1000
NTS-8	—	—	0.315	8.0	0.240	6.1	0.250	6.4	1000
CBMFTS230A	—	—	0.354	9.0	0.236	6.0	0.236	6.0	1000
NTS-10	—	—	0.394	10.0	0.310	7.9	0.236	6.0	1000
CBMFTS240A	—	—	0.413	10.5	0.236	6.0	0.236	6.0	1000
NTS-11	—	—	0.433	11.0	0.310	7.9	0.236	6.0	1000
CBMFTS250A	—	—	0.472	12.0	0.236	6.0	0.236	6.0	1000
NTS-12	—	—	0.500	12.7	0.390	9.9	0.250	6.4	1000
CBMFTS260A	—	—	0.512	13.0	0.236	6.0	0.236	6.0	1000
CBMFTS265A	—	—	0.551	14.0	0.236	6.0	0.236	6.0	1000
CBMFTS270A	—	NTS-15A	0.591	15.0	0.236	6.0	0.236	6.0	1000
NTS-16	—	—	0.630	16.0	0.390	9.9	0.236	6.0	1000
CBMFTS280A	—	—	0.650	16.5	0.236	6.0	0.236	6.0	1000
CBMFTS285A	—	—	0.669	17.0	0.236	6.0	0.236	6.0	1000
NTS-17.5	—	—	0.690	17.5	0.390	9.9	0.236	6.0	1000
CBMFTS290A	—	—	0.709	18.0	0.236	6.0	0.236	6.0	1000
CBMFTS295A	—	—	0.728	18.5	0.236	6.0	0.236	6.0	1000
CBMFTS300A	—	NTS-19	0.748	19.0	0.236	6.0	0.220	5.6	1000
NTS-20	—	—	0.787	20.0	0.390	9.9	0.236	6.0	1000
CBMFTS310A	—	—	0.827	21.0	0.236	6.0	0.236	6.0	1000
CBMFTS315A	—	—	0.866	22.0	0.236	6.0	0.236	6.0	1000
CBMFTS320A	—	—	0.965	24.5	0.236	6.0	0.236	6.0	1000
NTS-25	—	—	0.984	25.0	0.390	9.9	0.260	6.6	1000
CBMFTS330A	—	—	1.063	27.0	0.236	6.0	0.236	6.0	500
CBMFTS335A	—	—	1.181	30.0	0.236	6.0	0.236	6.0	1000
CBMFTS340A	—	—	1.299	33.0	0.236	6.0	0.236	6.0	1000
CBMFTS345A	—	—	1.378	35.0	0.236	6.0	0.236	6.0	1000
—	—	NTS-37	1.160	37.1	0.345	8.0	0.220	5.6	200

HTSN-2 M3, M4 Metric Hex Male/Female Threaded Standoff

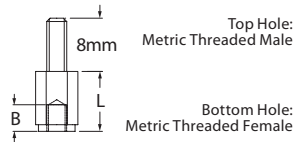

- Both ends are threaded and can be secured with nylon nuts and screws. See pages 784 - 788, 814 and 815.
- Material: UL94 HB Nylon 6/6
- Color: Black

Item No.	Thread	Across Flats mm	"L" Standoff Height mm	Bulk Pack Qty.
HTSN-M3-6-6-2	M3	6	6	500
HTSN-M3-8-6-2	M3	6	8	500
HTSN-M3-10-6-2	M3	6	10	500
HTSN-M4-6-8-2	M4	8	6	500
HTSN-M4-8-8-2	M4	8	8	500
HTSN-M4-10-8-2	M4	8	10	500