

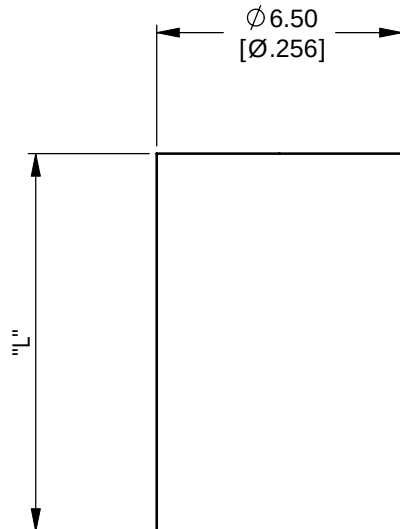
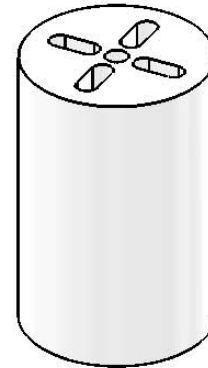
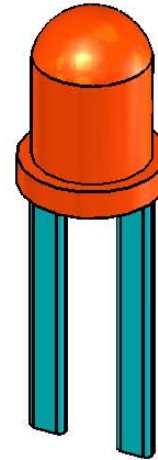


AVAILABLE BY SPECIAL ORDER NAFTA REGION ONLY

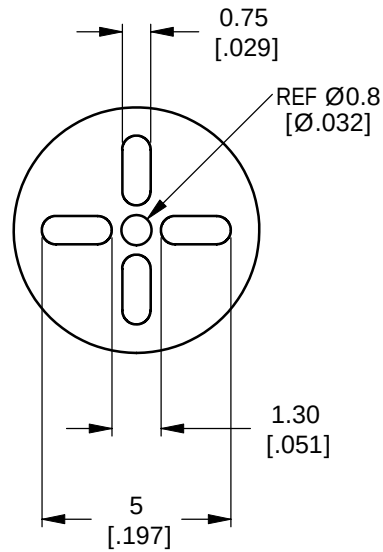

- NOTES:
- 1) FOR USE WITH 5mm, T-1 3/4 LEDs.
 - 2) PARTS AVAILABLE IN 1MM INCREMENTS.
 - 3) SPECIAL LENGTHS AVAILABLE BY SPECIAL ORDER.

REV.	MODIFICATION.	DATE	DRN
01	NEW DWG	25/05/01	JPM
02	SCN04-093	25/05/01	OW
03	SCN04-096	25/05/01	OW
04	SCN04-100	14/10/04	OW
05	ECN05-021	26/01/05	OW
06	CO-2010553	09/02/09	OW

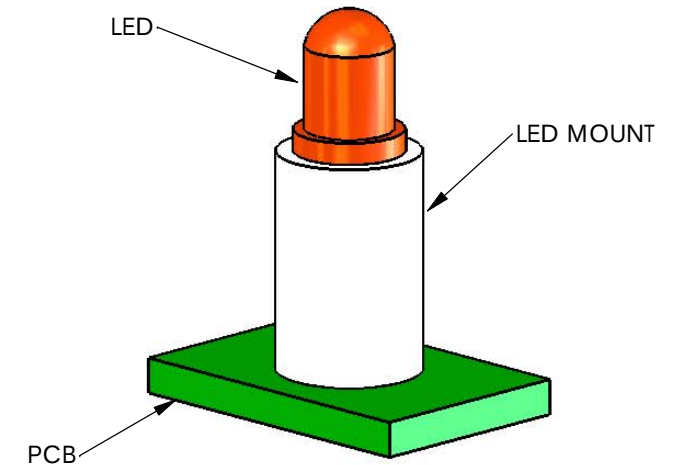

TYPICAL APPLICATION VIEW

INFORMATION CONTAINED IN THIS DOCUMENT IS CONFIDENTIAL TO RICHCO INTERNATIONAL Co. Ltd. AND MAY NOT BE DISCLOSED OR REPRODUCED IN WHOLE OR PART WITHOUT THEIR WRITTEN CONSENT



ALL PRIMARY DIMENSIONS IN mm
ALL SECONDARY DIMENSIONS IN INCHES
METRIC GENERAL TOLERANCES ± 0.25
ARE PRIMARY UNLESS OTHERWISE STATED
1 DECIMAL PLACE $\pm$
2 DECIMAL PLACES $\pm$
ANGULAR $\pm 1^\circ$
IMPERIAL GENERAL TOLERANCES ± 0.010
ARE FOR REFERENCE UNLESS OTHERWISE
1 DECIMAL PLACE $\pm$
2 DECIMAL PLACES $\pm$
ANGULAR $\pm 1^\circ$

MATERIAL: PVC UL94 V-0 (RMS-388)		COLOUR: BLACK	
TITLE: LED MOUNTS		PART No: LEDM-3-XX	
DRG No: 786-9020	NPR REF: N/A		SIZE A4
DRN OW	DATE 14/10/04		
CHKD NJB	DATE 14/10/04	SCALE NTS	SHEET No 1 OF 1

PART No.	LENGTH
LEDM-3-02 - LEDM-3-30	2.0mm - 30mm