



TUBE INSERT & GLIDE SELECTOR GUIDE



Step 1: Determine Tube Size = Actual O.D. of Tubing

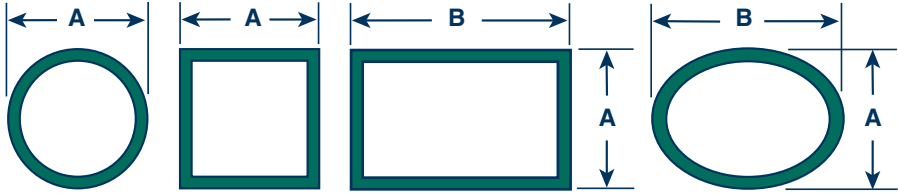


Step 2: Determine the Wall Thickness to Determine Tube Gauge

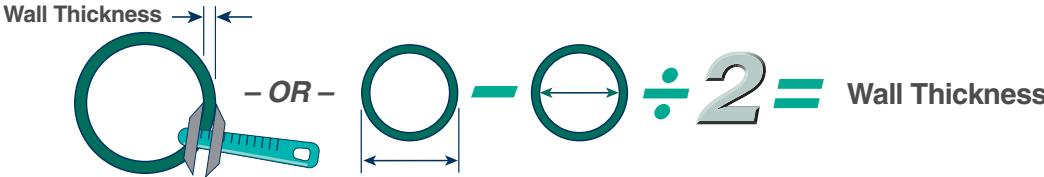


Wall Thickness (Inches)	0.239	0.224	0.209	0.194	0.179	0.164	0.149	0.134	0.120	0.109	0.095	0.083	0.072	0.065	0.058	0.049	0.042	0.035	0.028
(mm)	6.1	5.7	5.3	4.9	4.5	4.2	3.8	3.4	3	2.8	2.4	2.1	1.8	1.7	1.5	1.2	1.1	0.9	0.7
Tube Gauge	3	4	5	6	7	8	9	10	11	12	13	14	15	16	17	18	19	20	22

Step 3: Select your desired...

Style:

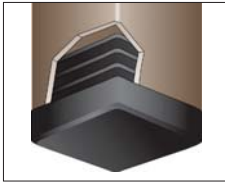

Ribbed Design – Fits Multiple Gauges Non-Load Bearing

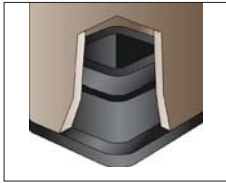

Straight Wall Design – Fits Single Gauge Load Bearing

Shape & Finish:



Flat, Rounded, Angled, or Articulating



Polished, Textured (Matte), or Chromed



SQH SERIES

Square Heavy Duty Threaded Inserts



Specifications:

- Material: Glass-filled nylon with brass threaded insert
- Color: Black

Features:

- Threaded brass insert for indoor and outdoor use
- High load rating is ideal for machinery use

Item No.	Tube Size In	Thread Size	Tube Gauge	Wall Thickness In	Load Capacity lbs.	Pack Qty.	Bulk Pack Qty.
SQH0100A	1.5	3/8-16	16	0.065	1350	1	48
SQH0150A	1.5	1/2-13	16	0.065	1350	1	48
SQH0200A	1.5	5/8-11	16	0.065	1350	1	48
SQH0250A	1.5	3/4-10	16	0.065	1800	1	48
SQH0300A	1.5	3/8-16	11	0.12	1350	1	48
SQH0350A	1.5	1/2-13	11	0.12	1350	1	48
SQH0400A	1.5	5/8-11	11	0.12	1350	1	48
SQH0450A	1.5	3/4-10	11	0.12	1800	1	48

Item No.	Tube Size In	Thread Size	Tube Gauge	Wall Thickness In	Load Capacity lbs.	Pack Qty.	Bulk Pack Qty.
SQH0500A	2	3/8-16	16	0.065	1350	1	24
SQH0550A	2	1/2-13	16	0.065	1350	1	24
SQH0600A	2	5/8-11	16	0.065	1350	1	24
SQH0650A	2	3/4-10	16	0.065	2000	1	24
SQH0700A	2	3/8-16	12	0.109	1350	1	24
SQH0750A	2	1/2-13	12	0.109	1350	1	24
SQH0800A	2	5/8-11	12	0.109	1350	1	24
SQH0850A	2	3/4-10	12	0.109	2000	1	24

RDH Series

Round Heavy Duty Threaded Inserts



Specifications:

- Material: Glass-filled nylon with brass threaded insert
- Color: Black

Features:

- Threaded brass insert for indoor and outdoor use
- High load rating is ideal for machinery use

Item No.	Tube Size In	Thread Size	Tube Gauge	Wall Thickness In	Load Capacity lbs.	Pack Qty.	Bulk Pack Qty.
RDH0100A	1.500	3/8-16	16	0.065	1100	1	48
RDH0150A	1.500	1/2-13	16	0.065	1100	1	48
RDH0200A	1.500	5/8-11	16	0.065	1100	1	48
RDH0250A	1.500	3/4-10	16	0.065	1100	1	48
RDH0300A	2.000	3/8-16	16	0.065	1250	1	24
RDH0350A	2.000	1/2-13	16	0.065	1250	1	24

Item No.	Tube Size In	Thread Size	Tube Gauge	Wall Thickness In	Load Capacity lbs.	Pack Qty.	Bulk Pack Qty.
RDH0400A	2.000	5/8-11	16	0.065	1250	1	24
RDH0450A	2.000	3/4-10	16	0.065	2000	1	24
RDH0500A	2.000	3/8-16	12	0.109	1250	1	24
RDH0550A	2.000	1/2-13	12	0.109	1250	1	24
RDH0600A	2.000	5/8-11	12	0.109	1250	1	24
RDH0650A	2.000	3/4-10	12	0.109	2000	1	24




WE ARE HERE TO HELP!

Our Customer Service team is friendly, knowledgeable, and ready to help you find the right product for your application.





SQM Series
Square Metal Threaded Inserts

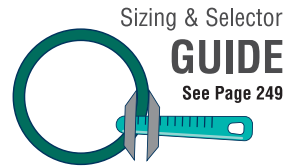

Specifications:

- Material: HDPE with Zinc-Plated Steel-Threaded Insert
- Color: Black

Features:

- Tube inserts with internal threads to accommodate adjustable leveling mounts and feet
- Ribbed to accommodate multiple gauges

Item No.	Tube Size	Thread Size	Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
SQM0150A	0.750	1/4-20	16-18	0.049-0.065	1	1000
SQM0200A	0.875	1/4-20	16-18	0.049-0.065	1	1000
SQM0300A	1.000	1/4-20	16-18	0.049-0.065	1	1000
SQM0350A	1.000	5/16-18	16-18	0.049-0.065	1	1000
SQM0400A	1.000	1/4-20	12-14	0.083-0.109	1	1000
SQM0450A	1.000	5/16-18	12-14	0.083-0.109	1	1000
SQM0500A	1.000	1/4-20	10-11	0.120-0.134	1	1000
SQM0550A	1.000	5/16-18	10-11	0.120-0.134	1	1000

Item No.	Tube Size	Thread Size	Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
SQM0600A	1.250	5/16-18	16-18	0.049-0.065	1	500
SQM0650A	1.250	3/8-16	16-18	0.049-0.065	1	500
SQM0700A	1.250	5/16-18	12-14	0.083-0.109	1	500
SQM0750A	1.250	3/8-16	12-14	0.083-0.109	1	500
SQM0800A	1.250	5/16-18	10-11	0.120-0.134	1	500
SQM0850A	1.250	3/8-16	10-11	0.120-0.134	1	500
SQM0900A	1.375	3/8-16	16-18	0.049-0.065	1	500
SQM1000A	1.500	3/8-16	16-18	0.049-0.065	1	500

RDM Series
Round Metal Threaded Inserts



Specifications:

- Material: HDPE with Zinc-Plated Steel-Threaded Insert
- Color: Black

Features:

- Tube inserts with internal threads to accommodate adjustable leveling mounts and feet
- Ribbed to accommodate multiple gauges

Item No.	Tube Size	Thread Size	Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
RDM0100A	0.750	1/4-20	16-18	0.049-0.065	1	1000
RDM0150A	0.875	1/4-20	16-18	0.049-0.065	1	1000
RDM0200A	0.875	1/4-20	12-14	0.083-0.109	1	1000
RDM0250A	0.875	1/4-20	10-11	0.120-0.134	1	1000
RDM0300A	1.000	1/4-20	16-18	0.049-0.065	1	1000
RDM0350A	1.000	5/16-18	16-18	0.049-0.065	1	1000
RDM0400A	1.000	1/4-20	12-14	0.083-0.109	1	750
RDM0450A	1.000	5/16-18	12-14	0.083-0.109	1	750
RDM0500A	1.000	1/4-20	10-11	0.120-0.134	1	750
RDM0550A	1.000	5/16-20	10-11	0.120-0.134	1	750
RDM0600A	1.125	5/16-18	16-18	0.049-0.065	1	500
RDM0650A	1.125	3-8-16	16-18	0.049-0.065	1	500

Item No.	Tube Size	Thread Size	Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
RDM0700A	1.250	5/16-18	16-18	0.049-0.065	1	500
RDM0750A	1.250	3/8-16	16-18	0.049-0.065	1	500
RDM0800A	1.250	5/16-18	12-14	0.083-0.109	1	500
RDM0850A	1.375	3/8-16	12-14	0.083-0.109	1	500
RDM0950A	1.375	3/8-16	16-18	0.049-0.065	1	500
RDM1050A	1.500	5/16-18	16-18	0.049-0.065	1	500
RDM1100A	1.500	3/8-16	16-18	0.049-0.065	1	500
RDM1150A	1.500	5/16-18	12-14	0.083-0.109	1	500
RDM1200A	1.500	3/8-16	12-14	0.083-0.109	1	500
RDM2000A	2.000	5/16-18	14-16	0.065-0.083	1	500
RDM2050A	2.000	3/8-16	14-16	0.065-0.083	1	500

RCM Series
Rectangular Metal Threaded Inserts



Specifications:

- Material: HDPE with Zinc-Plated Steel-Threaded Insert
- Color: Black

Features:

- Tube inserts with internal threads to accommodate adjustable leveling mounts and feet
- Ribbed to accommodate multiple gauges

Item No.	Tube Size	Thread Size	Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
RCM0150A	0.75 X 1.50	1/4-20	16-18	0.049-0.065	1	500
RCM0250A	1.00 X 1.50	1/4-20	16-18	0.049-0.065	1	500
RCM0300A	1.00 X 1.50	5/16-18	16-18	0.049-0.065	1	500
RCM0350A	2.00 X 1.00	5/16-18	16-18	0.049-0.065	1	250
RCM0400A	2.00 X 1.00	5/16-18	14-16	0.065-0.083	1	250
RCM0600A	3.00 X 1.50	3/8-16	14-16	0.065-0.083	1	250



RDMM, SQMM, RCMM Series Threaded Insert Glides Metric

Specifications:

- Material: HDPE with Zinc-Plated Steel-Threaded Insert
- Color: Black

Features:

- Tube inserts with internal threads to accommodate adjustable leveling mounts and feet
- Ribbed to accommodate multiple gauges

Round Metal Threaded Inserts



Item No.	Dimensions (mm)			Pack Qty.	Bulk Pack Qty.
	Tube Size	Tube Gauge	Thread		
466242	19	1.0 - 2.0	M6	1	1000
466243	20	1.0 - 2.0	M6	1	1000
466244	20	1.0 - 2.0	M8	1	1000
466245	25	1.0 - 2.0	M6	1	1000
466246	25	1.0 - 2.0	M8	1	1000
466247	30	1.0 - 2.0	M8	1	1000
466248	30	1.0 - 2.0	M10	1	1000
466249	32	1.0 - 2.0	M8	1	1000
466250	32	1.0 - 2.0	M10	1	1000
466251	35	1.0 - 2.0	M8	1	500
466252	35	1.0 - 2.0	M10	1	500
466253	38	1.0 - 2.0	M8	1	500

Item No.	Dimensions (mm)			Pack Qty.	Bulk Pack Qty.
	Tube Size	Tube Gauge	Thread		
466254	38	1.0 - 2.0	M10	1	500
466255	38	1.0 - 2.0	M12	1	500
466256	40	1.0 - 2.0	M8	1	250
466257	40	1.0 - 2.0	M10	1	250
466258	40	1.0 - 2.0	M12	1	500
466262	50	1.0 - 2.0	M8	1	500
466263	50	1.0 - 2.0	M10	1	250
466264	50	1.0 - 2.0	M12	1	500
466265	60	1.0 - 2.0	M8	1	500
466266	60	1.0 - 2.0	M10	1	250
466267	60	1.0 - 2.0	M12	1	500


Square Metal Threaded Inserts



Item No.	Dimensions (mm)			Pack Qty.	Bulk Pack Qty.
	Tube Size	Tube Gauge	Thread		
466268	19	1.0 - 2.0	M6	1	1000
466269	20	1.0 - 2.0	M6	1	1000
466270	20	1.0 - 2.0	M8	1	1000
466271	25	1.0 - 2.0	M6	1	1000
466272	25	1.0 - 2.0	M8	1	1000
466273	30	1.0 - 2.0	M8	1	1000
466274	30	1.0 - 2.0	M10	1	1000
466275	35	1.0 - 2.0	M8	1	500

Item No.	Dimensions (mm)			Pack Qty.	Bulk Pack Qty.
	Tube Size	Tube Gauge	Thread		
466276	35	1.0 - 2.0	M10	1	500
466277	40	1.0 - 2.0	M8	1	500
466278	40	1.0 - 2.0	M10	1	500
466279	40	1.0 - 2.0	M12	1	500
466280	50	1.0 - 2.0	M8	1	250
466281	50	1.0 - 2.0	M10	1	250
466282	50	1.0 - 2.0	M12	1	250

Rectangular Metal Threaded Inserts

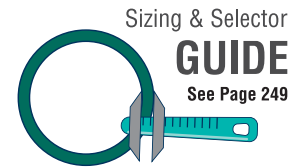

Item No.	Dimensions (mm)			Pack Qty.	Bulk Pack Qty.
	Tube Size	Tube Gauge	Thread		
466283	30 x 20	1.0 - 2.0	M8	1	1000
466284	30 x 20	1.0 - 2.0	M10	1	1000
466285	40 x 20	1.0 - 2.0	M8	1	500
466286	40 x 20	1.0 - 2.0	M10	1	500
466287	40 x 30	1.0 - 2.0	M8	1	500
466288	40 x 30	1.0 - 2.0	M10	1	500
466289	50 x 25	1.0 - 2.0	M8	1	500

Item No.	Dimensions (mm)			Pack Qty.	Bulk Pack Qty.
	Tube Size	Tube Gauge	Thread		
466290	50 x 25	1.0 - 2.0	M10	1	500
466291	30 x 30	1.0 - 2.0	M8	1	500
466292	50 x 30	1.0 - 2.0	M10	1	500
466293	60 x 30	1.0 - 2.0	M8	1	250
466294	60 x 30	1.0 - 2.0	M10	1	250



TAS Series
 Square Threaded All Metal Inserts



Specifications:

- Material: Steel with Zinc plated finish

Features:

- Metal ribs lock onto inside of square tube

Item No.	Fits Tube In	Thread	Fits Gauge	Pack Qty.	Bulk Pack Qty.
TAS240A	1	5/16-18	16-18	1	1000
TAS260A	1-1/4	5/16-18	16-18	1	500
TAS460A	1-1/4	3/8-16	16-18	1	500
TAS270A	1-1/2	5/16-18	16-18	1	500
TAS470A	1-1/2	3/8-16	16-18	1	500

TAR Series
 Round Threaded All Metal Inserts



Specifications:

- Material: Steel with Zinc plated finish

Features:

- Metal ribs lock onto inside of round tube

Item No.	Fits Tube	Thread	Fits Gauge	Pack Qty.	Bulk Pack Qty.
TAR010A	5/8"	1/4-20	16-18	1	1000
TAR020A	3/4"	1/4-20	16-18	1	1000
TAR030A	7/8"	1/4-20	16-18	1	1000
TAR230A	7/8"	5/16-18	16-18	1	1000
TAR040A	1"	1/4-20	16-18	1	1000
TAR240A	1"	5/16-18	16-18	1	1000
TAR260A	1-1/4"	5/16-18	16-18	1	500
TAR460A	1-1/4"	3/8-16	16-18	1	500
TAR270A	1-1/2"	5/16-18	16-18	1	500
TAR470A	1-1/2"	3/8-16	16-18	1	500

STI Series
 Square Plastic Threaded Inserts



Specifications:

- Material: Nylon
- Color: Black or Natural

Features:

- Can be used with either adjustable feet or tilt glides

Item No.	Color	Tube Dia In	Tube Gauge	Thread Size	Pack Qty.	Bulk Pack Qty.
STI1200B	Black	0.750	16	1/4-20	1	5000
STI1215A	Natural	0.875	16	1/4-20	1	1900
STI1215B	Black	0.875	16	1/4-20	1	1900
STI1220A	Natural	1.000	16	1/4-20	1	3000
STI1240A	Natural	1.000	18	1/4-20	1	2700
STI1260A	Natural	1.000	18	5/16-18	1	2700
STI1260B	Black	1.000	18	5/16-18	1	2700
STI1270A	Natural	1.250	16	5/16-18	1	1800

LRT & RTI Series
 Round Plastic Threaded Inserts



Specifications:

- Material: Nylon and HDPE
- Color: Black or Natural

Features:

- Can be used with either adjustable feet or tilt glides
- Tube inserts with internal threads to accommodate adjustable leveling mounts and feet

Item No.	Color	Material	Tube O.D. In	Tube Gauge	Thread Size	Pack Qty.	Bulk Pack Qty.
LRT1100A	Natural	HDPE	0.625	18	1/4"-20	1	4200
LRT1100B	Black	HDPE	0.625	18	1/4"-20	1	4200
RTI1100A	Natural	NYLON	0.750	17	1/4"-20	1	4000
RTI1100B	Black	NYLON	0.750	17	1/4"-20	1	4000
LRT1110A	Natural	HDPE	0.750	18	1/4"-20	1	4000
LRT1120A	Natural	HDPE	0.875	18	1/4"-20	1	3800
LRT1130A	Natural	HDPE	1.000	16	1/4"-20	1	3500
RTI1210A	Natural	NYLON	1.000	16	1/4"-20	1	2000
LRT1140A	Natural	HDPE	1.000	18	1/4"-20	1	3000



RDR Series Round Multi-Gauge Ribbed Tube Inserts



Specifications:

- Material: LDPE
- Surface Finish: Polished or Textured

Features:

- Ideal for aesthetic or light-duty load bearing applications
- Perimeter rib design allows for easy assembly and a secure fit
- Used on a wide range of furniture and metal tubing applications

See page 249 for Sizing and Selector Guide.

Imperial

Black Item No.		White Item No.		Tube OD	Tube Gauge	Pack Qty.	Bulk Pack Qty.
Polished	Textured	Polished	Textured				
RDR111033A	RDR111053A	RDR111073A	—	0.500	16-20	1	2500
RDR111036A	RDR111056A	RDR111076A	—	0.750	14-20	1	1500
—	RDR081012A	—	RDR081012D	0.875	10-12	1	5000
RDR081420D	—	RDR111078A	—	0.875	14-20	1	5000
—	RDR101111A	—	—	1.000	10-12	1	2000
RDR101420D	RDR101420F	—	—	1.000	14-20	1	4000
RDR111040A	RDR111060A	RDR111080A	—	1.000	11-19	1	1000
RDR111042A	RDR111062A	RDR111082A	—	1.125	11-19	1	1000
RDR121014B	—	—	—	1.250	10-14	1	2500
RDR111044A	RDR111064A	RDR111084A	—	1.250	11-19	1	1000
RDR131418A	—	—	—	1.375	14-18	1	1200
RDR111492A	RDR111530A	—	—	1.375	11-19	1	1500
RDR150812A	—	—	—	1.500	8-12	1	1500
—	RDR151012A	—	—	1.500	10-12	1	1500
RDR111046A	RDR111066A	—	—	1.500	11-19	1	1000
RDR111495A	RDR111533A	RDR111571A	RDR111609A	1.625	11-19	1	1000
—	RDR171012A	—	—	1.750	10-12	1	1000
RDR111497A	RDR111535A	—	RDR111611A	1.750	11-19	1	1000
RDR111498A	RDR111536A	—	RDR111612A	1.875	11-19	1	800
RDR201014A	—	—	—	2.000	10-14	1	500
—	RDR201420A	—	—	2.000	14-18	1	500
RDR111049A	RDR111069A	RDR111089A	—	2.000	11-19	1	500
RDR230508B	RDR230508A	—	—	2.375	5-8	1	400
—	RDR231014A	—	—	2.375	10-14	1	400
—	RDR250812A	—	—	2.500	8-12	1	400
RDR111500A	RDR111538A	—	RDR111614A	2.500	11-19	1	250
RDR460674A	RDR465601A	—	—	2.750	8-14	1	500
—	RDR280407A	—	—	2.875	4-7	1	300
—	RDR300812A	—	—	3.000	8-12	1	250
—	RDR301418A	—	—	3.000	14-18	1	250
RDR111052A	RDR111072A	RDR111092A	—	3.000	8-14	1	250
RDR400511A	—	—	—	4.000	5-11	1	150
RDR450711A	—	—	—	4.500	7-11	1	100

Metric

Black Item No.		White Item No.		Tube OD	Tube Gauge	Pack Qty.	Bulk Pack Qty.
Polished	Textured	Textured	Textured				
—	RDR111527A	—	—	10.00	11-19	1	2500
RDR111490A	RDR111528A	RDR111603A	—	12.00	14-20	1	2500
RDR111034A	—	—	—	13.00	14-20	1	2500
—	RDR460660A	—	—	15.00	14-20	1	2500
RDR111035A	RDR111055A	—	—	16.00	14-20	1	5000
RDR111037A	RDR111057A	—	—	20.00	14-20	1	1500
RDR111038A	RDR111058A	—	—	22.00	14-20	1	1500
RDR111043A	RDR111063A	—	—	30.00	11-19	1	1000

Black Item No.		White Item No.		Tube OD	Tube Gauge	Pack Qty.	Bulk Pack Qty.
Polished	Textured	Textured	Textured				
RDR111044A	RDR111064A	RDR111084A	—	32.00	11-19	1	1000
RDR111794A	RDR111795A	—	—	32.00	11-14	1	1000
—	RDR111067A	—	—	40.00	11-19	1	1000
RDR111494A	RDR111532A	—	—	42.00	11-19	1	1000
RDR111496A	—	RDR111610A	—	45.00	11-19	1	1000
—	RDR465600A	—	—	55.00	11-19	1	600
RDR111050A	RDR111070A	—	—	60.00	11-19	1	400
—	RDR465596A	—	—	105.00	7-14	1	75

ACCESS HARDWARE

Pages 120 - 185





RDG Series
Round Load Bearing Glides



Specifications:

- Material: Refer to Chart
- Color: Black

Features:

- Glides are designed for use as a glide or plug style closure
- A reduced diameter step-lead is provided for easy positioning and insertion
- Ideal for moderate to heavy-duty applications



Item No.	Tube O.D. In	Tube Gauge	Wall Thickness In	Material	Pack Qty.	Bulk Pack Qty.
RDG1100A	0.375	19	0.042	ABS	1	9000
RDG1105A	0.500	16	0.065	ABS	1	10000
RDG1110A	0.500	18	0.049	ABS	1	15000
RDG1115A	0.500	20	0.035	ABS	1	15000
RDG1120A	0.500	21	0.032	ABS	1	15000
RDG1125A	0.500	22	0.028	ABS	1	13000
RDG1127A	0.563	19	0.042	HDPE	1	10000
RDG1130A	0.563	20	0.035	ABS	1	13000
RDG1135A	0.563	22	0.028	ABS	1	6500
RDG1140A	0.625	11	0.120	ABS	1	13000
RDG1145A	0.625	12	0.109	ABS	1	13000
RDG1150A	0.625	13	0.095	ABS	1	15000
RDG1155D	0.625	14	0.083	ABS	1	3000
RDG1160A	0.625	15	0.072	ABS	1	7000
RDG1165A	0.625	16	0.065	ABS	1	7000
RDG1168B	0.625	17	0.058	Butyrate	1	10000
RDG1170A	0.625	17	0.058	ABS	1	8000
RDG1175A	0.625	18	0.049	ABS	1	8000
RDG1180A	0.625	20	0.035	ABS	1	5000
RDG1185A	0.625	22	0.028	ABS	1	8000
RDG1190A	0.750	13	0.095	ABS	1	6500
RDG1195C	0.750	14	0.083	ABS	1	1500
RDG1196A	0.750	14	0.083	ABS	1	6500
RDG1200A	0.750	16	0.065	ABS	1	7000
RDG1205A	0.750	17	0.058	ABS	1	8000
RDG1210A	0.750	18	0.049	ABS	1	7000
RDG1215A	0.750	19	0.042	ABS	1	6500
RDG1220A	0.750	20	0.035	ABS	1	6500
RDG1225A	0.750	22	0.028	ABS	1	3000
RDG1228B	0.875	13	0.095	LDPE	1	4500
RDG1230A	0.875	14	0.083	ABS	1	5000
RDG1235A	0.875	16	0.065	ABS	1	5000
RDG1237B	0.875	17	0.058	Nylon	1	5000
RDG1240A	0.875	18	0.049	ABS	1	4500
RDG1245A	0.875	19	0.042	ABS	1	5000
RDG1250A	0.875	20	0.035	ABS	1	4500
RDG1255A	1.000	12	0.109	ABS	1	4000
RDG1264B	1.000	14	0.083	Butyrate	1	4000
RDG1265A	1.000	14	0.083	ABS	1	4000
RDG1270A	1.000	15	0.072	ABS	1	4000
RDG1273B	1.000	16	0.065	Butyrate	1	4000
RDG1274D	1.000	16	0.065	Nylon	1	3500

Item No.	Tube O.D. In	Tube Gauge	Wall Thickness In	Material	Pack Qty.	Bulk Pack Qty.
RDG1275A	1.000	16	0.065	ABS	1	4000
RDG1280A	1.000	17	0.058	ABS	1	3500
RDG1285A	1.000	18	0.049	ABS	1	3500
RDG1290A	1.000	19	0.042	ABS	1	3500
RDG1295C	1.000	20	0.035	ABS	1	3500
RDG1305C	1.125	12	0.109	ABS	1	2500
RDG1310A	1.125	14	0.083	ABS	1	2800
RDG1315A	1.125	16	0.065	ABS	1	2800
RDG1320B	1.125	18	0.049	ABS	1	2800
RDG1325A	1.125	19	0.042	ABS	1	2800
RDG1327B	1.130	20	0.035	LDPE	1	2400
RDG1330A	1.250	11	0.120	ABS	1	2500
RDG1335C	1.250	12	0.109	ABS	1	2500
RDG1340A	1.250	14	0.083	ABS	1	2300
RDG1345A	1.250	16	0.065	ABS	1	2300
RDG1350D	1.250	18	0.049	ABS	1	2300
RDG1355A	1.375	13	0.095	ABS	1	1100
RDG1360A	1.375	14	0.083	ABS	1	2000
RDG1365A	1.375	16	0.065	ABS	1	2000
RDG1370C	1.375	18	0.049	ABS	1	2000
RDG1375A	1.375	20	0.035	ABS	1	1600
RDG1380A	1.500	12	0.109	ABS	1	1200
RDG1385A	1.500	14	0.083	ABS	1	1500
RDG1390A	1.500	16	0.065	ABS	1	1500
RDG1394B	1.500	18	0.049	Butyrate	1	1400
RDG1395D	1.500	18	0.049	ABS	1	1500
RDG1400A	1.500	19	0.042	ABS	1	1500
RDG1405A	1.500	20	0.035	ABS	1	1500
RDG1408B	1.625	16	0.065	Nylon	1	1400
RDG1410A	1.625	18	0.049	ABS	1	1000
RDG1415A	1.750	11	0.120	ABS	1	1100
RDG1420A	1.750	14	0.083	ABS	1	1100
RDG1425A	1.750	16	0.065	ABS	1	1100
RDG1430A	1.750	18	0.049	ABS	1	1100
RDG1435A	1.750	20	0.035	ABS	1	1000
RDG1445A	2.000	11	0.120	ABS	1	850
RDG1455A	2.000	16	0.065	ABS	1	850
RDG1460A	2.000	18	0.049	ABS	1	850
RDG1465A	2.000	20	0.035	ABS	1	1000
RDG1470A	2.500	18	0.049	ABS	1	500
RDG1475A	3.000	13	0.095	ABS	1	500

LRDR Series
Round Ribbed Tube Inserts



Specifications:

- Material: High-Density Polyethylene
- Color: Black with Matte Finish

Features:

- Designed for light load-bearing applications or cosmetic finishing



Item No.	Tube O.D.		Tube Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
	In	mm				
LRDR071620A	0.750	19.05	16-20	0.035-0.065	1	5500
LRDR081420A	0.875	22.22	14-20	0.035-0.083	1	3500
LRDR101420A	1.000	25.40	14-20	0.035-0.083	1	2800

Item No.	Tube O.D.		Tube Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
	In	mm				
LRDR111418A	1.125	28.57	14-18	0.035-0.083	1	2200
LRDR121620A	1.250	31.75	16-20	0.035-0.065	1	1500



RLI Series
Round Low Profile Insert Glides



Specifications:

- Material: Low-Density Polyethylene
- Color: Black

Features:

- Lightweight insert glides present a low-cost option for neatly finishing steel tubes

Item No.	Tube O.D.		Tube Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
	In	mm				
RLI0516A	0.500	12.70	16	0.065	1	10000
RLI0518A	0.500	12.70	18	0.049	1	10000
RLI0520A	0.500	12.70	20	0.035	1	10000
RLI0616A	0.625	15.87	16	0.065	1	10000
RLI0618A	0.625	15.87	18	0.049	1	10000
RLI0716A	0.750	19.05	16	0.065	1	5000
RLI0718A	0.750	19.05	18	0.049	1	5000
RLI0816A	0.875	22.22	16	0.065	1	5000
RLI0818A	0.875	22.22	18	0.049	1	5000
RLI1016A	1.000	25.40	16	0.065	1	5000

Item No.	Tube O.D.		Tube Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
	In	mm				
RLI1018A	1.000	25.40	18	0.049	1	5000
RLI1116A	1.125	28.57	16	0.065	1	4000
RLI1118A	1.125	28.57	18	0.049	1	4000
RLI1216A	1.250	31.75	16	0.065	1	2500
RLI1218A	1.250	31.75	18	0.049	1	2500
RLI1516A	1.500	38.10	16	0.065	1	2000
RLI1518A	1.500	38.10	18	0.049	1	2000
RLI1716A	1.750	44.45	16	0.065	1	1500
RLI1718A	1.750	44.45	18	0.049	1	1500
RLI2018A	2.000	50.80	18	0.049	1	800

RLP Series
Round Metric Low Profile Insert Glides



Specifications:

- Material: Low Density Polyethylene
- Color: Black




Features:

- Low profile design allows for a finishing component with limited space

Item No.	Tube OD		Wall Thickness	Pack Qty.	Bulk Pack Qty.
	mm	Tube Gauge			
466562	10	16-20	0.80 - 1.50	1	5000
466563	12	14-16	1.50 - 2.00	1	5000
466564	14	14-16	1.50 - 2.00	1	5000
RDR466565A	15	16-20	0.80 - 2.00	1	2000
466566	16	16-20	0.80 - 2.00	1	2500
466567	18	16-20	0.80 - 2.00	1	2000
466568	19	16-20	0.80 - 2.00	1	2000
466569	20	13-20	0.80 - 2.50	1	2000
466570	22	13-20	1.00 - 2.50	1	2000
466571	24	13-20	1.00 - 2.50	1	2000
466572	25	13-20	1.00 - 2.50	1	3500

Item No.	Tube OD		Wall Thickness	Pack Qty.	Bulk Pack Qty.
	mm	Tube Gauge			
466573	28	13-20	0.80 - 2.50	1	3000
466574	30	13-20	0.80 - 2.50	1	2500
466575	32	13-20	0.80 - 2.50	1	2250
466576	35	11-19	1.00 - 3.00	1	1750
466577	38	11-19	1.00 - 3.00	1	1500
466578	40	11-19	1.00 - 3.00	1	1500
460789	42	13-20	0.80 - 2.50	1	1250
466579	45	11-19	1.00 - 3.00	1	1000
466580	50	13-20	1.00 - 2.50	1	800
466581	55	11-19	1.00 - 3.00	1	700
466582	60	11-16	1.50 - 3.00	1	500

GSB & GFB Series
Round Ribbed Inserts
Felt and Steel Based

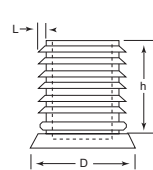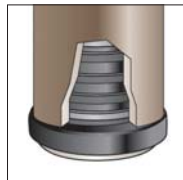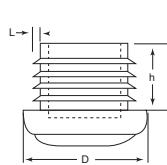

Specifications:

- Insert Material: Nylon
- Base Material: See Chart
- Color: Black

Material	Felt	Steel
Surface Uses	Wood and other soft surfaces	Smooth Surfaces

GFB Series

GSB Series

Item No.	D	h		L= Fits		Pack Qty.	Bulk Pack Qty.			
		In	mm	Wall (In)	Gauge		Felt Based	Steel Based		
GFB465535A	-	0.748	19.00	0.748	19.00	0.060-0.090	14-17	1	1750	-
GFB465536A	GSB465537A	0.787	20.00	0.748	19.00	0.060-0.090	14-17	1	1750	2000
GFB465538A	GSB465539A	0.866	22.00	0.748	19.00	0.060-0.090	14-17	1	2500	1750
GFB465540A	GSB465541A	0.984	25.00	0.748	19.00	0.060-0.090	14-17	1	2250	1250
GFB465542A	GSB465543A	1.102	28.00	0.748	19.00	0.060-0.090	14-17	1	1500	1000
GFB465544A	GSB465545A	1.181	30.00	0.748	19.00	0.060-0.090	14-17	1	1250	900
GFB465546A	GSB465547A	1.260	32.00	0.748	19.00	0.060-0.090	14-17	1	1250	800



TSNB, TSFB & TSSB SERIES
Round Ribbed Inserts
Nylon, Felt & Steel Based




Specifications:

- Insert Material: Nylon
- Base Material: See Chart
- Color: Black

Material	Nylon	Felt	Steel
Surface Uses	Hard Surfaces	Wood and other soft surfaces	Smooth Surfaces

Item No.		D		d		h		L= Fits		Bulk Pack Qty.				
TSNB Series Nylon Based	TSFB Series Felt Based	TSSB Series Steel Based	In	mm	In	mm	In	mm	Wall (In)	Gauge	Pack Qty.	Nylon Based	Felt Based	Steel Based
TSNB465550A	TSFB465548A	TSSB465549A	0.984	25.00	0.748	19.00	0.965	24.50	0.060-0.090	14-17	1	1250	1500	1250
TSNB465553A	TSFB465551A	TSSB465552A	0.984	25.00	0.787	20.00	0.965	24.50	0.060-0.090	14-17	1	1000	1250	1250
TSNB465556A	TSFB465554A	TSSB465555A	0.984	25.00	0.866	22.00	0.965	24.50	0.060-0.090	14-17	1	1000	1000	1000
TSNB465559A	TSFB465557A	TSSB465558A	0.984	25.00	0.984	25.00	0.965	24.50	0.060-0.090	14-17	1	800	800	1000
TSNB465562A	TSFB465560A	TSSB465561A	0.984	25.00	1.102	28.00	0.965	24.50	0.060-0.090	14-17	1	800	800	1250
TSNB465565A	TSFB465563A	TSSB465564A	1.181	30.00	0.748	19.00	0.965	24.50	0.060-0.090	14-17	1	1000	625	625
TSNB465568A	TSFB465566A	TSSB465567A	1.181	30.00	0.787	20.00	0.965	24.50	0.060-0.090	14-17	1	1000	500	500
TSNB465571A	TSFB465570A	TSSB465569A	1.181	30.00	0.866	22.00	0.965	24.50	0.060-0.090	14-17	1	800	400	400
TSNB465574A	TSFB465573A	TSSB465572A	1.181	30.00	0.984	25.00	0.965	24.50	0.060-0.090	14-17	1	800	400	400
TSNB465577A	TSFB465575A	TSSB465576A	1.181	30.00	1.102	28.00	0.965	24.50	0.060-0.090	14-17	1	800	350	375

RDP Series
Round Ribbed Tube Inserts
Chrome Finish

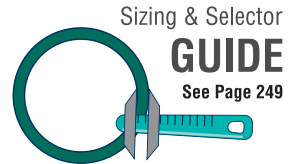


Specifications:


- Material: Low-Density Polyethylene
- Color: Black with High-Polished Metal-Finish Shell

Features:

- Polished metallic finish provides enhanced aesthetic appearance
- Horizontal ribbing allows for built-in flexibility to fit multiple tube gauges

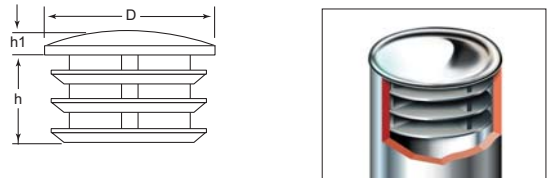

Item No.	D		h		h1		Fits		Pack Qty.	Bulk Pack Qty.
	In	mm	In	mm	In	mm	Gauge (In)	mm		
RDP465335A	0.512	13.00	0.315	8.00	0.079	2.00	14-19 (.040-.080)	1.0-2.0	1	1000
RDP463586A	0.630	16.00	0.394	10.00	0.079	2.00	14-19 (.040-.080)	1.0-2.0	1	2000
RDP465333A	0.709	18.00	0.394	10.00	0.079	2.00	14-19 (.040-.080)	1.0-2.0	1	2000
RDP465336A	0.750	19.05	0.394	10.00	0.079	2.00	14-19 (.040-.080)	1.0-2.0	1	1000
RDP465338A	0.787	20.00	0.394	10.00	0.118	3.00	14-19 (.040-.080)	1.0-2.0	1	3000
RDP465334A	0.866	22.00	0.433	11.00	0.118	3.00	14-19 (.040-.080)	1.0-2.0	1	3000
RDP462994A	0.984	25.00	0.591	15.00	0.118	3.00	14-19 (.040-.080)	1.0-2.0	1	2000
RDP463587A	1.102	28.00	0.591	15.00	0.118	3.00	14-19 (.040-.080)	1.0-2.0	1	500
RDP463020A	1.181	30.00	0.630	16.00	0.118	3.00	14-19 (.040-.080)	1.0-2.0	1	500
RDP463588A	1.260	32.00	0.630	16.00	0.118	3.00	14-19 (.040-.080)	1.0-2.0	1	250
RDP463021A	1.378	35.00	0.630	16.00	0.118	3.00	14-19 (.040-.080)	1.0-2.0	1	500
RDP465337A	1.496	38.00	0.630	16.00	0.118	3.00	14-19 (.040-.080)	1.0-2.0	1	250
RDP463022A	1.575	40.00	0.630	16.00	0.118	3.00	14-19 (.040-.080)	1.0-2.0	1	250
RDP465339A	1.772	45.00	0.630	16.00	0.118	3.00	14-19 (.040-.080)	1.0-2.0	1	250
RDP463023A	1.969	50.00	0.472	12.00	0.118	3.00	16-17 (.065-.058)	1.50	1	200
RDP465332A	2.362	60.00	0.472	12.00	0.118	3.00	16-17 (.065-.058)	1.50	1	200

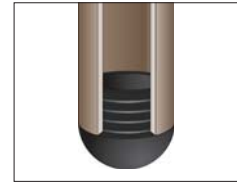**DFRD Series**
Round Domed Tube Inserts


Specifications:

- Material: Low-Density Polyethylene
- Color: Black

Features:

- Can accommodate any degree of leg angle, while the horizontal ribbed design has built-in flexibility to fit multiple tube gauge sizes

Item No.	Tube O.D.		Tube Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
	In	mm				
DFRD111522A	0.875	22.22	14-20	0.035-0.083	1	2000
DFRD121620A	1.250	31.75	14-18	0.049-0.083	1	2000

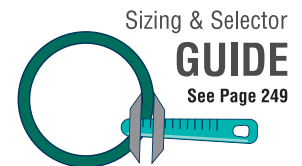
BI & LBI Series
Round Domed Tube Glides

Specifications:

- Material: Refer to Chart
- Color: Black or Natural

Features:

- Provides a neat finish for steel tubing

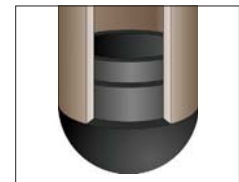

Item No.	Material	Color	Tube O.D.		Tube Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
			In	mm				
BH1000A	ABS	Black	0.625	15.88	18	0.049	1	10000
BH1100A	ABS	Black	0.750	19.05	15	0.072	1	3000
LBH1130A	LDPE	Black	0.750	19.05	16	0.065	1	5500
LBH1132A	LDPE	Black	0.750	19.05	16	0.065	1	5500
BH1110A	ABS	Black	0.875	22.23	14	0.083	1	3500
LBH1140A	LDPE	Black	0.875	22.23	14	0.083	1	3500
BH1120A	ABS	Black	0.875	22.23	16	0.065	1	3500
BH1130A	ABS	Black	0.875	22.23	20	0.035	1	4000
BH1140A	ABS	Black	1.000	25.40	14	0.083	1	2700
BH1150A	ABS	Black	1.000	25.40	16	0.065	1	2500
LBH1180A	LDPE	Black	1.000	25.40	16	0.065	1	3000
BH1160A	ABS	Black	1.000	25.40	18	0.049	1	2500

Item No.	Material	Color	Tube O.D.		Tube Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
			In	mm				
LBH1190A	LDPE	Black	1.000	25.40	18	0.049	1	3100
BH1170A	ABS	Black	1.000	25.40	20	0.035	1	2600
BH1180A	ABS	Black	1.125	28.58	12	0.109	1	2000
BH1200A	ABS	Black	1.125	28.58	16	0.065	1	2500
BH1210A	ABS	Black	1.125	28.58	18	0.049	1	1600
BH1220A	ABS	Black	1.228	31.19	14	0.083	1	1600
BH1230A	ABS	Black	1.250	31.75	16	0.065	1	1500
BH1240A	ABS	Black	1.375	34.93	14	0.083	1	1200
BH1250A	ABS	Black	1.500	38.10	11	0.120	1	1000
BH1260A*	ABS	Black	1.500	38.10	14	0.083	1	1000
BH1270A	ABS	Black	1.500	38.10	16	0.065	1	1000

* This part has a textured (not polished) finish

RAG Series
Round Angled Tube Inserts

Specifications:

- Material: Nylon
- Color: Black or Natural

Features:

- Ideal for applications with fixed leg angles
- Round angle insert glides fit flush with tubing outer dimensions for a clean, finished look
- Ideal for load bearing applications



Item No.	Material	Color	Tube O.D.		Tube Gauge	Wall Thickness In	Degree	Pack Qty.	Bulk Pack Qty.
			In	mm					
RAG1220A	—	Natural	0.750	19.05	16	0.065	25.5°	1	2500
RAG1240A	—	Natural	0.875	22.23	16	0.065	19°	1	3500
RAG1260A	—	Natural	0.875	22.23	17	0.058	19°	1	3500
RAG1270A	—	Natural	1.000	25.40	16	0.065	12°	1	3200
—	—	Natural	1.000	25.40	16	0.065	19°	1	3000
RAG1310A	—	Natural	1.000	25.40	18	0.049	12°	1	3000

Item No.	Material	Color	Tube O.D.		Tube Gauge	Wall Thickness In	Degree	Pack Qty.	Bulk Pack Qty.
			In	mm					
—	—	Natural	1.000	25.40	18	0.049	19°	1	3000
RAG1325A	—	Natural	1.125	28.58	16	0.065	15°	1	2000
RAG1340A	—	Natural	1.250	31.75	16	0.065	15°	1	1800
RAG1350A	—	Natural	1.250	31.75	17	0.058	7°	1	900
RAG1360A	—	Natural	1.250	31.75	18	0.049	15°	1	1200
RAG1375A	—	Natural	1.500	38.10	16	0.065	19°	1	900



HLD Series
High Line Domed Ferrule Caps



Specifications:

- Material: Elastomeric Polyethylene
- Color: Black

Features:

- High-line domed caps are tall and durable
- Ideal for non-skid applications. (These caps have a thinner wall section resulting in ease of installation)

Item No.		Tube O.D.		Pack Qty.	Bulk Pack Qty.
Black	White	In	mm		
HLD0750A	HLD0750C	0.750	19.05	1	1100
HLD0875A	HLD0875C	0.875	22.22	1	1100
HLD1000A	HLD1000C	1.000	25.40	1	2000

HDC Series
Heavy Duty Ferrule Caps



Specifications:


- Material: Low-Density Polyethylene
- Color: Black

Features:

- Style A – Low-silhouette cap for general applications (1/2" height)
- Style B – High-line cap for heavy-duty applications (1" height)
- Style C – Heavy-duty caps, designed for institutional applications, incorporate a thick internal ledge to resist cut-thru by sharp tubing ends (1" height)

Item No.	To Fit Tube Size		Style	Pack Qty.	Bulk Pack Qty.
	In	mm			
HDC0375A	0.375	9.53	B	1	10000
HDC0750A	0.750	19.05	A	1	6500
HDC0875A	0.875	22.23	B	1	3000
HDC1125A	1.125	28.58	C	1	650
HDC1250A	1.250	31.75	A	1	1800
HDC1500A	1.500	38.10	A	1	1300

FRD Series
Round Ferrule Caps

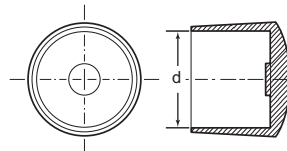

Specifications:

- Material: Low-Density Polyethylene

Features:

- Provides a neat finish to products manufactured from tubular steel

Item No.	d	Pack Qty.	Bulk Pack Qty.
FRD0437A	0.437	1	10000
FRD0500A	0.500	1	10000
FRD0625A	0.625	1	5000
FRD0750A	0.750	1	4000
FRD0875A	0.875	1	2500
FRD1000A	1.000	1	1500

Item No.	d	Pack Qty.	Bulk Pack Qty.
FRD1125A	1.125	1	1000
FRD1250A	1.250	1	1000
FRD1500A	1.500	1	500
FRD1750A	1.750	1	500
FRD2000A	2.000	1	300
FRD3000A	3.000	1	150




END CAPS

Pages 988 - 989



FTP Series
Round Tapered Ferrule Caps

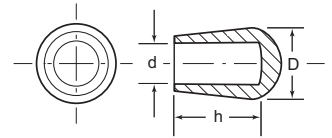

Specifications:


- Material: PVC or LDPE
- Color: Black

Features:

- Tapered ferrules are often used as a safety cap on protruding steel rods or bars

Item No.	d In	h In	D In	Material	Pack Qty.	Bulk Pack Qty.
FTP0187A	0.187	0.468	0.406	PVC	1	10000
FTP0250A	0.250	0.468	0.406	PVC	1	10000
FTP0312A	0.312	0.562	0.500	PVC	1	10000
FTP0312LPA	0.312	0.906	0.516	LDPE	1	5000
FTP0375A	0.375	0.625	0.594	PVC	1	5000
FTP0500LPA	0.500	0.906	0.735	LDPE	1	4000

DM Series
Round Vinyl End Caps

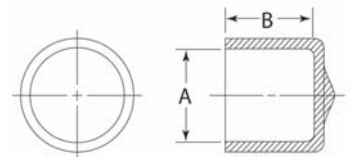

Specifications:


- Material: Vinyl (PVC)
- Color: White
- Temperature Range: Up to 350°F (176°C)

Features:

- Designed to fit standard tube dimension
- Glossy Finish for attractive finish

Item No.	Shape	A In	B in	Pack Qty.	Bulk Pack Qty.
DM0750-1H	Round	3/4	1	1	2500
DM0875-1G	Round	7/8	1	1	2500
DM1000-1C	Round	1	1	1	2000

RSC Series
Round End Caps

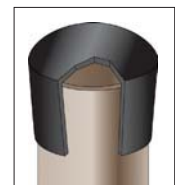

Specifications:

- Material: Low-Density Polyethylene (RSC)
- Elastomeric Polyethylene (LLD)
- Color: Black

Features:

- Slenda™ cap is an industry standard for light-duty applications
- An integrated step lead permits fast positioning and quick assembly for an economical and attractive way of finishing the end of a rod or tube
- The LLD caps have a thick rounded base for long wear and use on a wide range of leg angles

Item No.	To Fit Tube Size		Pack Qty.	Bulk Pack Qty.
	In			
RSC0375A	0.375	1	12000	
RSC0500A	0.500	1	7000	
RSC0625A	0.625	1	5000	
RSC0750A	0.750	1	3000	
RSC0875A	0.875	1	3000	

Item No.	To Fit Tube Size		Pack Qty.	Bulk Pack Qty.
	In			
RSC1000A	1.000	1	2500	
LLD1000A	1.000	1	1500	
RSC1125A	1.125	1	1600	
RSC1250A	1.250	1	1800	

BC Series
Round Ball Caps



Specifications:

- Material: Low-Density Polyethylene
- Color: Black

Features:

- Ball caps are a popular style of a heavy-duty glide in which the ball will greatly enhance the leg design of a given application, as well as accommodate a wide variety of leg angles
- Ball caps may also be used as a decorative top or finial and maintain an excellent press fit

Item No.	Tube O.D.		Ball O.D.		Pack Qty.	Bulk Pack Qty.
	In	mm	In	mm		
BC010A	0.312	7.92	0.625	15.87	1	10000
BC015A	0.500	12.70	0.875	22.22	1	4300
BC020A	0.625	15.87	1.000	25.40	1	3000



TR Series
Anti-Rattle Tubing Reducers



Specifications:

- Material: LDPE
- Color: Gray or Black


Features:

- Ideal coupling for different sized telescope tubes

Item No.	Color	To Fit Tube	Coupling I.D.		Reducer I.D.		Pack Qty.	Bulk Pack Qty.
			In	mm	In	mm		
TR1000A	Gray	11/16 X 3/4	0.745	18.92	0.680	17.27	1	4000
TR1000B	Black	11/16 X 3/4	0.745	18.92	0.680	17.27	1	4000
TR1050B	Gray	3/4 X 7/8	0.865	21.97	0.740	18.80	1	2500
TR1050C	Black	3/4 X 7/8	0.865	21.97	0.740	18.80	1	2500
TR1099C	Gray	1 X 7/8	0.985	25.02	0.887	22.53	1	1500
TR1099B	Black	1 X 7/8	0.985	25.02	0.887	22.53	1	1500

Item No.	Color	To Fit Tube	Coupling I.D.		Reducer I.D.		Pack Qty.	Bulk Pack Qty.
			In	mm	In	mm		
TR1100C	Gray	1 X 7/8	0.995	25.27	0.873	22.17	1	1500
TR1100B	Black	1 X 7/8	0.995	25.27	0.873	22.17	1	1500
TR1200A	Gray	1-1/8 X 1	1.115	28.32	1.005	25.53	1	2100
TR1200B	Black	1-1/8 X 1	1.115	28.32	1.005	25.53	1	2100
TR1300A	Gray	1-3/4 X 1-1/2	1.738	44.15	1.490	37.85	1	1100
TR1300B	Black	1-3/4 X 1-1/2	1.738	44.15	1.490	37.85	1	1100

RTR Series
Tube Connectors

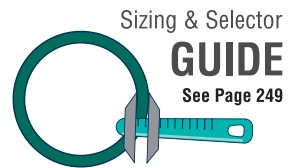


Specifications:

- Material: Nylon
- Color: Natural

Features:

- Rigidly joins metal or wood tubing together
- Eliminates the cost of welding
- Designed for easy assembly

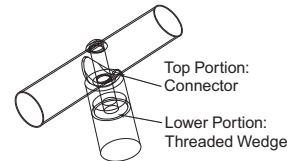


Tube Connector

Item No.	Tube Size In	Tube Gauge	Matching Part	Pack Qty.	Bulk Pack Qty.
RTR1000A	0.750	18	RTR1001A	1	2300
RTR1100A	1.000	16	RTR1101A	1	2300
RTR1200A	1.000	18	RTR1201A	1	2300
RTR1300A	1.000	20	—	1	2200

Threaded Bushing

Item No.	Thread	Matching Part	Pack Qty.	Bulk Pack Qty.
RTR1001A	1/4-20	RTR1000A	1	2300
RTR1101A	1/4-20	RTR1100A	1	2300
RTR1201A	1/4-20	RTR1200A	1	6000

 DMHC Series
Round Vinyl Hanger Caps



Specifications:

- Material: Vinyl (PVC)
- Color: Black
- Temperature Range: Up to 350°F (176°C)
- Maximum Length: 5-1/2 inches

Features:

- Designed to allow your tube application to hang from a peg hook or similar fixture
- Flexible material can stretch onto slightly larger diameters for a snug fit without tearing, splitting or shredding
- The glossy and attractive finish makes this part ideal for use as a decorative end cap

B = 1/2"		B = 1"		B = 1-1/2"		A		Pack Qty.	Bulk Pack Qty.	
In	mm	In	mm	In	mm	1/2"	1"		1-1/2"	
DMHC1000-1/2A	DMHC1000-1A	DMHC1000-1-1/2A	1.000	25.40	1	700	400	500		
DMHC1250-1/2A	DMHC1250-1A	DMHC1250-1-1/2A	1.250	31.75	1	700	400	500		
DMHC1500-1/2A	DMHC1500-1A	DMHC1500-1-1/2A	1.500	38.10	1	400	400	500		



SQR Series Square Multi-Gauge Ribbed Tube Inserts

Specifications:

- Material: LDPE
- Surface Finish: Polished and Textured

Features:

- Ideal for aesthetic or light-duty load bearing applications
- Perimeter rib design allows for easy assembly and a secure fit
- Used on a wide range of furniture and metal tubing applications



Imperial

Black Item No.		White Item No.		Tube OD In	Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
Polished	Textured	Polished	Textured					
SQR051620A	—	—	—	0.500	16-20	0.035-0.065	1	10000
SQR111193A	SQR111211A	SQR111229A	—	0.500	14-20	0.035-0.083	1	2500
SQR061620C	—	—	—	0.625	16-20	0.035-0.065	1	5000
SQR111195A	SQR111213A	—	—	0.625	12-20	0.035-0.109	1	2500
SQR111196A	SQR111214A	SQR111232A	—	0.750	12-20	0.035-0.109	1	2500
SQR071620C	—	—	—	0.750	16-20	0.035-0.065	1	5000
SQR081618A	—	—	—	0.875	16-18	0.049-0.065	1	4000
SQR101014A	—	SQR101014D	—	1.000	10-14	0.083-0.134	1	2000
SQR101420D	—	—	—	1.000	14-20	0.035-0.083	1	2500
SQR111200A	SQR111218A	SQR111235A	—	1.000	11-19	0.042-0.120	1	2500
SQR111620A	—	—	—	1.125	16-20	0.035-0.065	1	2000
—	—	SQR199150A	—	1.125	14-20	0.035-0.083	1	2000
SQR121014A	—	—	—	1.250	10-14	0.083-0.134	1	2000
SQR121420A	—	—	—	1.250	14-20	0.035-0.083	1	2000
—	—	—	SQR111616A	1.250	11-19	0.042-0.120	1	1500
SQR131016A	—	—	—	1.375	10-16	0.065-0.134	1	900
SQR111202A	SQR111220A	SQR111238A	—	1.375	11-19	0.042-0.120	1	1500
SQR151014A	—	—	—	1.500	10-12	0.083-0.109	1	1000
SQR111503A	SQR111541A	SQR111617A	—	1.500	12-19	0.042-0.120	1	1000
SQR151418A	—	—	—	1.500	14-18	0.049-0.083	1	1000
SQR171014A	—	SQR171014C	—	1.750	10-14	0.083-0.134	1	500
SQR171418A	—	SQR171418C	—	1.750	14-18	0.049-0.083	1	500
—	SQR200508A	—	—	2.000	5-8	0.164-0.209	1	500
SQR201014A	—	—	—	2.000	10-14	0.083-0.134	1	350
SQR201418A	—	—	—	2.000	14-18	0.049-0.083	1	500
SQR111206A	SQR111224A	SQR111242A	—	2.000	11-19	0.042-0.120	1	500
—	SQR251014A	—	—	2.500	10-14	0.083-0.134	1	250
SQR111504A	SQR111542A	—	—	2.500	11-19	0.042-0.120	1	250
—	SQR300508A	—	—	3.000	5-8	0.164-0.209	1	200
—	SQR301014A	—	—	3.000	10-14	0.083-0.134	1	200
SQR111507A	SQR111545A	—	SQR111621A	3.000	8-14	0.083-0.164	1	200
SQR3511B	—	—	—	3.500	8-11	0.120-0.164	1	70
—	SQR400711B	—	—	4.000	7-11	0.120-0.179	1	70
—	SQR500711A	—	—	5.000	7-11	0.120-0.179	1	48
—	SQR60188A	—	—	6.000	10-14	0.083-0.134	1	26

Metric

Black Item No.		Tube OD In	Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
Polished	Textured					
SQR111197A	SQR111215A	20.00	12-20	0.035-0.109	1	2500
SQR111198A	SQR111216A	22.00	12-20	0.035-0.109	1	2500
SQR111199A	SQR111217A	25.00	12-20	0.035-0.109	1	2500
SQR111502A	SQR111540A	32.00	11-19	0.042-0.120	1	1500
SQR111203A	SQR111221A	40.00	11-19	0.042-0.120	1	500
SQR111204A	SQR111222A	45.00	11-19	0.042-0.120	1	500

Black Item No.		Tube OD In	Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
Polished	Textured					
SQR111205A	SQR111223A	50.00	11-19	0.042-0.120	1	500
SQR111207A	SQR111225A	60.00	11-19	0.042-0.120	1	250
SQR111810A	SQR111811A	60.00	9-14	0.083-0.149	1	250
SQR111506A	SQR111544A	75.00	8-14	0.083-0.164	1	200
SQR111209A	SQR111227A	80.00	8-14	0.083-0.164	1	150
SQR111210A	SQR111228A	100.00	8-14	0.083-0.164	1	100

SIG Series Square Load Bearing Glides

Specifications:

- Material: ABS or Butyrate
- Color: Black or Clear

Features:

- Suitable for light and heavy-duty applications
- Step lead provides easy installation
- Press fit assures a secure hold in tubing



See page 249 for Sizing and Selector Guide.

Item No.	Tube Size In	Tube Gauge	Material	Wall Thickness In	Color	Pack Qty.	Bulk Pack Qty.
SIG1100A	0.375	16	ABS	0.065	Black	1	5000
SIG1105A	0.375	19	ABS	0.042	Black	1	5000
SIG1108A	0.500	14	ABS	0.083	Black	1	4000
SIG1110A	0.500	16	ABS	0.065	Black	1	15000
SIG1115A	0.500	18	ABS	0.049	Black	1	15000
SIG1120A	0.625	16	ABS	0.065	Black	1	8000
SIG1125A	0.625	17	ABS	0.058	Black	1	8000
SIG1130A	0.625	18	ABS	0.049	Black	1	8000
SIG1135A	0.625	20	ABS	0.035	Black	1	8000
SIG1140A	0.695	18	ABS	0.049	Black	1	5000
SIG1145A	0.715	18	ABS	0.049	Black	1	5000
SIG1150A	0.725	11	ABS	0.120	Black	1	5000

Item No.	Tube Size In	Tube Gauge	Material	Wall Thickness In	Color	Pack Qty.	Bulk Pack Qty.
SIG1155A	0.725	16	ABS	0.065	Black	1	5000
SIG1160A	0.750	11	ABS	0.120	Black	1	5800
SIG1165A	0.750	13	ABS	0.095	Black	1	6000
SIG1170A	0.750	15	ABS	0.072	Black	1	4000
SIG1175A	0.750	16	ABS	0.065	Black	1	5500
SIG1180A	0.750	18	ABS	0.049	Black	1	5500
SIG1185A	0.750	19	ABS	0.042	Black	1	5500
SIG1190A	0.750	20	ABS	0.035	Black	1	5500
SIG1200A	0.812	14	ABS	0.083	Black	1	4500
SIG1205A	0.812	16	ABS	0.065	Black	1	4500
SIG1210A	0.812	18	ABS	0.049	Black	1	4500
SIG1215A	0.875	11	ABS	0.120	Black	1	5000




SIG Series
 Square Load Bearing Glides (continued)



Item No.	Tube Size		Material	Wall Thickness In	Color	Pack Qty.	Bulk Pack Qty.
	In	Gauge					
SIG1220C	0.875	16	ABS	0.065	Black	1	4000
SIG1225A	0.875	18	ABS	0.049	Black	1	4000
SIG1235A	1.000	11	ABS	0.120	Black	1	3200
SIG1240A	1.000	14	ABS	0.083	Black	1	3000
SIG1244C	1.000	16	BUTYRATE	0.065	Clear	1	2800
SIG1245A	1.000	16	ABS	0.065	Black	1	2800
SIG1250A	1.000	17	ABS	0.058	Black	1	2800
SIG1255A	1.000	18	ABS	0.049	Black	1	2800
SIG1260A	1.000	20	ABS	0.035	Black	1	3200
SIG1265A	1.000	22	ABS	0.035	Black	1	3200
SIG1270A	1.125	16	ABS	0.065	Black	1	2200
SIG1275A	1.125	18	ABS	0.049	Black	1	2200
SIG1280A	1.250	11	ABS	0.120	Black	1	2200
SIG1285A	1.250	12	ABS	0.109	Black	1	2000
SIG1290A	1.250	14	ABS	0.083	Black	1	1500
SIG1295A	1.250	16	ABS	0.065	Black	1	1700
SIG1300A	1.250	18	ABS	0.049	Black	1	1800
SIG1302B	1.255	19	BUTYRATE	0.042	Clear	1	1500

Item No.	Tube Size		Material	Wall Thickness In	Color	Pack Qty.	Bulk Pack Qty.
	In	Gauge					
SIG1305A	1.500	10	ABS	0.134	Black	1	1800
SIG1310A	1.500	11	ABS	0.120	Black	1	1200
SIG1315A	1.500	12	ABS	0.109	Black	1	1200
SIG1320C	1.500	14	ABS	0.083	Black	1	1300
SIG1325A	1.500	16	ABS	0.065	Black	1	1100
SIG1330A	1.500	18	ABS	0.049	Black	1	1200
SIG1335A	1.500	20	ABS	0.035	Black	1	1200
SIG1340A	1.750	11	ABS	0.120	Black	1	1000
SIG1345A	1.750	14	ABS	0.083	Black	1	1000
SIG1350A	1.750	16	ABS	0.065	Black	1	900
SIG1353C	2.000	11	ABS	0.120	Black	1	1000
SIG1365A	2.000	12	ABS	0.109	Black	1	1000
SIG1370A	2.000	14	ABS	0.083	Black	1	1000
SIG1375A	2.000	16	ABS	0.065	Black	1	1000
SIG1380A	2.000	18	ABS	0.049	Black	1	1000
SIG1385A	2.500	11	ABS	0.120	Black	1	500
SIG1390A	3.000	11	ABS	0.120	Black	1	500

SQS Series
 Square Tube Insert Glides

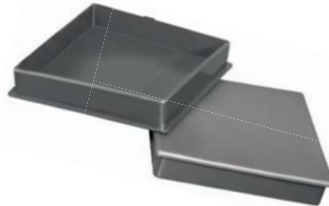

Specifications:

- Material: Low-Density Polyethylene
- Color: Black

Features:

- Ideal for general purpose tube-fitting applications

Item No.	Tube Size		Tube Gauge	Pack Qty.	Bulk Pack Qty.
	In	mm			
SQS5006A	5.000	127.00	6	1	50
SQS6006A	6.000	152.40	6	1	40



LSQR Series
 Square Ribbed Tube Inserts




Specifications:

- Material: High-Density Polyethylene
- Color: Black with Textured Finish

Features:

- Not recommended for load-bearing applications

Item No.	Tube Size		Tube Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
	In	mm				
LSQR061620A	0.625	15.87	16-20	0.035-0.065	1	6000
LSQR071620A	0.750	19.05	16-20	0.035-0.065	1	4000
LSQR101420A	1.000	25.40	14-20	0.035-0.083	1	2000
LSQR111620A	1.125	28.32	16-20	0.035-0.065	1	3000
LSQR121420A	1.250	31.75	14-20	0.035-0.083	1	1300

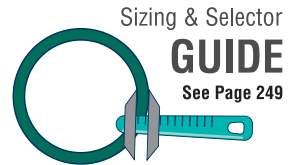

SQC Series
 Square Heavy Duty End Caps



Specifications:

- Material: Low-Density Polyethylene or ABS*
- Color: Black

Features:

- End cap style design fits most popular sizes of square tubular steel

Item No.	Tube Size		Pack Qty.	Bulk Pack Qty.
	In	mm		
SQC0500A	0.500	12.70	1	5000
SQC1000A*	1.000	25.40	1	1700
SQC1250A	1.250	31.75	1	1200
SQC3000A	3.000	76.20	1	100





SQUARE INSERT GLIDES

Buy One or Buy Bulk & SAVE

 
SQP Series Square Ribbed Tube Inserts Chrome Finish

Specifications:

- Material: Low-Density Polyethylene
- Color: Black with High-Polished Metal-Finish Shell

Features:

- Polished metallic finish provides enhanced aesthetic appearance
- Horizontal ribbing allows for built-in flexibility to fit multiple tube gauges



Item No.	D		d		h		Gauge (In)		Fits		Pack Qty.	Bulk Pack Qty.
	In	mm	In	mm	In	mm	In	mm	In	mm		
SQP465341A	0.625	15.88	0.079	2.00	0.354	9.00	14-19	(.040-.080)	1.0 - 2.0		1	1000
SQP460959A	0.709	18.00	0.079	2.00	0.354	9.00	14-19	(.040-.080)	1.0 - 2.0		1	1000
SQP465340A	0.750	19.05	0.079	2.00	0.394	10.00	14-19	(.040-.080)	1.0 - 2.0		1	1000
SQP465343A	1.000	25.40	0.079	2.00	0.394	10.00	14-19	(.040-.080)	1.0 - 2.0		1	1000
SQP465342A	1.181	30.00	0.118	3.00	0.394	10.00	14-19	(.040-.080)	1.0 - 2.0		1	1000
SQP460964A	1.375	35.00	0.118	3.00	0.472	12.00	14-19	(.040-.080)	1.0 - 2.0		1	1000
SQP465344A	1.575	40.00	0.118	3.00	0.472	12.00	14-19	(.040-.080)	1.0 - 2.0		1	1000


AFSQ Series Square Angled Tube Inserts

Specifications:

- Material: Low-Density Polyethylene
- Color: Black

Features:

- These angled feet are ideal for stacking chairs, children's play equipment and step ladders

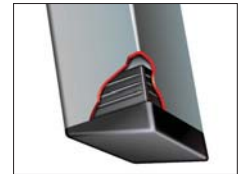

Item No.	Tube Size		Tube Gauge	Wall Thickness In	Degree	Pack Qty.	Bulk Pack Qty.
	In	mm					
AFSQ07161805A*	0.750	19.05	16-18	0.049-0.065	5°	1	2500
AFSQ07161825A*	0.750	19.05	16-18	0.049-0.065	25°	1	2500
AFSQ08161805A	0.875	22.22	16-18	0.049-0.065	5°	1	2500
AFSQ08161825A*	0.875	22.22	16-18	0.049-0.065	25°	1	2500
AFSQ10162015A	1.000	25.40	16-20	0.035-0.065	15°	1	1000

* Has a built-in bumper

SRG Series Square Domed Tube Glides

Specifications:

- Material: ABS
- Color: Black

Features:

- Ideal for applications with variable leg angles
- Square rocker glides fit flush with tubing outer dimensions for a clean, finished look



Item No.	Tube Size		Wall Thickness In	Pack Qty.	Bulk Pack Qty.
	In	Tube Gauge			
SRG1010A	0.750	16	0.065	1	4000
SRG1020A	0.750	18	0.049	1	4000
SRG1030A	0.813	16	0.065	1	3000
SRG1115A	0.813	17	0.058	1	4000
SRG1120A	0.813	18	0.049	1	700
SRG1045A	0.875	16	0.065	1	3000
SRG1055A	0.875	18	0.049	1	2700

Item No.	Tube Size		Wall Thickness In	Pack Qty.	Bulk Pack Qty.
	In	Tube Gauge			
SRG1075A	0.940	18	0.049	1	2700
SRG1080A	1.000	16	0.065	1	2000
SRG1100A	1.000	18	0.049	1	2000
SRG1125A	1.250	16	0.065	1	1100
SRG1135A	1.250	18	0.049	1	1100
SRG1145A	1.500	18	0.049	1	1000


DFSQ Series Square Domed Tube Inserts

Specifications:

- Material: Low-Density Polyethylene
- Color: Black

Features:

- Can accommodate any degree of leg angle, while the horizontal ribbed design has built-in flexibility to fit multiple tube gauge sizes

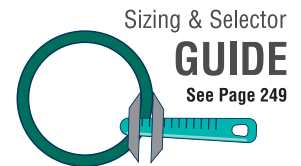


Item No.	Tube Size		Tube Gauge	Pack Qty.	Bulk Pack Qty.
	In	mm			
DFSQ111525A	0.787	20.00	18-25	1	2500
DFSQ081620A	0.875	22.22	16-20	1	1750
DFSQ101620A	1.000	25.40	16-20	1	1250

SQUARE & RECTANGULAR INSERT GLIDES



DMSQ Series Square Vinyl End Caps

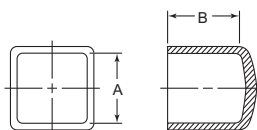

Specifications:

- Material: Vinyl (PVC)
- Color: Black and White
- Temperature Range: Up to 350°F (176°C)

Features:

- Designed to fit the most popular sizes of square tubular steel
- Material flexibility will stretch to fit normal tube diameter tolerance variations
- Glossy and attractive finish makes this part ideal for use as a decorative end cap

Black Item No.		White Item No.		A		Bulk Pack Qty.	
1/2" Length (B)	1" Length (B)	1" Length (B)	In	mm	Pack Qty.	1/2" Length (B)	1" Length (B)
DMSQ0250-1/2A	DMSQ0250-1A	—	0.250	6.35	1	5000	6500
DMSQ0312-1/2A	DMSQ0312-1A	—	0.312	7.92	1	5000	5000
DMSQ0375-1/2A	DMSQ0375-1A	—	0.375	9.52	1	5000	5000
DMSQ0437-1/2A	DMSQ0437-1A	—	0.437	11.09	1	5000	5000
DMSQ0500-1/2A	DMSQ0500-1A	—	0.500	12.70	1	5000	4000
DMSQ0625-1/2A	DMSQ0625-1A	—	0.625	15.87	1	3500	2000
DMSQ0750-1/2A	DMSQ0750-1A	DMSQ0750-1C	0.750	19.05	1	3500	2000
DMSQ1000-1/2A	DMSQ1000-1A	DMSQ1000-1C	1.000	25.40	1	2000	1500
DMSQ1250-1/2A	DMSQ1250-1A	—	1.250	31.75	1	2000	1000
DMSQ1500-1/2A	DMSQ1500-1A	—	1.500	38.10	1	1500	500
DMSQ2000-1/2A	DMSQ2000-1A	—	2.000	50.80	1	500	325

FSQ Series Square Ferrule End Caps



Specifications:

- Material: Low-Density Polyethylene
- Color: Black

Features:

- Provides a neat finish to products manufactured from square tubular steel

Item No.	Tube O.D.		Pack Qty.	Bulk Pack Qty.
	In	mm		
FSQ0625A	0.625	15.87	1	4000
FSQ0875A	0.875	22.22	1	2000
FSQ1000A	1.000	25.40	1	1000
FSQ2000A	2.000	50.80	1	250

RCR Series Rectangular Ribbed Tube Inserts


Specifications:

- Material: Low-Density Polyethylene
- Surface Finish: Polished and Textured

Features:

- Perimeter rib design allows for easy assembly and secure fit
- Tube inserts fit a wider gauge range

See page 251 - 242 for Threaded Tube Ends.

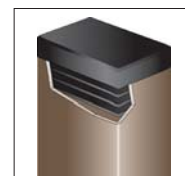

Imperial

Black Item No.		White Item No.		Tube Size In	Gauge	Pack Qty.	Bulk Pack Qty.
Polished	Textured	Polished	Textured				
RCR111339A	RCR111356A	—	—	1.000 X 0.500	16-20	1	1000
RCR111508A	RCR111546A	—	RCR111622A	1.375 X 0.625	11-19	1	2500
RCR111343A	RCR111360A	RCR111377A	—	1.500 X 0.750	11-19	1	1000
RCR111510A	RCR111548A	—	RCR111624A	1.500 X 1.000	11-19	1	2000
RCR111348A	RCR111365A	RCR111382A	—	2.000 X 1.000	11-19	1	1000
RCR111512A	RCR111550A	—	RCR111626A	2.000 X 1.250	11-19	1	1000
RCR25101618A	—	—	—	2.500 X 1.000	16-18	1	1000
RCR25151216A	—	—	—	2.500 X 1.500	12-16	1	500
RCR111514A	RCR111552A	—	RCR111628A	3.000 X 1.500	8-14	1	250
RCR111516A	RCR111554A	—	RCR111630A	3.000 X 2.000	8-14	1	250

Metric

Black Item No.		Tube Size mm	Gauge	Pack Qty.	Bulk Pack Qty.
Polished	Textured				
RCR111338A	RCR111355A	25mm X 10mm	16-20	1	2000
RCR199254A	—	30mm X 10mm	17-20	1	5000
RCR111340A	RCR111357A	30mm X 15mm	11-19	1	1000
RCR111341A	RCR111358A	30mm X 20mm	11-19	1	1000
RCR111509A	RCR111547A	35mm X 20mm	11-19	1	2000
—	RCR466544A	40mm X 15mm	14-17	1	1000
RCR111344A	RCR111361A	40mm X 20mm	11-19	1	1000
RCR111511A	RCR111549A	40mm X 25mm	8-14	1	1500
RCR111481A	RCR111482A	60mm X 30mm	11-19	1	500
RCR111802A	RCR111803A	60mm X 40mm	11-19	1	500
RCR111351A	RCR111368A	60mm X 40mm	8-14	1	500

Black Item No.		Tube Size mm	Gauge	Pack Qty.	Bulk Pack Qty.
Polished	Textured				
—	RCR460727A	70mm X 25mm	14-19	1	500
—	RCR199283A	75mm X 25mm	14-16	1	500
RCR111515A	RCR111553A	75mm X 50mm	8-14	1	250
—	RCR111474A	80mm X 40mm	11-19	1	250
RCR111353A	RCR111370A	80mm X 50mm	8-14	1	250
—	RCR460736A	90mm X 40mm	8-14	1	300
—	RCR199231A	100mm X 40mm	8-14	1	250
—	RCRM10502040A	100mm X 50mm	10-14	1	200
—	RCR460743A	120mm X 30mm	13-19	1	300
—	RCR460749A	150mm X 50mm	8-14	1	100




RTG Series
Rectangular Load Bearing Glides

Specifications:

- Material: ABS
- Color: Black

Features:

- Suitable for light- and heavy-duty applications
- Step lead provides for easy installation
- Press fit assures a secure hold in tubing

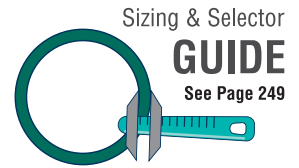

Item No.	Tube Size In	Tube Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
RTG1100A	0.500 x 1.000	16	0.065	1	6000
RTG1110A	0.500 x 1.000	18	0.049	1	3800
RTG1120A	0.500 x 1.250	16	0.065	1	5000
RTG1150A	0.500 x 1.500	16	0.065	1	4000
RTG1160A	0.500 x 1.500	18	0.049	1	4000
RTG1190A	0.750 x 1.250	18	0.049	1	2800
RTG1210A	0.750 x 1.500	14	0.083	1	2500
RTG1220A	0.750 x 1.500	16	0.065	1	2200
RTG1230A	0.750 x 1.500	18	0.049	1	2200
RTG1240A	0.750 x 2.000	16	0.065	1	2000
RTG1250A	1.000 x 1.500	11	0.120	1	2000
RTG1270A	1.000 x 1.500	14	0.083	1	2000
RTG1280A	1.000 x 1.500	16	0.065	1	1800
RTG1290A	1.000 x 1.500	18	0.049	1	2100
RTG1310A	1.000 x 2.000	11	0.120	1	1400
RTG1340A	1.000 x 2.000	14	0.083	1	1400
RTG1350A	1.000 x 2.000	16	0.065	1	1200
RTG1359B	1.000 x 2.000	17	0.058	1	1400
RTG1370A	1.000 x 2.000	18	0.049	1	1400
RTG1390A	1.000 x 3.000	11	0.120	1	1300
RTG1400A	1.000 x 3.000	14	0.083	1	1300

Item No.	Tube Size In	Tube Gauge	Wall Thickness In	Pack Qty.	Bulk Pack Qty.
RTG1410A	1.000 x 3.000	16	0.065	1	1300
RTG1420A	1.250 x 2.000	12	0.109	1	1200
RTG1430A	1.250 x 2.000	14	0.083	1	800
RTG1440A	1.250 x 2.000	16	0.065	1	800
RTG1450A	1.500 x 2.000	11	0.120	1	900
RTG1460A	1.500 x 2.000	14	0.083	1	900
RTG1470A	1.500 x 2.000	15	0.072	1	900
RTG1480A	1.500 x 2.000	16	0.065	1	900
RTG1490A	1.500 x 2.500	11	0.120	1	500
RTG1500A	1.500 x 2.500	12	0.109	1	600
RTG1510A	1.500 x 2.500	16	0.065	1	900
RTG1521A	1.500 x 3.000	11	0.120	1	900
RTG1530A	1.500 x 3.000	14	0.083	1	1000
RTG1540A	1.500 x 3.000	16	0.065	1	500
RTG1550A	1.500 x 4.000	16	0.065	1	500
RTG1560A	2.000 x 3.000	11	0.120	1	700
RTG1570A	2.000 x 3.000	14	0.083	1	700
RTG1580B	2.000 x 4.000	11	0.120	1	350
RTG1590B	2.000 x 4.000	13	0.095	1	350
RTG1600B	2.000 x 4.000	16	0.065	1	350

RCP Series
Rectangular Ribbed Tube Inserts
Chrome Finish

 


Specifications:

- Material: Low-Density Polyethylene
- Color: Black with Highly-Polished Metal-Finish Shell

Features:

- Polished metallic finish provides enhanced aesthetic appearance
- Horizontal ribbing allows for built-in flexibility to fit multiple tube gauges



Item No.	L1 x L		h		h1		Gauge Wall		Pack Qty.	Bulk Pack Qty.
	In	mm	In	mm	In	mm	In	mm		
RCP460966A	0.394 X 0.787	10 x 20	0.394	10.00	0.059	1.50	.040-.080	1.0-2.0	1	1000
RCP460967A	0.591 X 0.787	15 x 20	0.394	10.00	0.079	2.00	.040-.080	1.0-2.0	1	1000
RCP460968A	0.591 X 1.181	15 x 30	0.394	10.00	0.079	2.00	.040-.080	1.0-2.0	1	1000
RCP460969A	0.787 X 1.575	20 x 40	0.433	11.00	0.079	2.00	.040-.080	1.0-2.0	1	500

OVP Series
Oval Ribbed Tube Inserts
Chrome Finish

 


Specifications:

- Material: Low-Density Polyethylene
- Color: Black with Highly-Polished Metal-Finish Shell

Features:

- Polished metallic finish provides enhanced aesthetic appearance
- Horizontal ribbing allows for built-in flexibility to fit multiple tube gauges



Item No.	L1 x L		h		h1		Gauge (In)		Pack Qty.	Bulk Pack Qty.
	In	mm	In	mm	In	mm	In	mm		
OVP200100A	0.787 x 0.394	20 x 10	0.394	10.00	0.079	2.00	14-19 (.040-.080)	1.0-2.0	1	3000
OVP463024A	1.181 x 0.591	30 x 15	0.394	10.00	0.098	2.50	14-19 (.040-.080)	1.0-2.0	1	1000
OVP465360A	1.575 x 0.787	40 x 20	0.394	10.00	0.118	3.00	14-19 (.040-.080)	1.0-2.0	1	500



BSC Series
Rectangular Bar Stock Caps



Specifications:

- Material: Nylon or Polyethylene
- Color: Black or Natural

Features:

- Rectangular caps for bar steel are manufactured with a rounded or flat base, and serve as an excellent means for capping the ends of bar steel

Item No.	Bar Dimensions		Base Depth		Base Style	Material	Color	Pack Qty.	Bulk Pack Qty.
	In	mm	In	mm					
BSC100A	0.045 x 0.575	1.14 x 14.61	0.287	7.28	Round	Nylon	Natural	1	7000
BSC200A	0.125 x 0.750	3.18 x 19.05	0.406	10.31	Flat	Polyethylene	Black	1	8000
BSC300A	0.250 x 1.000	6.35 x 25.40	0.625	15.87	Flat	Polyethylene	Black	1	2500

AIC Series
Angle Iron Caps



Specifications:

- Material: Low-Density Polyethylene
- Color: Black

Features:

- Angle iron caps are an affordable answer to the problem of protecting floors from the sharp edges of angle iron furniture
- Angle iron caps are also used as caps on metal bed frames and shelves and will not rust while also eliminating the cost of welding steel closures



Item No.	Leg Length		Leg Gauge		Pack Qty.	Bulk Pack Qty.
	In	mm	In	mm		
AIC1000A	1.000	25.40	0.125	3.18	1	2200
AIC1125A	1.250	31.74	0.125	3.18	1	1400
AIC1128A	1.500	38.10	0.125	3.18	1	1000
AIC2000A	1.290	32.78	0.125	3.18	1	600

End Caps



Item No.	Color	Pack Qty.
AES-9210	Black	1
AES-9110	Gray	1

Two-Way Connectors



Item No.	Color	Pack Qty.
AES-9215	Black	1
AES-9115	Gray	1

Two-Way Corners



Item No.	Color	Pack Qty.
AES-9220	Black	1
AES-9120	Gray	1

Three-Way Tee



Item No.	Color	Pack Qty.
AES-9230	Black	1
AES-9130	Gray	1

Straight 90 degree Base Connectors



Item No.	Color	Pack Qty.
AES-9240	Black	1
AES-9140	Gray	1

Three-Way Corner



Item No.	Color	Pack Qty.
AES-9250	Black	1
AES-9150	Gray	1

Cross Connector



Item No.	Color	Pack Qty.
AES-9260	Black	1
AES-9160	Gray	1

Four-Way Connector



Item No.	Color	Pack Qty.
AES-9270	Black	1
AES-9170	Gray	1

Five-Way Connector



Item No.	Color	Pack Qty.
AES-9280	Black	1
AES-9180	Gray	1