




**STL**  
Standoff Twist Lock

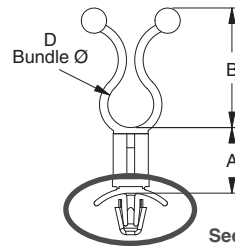

Hole Ø: .187 (4.75)  
Panel Thickness:  
.031-.078 (0.8-2)

See Individual Styles for Mounting Details


**STL Basic Style**

Specifications:

- Material: UL94 V-2 Nylon 6/6
- Color: Natural


Features:

- Lifts wires off board to isolate from other board components
- Cable and wire bundles load and unload with a fingertip twist
- Four mounting styles

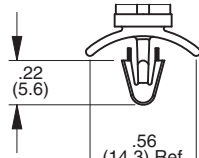


Hole Ø: .156 (4)  
Panel Thickness:  
.031-.078 (0.8-2)

**STL-1**

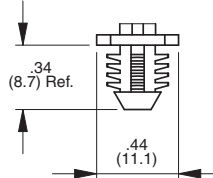

Hole Ø: .312 (7.9)  
Panel Thickness:  
.250 (7.9) Minimum

**STL-3**

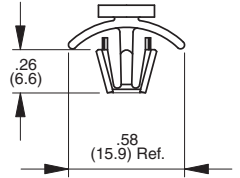


Hole Ø: .236 (6)  
Panel Thickness:  
.031-.078 (0.8-2)

**STL-6**

Item No.	Approval	D Bundle Ø		A Spacer Length		B Ref.		Bulk Pack Qty.
		In	mm	In	mm	In	mm	
STL-250-3-01	UL	.200 - .300	5.1 - 7.6	0.187	4.8	0.750	19.1	1000
STL-250-8-01	UL	.200 - .300	5.1 - 7.6	0.500	12.7	0.750	19.1	1000
STL-350-3-01	UL	.300 - .400	7.6 - 10.2	0.187	4.8	0.910	23.1	1000
STL-350-8-01	UL	.300 - .400	7.6 - 10.2	0.500	12.7	0.910	23.1	1000
STL-450-3-01	UL	.400 - .500	10.2 - 12.7	0.187	4.8	1.090	27.7	1000
STL-450-8-01	UL	.400 - .500	10.2 - 12.7	0.500	12.7	1.090	27.7	1000
STL-600-3-01	UL	.500 - .600	12.7 - 15.2	0.187	4.8	1.280	32.5	1000
STL-600-8-01	UL	.500 - .600	12.7 - 15.2	0.500	12.7	1.280	32.5	1000
STL-750-3-01	UL	.700 - .800	17.8 - 20.3	0.187	4.8	1.450	36.8	1000
STL-750-8-01	UL	.700 - .800	17.8 - 20.3	0.500	12.7	1.450	36.8	1000

**BHKL**  
Fir-Tree Curly Lock

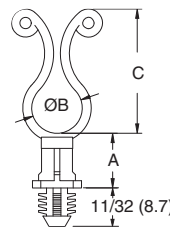

Specifications:


- Material: UL94 V-2 Nylon 6/6
- Color: Natural
- To press fit in a .312 (7.9) Ø hole in a .250 (6.4) minimum panel thickness

Features:

- Ends twist into place with very little effort
- Releasable and reusable for easy wire bundling
- Rounded edges prevent abrasion

Item No.	Approval	A		Bundle Ø B		C Ref.		Bulk Pack Qty.
		In	mm	In	mm	In	mm	
BHKL-350-4-01	UL	0.250	6.4	0.300 - 0.400	7.6 - 10.2	1.000	25.4	1000
BHKL-350-10-01	UL	0.625	15.9	0.300 - 0.400	7.6 - 10.2	1.000	25.4	1000
BHKL-450-4-01	UL	0.250	6.4	0.400 - 0.500	10.2 - 12.7	1.125	28.6	1000
BHKL-450-6-01	UL	0.375	9.5	0.400 - 0.500	10.2 - 12.7	1.125	28.6	1000
BHKL-750-4-01	UL	0.250	6.4	0.700 - 0.800	17.8 - 20.3	1.500	38.1	1000
BHKL-750-6-01	UL	0.375	9.5	0.700 - 0.800	17.8 - 20.3	1.500	38.1	1000

**KLBS**  
Adhesive Mount Standoff Curly Lock

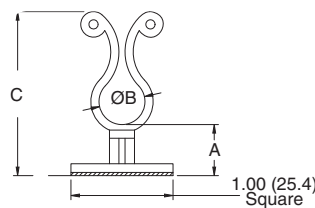

Specifications:

- Material: UL94 V-2 Nylon 6/6
- Color: Natural

Features:

- Ends twist into place with very little effort
- Releasable and reusable for easy wire bundling
- Rounded edges prevent abrasion

Item No.	Approval	A		Bundle Ø B		C Ref.		Bulk Pack Qty.
		In	mm	In	mm	In	mm	
KLBS-350-401A	UL	0.250	6.4	0.300 - 0.400	7.6 - 10.2	1.281	32.5	1000
KLBS-3508-01A	UL	0.500	12.7	0.300 - 0.400	7.6 - 10.2	1.531	38.9	1000
KLBS-35012-01A	UL	0.750	19.1	0.300 - 0.400	7.6 - 10.2	1.781	45.2	1000
KLBS-35016-01A	UL	1.000	25.4	0.300 - 0.400	7.6 - 10.2	2.031	51.6	1000