


[See all specs and customise](#) ↓

SR_1952 | Essentra Components UK

Nylon Slotted Pan Machine Screw - Thread Size M4x12 Thread Length 12.0 mm | 0.472 in Head Diameter 8.0 mm | 0.315 in

Item code: **NSE-1580-M4-12** ● 1980 In stock

Nylon 6/6 M4x12 Pan Slotted Machine Screw

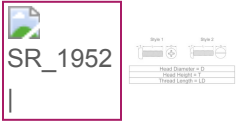

Order sample:

Add sample +

Pricing and options

Standard pack: 1000

Order any quantity

Quantity

Quantity	Unit price
1 - 499	£0.2024
500 - 999	£0.097
1000 - 4999	£0.0573
5000 - 9999	£0.0561
10000 - 24999	£0.055
25000 - 49999	£0.0538
50000+	£0.0527

Total price
£0.20
1 x £0.2

Feedback

Add to cart

+ [Add item to wish list](#)

Need a quote?

For large volumes and customised products, add to your cart and click request a quote, or email sales@essentracomponents.co.uk. Once received we will respond within 1 working day

Can't find what you're looking for?
Tell us what you are looking for...

Send us your enquiry and we will aim to get back to you in 1 business day


Contact us

Request a quote

Specifications

Head Diameter	8.0 mm
Head Height	2.40 mm
Thread Length	12.0 mm
Thread Size	M4x12
Colour	Natural
Material	Nylon
Full Material	Nylon 6/6
Finish	No Finish
Screw Type	Machine Screw
Head Type	Pan
Drive Type	Slotted

Recently viewed items

 **Nylon Slotted Pan Machine Screw - Thread Size M4x12 Thread Length 12.0 mm | 0.472 in Head Diameter 8.0 mm | 0.315 in**

Nylon Slotted Pan Machine Screw - Thread Size ...

Nylon 6/6 M4x12 Pan Slotted Machine Screw

[See our selection](#) →



Natural Nylon Mini Pawl Lock Push-In Rivet - ...

These rivets go into a diameter hole with a 1.9...

[See our selection](#) →

