


I/O Connector -> Audio Jack Connector

Audio Jack Connector 3 Pole: JA3333L-D21P-4F

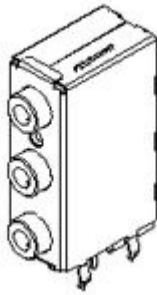

JA Series
 Triple Jack, R/A, T/H Type
 ϕ 3.5mm [.138"]
 13 Pos.



Feature	Attribute
Number of Positions:	13
PCB Mount Style:	T/H
Contact Materials:	Copper alloy
Plating:	PdNi + gold flash
Housing Material:	Thermal Plastic
Color:	PC 99
Stack Height:	
Durability:	1500
Available Status:	active
RoHS Status:	RoHS-6 compliant
Business Unit:	DS
Lead-Time (Week):	4
MOQ (pc):	720