




Quartz Crystal

SMD-version


part no.	12.60370
model	KX – 7T
frequency range	12.0 MHz
mode	fundamental
operating temperature	-40° ~ + 85°C
frequency tolerance at +25°C	±10 ppm
temperature tolerance -40° ~ +85°C	±15 ppm
load capacitance C_L	12 pF
series resistance R_1 (ESR) max.	100 Ohm
aging at +25°C (first year) max.	±2 ppm
shunt capacitance C_0 max.	3.0 pF
drive level max.	200 µW
contents of reel	1000 pcs.

Dimensions:

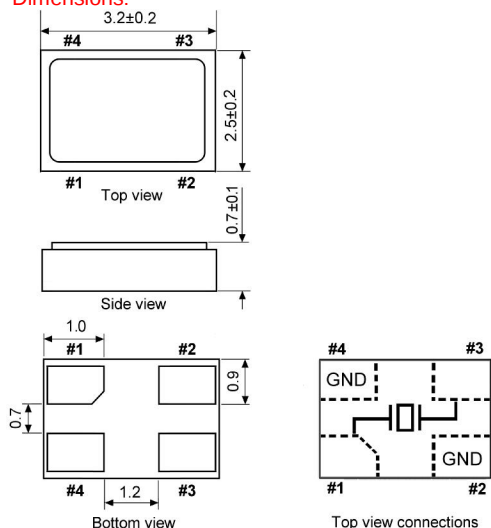


#2 & #4: connected to metal lid

Suggested soldering pad:

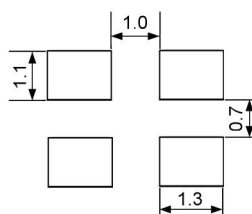

Reflow soldering condition:

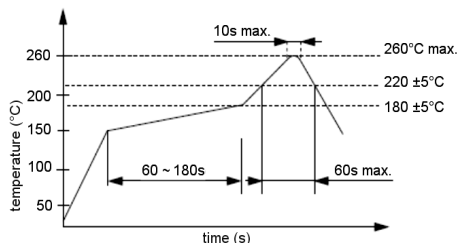

Tape specification:

