




## Tuning Fork Crystal


SMD-version

part no.	12.87170
model	KX-327FT
frequency	32.768 kHz
operating temperature	-40° ~ +85°C
frequency tolerance (df/F) at +25°C ± 3°C	±20 ppm
temperature tolerance (parabolic coefficient)	-0.036 ppm ±0.01/°C <sup>2</sup> typ.
turnover temperature	+25°C ±5°C
storage temperature range	-55°C ~ +125°C
load capacitance C <sub>L</sub>	12.5 pF
motional capacitance( C <sub>1</sub> )	7.0 pF typ.
series resistance R1	60k Ohm typ., 90k Ohm max.
aging at +25°C (first year) max.	±3 ppm
drive level	0.5 μW typ.
contents of reel	3000 pcs.


### Dimensions (mm)

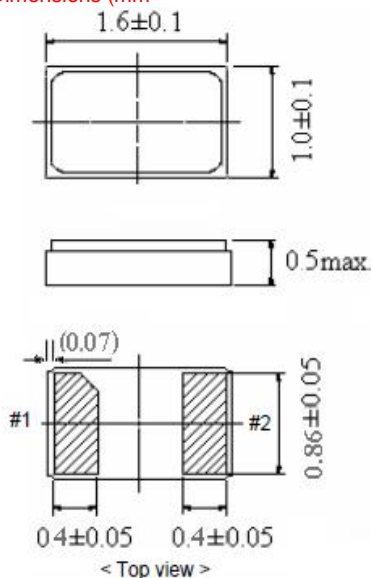

### Reflow soldering condition:

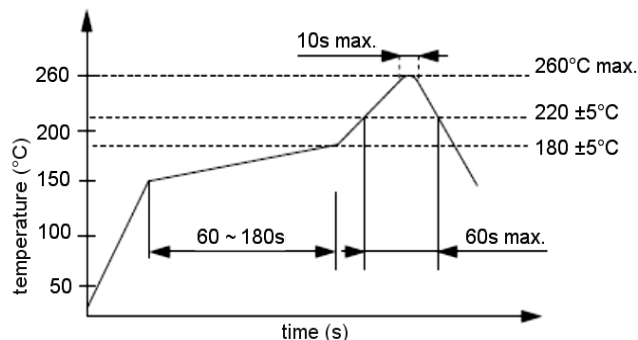

### Suggested soldering pad:

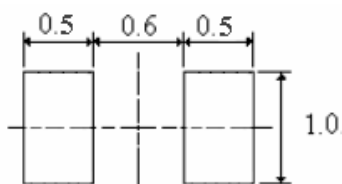

### Tape specification:

