

Leiterplatten Adapter Han Q7/0 2,4mm

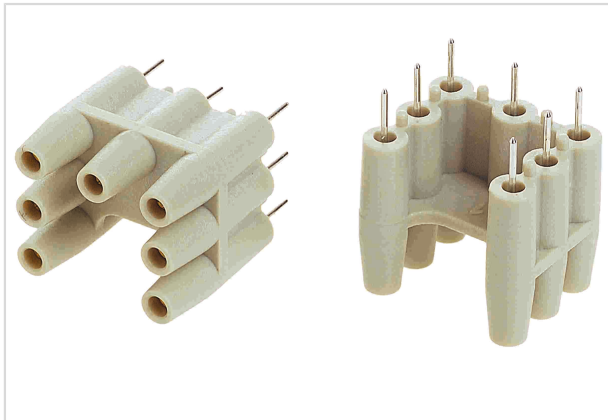


Image is for illustration purposes only. Please refer to product description.

Part number	09 12 000 9908
Specification	Leiterplatten Adapter Han Q7/0 2,4mm
HARTING eCatalogue	https://b2b.harting.com/09120009908

Identification

Category	Accessories
Type of accessory	PCB adapter
Description of the accessory	In the Han [®] Q 7/0

Version

Gender	Female
Details	for PCB's up to 2.4 mm

Technical characteristics

Rated current	7.5 A
Rated voltage	250 V
Rated impulse voltage	4 kV
Pollution degree	3
Limiting temperature	-40 ... +125 °C

Material properties

Material (insert)	Polycarbonate (PC)
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No



Pushing Performance

Material properties

REACH SVHC substances Yes

REACH SVHC substances Lead

Commercial data

Packaging size 10

Net weight 2.8 g

Country of origin Romania

European customs tariff number 85366990

eCl@ss 27460201 PCB connector (board connector)