

## Pneumatic contact female 4,0 mm

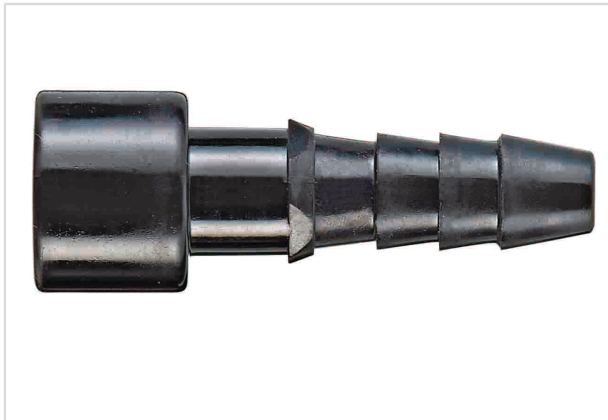


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 000 6253
Specification	Pneumatic contact female 4,0 mm
HARTING eCatalogue	<a href="https://b2b.harting.com/09140006253">https://b2b.harting.com/09140006253</a>

### Identification

Category	Contacts
Type of contact	Pneumatic contact
Description of the contact	Without shut-off Straight

### Version

Gender	Female
Manufacturing process	Turned contacts

### Technical characteristics

Limiting temperature	-40 ... +80 °C
Operating pressure	≤8 bar
Tube inner diameter	4 mm

### Material properties

Material (contacts)	Delrin acetal
Material (seal)	Buna-N
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No



Pushing Performance

## Material properties

REACH SVHC substances	No
-----------------------	----

## Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076
	CSA-C22.2 No. 182.3 ECBT8.E235076

## Commercial data

Packaging size	10
Net weight	0.48 g
Country of origin	Germany
European customs tariff number	39269097
eCl@ss	27440204 Contact for industrial connectors